

AMPHENOL Fiber Optic Assemblies

Amphenol®



This page of product is compliant.

MULTIMODE FIBER CABLE ASSEMBLIES


The EC Series is an extensive line of singlemode and multimode cable assemblies designed for use in enterprise, data storage, and data communication networks. Assemblies meet the applicable requirements for Infiniband, Fiber Channel, Ethernet, and LAN applications. Every cable receives inspection for both insertion loss and visual defects under 1200x video magnification. Interferometers are used for accurate end face geometry testing. All assemblies are designed to intermateability standards for optical and physical performance criteria as dictated by EIA/TIA, IEC, JIS, NIT, ANSI, and Telcordia (where applicable).

Features:

- 100 % Optically tested
- Temp range: -20° to + 75°C
- Variety of connectors and cable types

Custom Cable Assemblies available.
Please contact your sales representative for more information

MOUSER STOCK NO.	Amphenol Part No.	Fig.	Cable Length: m (ft)	Fiber Type	Price Each		
					1	10	50
LC Duplex 2 Fiber Zipcord							
523-EC127-22P2P-001	EC127-22P2P-001	A	1 (3.28)	50/125			
523-EC127-22P2P-002	EC127-22P2P-002	A	2 (6.56)	50/125			
523-EC127-22P2P-003	EC127-22P2P-003	A	3 (9.84)	50/125			
523-EC127-22P2P-005	EC127-22P2P-005	A	5 (16.40)	50/125			
523-EC127-22P2P-010	EC127-22P2P-010	A	10 (32.81)	50/125			
SC Duplex 2 Fiber Zipcord							
523-EC127-24P4P-001	EC127-24P4P-001	B	1 (3.28)	50/125			
523-EC127-24P4P-002	EC127-24P4P-002	B	2 (6.56)	50/125			
523-EC127-24P4P-003	EC127-24P4P-003	B	3 (9.84)	50/125			
523-EC127-24P4P-005	EC127-24P4P-005	B	5 (16.40)	50/125			
523-EC127-24P4P-010	EC127-24P4P-010	B	10 (32.81)	50/125			
523-EC127-24P4P-020	EC127-24P4P-020	B	20 (65.62)	50/125			
LC to SC Duplex 2 Fiber Zipcord							
523-EC127-22P4P-001	EC127-22P4P-001	C	1 (3.28)	50/125			
523-EC127-22P4P-002	EC127-22P4P-002	C	2 (6.56)	50/125			
523-EC127-22P4P-003	EC127-22P4P-003	C	3 (9.84)	50/125			
523-EC127-22P4P-005	EC127-22P4P-005	C	5 (16.40)	50/125			
523-EC127-22P4P-010	EC127-22P4P-010	C	10 (32.81)	50/125			
523-EC127-22P4P-020	EC127-22P4P-020	C	20 (65.62)	50/125			
ST Duplex 2 Fiber Zipcord							
523-EC127-25P5P-003	EC127-25P5P-003	D	3 (9.84)	50/125			
523-EC127-25P5P-005	EC127-25P5P-005	D	5 (16.40)	50/125			
523-EC127-25P5P-010	EC127-25P5P-010	D	10 (32.81)	50/125			
SC to ST Duplex 2 Fiber Zipcord							
523-EC127-24P5P-001	EC127-24P5P-001	E	1 (3.28)	50/125			
523-EC127-24P5P-002	EC127-24P5P-002	E	2 (6.56)	50/125			
523-EC127-24P5P-003	EC127-24P5P-003	E	3 (9.84)	50/125			
523-EC127-24P5P-005	EC127-24P5P-005	E	5 (16.40)	50/125			
523-EC127-24P5P-010	EC127-24P5P-010	E	10 (32.81)	50/125			
523-EC127-24P5P-020	EC127-24P5P-020	E	20 (65.62)	50/125			
LC Simplex Single Fiber Jumper							
523-EC124-21P1P-002	EC124-21P1P-002	F	2 (6.56)	50/125			
523-EC124-21P1P-003	EC124-21P1P-003	F	3 (9.84)	50/125			
523-EC124-21P1P-005	EC124-21P1P-005	F	5 (16.40)	50/125			
523-EC124-21P1P-010	EC124-21P1P-010	F	10 (32.81)	50/125			
523-EC124-21P1P-020	EC124-21P1P-020	F	20 (65.62)	50/125			
SC Simplex Single Fiber Jumper							
523-EC124-23P3P-001	EC124-23P3P-001	G	1 (3.28)	50/125			
523-EC124-23P3P-002	EC124-23P3P-002	G	2 (6.56)	50/125			
523-EC124-23P3P-003	EC124-23P3P-003	G	3 (9.84)	50/125			
523-EC124-23P3P-005	EC124-23P3P-005	G	5 (16.40)	50/125			
523-EC124-23P3P-010	EC124-23P3P-010	G	10 (32.81)	50/125			
523-EC124-23P3P-020	EC124-23P3P-020	G	20 (65.62)	50/125			
LC to SC Simplex Single Fiber Jumper							
523-EC124-21P3P-001	EC124-21P3P-001	H	1 (3.28)	50/125			
523-EC124-21P3P-002	EC124-21P3P-002	H	2 (6.56)	50/125			
523-EC124-21P3P-003	EC124-21P3P-003	H	3 (9.84)	50/125			
523-EC124-21P3P-005	EC124-21P3P-005	H	5 (16.40)	50/125			
523-EC124-21P3P-010	EC124-21P3P-010	H	10 (32.81)	50/125			
523-EC124-21P3P-020	EC124-21P3P-020	H	20 (65.62)	50/125			
ST Simplex Single Fiber Jumper							
523-EC124-25P5P-002	EC124-25P5P-002	I	2 (6.56)	50/125			
523-EC124-25P5P-003	EC124-25P5P-003	I	3 (9.84)	50/125			
523-EC124-25P5P-005	EC124-25P5P-005	I	5 (16.40)	50/125			
SC to ST Simplex Single Fiber Jumper							
523-EC124-23P5P-001	EC124-23P5P-001	J	1 (3.28)	50/125			
523-EC124-23P5P-002	EC124-23P5P-002	J	2 (6.56)	50/125			
523-EC124-23P5P-003	EC124-23P5P-003	J	3 (9.84)	50/125			
523-EC124-23P5P-005	EC124-23P5P-005	J	5 (16.40)	50/125			
523-EC124-23P5P-010	EC124-23P5P-010	J	10 (32.81)	50/125			
523-EC124-23P5P-020	EC124-23P5P-020	J	20 (65.62)	50/125			

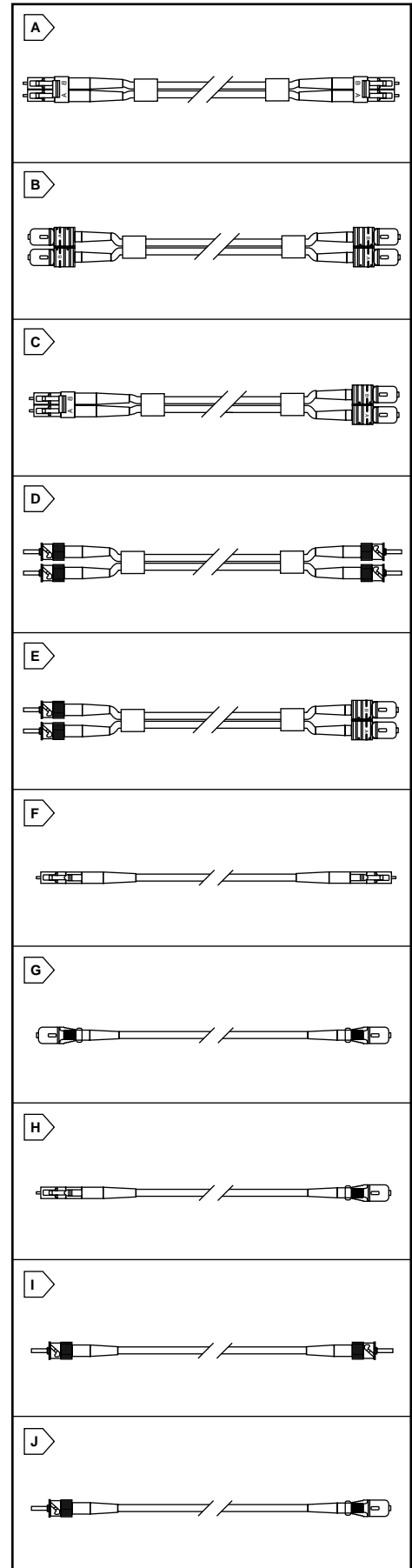

Cable Assemblies
Amphenol