

AMPHENOL Fiber Optic Assemblies

Amphenol®

MULTIMODE FIBER CABLE ASSEMBLIES

RoHS Compliant This page of product is compliant.

The EC Series is an extensive line of singlemode and multimode cable assemblies designed for use in enterprise, data storage, and data communication networks. Assemblies meet the applicable requirements for Infiniband, Fiber Channel, Ethernet, and LAN applications. Every cable receives 100% inspection for both insertion loss and visual defects under 1200x magnification. Interferometers are used for accurate end face geometry testing. All assemblies are designed to intermateability standards for optical and physical performance criteria as dictated by EIA/TIA, IEC, JIS, NIT, ANSI, and Telcordia (where applicable).


Features:

- Temp range: -20° to +75°C
- 100 % Optically tested
- Variety of connectors and cable types

Custom Cable Assemblies available.
Please contact your sales representative for more information

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	Fig	Cable Length m (ft)	Fiber Type	Price Each		
					1	10	50
LC Duplex 2 Fiber Zipcord							
523-EC137-22P2P-001	EC137-22P2P-001	A	1 (3.28)	62.5/125			
523-EC137-22P2P-002	EC137-22P2P-002	A	2 (6.56)	62.5/125			
523-EC137-22P2P-003	EC137-22P2P-003	A	3 (9.84)	62.5/125			
523-EC137-22P2P-005	EC137-22P2P-005	A	5 (16.40)	62.5/125			
523-EC137-22P2P-010	EC137-22P2P-010	A	10 (32.81)	62.5/125			
523-EC137-22P2P-020	EC137-22P2P-020	A	20 (65.62)	62.5/125			
SC Duplex 2 Fiber Zipcord							
523-EC137-24P4P-001	EC137-24P4P-001	B	1 (3.28)	62.5/125			
523-EC137-24P4P-002	EC137-24P4P-002	B	2 (6.56)	62.5/125			
523-EC137-24P4P-003	EC137-24P4P-003	B	3 (9.84)	62.5/125			
523-EC137-24P4P-005	EC137-24P4P-005	B	5 (16.40)	62.5/125			
523-EC137-24P4P-010	EC137-24P4P-010	B	10 (32.81)	62.5/125			
523-EC137-24P4P-020	EC137-24P4P-020	B	20 (65.62)	62.5/125			
ST Duplex 2 Fiber Zipcord							
523-EC137-25P5P-002	EC137-25P5P-002	C	2 (6.56)	62.5/125			
523-EC137-25P5P-003	EC137-25P5P-003	C	3 (9.84)	62.5/125			
523-EC137-25P5P-010	EC137-25P5P-010	C	10 (32.81)	62.5/125			
LC Simplex Single Fiber Jumper							
523-EC134-21P1P-001	EC134-21P1P-001	D	1 (3.28)	62.5/125			
523-EC134-21P1P-002	EC134-21P1P-002	D	2 (6.56)	62.5/125			
523-EC134-21P1P-003	EC134-21P1P-003	D	3 (9.84)	62.5/125			
523-EC134-21P1P-005	EC134-21P1P-005	D	5 (16.40)	62.5/125			
523-EC134-21P1P-010	EC134-21P1P-010	D	10 (32.81)	62.5/125			
523-EC134-21P1P-020	EC134-21P1P-020	D	20 (65.62)	62.5/125			
SC Simplex Single Fiber Jumper							
523-EC134-23P3P-002	EC134-23P3P-002	E	2 (6.56)	62.5/125			
523-EC134-23P3P-003	EC134-23P3P-003	E	3 (9.84)	62.5/125			
523-EC134-23P3P-005	EC134-23P3P-005	E	5 (16.40)	62.5/125			
523-EC134-23P3P-010	EC134-23P3P-010	E	10 (32.81)	62.5/125			
523-EC134-23P3P-020	EC134-23P3P-020	E	20 (65.62)	62.5/125			
ST Simplex Single Fiber Jumper							
523-EC134-25P5P-003	EC134-25P5P-003	F	3 (9.84)	62.5/125			
523-EC134-25P5P-005	EC134-25P5P-005	F	5 (16.40)	62.5/125			

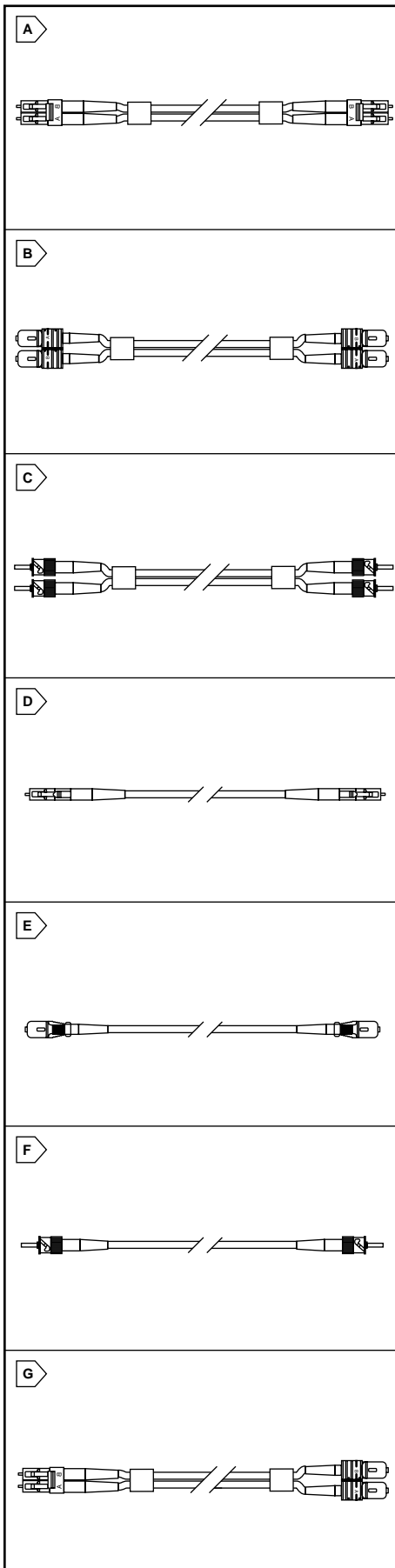

Amphenol Cable Assemblies

SINGLE MODE FIBER CABLE ASSEMBLIES

Custom Cable Assemblies available.
Please contact your sales representative for more information

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	Fig	Cable Length m (ft)	Fiber Type	Price Each		
					1	10	50
LC Duplex 2 Fiber Zipcord							
523-EC117-22U2U-001	EC117-22U2U-001	A	1 (3.28)	9/125			
523-EC117-22U2U-002	EC117-22U2U-002	A	2 (6.56)	9/125			
523-EC117-22U2U-003	EC117-22U2U-003	A	3 (9.84)	9/125			
523-EC117-22U2U-005	EC117-22U2U-005	A	5 (16.40)	9/125			
523-EC117-22U2U-010	EC117-22U2U-010	A	10 (32.81)	9/125			
523-EC117-22U2U-020	EC117-22U2U-020	A	20 (65.62)	9/125			
SC Duplex 2 Fiber Zipcord							
523-EC117-24U4U-001	EC117-24U4U-001	B	1 (3.28)	9/125			
523-EC117-24U4U-002	EC117-24U4U-002	B	2 (6.56)	9/125			
523-EC117-24U4U-003	EC117-24U4U-003	B	3 (9.84)	9/125			
523-EC117-24U4U-005	EC117-24U4U-005	B	5 (16.40)	9/125			
523-EC117-24U4U-010	EC117-24U4U-010	B	10 (32.81)	9/125			
523-EC117-24U4U-020	EC117-24U4U-020	B	20 (65.62)	9/125			
LC to SC Duplex 2 Fiber Zipcord							
523-EC117-22U4U-001	EC117-22U4U-001	G	1 (3.28)	9/125			
523-EC117-22U4U-002	EC117-22U4U-002	G	2 (6.56)	9/125			
523-EC117-22U4U-003	EC117-22U4U-003	G	3 (9.84)	9/125			
523-EC117-22U4U-005	EC117-22U4U-005	G	5 (16.40)	9/125			
523-EC117-22U4U-010	EC117-22U4U-010	G	10 (32.81)	9/125			
523-EC117-22U4U-020	EC117-22U4U-020	G	20 (65.62)	9/125			
LC Simplex Single Fiber Jumper							
523-EC114-21U1U-001	EC114-21U1U-001	D	1 (3.28)	9/125			
523-EC114-21U1U-002	EC114-21U1U-002	D	2 (6.56)	9/125			
523-EC114-21U1U-003	EC114-21U1U-003	D	3 (9.84)	9/125			
523-EC114-21U1U-005	EC114-21U1U-005	D	5 (16.40)	9/125			
523-EC114-21U1U-010	EC114-21U1U-010	D	10 (32.81)	9/125			
523-EC114-21U1U-020	EC114-21U1U-020	D	20 (65.62)	9/125			
SC Simplex Single Fiber Jumper							
523-EC114-23U3U-001	EC114-23U3U-001	E	1 (3.28)	9/125			
523-EC114-23U3U-002	EC114-23U3U-002	E	2 (6.56)	9/125			
523-EC114-23U3U-003	EC114-23U3U-003	E	3 (9.84)	9/125			
523-EC114-23U3U-005	EC114-23U3U-005	E	5 (16.40)	9/125			
523-EC114-23U3U-010	EC114-23U3U-010	E	10 (32.81)	9/125			
523-EC114-23U3U-020	EC114-23U3U-020	E	20 (65.62)	9/125			