


RoHS Compliant This product is RoHS compliant.

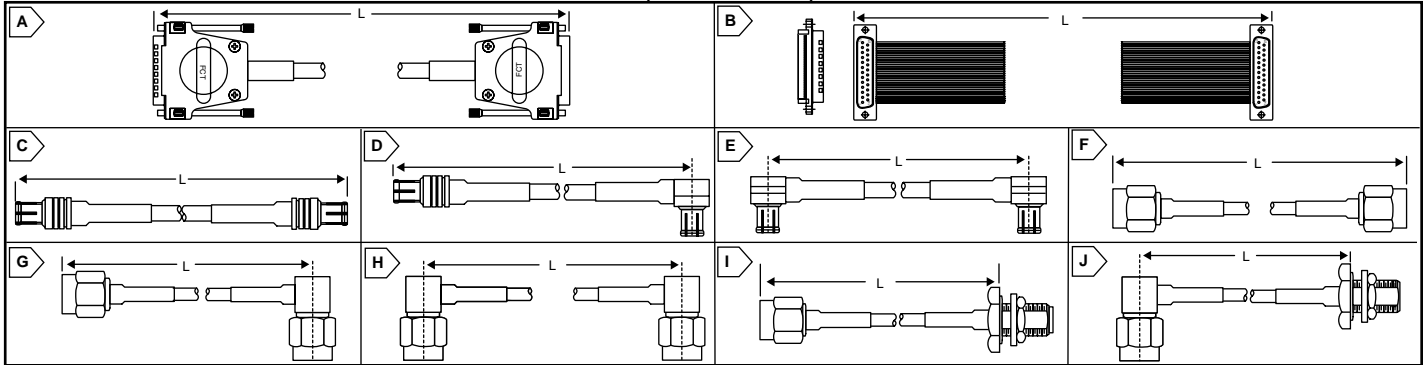

## SHIELDED D-SUB CABLE ASSEMBLIES

### Male to Female Jumper/Extension Cables

- Features:**
- Designed for RS-232, Computer Interconnect, Control Circuits, Data Transmission
  - Die Cast FCT Backshell with Steel Thumb Screw Retention
  - PVC Jacketed Cable Temp rated to -20C to +80C
  - 100% Flexfoil aluminum/polyester shield, grounded to backshell
  - UL Style 2462, 80C, 300V

For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	FCT Part No.	Fig.	No. of Contacts	Length (L) In.	Price Each		
					1	5	10
152-SDB09P09S-012	SDB09P09S-012	A	9	12			
152-SDB09P09S-024	SDB09P09S-024	A	9	24			
152-SDB09P09S-036	SDB09P09S-036	A	9	36			
152-SDB09P09S-060	SDB09P09S-060	A	9	60			
152-SDB15P159S-012	SDB15P159S-012	A	15	12			
152-SDB15P159S-024	SDB15P159S-024	A	15	24			
152-SDB15P159S-036	SDB15P159S-036	A	15	36			
152-SDB15P159S-060	SDB15P159S-060	A	15	60			
152-SDB25P25S-012	SDB25P25S-012	A	25	12			
152-SDB25P25S-024	SDB25P25S-024	A	25	24			
152-SDB25P25S-036	SDB25P25S-036	A	25	36			
152-SDB25P25S-060	SDB25P25S-060	A	25	60			
152-SDB37P37S-024	SDB37P37S-024	A	37	24			
152-SDB37P37S-036	SDB37P37S-036	A	37	36			
152-SDB37P37S-060	SDB37P37S-060	A	37	60			
152-SDB37P37S-120	SDB37P37S-120	A	37	120			
152-SDB50P50S-024	SDB50P50S-024	A	50	24			
152-SDB50P50S-036	SDB50P50S-036	A	50	36			
152-SDB50P50S-060	SDB50P50S-060	A	50	60			

## SHIELDED HIGH DENSITY D-SUB CABLE ASSEMBLIES

### Male to Female Jumper/Extension Cables

- Features:**
- Designed for RS-232, Computer Interconnect, Control Circuits, Data Transmission
  - Die Cast FCT Backshell with Steel Thumb Screw Retention
  - PVC Jacketed Cable Temp rated to -20C to +80C
  - 100% Flexfoil aluminum/polyester shield, grounded to backshell
  - UL Style 2462, 80C, 300V

For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	FCT Part No.	Fig.	No. of Contacts	Length (L) In.	Price Each		
					1	5	10
152-SHD15P15S-012	SHD15P15S-012	A	15	12			
152-SHD15P15S-024	SHD15P15S-024	A	15	24			
152-SHD15P15S-036	SHD15P15S-036	A	15	36			
152-SHD15P15S-060	SHD15P15S-060	A	15	60			
152-SHD26P26S-012	SHD26P26S-012	A	26	12			
152-SHD26P26S-024	SHD26P26S-024	A	26	24			
152-SHD26P26S-036	SHD26P26S-036	A	26	36			
152-SHD26P26S-060	SHD26P26S-060	A	26	60			
152-SHD44P44S-012	SHD44P44S-012	A	44	12			
152-SHD44P44S-024	SHD44P44S-024	A	44	24			
152-SHD44P44S-036	SHD44P44S-036	A	44	36			
152-SHD44P44S-060	SHD44P44S-060	A	44	60			

## D-SUB FLAT RIBBON CABLE ASSEMBLIES

### Male to Male Jumper Cables

- Features:**
- Designed for RS-232, Computer Interconnect, PCB Interconnect
  - PVC Jacketed Cable Temp rated to -20C to +105C
  - Stranded wire provides flexibility and extended product life
  - AWM 2651, 105C, 300V, VW1

For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	FCT Part No.	Fig.	No. of Contacts	Length (L) In.	Price Each		
					1	5	10
152-RB09P09P-006	RB09P09P-006	B	9	6			
152-RB09P09P-012	RB09P09P-012	B	9	12			
152-RB09P09P-024	RB09P09P-024	B	9	24			
152-RB15P15P-006	RB15P15P-006	B	15	6			
152-RB15P15P-012	RB15P15P-012	B	15	12			
152-RB15P15P-024	RB15P15P-024	B	15	24			
152-RB25P25P-006	RB25P25P-006	B	25	6			
152-RB25P25P-012	RB25P25P-012	B	25	12			
152-RB25P25P-024	RB25P25P-024	B	25	24			
152-RB37P37P-006	RB37P37P-006	B	37	6			
152-RB37P37P-012	RB37P37P-012	B	37	12			
152-RB37P37P-024	RB37P37P-024	B	37	24			

## SMA & MCX CONFORMABLE JUMPER CABLES

### 50 Ohm, 0.086 Dia, DC to 6GHz

- Features:**
- Designed for use in DC to 6GHz RF Applications
  - Gold Plated Brass Connectors with PTFE Insulators
  - VSWR Better than 1.20:1 @ 2GHz and 1.30:1 < 6GHz
  - Insertion Loss < 0.5dB, Operating Temp -20C to 105C
  - Silver Plated Copper Covered Steel Cable, UL AWM Style 10245

For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	FCT Part No.	Fig.	Length (L) In.	Price Each		
				1	5	10
<b>MCX Straight Male to MCX Straight Male</b>						
152-25P103C25P1-003	25P103C25P1-003	C	3			
152-25P103C25P1-006	25P103C25P1-006	C	6			
152-25P103C25P1-012	25P103C25P1-012	C	12			
152-25P103C25P1-018	25P103C25P1-018	C	18			
<b>MCX Straight Male to MCX R/A Male</b>						
152-25P103C25P2-003	25P103C25P2-003	D	3			
152-25P103C25P2-006	25P103C25P2-006	D	6			
152-25P103C25P2-012	25P103C25P2-012	D	12			
152-25P103C25P2-018	25P103C25P2-018	D	18			
<b>MCX R/A Male to MCX R/A Male</b>						
152-25P203C25P2-003	25P203C25P2-003	E	3			
152-25P203C25P2-006	25P203C25P2-006	E	6			
152-25P203C25P2-012	25P203C25P2-012	E	12			
152-25P203C25P2-018	25P203C25P2-018	E	18			
<b>SMA Straight Male to SMA Straight Male</b>						
152-24P103C24P1-003	24P103C24P1-003	F	3			
152-24P103C24P1-006	24P103C24P1-006	F	6			
152-24P103C24P1-012	24P103C24P1-012	F	12			
152-24P103C24P1-018	24P103C24P1-018	F	18			
<b>SMA Straight Male to SMA R/A Male</b>						
152-24P103C24P2-003	24P103C24P2-003	G	3			
152-24P103C24P2-006	24P103C24P2-006	G	6			
152-24P103C24P2-012	24P103C24P2-012	G	12			
152-24P103C24P2-018	24P103C24P2-018	G	18			
<b>SMA R/A Male to SMA R/A Male</b>						
152-24P203C24P2-003	24P203C24P2-003	H	3			
152-24P203C24P2-006	24P203C24P2-006	H	6			
152-24P203C24P2-012	24P203C24P2-012	H	12			
152-24P203C24P2-018	24P203C24P2-018	H	18			
<b>SMA Straight Male to SMA Bulkhead Female</b>						
152-24P103C24J1-003	24P103C24J1-003	I	3			
152-24P103C24J1-006	24P103C24J1-006	I	6			
152-24P103C24J1-012	24P103C24J1-012	I	12			
152-24P103C24J1-018	24P103C24J1-018	I	18			
<b>SMA R/A Male to SMA Bulkhead Female</b>						
152-24P203C24J1-003	24P203C24J1-003	J	3			
152-24P203C24J1-006	24P203C24J1-006	J	6			
152-24P203C24J1-012	24P203C24J1-012	J	12			
152-24P203C24J1-018	24P203C24J1-018	J	18			

### 50 Ohm, 0.141Dia, DC to 6GHz

For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	FCT Part No.	Fig.	Length (L) In.	Price Each		
				1	5	10
<b>SMA Straight Male to SMA Straight Male</b>						
152-24P104C24P1-003	24P104C24P1-003	F	3			
152-24P104C24P1-006	24P104C24P1-006	F	6			
152-24P104C24P1-012	24P104C24P1-012	F	12			
152-24P104C24P1-018	24P104C24P1-018	F	18			
<b>SMA Straight Male to SMA R/A Male</b>						
152-24P104C24P2-003	24P104C24P2-003	G	3			
152-24P104C24P2-006	24P104C24P2-006	G	6			
152-24P104C24P2-012	24P104C24P2-012	G	12			
152-24P104C24P2-018	24P104C24P2-018	G	18			
<b>SMA R/A Male to SMA R/A Male</b>						
152-24P204C24P2-003	24P204C24P2-003	H	3			
152-24P204C24P2-006	24P204C24P2-006	H	6			
152-24P204C24P2-012	24P204C24P2-012	H	12			
152-24P204C24P2-018	24P204C24P2-018	H	18			
<b>SMA Straight Male to SMA Bulkhead Female</b>						
152-24P104C24J1-003	24P104C24J1-003	I	3			
152-24P104C24J1-006	24P104C24J1-006	I	6			
152-24P104C24J1-012	24P104C24J1-012	I	12			
152-24P104C24J1-018	24P104C24J1-018	I	18			
<b>SMA R/A Male to SMA Bulkhead Female</b>						
152-24P204C24J1-003	24P204C24J1-003	J	3			
152-24P204C24J1-006	24P204C24J1-006	J	6			
152-24P204C24J1-012	24P204C24J1-012	J	12			
152-24P204C24J1-018	24P204C24J1-018	J	18			