


AMP RF Connectors and Tools

This product is RoHS compliant.

Authorized Distributor

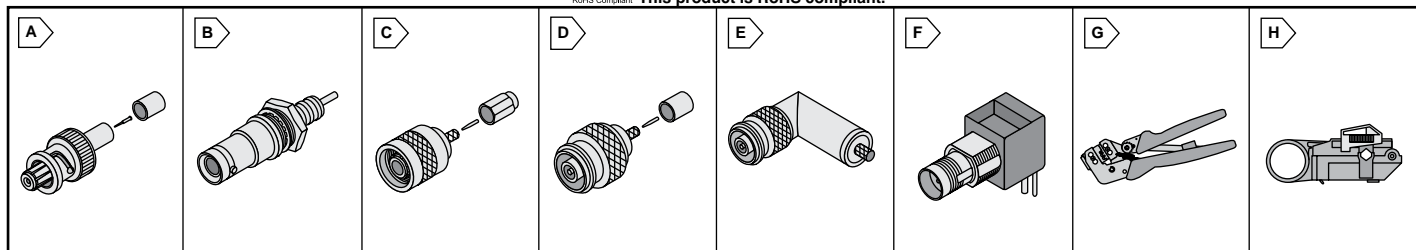

SHV CONNECTORS

- Center contact : Gold
- Dual crimp
- SHV: Safe High Voltage
- RoHS Compliant per Tyco Electronics documentation

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Description	Cable Type RG/U	Price Each		
					1	10	25
571-5051426-4	5051426-4	A	Plug, Nickel, Teflon	58, 58A, 58B, 58C 124, 140, 210, 62, 62A, 62B, 59, 59A, 59B, Belden 9291, 9209, 9269			
571-5051426-2	5051426-2	A	Plug, Silver, Teflon				
571-514942	51494-2	B	Bulkhead Solder Jack, Nickel	-----			

TNC PLUGS

- 50Ω
- Center contacts: Gold
- RoHS Compliant per Tyco Electronics documentation

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Description	Cable Type RG/U	Price Each		
					1	10	25
Hex Crimp							
571-5222506-5	5222506-5	C	Nickel, Polypropylene	174, 188, 188A, 316			
571-5222506-1	5222506-1	C	Nickel, Polypropylene	58, 58A, 58B, 58C			
Dual Crimp - Weatherproof - Mil Type							
571-5225555-6	5225555-6	D	Nickel, Teflon	142, 142A, 142B, 400			
571-5225559-2	5225559-2	E	Right Angle, Nickel, Teflon	58, 58A, 58B, 58C			
571-5225554-6	5225554-6	E	Right Angle, Silver, Teflon	142, 142A, 142B, 400			

TNC JACK

- Right Angle
- 50Ω
- Center contact plating: Gold
- Body material: Metal
- PC Board/Panel Mount
- 1/2-28 Thread
- Mounting Height: 15.88 (.625)
- For Panel Mount: lockwasher (571-13296322) and jam nut (571-13296312) required, sold separately
- RoHS Compliant per Tyco Electronics documentation

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Description	Cable Type RG/U	Price Each		
					1	10	25
571-5227839-1	5227839-1	F	With mounting posts	-----			

TOOLS AND DIES FOR RF CONNECTORS

For quantities of 5 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Description	Termination Type	Cable Type RG/U	Price Each
50 Ohm						
571-584331	58433-1	G	PRO-CRIMPER III w/die	BNC Dual "O" Crimp Comm.	---	
571-3549401	354940-1	G	PRO-CRIMPER III (Frame only)	O Crimp Commercial	210, 62, 62A, 62B, 59, 59A, 59B, Belden 9169, 9209, 9291, 89269	
571-584332	58433-2	G	PRO-CRIMPER III w/die	BNC Hex Crimp	---	
571-584363	58436-3	---	Die for PRO-CRIMPER	BNC Hex Crimp	161, 174, 179, 179A, 179B, 180, 180A, 187, 187A, 188, 188A, 195, 195A, 316, Belden 9221, C1180B	
571-584362	58436-2	---	Die for PRO-CRIMPER	BNC Hex Crimp Comm.	Belden 8281, 9141, 9231, Western Electric, 724, 728, 3049	
571-584351	58435-1	---	Die for PRO-CRIMPER	BNC "O" Crimp Comm.	---	
571-3184502	318450-2	---	Die for PRO-CRIMPER	"O" Crimp Comm.	---	
571-583301	58330-1	---	Die for PRO-CRIMPER	---	---	
571-3184522	318452-2	---	Die for PRO-CRIMPER	BNC "O" Crimp Comm.	---	
571-2201893	220189-3	---	Die for PRO-CRIMPER	O Crimp Mil Type	---	
571-2201891	220189-1	---	Die for PRO-CRIMPER	O Crimp Comm.	55, 55A, 55B, 58, 58A, 58B, 58C, 141, 141A, 142, 142A, 142B, 223, 303, 400, Belden 88240, Berk-Tek BTDC-58, Comm/Scope 2135	
571-585371	58537-1	---	Die for PRO-CRIMPER	O Crimp Mil Type	55, 55A, 55B, 58, 58A, 58B, 58C, 141, 141A, 142, 142A, 142B, 223, 303, 400, 59, 59A, 59B, 62, 62A, 62B, 124, 140, 210, 302, Belden 9104, 9112, 9167, 9209, 9240, 9259, 9266, 9291, 9269, 88241, 89269, Hi-Temp	
571-2201892	220189-2	---	Die for PRO-CRIMPER	O Crimp Comm.	59 & 62A, Times PL59, PL62, PLF59, FM-59, Berk-Tek, BTDC-59, BTDC-62	
571-220022-1	220022-1	---	Certi-Crimp Hand Tool	---	124, 140, 210, 62, 62A, 62B, 59, 59A, 59B, Belden 9209, 9269, 9291	
571-584361	58436-1	---	Die Set	---	RG58/59 Hex IS9159	
75 Ohm						
571-584252	58425-2	---	Die for PRO-CRIMPER	TNC Hex Crimp Comm.	179, 179A, 179B, 187, 187A, Belden 9221	
571-584251	58425-1	---	Die for PRO-CRIMPER	TNC Hex Crimp Comm.	210, 62, 62A, 62B, 59, 59A, 59B, 302, Belden 9104, 9112, 9167, 9209, 9240, 9259, 9209, 9240, 9259, 9266, 9269, 9291, 88241, 89269, Hi-Temp 62A, Times PL62, FM-59, Berk-Tek BTDC-59, BTDC-62	
571-585312	58531-2	---	PRO-CRIMPER w/ Die	---	---	
571-580851	58085-1	---	Die for PRO-CRIMPER	---	---	
571-585381	58538-1	---	Die for PRO-CRIMPER	TNC "O" Crimp Comm.	Belden 8281, 9141, 9231	
571-581741	58174-1	---	Die for PRO-CRIMPER	TNC "O" Crimp Comm.	AT&T 735A	
571-580861	58086-1	---	Die for PRO-CRIMPER	---	---	
N Type						
571-585011	58501-1	---	PRO-CRIMPER w/ Die	---	---	
571-584851	58485-1	---	Die Set for PRO-CRIMPER	Hex Crimp	8, 9, 213, 214, Belden 9880	
571-91902-1	91902-1	---	Die Set for 225361-1 & 225361-4	---	RG141	
Cable Stripper						
571-603995-1	603995-1	H	Coax Cable Stripper	BNC Single Crimp	---	