

BOMAR RF Connectors




BNC PRINTED CIRCUIT BOARD RIGHT ANGLE JACKS

- 50Ω versions have been approved by most U.S. manufacturers of LAN cards.
- 75Ω versions are in wide use in High Definition Video which require the use of a true 75Ω connector

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Imp. Ω	Description	Body Material	Price Each			
						1	10	25	100
678-364A595	364A595	A	50	Standard profile with posts	White Valox				
678-364A595B	364A595B	A	50	Standard profile with posts	Black Valox				
678-364A795	364A795	A	75	Standard profile with posts	White Valox				
678-364A795B	364A795B	A	75	Standard profile with posts	Black Valox				
678-364A595BL	364A595BL	A	50	Low profile with posts	White Valox				
678-364A595BLB	364A595BLB	A	50	Low profile with posts	White Valox				
678-364A795BL	364A795BL	A	75	Low profile with posts	White Valox				
678-364M595	364M595	B	50	Standard profile with posts	Nickel / Zinc				
678-364M595L	364M595L	B	50	Low profile with posts	Nickel / Zinc				
678-364M795	364M795	B	75	Standard profile with posts	Metal				
678-364M595M	364M595M	C	50	Super low profile with clips	Nickel / Zinc				
678-364A2595	364A2595	D	50	X-2 Dual stacked	White Valox				
678-364A2795	364A2795	D	75	X-2 Dual stacked	White Valox				
678-364A2795B	364A2795B	D	75	X-2 Dual stacked	Black Valox				
678-364A2795FS	364A2795FS	D	75	X-2 Dual full shield	White Valox				
678-364M2595	364M2595	E	50	X-2M Dual stacked	Nickel / Zinc				
678-364M2795	364M2795	E	75	X-2M Dual stacked	Nickel / Zinc				
678-364M2795FS	364M2795FS	E	75	X-2M Dual full shield	Nickel / Zinc				
678-364NT	364NT	--	--	Jam nut	Nickel				
678-364KNT	364KNT	--	--	Knurled nut	Nickel				
678-364LW	364LW	--	--	Lock washer	Nickel				

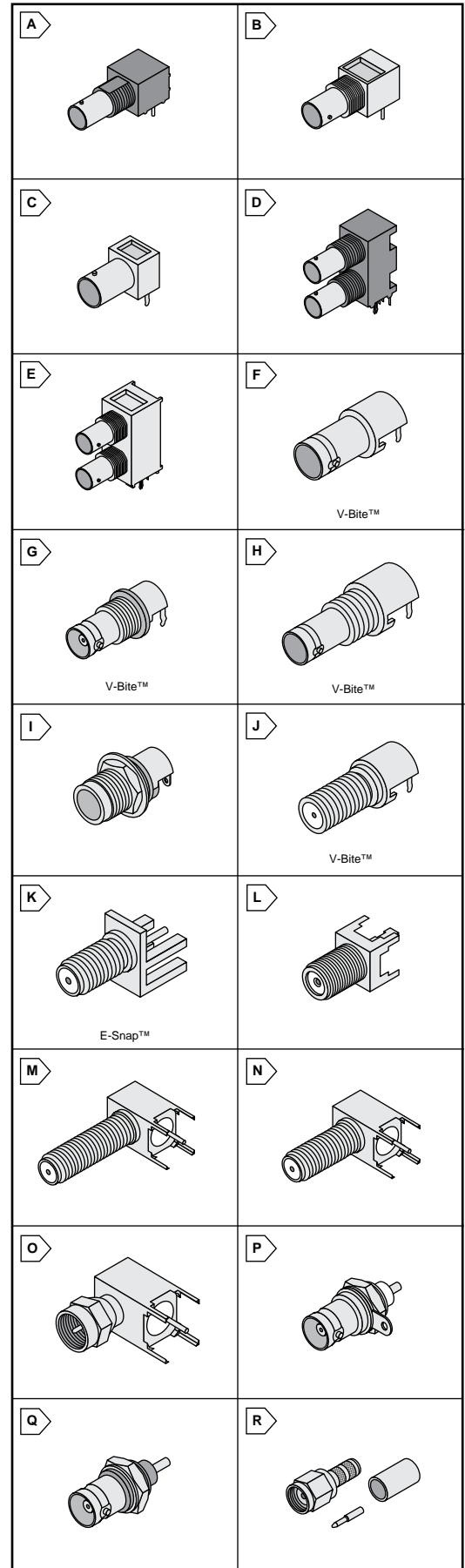

PRINTED CIRCUIT BOARD EDGE MOUNT JACKS

- V-Bite™ features an award winning PCB lock-in design providing extreme anti-rotation.
- E-Snap™ snaps into 2 holes in PC board and locks into place for reflow soldering.

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Imp. Ω	Type	Description	Mounting Type	Price Each			
							1	10	25	100
678-361V509E	361V509E	F	50	BNC	Polyethylene Insul.	V-Bite™				
678-361V504ER	361V504ER	F	50	BNC	Teflon insul. for reflow	V-Bite™				
678-361V504EFT082	361V504EFT082	G	50	BNC	w/Flange, for .082 PCB	V-Bite™				
678-361V504EFT	361V504EFT	G	50	BNC	Teflon insul. /flange	V-Bite™				
678-361V504ET	361V504ET	H	50	BNC	Teflon insul. for reflow	V-Bite™				
678-361V704ER	361V704ER	F	75	BNC	Teflon insul. for reflow	V-Bite™				
678-361V704EFT	361V704EFT	G	75	BNC	Teflon insul. /flange	V-Bite™				
678-161V504EFT	161V504EFT	I	50	N	w/Flange TFE insul./re-flow	V-Bite™				
678-861V509E	861V509E	J	NCI	F	RG59	V-Bite™				
678-861V509ER	861V509ER	J	NCI	F	Teflon for reflow, RG59	V-Bite™				
678-861V509ER6	861V509ER6	J	75	F	Teflon for reflow, RG6/59	V-Bite™				
678-961E504	961E504	K	50	SMA	PTFE Insul.	E-Snap™				

F SERIES PRINTED CIRCUIT BOARD AND CABLE CONNECTORS

- These F type connectors are widely used in CATV, MATV, and CCTV.

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Description	Mount/Cable Type	Price Each			
					1	10	25	100
PCB Connectors-Non Constant Impedance								
678-861A509	861A509	L	Jack, straight	Vertical				
678-864B509	864B509	M	Jack, long, .90" barrel	Right Angle				
678-864B509S	864B509S	N	Jack, short, .70" barrel	Right Angle				
678-866B509	866B509	O	Male, direct to tuner connection	Right Angle				
678-864NT	864NT	--	Nut	---				
678-864LW	864LW	--	Washer	---				

BNC BULKHEAD JACKS

- These jacks are held into the panel by a hex-nut and lock washer.
- All units feature nickel plated, brass bodies, and gold phosphor-bronze contacts

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Description	Price Each			
				1	10	25	100
678-326A515	326A515	P	F/M Solder, Grounded				
678-326R515	326R515	Q	F/M Solder, Isolated, White Bushing				
678-326R515RD	326R515RD	Q	F/M Solder, Isolated, Red Bushing				
678-326R515GN	326R515GN	Q	F/M Solder, Isolated, Green Bushing				
678-326R515BL	326R515BL	Q	F/M Solder, Isolated, Blue Bushing				

SMA CONNECTOR

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Description	Mount/Cable Type	Price Each			
					1	10	25	100
678-910A205F	910A205F	R	Straight Crimp Plug, Nickel Body	RG58/U, 141/U, 142/U				

Bomar RF Connectors

