

AMP Modular Jacks

RoHS Compliant This product is RoHS compliant.

SINGLE PORT R/A MODULAR JACKS

Specifications:

- Color: Black
- Current Rating: 1.5 amp max.
- Voltage Rating: 150 volts ac max.
- Durability: 750 mating cycles
- Housing: Through-Hole: Polyester, UL 94V-0 rated
- Housing STM: Polyphenylene Sulfide, UL 94V-0 rated

Features:

- Meets or exceeds FCC Part 68 rules & regulations
- Meets 1000 volt dielectric requirement
- Designed for ease of soldering & board cleaning
- Designed for direct mounting on pc boards
- SMT jacks compatible with vapor phase & IR reflow soldering

Through-Hole, Standard Profile, Solder PCB Termination

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Positions-Contacts	LED	Description	Price Each		
						1	25	50
With Panel Stops								
571-555140-1	5555140-1	A	6/6	-	Shielded, Cat 3, Panel & PCB Ground Options			
571-555140-2	5555140-2	A	6/4	-	Shielded, Cat 3, Panel & PCB Ground Options			
571-5557789-1	5557789-1	B	8/8	-	Cat 3, PCB Ground Options			
571-5520250-1	5520250-1	B	6/2	-	Cat 3, w/o Ground Options			
571-5557786-1	5557786-1	A	8/8	-	Shielded, Cat 3, w/ PCB Ground Options			
571-5558343-1	5558343-1	B	8/8	-	Cat 5, w/o Ground Options			
571-5520251-4	5520251-4	B	8/8	-	Cat 3, w/o Ground Options			
Without Panel Stops								
571-1116503-2	1116503-2	A	8/8	-	Shielded, Cat 5, PCB Ground Options			
571-5558070-1	5558070-1	A	10/10	-	Shielded, Cat 3, Panel & PCB Ground Options			
571-5569118-1	5569118-1	B	8/8	-	Cat 3, w/o Ground Options			
571-5569564-1	5569564-1	A	8/8	Grn/Yel	Shielded, Cat 3, Panel & PCB Ground Options			
571-1-406541-1	1-406541-1	A	8/8	-	Shielded, Cat 5, Panel & PCB Ground Options			
571-2-406549-4	2-406549-4	A	8/8	Yel/Grn	Shielded, Cat 5, Panel & PCB Ground Options			
571-5406299-1	5406299-1	A	8/8	-	Shielded, Cat 5, Panel & PCB Ground Options			
571-2-406549-1	2-406549-1	A	8/8	Grn/Yel	Shielded, Cat 5, Panel & PCB Ground Options			
571-5558341-1	5558341-1	B	8/8	-	Cat 5, w/o Ground Options			
571-5558342-1	5558342-1	A	8/8	-	Shielded, Cat 5, PCB Ground Options			
571-5558344-1	5558344-1	A	8/8	-	Shielded, Cat 5, Panel & PCB Ground Options			

Through-Hole, Standard Profile with Center Latch

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Positions-Contacts	Description	Price Each		
					1	25	50
Flanged							
571-5520241-2	5520241-2	C	4/4	Cat 3, w/o Ground Options			
571-5520242-3	5520242-3	C	6/6	Cat 3, w/o Ground Options			
571-5520243-4	5520243-4	C	8/8	Cat 3, w/o Ground Options			
With Panel Stops							
571-5520249-2	5520249-2	D	4/4	Cat 3, w/o Ground Options			
571-5520250-2	5520250-2	D	6/4	Cat 3, w/o Ground Options			
571-5520250-3	5520250-3	D	6/6	Cat 3, w/o Ground Options			
571-5520251-4	5520251-4	D	8/8	Cat 3, w/o Ground Options			
571-5520252-4	5520252-4	D	8/8	Cat 3, w/o Ground Options, Keyed			
Without Panel Stops							
571-5555980-1	5555980-1	D	4/4	Cat 3, w/o Ground Options			
571-5555979-1	5555979-1	D	6/4	Cat 3, w/o Ground Options			
571-5520470-3	5520470-3	D	6/6	Cat 3, w/o Ground Options			
571-5520426-4	5520426-4	D	8/8	Cat 3, w/o Ground Options			
571-5554517-1	5554517-1	D	8/8	Cat 3, w/o Ground Options, Keyed			

Through-Hole, Low Profile, Solder PCB Termination

For quantities of 100 and up, call for quote.

With Panel Stops								
571-5555163-1	5555163-1	E	6/6	Cat 3, w/o Ground Options				
571-5555163-2	5555163-2	E	6/4	Cat 3, w/o Ground Options				
571-5555162-1	5555162-1	E	8/8	Cat 3, w/o Ground Options				
571-5555166-1	5555166-1	E	8/8	Cat 3, w/o Ground Options, Keyed				
Without Panel Stops								
571-5555165-1	5555165-1	E	6/6	Cat 3, w/o Ground Options				
571-5555165-2	5555165-2	E	6/4	Cat 3, w/o Ground Options				
571-5555164-1	5555164-1	E	8/8	Cat 3, w/o Ground Options				
571-5555167-1	5555167-1	E	8/8	Cat 3, w/o Ground Options, Keyed				
571-5569026-1	5569026-1	E	6/6	Cat 3, w/o Ground Options				
Shielded								
571-5555154-1	5555154-1	E	6/6	Shielded, Cat 3, w/ PCB Ground Options				
571-5555153-1	5555153-1	E	8/8	Shielded, Cat 3, w/ PCB Ground Options				
571-5555141-1	5555141-1	E	8/8	Shielded, Cat 3, w/ Panel & PCB Ground Options				
571-5556591-1	5556591-1	E	8/8	Shielded, Cat 3, w/ PCB Ground Options, Keyed				
571-5555153-6	5555153-6	E	8/8	Shielded, Cat 3, w/ PCB Ground Options				
571-5555154-2	5555154-2	E	6/4	Shielded, Cat 3, w/ PCB Ground Options				

Surface Mount, Low Profile, Solder PCB Termination


For quantities of 100 and up, call for quote.

With Panel Stops								
571-5555077-1	5555077-1	F	6/6	Cat 3, w/o Ground Options				
571-5555248-1	5555248-1	F	8/8	Cat 3, w/o Ground Options				
571-5558178-1	5558178-1	F	8/8	Shielded, Cat 3, PCB Ground Options				
Without Panel Stops								
571-5557314-1	5557314-1	F	6/6	Cat 3, w/o Ground Options				
571-5555764-1	5555764-1	F	8/8	Cat 3, w/o Ground Options				
571-5555078-1	5555078-1	F	8/8	Cat 3, w/o Ground Options, Keyed				

Single Port Top Entry Modular Jacks Through-Hole, Standard Profile

For quantities of 100 and up, call for quote.

PCB Termination - Solder With Panel Stops								
571-5520257-2	5520257-2	G	4/4	Cat 3, w/o Ground Options				
571-5520258-2	5520258-2	G	6/4	Cat 3, w/o Ground Options				
571-5520258-3	5520258-3	G	6/6	Cat 3, w/o Ground Options				
571-5520259-4	5520259-4	G	8/8	Cat 3, w/o Ground Options				
571-5520260-4	5520260-4	G	8/8	Cat 3, w/o Ground Options, Keyed				
571-5557969-1	5557969-1	G	8/8	Cat 3, Panel & PCB Ground Options				
571-5557730-1	5557730-1	G	8/8	Shielded, Cat 3, Panel & PCB Ground Options, Keyed				
571-5557969-2	5557969-2	G	8/8	Shielded, Cat 3, Panel & PCB Ground Options				
571-5520258-3	5520258-3	G	6/6	Cat 3, w/o Ground Options				
Without Panel Stops								
571-5558872-1	5558872-1	G	4/4	Cat 3, w/o Ground Options				
571-5520425-2	5520425-2	G	6/4	Cat 3, w/o Ground Options				
571-5520425-3	5520425-3	G	6/6	Cat 3, w/o Ground Options				
571-5556416-1	5556416-1	G	8/8	Cat 3, w/o Ground Options				
571-5555799-1	5555799-1	G	8/8	Cat 3, w/o Ground Options, Keyed				
571-5520425-3	5520425-3	G	6/6	Cat 3, w/o Ground Options, Solder				
PCB Termination - Press-Fit								
571-6116418-1	6116418-1	G	8/8	Shielded, Cat 5, Panel & PCB Ground Options				
571-6116202-1	6116202-1	G	8/8	Shielded, Cat 5, PCB Ground Options, Press-Fit				

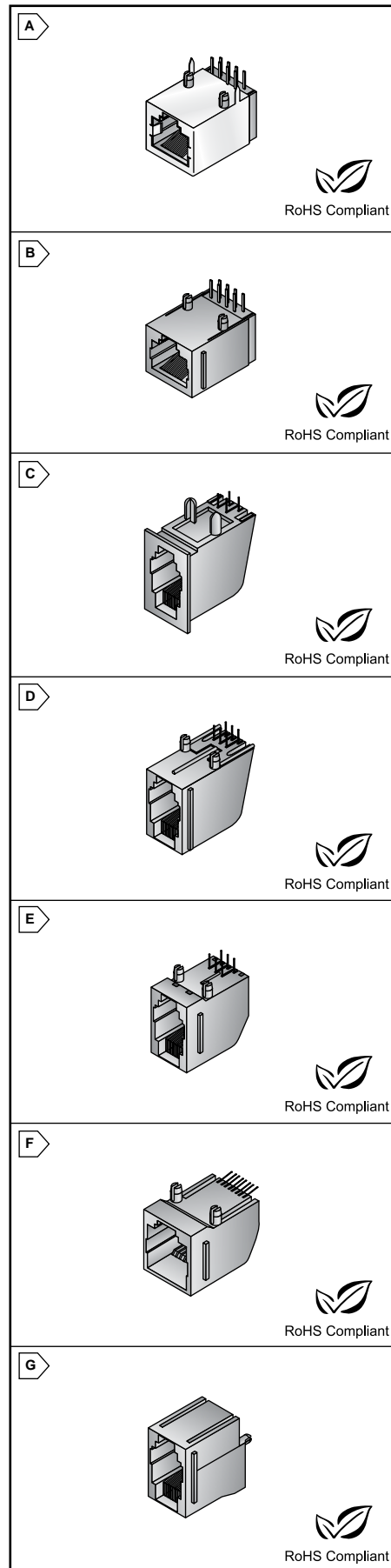

Data/Network/Telecom AMP