


SUNBRITE LED Replacements

Products may be RoHS compliant.
Check mouser.com for RoHS status.



DIMENSIONS: mm (in.)

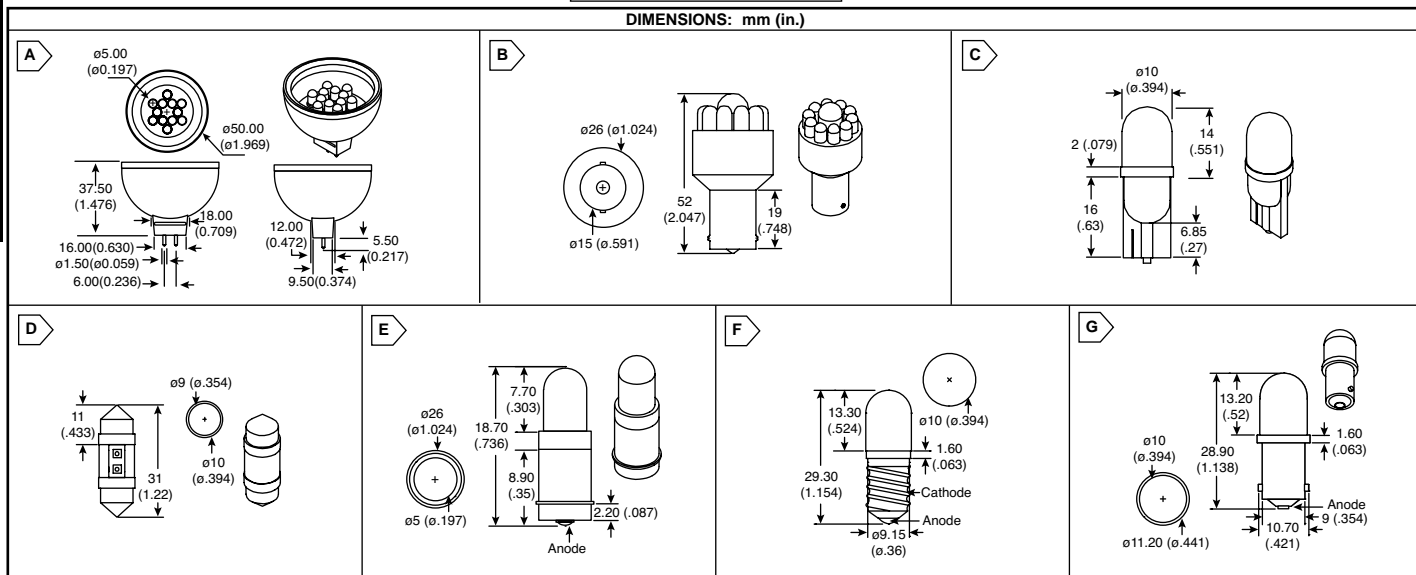

SUNBRITE LED REPLACEMENTS FOR INCANDESCENT LAMPS

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Sunbrite Part No.	Fig.	Emitted Color	Lens	Intensity (mcd)	Peak Wavelength (nm)	Vf (V) Typ.	Peak Forward Current Max. (mA)	Viewing Angle	Price Each				
										1	10	100	500	
MR16 LED Lamp														
697-SSP11CR6U12	SSP-11CR6U12	A	Ultra Red	Water Clear	11,000	626	12	70	60°					
697-SSP11CR3S12	SSP-11CR3S12	A	Super Yellow	Water Clear	11,000	590	12	70	60°					
697-SSP11CR2UP12	SSP-11CR2UP12	A	Ultra Green	Water Clear	12,000	525	12	70	60°					
697-SSP11CR7U12	SSP-11CR7U12	A	Ultra Super Blue	Water Clear	10,000	470	12	70	60°					
697-SSP11CR912	SSP-11CR912	A	White	Water Clear	12,000	—	12	70	60°					
1156 LED Replacement Lamp														
697-1156B156U12	SSP-1156B156U12	B	Red	Water Clear	5000	626	12	110	20°					
697-1156B153S12	SSP-1156B153S12	B	Yellow	Water Clear	3500	590	12	110	20°					
697-1156B152UP12	SSP-1156B152UP12	B	Green	Water Clear	4000	525	12	110	20°					
697-1156B157U12	SSP-1156B157U12	B	Super Blue	Water Clear	4500	470	12	110	20°					
697-1156B15912	SSP-1156B15912	B	Ultra White	Water Clear	7000	—	12	110	20°					
T 3 1/4 LED Miniature Wedge Base Replacement Lamp														
697-01TWB6UW12	SSP-01TWB6UW12	C	Red	White Diff.	2800	626	12	12	60°					
697-01TWB6UWB12	SSP-01TWB6UWB12	C	Red	Water Clear	8000	626	12	30	31°					
697-01TWB3SW12	SSP-01TWB3SW12	C	Super Yellow	White Diff.	2200	590	12	30	60°					
697-01TWB3SWB12	SSP-01TWB3SWB12	C	Super Yellow	Water Clear	7000	590	12	30	35°					
697-01TWB2UPW12	SSP-01TWB2UPW12	C	Ultra Green	White Diff.	2800	525	12	12	60°					
697-01TWB2UPWB12	SSP-01TWB2UPWB12	C	Pure Green	Water Clear	9000	525	12	30	30°					
697-01TWB7UW12	SSP-01TWB7UW12	C	Super Blue	White Diff.	1600	470	12	30	60°					
697-01TWB7UWB12	SSP-01TWB7UWB12	C	Super Blue	Water Clear	7000	470	12	30	30°					
697-01TWB9W12	SSP-01TWB9W12	C	Ultra White	Water Clear	3300	—	12	30	60°					
697-01TWB9WB12	SSP-01TWB9WB12	C	Ultra White	Water Clear	11000	—	12	30	30°					
Festoon LED Lamp														
697-SSP-02TFS912	SSP-02TFS912	D	Ultra White	Water Clear	5500	—	12	—	60°					
Midget Flange Base Replacement Lamp														
697-D19F9SIC-12V	SSP-D19F9SIC-12V	E	Red	Water Clear	1200	636	12	30	45°					
697-D19F9SYC-12V	SSP-D19F9SYC-12V	E	Yellow	Water Clear	1200	590	12	30	45°					
697-D19F9SUGC-12V	SSP-D19F9SUGC-12V	E	Green	Water Clear	300	574	12	25	45°					
Miniature Screw (E10) Base Replacement Lamp														
697-D29E10SIC-12V	SSP-D29E10SIC-12V	F	Red	Water Clear	2500	636	12	30	25°					
697-D29ESUGC-12V	SSP-D29ESUGC-12V	F	Green	Water Clear	1000	574	12	25	25°					
Miniature Bayonet (BA9S) Base Replacement Lamp														
697-D29B9SIC-12V	SSP-D29B9SIC-12V	G	Red	Water Clear	2500	636	12	12	40°					
697-D29B9SYC-12V	SSP-D29B9SYC-12V	G	Yellow	Water Clear	1500	590	12	12	40°					
697-D29B9SUGC-12V	SSP-D29B9SUGC-12V	G	Green	Water Clear	1000	574	12	12	40°					