

HARTING Heavy Duty Han® Power Connectors




HAN® INSERTS FOR TYPE B HOODS AND HOUSINGS

- Leading protective ground
- Polarized for correct mating
- Male and Female inserts are interchangeable between hoods and housings
- RoHS Compliant per HARTING documentation
- Crimp Contacts sold separately (see accessories page)
- Axial Screw terminations recommended VDE 0295 Tupe 5 fine Wire Strand



RoHS Compliant

Contact Arrangement View Is From Termination Side Of The Male Connector

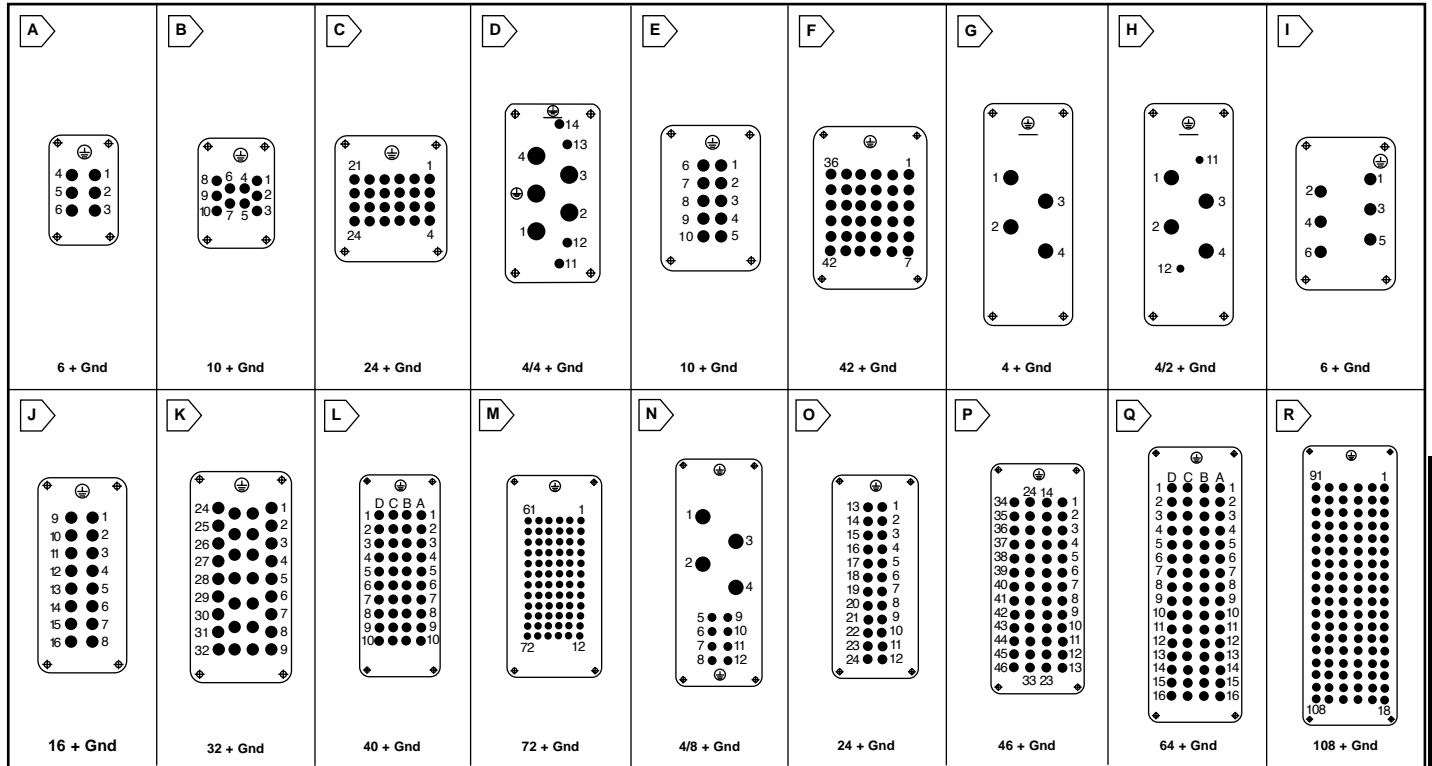

Rectangular Power

Inserts are organized by Hood and Housing size

*Crimp contacts sold separately (see accessories page)

For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	HARTING Part No.	Fig.	No. of Positions	Insert Type	Han® Hood & Housing Size	Contact * Type	AWG	Han® Insert Series	Contact Rating	Price Each	
										1	10
617-09-33-006-2601	09 33 006 2601	A	6 + Gnd	Male	6B	Screw	14	E	16A/600V		
617-09-33-006-2701	09 33 006 2701	A	6 + Gnd	Female	6B	Screw	14	E	16A/600V		
617-09-33-006-2602	09 33 006 2602	A	6 + Gnd	Male	6B	Crimp	20-12	E	16A/600V		
617-09-32-010-3001	09 32 010 3001	B	10 + Gnd	Male	6B	Crimp	20-12	EE	16A/600V		
617-09-32-010-3101	09 32 010 3101	B	10 + Gnd	Female	6B	Crimp	20-12	EE	16A/600V		
617-09-16-024-3001	09 16 024 3001	C	24 + Gnd	Male	6B	Crimp	26-14	DD	10A/600V		
617-09-16-024-3101	09 16 024 3101	C	24 + Gnd	Female	6B	Crimp	26-14	DD	10A/600V		
617-09-380082601	09 38 008 2601	D	4/4 + Gnd	Male	10B	Screw	Pwr 8-4/Sig 26-14	Han Com	Pwr 63A/Sig 16A		
617-09-380082701	09 38 008 2701	D	4/4 + Gnd	Female	10B	Screw	Pwr 8-4/Sig 26-14	Han Com	Pwr 63A/Sig 16A		
617-09-380082602	09 38 008 2602	D	4/4 + Gnd	Male	10B	Screw	Pwr 8-4/Sig 26-14	Han Com	Pwr 63A/Sig 16A		
617-09-380082702	09 38 008 2702	D	4/4 + Gnd	Female	10B	Screw	Pwr 8-4/Sig 26-14	Han Com	Pwr 63A/Sig 16A		
617-09-380082611	09 38 008 2611	D	4/4 + Gnd	Male	10B	Screw	Pwr 8-4/Sig 26-14	Han Com	Pwr 63A/Sig 16A		
617-09-380082612	09 38 008 2612	D	4/4 + Gnd	Female	10B	Screw	Pwr 8-4/Sig 26-14	Han Com	Pwr 63A/Sig 16A		
617-09-33-010-2601	09 33 010 2601	E	10 + Gnd	Male	10B	Screw	18-14	E	16A/600V		
617-09-33-010-2701	09 33 010 2701	E	10 + Gnd	Female	10B	Screw	18-14	E	16A/600V		
617-09-33-010-2602	09 33 010 2602	E	10 + Gnd	Male	10B	Crimp	20-12	E	16A/600V		
617-09-33-010-2702	09 33 010 2702	E	10 + Gnd	Female	10B	Crimp	20-12	E	16A/600V		
617-09-16-042-3001	09 16 042 3001	F	42 + Gnd	Male	10B	Crimp	26-14	DD	10A/600V		
617-09-16-042-3101	09 16 042 3101	F	42 + Gnd	Female	10B	Crimp	26-14	DD	10A/600V		
617-09-38-006-2611	09 38 006 2611	G	4 + Gnd	Male	16B	Screw	16-6	Han-Com	80A/600		
617-09-38-006-2711	09 38 006 2711	G	4 + Gnd	Female	16B	Screw	16-6	Han-Com	80A/600		
617-09-38-006-2601	09 38 006 2601	H	4/2 + Gnd	Male	16B	Screw	20-14	Han-Com	80A/16A/600V		
617-09-38-006-2701	09 38 006 2701	H	4/2 + Gnd	Female	16B	Screw	20-14	Han-Com	80A/16A/600V		
617-09-31-006-2601	09 31 006 2601	I	6 + Gnd	Male	16B	Screw	10	HsB	35A/600V		
617-09-31-006-2701	09 31 006 2701	I	6 + Gnd	Female	16B	Screw	10	HsB	35A/600V		
617-09-33-016-2601	09 33 016 2601	J	16 + Gnd	Male	16B	Screw	18-14	E	16A/600V		
617-09-33-016-2701	09 33 016 2701	J	16 + Gnd	Female	16B	Screw	18-14	E	16A/600V		
617-09-33-016-2602	09 33 016 2602	J	16 + Gnd	Male	16B	Crimp	20-12	E	16A/600V		
617-09-33-016-2702	09 33 016 2702	J	16 + Gnd	Female	16B	Crimp	20-12	E	16A/600V		
617-09-32-032-3001	09 32 032 3001	K	32 + Gnd	Male	16B	Crimp	20-12	EE	16A/600V		
617-09-32-032-3101	09 32 032 3101	K	32 + Gnd	Female	16B	Crimp	20-12	EE	16A/600V		
617-09-21-040-3001	09 21 040 3001	L	40 + Gnd	Male	16B	Crimp	26-14	D	10A/600V		
617-09-21-040-3101	09 21 040 3101	L	40 + Gnd	Female	16B	Crimp	26-14	D	10A/600V		
617-09-16-072-3001	09 16 072 3001	M	72 + Gnd	Male	16B	Crimp	26-14	DD	10A/600V		
617-09-16-072-3101	09 16 072 3101	M	72 + Gnd	Female	16B	Crimp	26-14	DD	10A/600V		
617-09-38-012-2601	09 38 012 2601	N	4/8 + Gnd	Male	24B	Screw	16-6/20-14	Han-Com	80A/16A/600V		
617-09-38-012-2701	09 38 012 2701	N	4/8 + Gnd	Female	24B	Screw	16-6/20-14	Han-Com	80A/16A/600V		
617-09-33-024-2601	09 33 024 2601	O	24 + Gnd	Male	24B	Screw	18-14	E	16A/600V		
617-09-33-024-2701	09 33 024 2701	O	24 + Gnd	Female	24B	Screw	18-14	E	16A/600V		
617-09-33-024-2602	09 33 024 2602	O	24 + Gnd	Male	24B	Crimp	20-12	E	16A/600V		
617-09-33-024-2702	09 33 024 2702	O	24 + Gnd	Female	24B	Crimp	20-12	E	16A/600V		
617-09-32-046-3001	09 32 046 3001	P	46 + Gnd	Male	24B	Crimp	20-12	EE	16A/600V		
617-09-32-046-3101	09 32 046 3101	P	46 + Gnd	Female	24B	Crimp	20-12	EE	16A/600V		
617-09-21-064-3001	09 21 064 3001	Q	64 + Gnd	Male	24B	Crimp	26-14	D	10A/600V		
617-09-21-064-3101	09 21 064 3101	Q	64 + Gnd	Female	24B	Crimp	26-14	D	10A/600V		
617-09-16-108-3001	09 16 108 3001	R	108 + Gnd	Male	24B	Crimp	26-14	DD	10A/600V		
617-09-16-108-3101	09 16 108 3101	R	108 + Gnd	Female	24B	Crimp	26-14	DD	10A/600V		