


3M™ .100" x .100" Wiremount Connectors



RoHS Compliant This page of product is compliant.

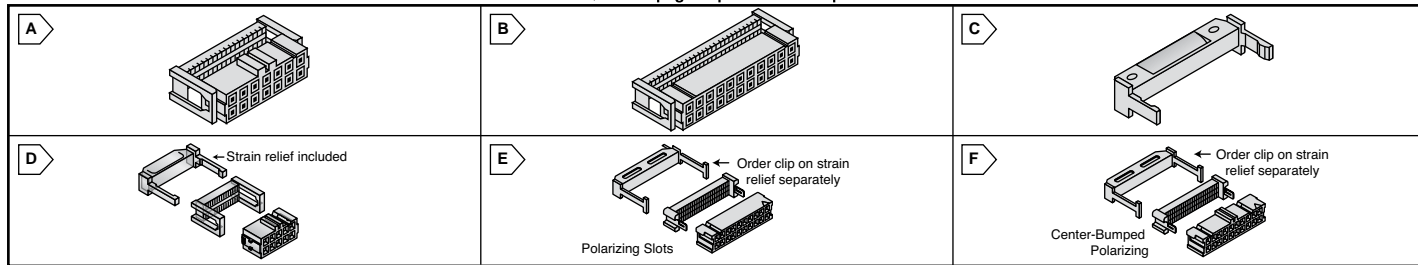

891 SERIES WIREMOUNT SOCKETS

Preassembled Wiremount Sockets

- Plating: 30µ Gold
- Contact Material: Phosphor Bronze (C510)
- Current Rating: 1A
- Mates with Header Series 3000, 2500 and 303, Plug Series 4600
- RoHS Compliant per 3M™ documentation

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Positions	Price Each			
				1	25	50	100
Centerbump Polarizing							
517-89110-0101	89110-0101	A	10				
517-89114-0101	89114-0101	A	14				
517-89116-0101	89116-0101	A	16				
517-89120-0101	89120-0101	A	20				
517-89126-0101	89126-0101	A	26				
517-89130-0101	89130-0101	A	30				
517-89134-0101	89134-0101	A	34				
517-89140-0101	89140-0101	A	40				
517-89150-0101	89150-0101	A	50				
Without Centerbump Polarizing							
517-89110-0001	89110-0001	B	10				
517-89114-0001	89114-0001	B	14				
517-89116-0001	89116-0001	B	16				
517-89120-0001	89120-0001	B	20				
517-89126-0001	89126-0001	B	26				
517-89134-0001	89134-0001	B	34				
517-89140-0001	89140-0001	B	40				
517-89150-0001	89150-0001	B	50				
517-89160-0001	89160-0001	B	60				
Optional Clip On Strain Relief							
517-3448-89110	3448-89110	C	10				
517-3448-89114	3448-89114	C	14				
517-3448-89116	3448-89116	C	16				
517-3448-89120	3448-89120	C	20				
517-3448-89126	3448-89126	C	26				
517-3448-89134	3448-89134	C	34				
517-3448-89140	3448-89140	C	40				
517-3448-89150	3448-89150	C	50				
517-3448-89160	3448-89160	C	60				
Centerbump Polarizing - Strain Relief Included							
517-8910	89110-0103	D	10				
517-8914	89114-0103	D	14				
517-8916	89116-0103	D	16				
517-8920	89120-0103	D	20				
517-8924	89124-0103	D	24				
517-8926	89126-0103	D	26				
517-8930	89130-0103	D	30				
517-8934	89134-0103	D	34				
517-8940	89140-0103	D	40				
517-8950	89150-0103	D	50				
517-8960	89160-0103	D	60				

Wiremount Sockets

- Plating: 10µ Gold
- Contact Material: Phosphor Bronze (C510)
- Current Rating: 1A
- Mates with Header Series 3000, 2500 and 303, Plug Series 4600
- RoHS Compliant per 3M™ documentation

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Positions	Price Each			
				1	25	50	100
Centerbump Polarizing							
517-D89110-0131HK	D89110-0131HK	A	10				
517-D89114-0131HK	D89114-0131HK	A	14				
517-D89116-0131HK	D89116-0131HK	A	16				
517-D89120-0131HK	D89120-0131HK	A	22				
517-D89126-0131HK	D89126-0131HK	A	26				
517-D89130-0131HK	D89130-0131HK	A	30				
517-D89134-0131HK	D89134-0131HK	A	34				
517-D89140-0131HK	D89140-0131HK	A	40				
517-D89150-0131HK	D89150-0131HK	A	50				
Without Centerbump Polarizing							
517-D89110-0031HK	D89110-0031HK	B	10				
517-D89114-0031HK	D89114-0031HK	B	14				
517-D89116-0031HK	D89116-0031HK	B	16				
517-D89120-0031HK	D89120-0031HK	B	22				
517-D89126-0031HK	D89126-0031HK	B	26				
517-D89130-0031HK	D89130-0031HK	B	30				
517-D89134-0031HK	D89134-0031HK	B	34				
517-D89140-0031HK	D89140-0031HK	B	40				
517-D89150-0031HK	D89150-0031HK	B	50				

Wiremount Sockets (Cont.)

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Positions	Price Each			
				1	25	50	100
Optional Clip On Strain Relief							
517-D3448-89110	D3448-89110	C	10				
517-D3448-89114	D3448-89114	C	14				
517-D3448-89116	D3448-89116	C	16				
517-D3448-89120	D3448-89120	C	22				
517-D3448-89126	D3448-89126	C	26				
517-D3448-89130	D3448-89130	C	30				
517-D3448-89134	D3448-89134	C	34				
517-D3448-89140	D3448-89140	C	40				
517-D3448-89150	D3448-89150	C	50				

3000 SERIES WIREMOUNT SOCKETS

- Industry standard IDC socket
- Current rating: 1A
- Positive locking metal "J" clips provide high cover retention
- Withstanding voltage: 1000Vrms
- Accepts flat cable or discrete wire
- Temperature rating: -55°C to +105°C
- Insulation material: Glass filled polyester (PBT), Gray, UL 94V-0
- Contact material: Copper alloy
- Wire accommodation: 26 & 28AWG solid or stranded
- Mates w/ Header Series: 3000, 2500, & 303; Plug Series: 4600
- Plating: 30µ" Gold
- Order strain reliefs separately
- RoHS compliant per 3M™ documentation

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Positions	Price Each			
				1	25	50	100
Polarizing Slots - Open-Ended for Daisy Chaining							
517-3473-6000	3473-6000	E	10				
517-3385-6000	3385-6000	E	14				
517-3452-6000	3452-6000	E	16				
517-3421-6000	3421-6000	E	20				
517-3626-6000	3626-6000	E	24				
517-3399-6000	3399-6000	E	26				
517-3414-6000	3414-6000	E	34				
517-3417-6000	3417-6000	E	40				
517-3425-6000	3425-6000	E	50				
Polarizing Slots - Closed-Ended for Line Termination							
517-3473-7000	3473-7000	E	10				
517-3385-7000	3385-7000	E	14				
517-3452-7000	3452-7000	E	16				
517-3421-7000	3421-7000	E	20				
517-3626-7000	3626-7000	E	24				
517-3399-7000	3399-7000	E	26				
517-3414-7000	3414-7000	E	34				
517-3417-7000	3417-7000	E	40				
517-3425-7000	3425-7000	E	50				
Center-Bumped Polarizing - Open-Ended for Daisy Chaining							
517-3473-6600	3473-6600	F	10				
517-3385-6600	3385-6600	F	14				
517-3452-6600	3452-6600	F	16				
517-3421-6600	3421-6600	F	20				
517-3626-6600	3626-6600	F	24				
517-3399-6600	3399-6600	F	26				
517-3419-6600	3419-6600	F	30				
517-3414-6600	3414-6600	F	34				
517-3417-6600	3417-6600	F	40				
517-3425-6600	3425-6600	F	50				
Center-Bumped Polarizing - Closed-Ended for Line Termination							
517-3473-7600	3473-7600	F	10				
517-3385-7600	3385-7600	F	14				
517-3452-7600	3452-7600	F	16				
517-3421-7600	3421-7600	F	20				
517-3626-7600	3626-7600	F	24				
517-3399-7600	3399-7600	F	26				
517-3419-7600	3419-7600	F	30				
517-3414-7600	3414-7600	F	34				
517-3417-7600	3417-7600	F	40				
517-3425-7600	3425-7600	F	50				
Plastic Clip On Strain Reliefs							
517-3448-3010	3448-3010	-	10				
517-3448-3014	3448-3014	-	14				
517-3448-3016	3448-3016	-	16				
517-3448-3020	3448-3020	-	20				
517-3448-3024	3448-3024	-	24				
517-3448-3026	3448-3026	-	26				
517-3448-3030	3448-3030	-	30				
517-3448-3034	3448-3034	-	34				
517-3448-3040	3448-3040	-	40				
517-3448-3050	3448-3050	-	50				

Rectangular Connectors 3M