

3M™ 2mm x 2mm Headers

RoHS Compliant This product is RoHS compliant.



951 SERIES PIN STRIP HEADERS

Features:

- Maximizes use of PC board space
- High temperature dielectric
- End stackable feature
- Mates with boardmount and wiremount products

Specifications:



- Insulation Material: High Temp., Thermoplastic, UL 94-V0
- Contact Material: Copper Alloy
- Color: Black
- Current Rating: 1A
- Plating 10µ Gold



Right Angle

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Cont.	Price Each			
				1	25	50	100
517-951204-7622-AR	951204-7622-AR	A	4				
517-951206-7622-AR	951206-7622-AR	A	6				
517-951208-7622-AR	951208-7622-AR	A	8				
517-951210-7622-AR	951210-7622-AR	A	10				
517-951212-7622-AR	951212-7622-AR	A	12				
517-951214-7622-AR	951214-7622-AR	A	14				
517-951216-7622-AR	951216-7622-AR	A	16				
517-951218-7622-AR	951218-7622-AR	A	18				
517-951220-7622-AR	951220-7622-AR	A	20				
517-951244-7622-AR	951244-7622-AR	A	44				
517-951280-7622-AR	951280-7622-AR	A	80				


For quantities of 200 and up, call for quote.

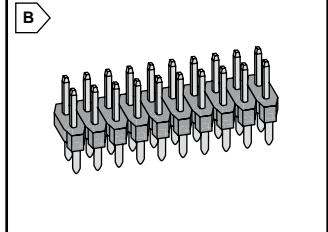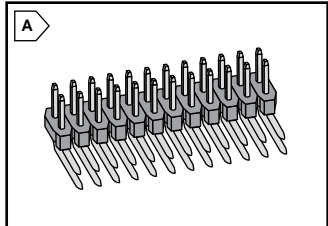

Straight

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Cont.	Price Each			
				1	25	50	100
517-951204-8622-AR	951204-8622-AR	B	4				
517-951206-8622-AR	951206-8622-AR	B	6				
517-951208-8622-AR	951208-8622-AR	B	8				
517-951210-8622-AR	951210-8622-AR	B	10				
517-951212-8622-AR	951212-8622-AR	B	12				
517-951214-8622-AR	951214-8622-AR	B	14				
517-951216-8622-AR	951216-8622-AR	B	16				
517-951218-8622-AR	951218-8622-AR	B	18				
517-951220-8622-AR	951220-8622-AR	B	20				
517-951280-8622-AR	951280-8622-AR	B	80				


For quantities of 200 and up, call for quote.

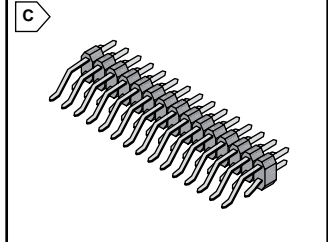

Right Angle Surface Mount

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Cont.	Price Each			
				1	25	50	100
517-951210-4620-ARTP	951210-4620-AR-TP	C	10				
517-951212-4620-ARTP	951212-4620-AR-TP	C	12				
517-951214-4620-ARTP	951214-4620-AR-TP	C	14				
517-951216-4620-ARTP	951216-4620-AR-TP	C	16				
517-951218-4620-ARTP	951218-4620-AR-TP	C	18				
517-951220-4620-ARTP	951220-4620-AR-TP	C	20				


For quantities of 200 and up, call for quote.

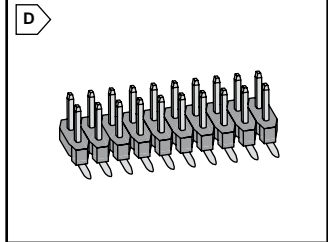

Straight Surface Mount

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Cont.	Price Each			
				1	25	50	100
517-951208-2550-ARPT	951208-2550-AR-PT	D	8				
517-951210-2550-ARPT	951210-2550-AR-PT	D	10				
517-951212-2550-ARPT	951212-2550-AR-PT	D	12				
517-951214-2550-ARPT	951214-2550-AR-PT	D	14				
517-951208-2520-ARPT	951208-2520-AR-TP	D	8				
517-951210-2520-ARPT	951210-2520-AR-TP	D	10				
517-951212-2520-ARPT	951212-2520-AR-TP	D	12				
517-951214-2520-ARPT	951214-2520-AR-TP	D	14				
517-951216-2520-ARPT	951216-2520-AR-TP	D	16				
517-951218-2520-ARPT	951218-2520-AR-TP	D	18				
517-951220-2520-ARPT	951220-2520-AR-TP	D	20				
517-951244-2520-ARPT	951244-2520-AR-TP	D	44				
517-951280-2520-ARPT	951280-2520-AR-TP	D	80				

For quantities of 200 and up, call for quote.

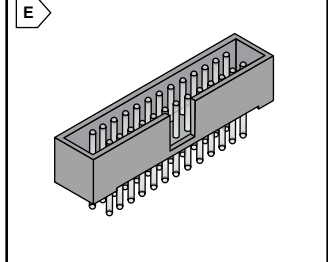

957 SERIES 2MM X 2MM BOX HEADERS

Features:

- High temperature dielectric
- "No lead" wave and reflow solder compatible
- Maximizes use of PC board space
- Center slot polarization prevents mis-insertion and reduces insertion time
- RoHS compliant per 3M documentation



Specifications:

- Insulation Material: High Temp., Thermoplastic, UL 94-V0
- Contact Material: Copper Alloy
- Color: Black
- Current Rating: 1A
- Plating 10µ Gold



For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Cont.	Price Each			
				1	25	50	100
Straight							
517-957210-6002-AR	957210-6002-AR	E	10				
517-957220-6002-AR	957220-6002-AR	E	20				
517-957226-6002-AR	957226-6002-AR	E	26				
517-957240-6002-AR	957240-6002-AR	E	40				
517-957244-6002-AR	957244-6002-AR	E	44				
517-957250-6002-AR	957250-6002-AR	E	50				
Right Angle							
517-957210-5002-AR	957210-5002-AR	F	10				
517-957212-5002-AR	957212-5002-AR	F	12				
517-957226-5002-AR	957226-5002-AR	F	26				
517-957240-5002-AR	957240-5002-AR	F	40				
517-957244-5002-AR	957244-5002-AR	F	44				
Surface Mount							
517-957210-2000-ARTP	957210-2000-AR-TP	G	10				
517-957212-2000-ARTP	957212-2000-AR-TP	G	12				
517-957220-2000-ARTP	957220-2000-AR-TP	G	20				
517-957226-2000-ARTP	957226-2000-AR-TP	G	26				
517-957250-2000-ARTP	957250-2000-AR-TP	G	50				

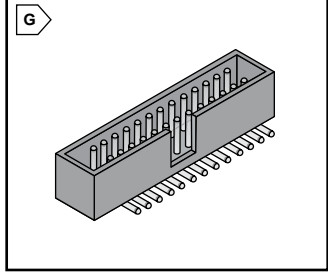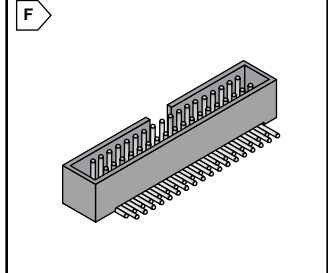

3M Rectangular Connectors