


AMP 2mm CT Connectors

This product is RoHS compliant.

Authorized Distributor

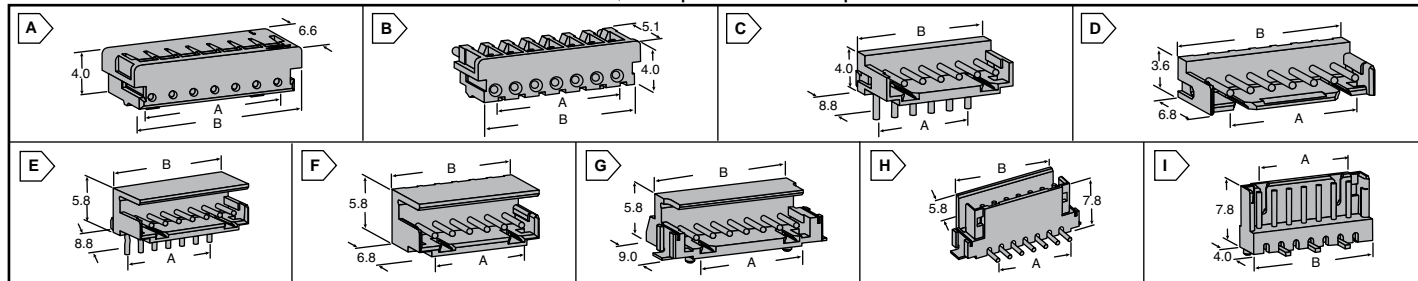

DIMENSIONS: mm

CT CONNECTORS

Features:

- Ensures substantial labor saving as well as improved quality and stability in harness assembly
- Both MT receptacle connectors and crimp-type receptacle connectors can share the same post headers when mated
- Both discrete wire and flat shielded cable can be used
- IDC receptacle contacts in MT (Mass Termination) housings
- AWG 30-22

Applications:

- Business Equipment
- Industrial Machines
- Anywhere where routing signals or power
- Wire-to-Board Applications



Receptacles

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	No. of Positions	Dimensions: mm		Price Each			
				A	B	1	25	50	100
2mm CT - Crimp Type II Receptacle Housings									
571-179228-2	179228-2	A	2	2.00	6.00				
571-179228-3	179228-3	A	3	4.00	8.00				
571-179228-4	179228-4	A	4	6.00	10.00				
571-179228-5	179228-5	A	5	8.00	12.00				
571-179228-6	179228-6	A	6	10.00	14.00				
571-179228-7	179228-7	A	7	12.00	16.00				
571-179228-8	179228-8	A	8	14.00	18.00				
571-179228-9	179228-9	A	9	16.00	20.00				
571-1-179228-0	1-179228-0	A	10	18.00	22.00				
571-1-179228-1	1-179228-1	A	11	20.00	24.00				
571-1-179228-2	1-179228-2	A	12	22.00	26.00				
571-1-179228-3	1-179228-3	A	13	24.00	28.00				
571-1-179228-4	1-179228-4	A	14	26.00	30.00				
571-1-179228-5	1-179228-5	A	15	28.00	32.00				
2mm CT - MT Receptacle Housing Assemblies									
571-173977-2	173977-2	B	2	2.00	4.80				
571-173977-3	173977-3	B	3	4.00	6.80				
571-173977-4	173977-4	B	4	6.00	8.80				
571-173977-5	173977-5	B	5	8.00	10.80				
571-173977-6	173977-6	B	6	10.00	12.80				
571-173977-7	173977-7	B	7	12.00	14.80				
571-173977-8	173977-8	B	8	14.00	16.80				
571-173977-9	173977-9	B	9	16.00	18.80				
571-1-173977-0	1-173977-0	B	10	18.00	20.80				
571-1-173977-1	1-173977-1	B	11	20.00	22.80				
571-1-173977-2	1-173977-2	B	12	22.00	24.80				
571-1-173977-3	1-173977-3	B	13	24.00	26.80				
571-1-173977-4	1-173977-4	B	14	26.00	28.80				
571-1-173977-5	1-173977-5	B	15	28.00	30.80				

Receptacle Contacts

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Description	Price Each			
			1	25	100	500
571-179609-1	179609-1	Receptacle Contact 30-26 AWG				
571-179227-1	179227-1	Receptacle Contact 26-22 AWG				

Headers

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	No. of Positions	Dimensions: mm		Price Each			
				A	B	1	25	50	100
2mm CT - Post Header Assemblies, Horizontal									
571-292253-2	292253-2	C	2	2.0	5.8				
571-292253-3	292253-3	C	3	4.0	7.8				
571-292253-4	292253-4	C	4	6.0	9.8				
571-292253-5	292253-5	C	5	8.0	11.8				
571-292253-6	292253-6	C	6	10.0	13.8				
571-292253-7	292253-7	C	7	12.0	15.8				
571-292253-8	292253-8	C	8	14.0	17.8				
571-292253-9	292253-9	C	9	16.0	19.8				
571-1-292253-0	1-292253-0	C	10	18.0	21.8				
571-1-292253-1	1-292253-1	C	11	20.0	23.8				
571-1-292253-2	1-292253-2	C	12	22.0	25.8				
571-1-292253-3	1-292253-3	C	13	24.0	27.8				
571-1-292253-4	1-292253-4	C	14	26.0	29.8				
571-1-292253-5	1-292253-5	C	15	28.0	31.8				
2mm CT - Post Header Assemblies, Vertical									
571-292161-2	292161-2	D	2	2.0	5.8				
571-292161-3	292161-3	D	3	4.0	7.8				
571-292161-4	292161-4	D	4	6.0	9.8				
571-292161-5	292161-5	D	5	8.0	11.8				
571-292161-6	292161-6	D	6	10.0	13.8				
571-292161-7	292161-7	D	7	12.0	15.8				

Headers (Cont.)

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	No. of Positions	Dimensions: mm		Price Each			
				A	B	1	25	50	100
2mm CT - Post Header Assemblies, Vertical (cont.)									
571-292161-8	292161-8	D	8	14.0	17.8				
571-292161-9	292161-9	D	9	16.0	19.8				
571-1-292161-0	1-292161-0	D	10	18.0	21.8				
571-1-292161-1	1-292161-1	D	11	20.0	23.8				
571-1-292161-2	1-292161-2	D	12	22.0	25.8				
571-1-292161-3	1-292161-3	D	13	24.0	27.8				
571-1-292161-4	1-292161-4	D	14	26.0	29.8				
571-1-292161-5	1-292161-5	D	15	28.0	31.8				
2mm CT - Post Header Assemblies, Box-H, DIP									
571-292250-2	292250-2	E	2	2.00	5.80				
571-292250-3	292250-3	E	3	4.00	7.80				
571-292250-4	292250-4	E	4	6.00	9.80				
571-292250-5	292250-5	E	5	8.00	11.80				
571-292250-6	292250-6	E	6	10.00	13.80				
571-292250-7	292250-7	E	7	12.00	15.80				
571-292250-8	292250-8	E	8	14.00	17.80				
571-292250-9	292250-9	E	9	16.00	19.80				
571-1-292250-0	1-292250-0	E	10	18.00	21.80				
571-1-292250-1	1-292250-1	E	11	20.00	23.80				
571-1-292250-2	1-292250-2	E	12	22.00	25.80				
571-1-292250-3	1-292250-3	E	13	24.00	27.80				
571-1-292250-4	1-292250-4	E	14	26.00	29.80				
571-1-292250-5	1-292250-5	E	15	28.00	31.80				
2mm CT - Post Header Assemblies, Box-V, DIP									
571-292132-2	292132-2	F	2	2.0	5.8				
571-292132-3	292132-3	F	3	4.0	7.8				
571-292132-4	292132-4	F	4	6.0	9.8				
571-292132-5	292132-5	F	5	8.0	11.8				
571-292132-6	292132-6	F	6	10.0	13.8				
571-292132-7	292132-7	F	7	12.0	15.8				
571-292132-8	292132-8	F	8	14.0	17.8				
571-292132-9	292132-9	F	9	16.0	19.8				
571-1-292132-0	1-292132-0	F	10	18.0	21.8				
571-1-292132-1	1-292132-1	F	11	20.0	23.8				
571-1-292132-2	1-292132-2	F	12	22.0	25.8				
571-1-292132-3	1-292132-3	F	13	24.0	27.8				
571-1-292132-4	1-292132-4	F	14	26.0	29.8				
571-1-292132-5	1-292132-5	F	15	28.0	31.8				
2mm CT - Post Header Assemblies, Box-V, SMT with Boss									
571-292173-2	292173-2	G	2	2.00	8.00				
571-292173-3	292173-3	G	3	4.00	10.00				
571-292173-4	292173-4	G	4	6.00	12.00				
571-292173-5	292173-5	G	5	8.00	14.00				
571-292173-6	292173-6	G	6	10.00	16.00				
571-292173-7	292173-7	G	7	12.00	18.00				
571-292173-8	292173-8	G	8	14.00	20.00				
571-292173-9	292173-9	G	9	16.00	22.00				
2mm CT - Post Header Assemblies, Box-H, SMT with Boss									
571-292174-2	292174-2	H	2	2.00	5.8				
571-292174-3	292174-3	H	3	4.00	7.8				
571-292174-4	292174-4	H	4	6.00	9.8				
571-292174-5	292174-5	H	5	8.00	11.8				
571-292174-6	292174-6	H	6	10.00	13.8				
571-292174-7	292174-7	H	7	12.00	15.8				
571-292174-8	292174-8	H	8	14.00	17.8				
571-292174-9	292174-9	H	9	16.00	19.8				
2mm CT - Post Header Assemblies, Standard-V, SMT									
571-292171-2	292171-2	I	2	2.00	6.00				
571-292171-3	292171-3	I	3	4.00	8.00				
571-292171-4	292171-4	I	4	6.00	10.00				
571-292171-5	292171-5	I	5	8.00	12.00				
571-292171-6	292171-6	I	6	10.00	14.00				
571-292171-7	292171-7	I	7	12.00	16.00				
571-292171-8	292171-8	I	8	14.00	18.00				
571-292171-9									