


AMP-LATCH Connectors

This product is RoHS compliant.

Authorized Distributor

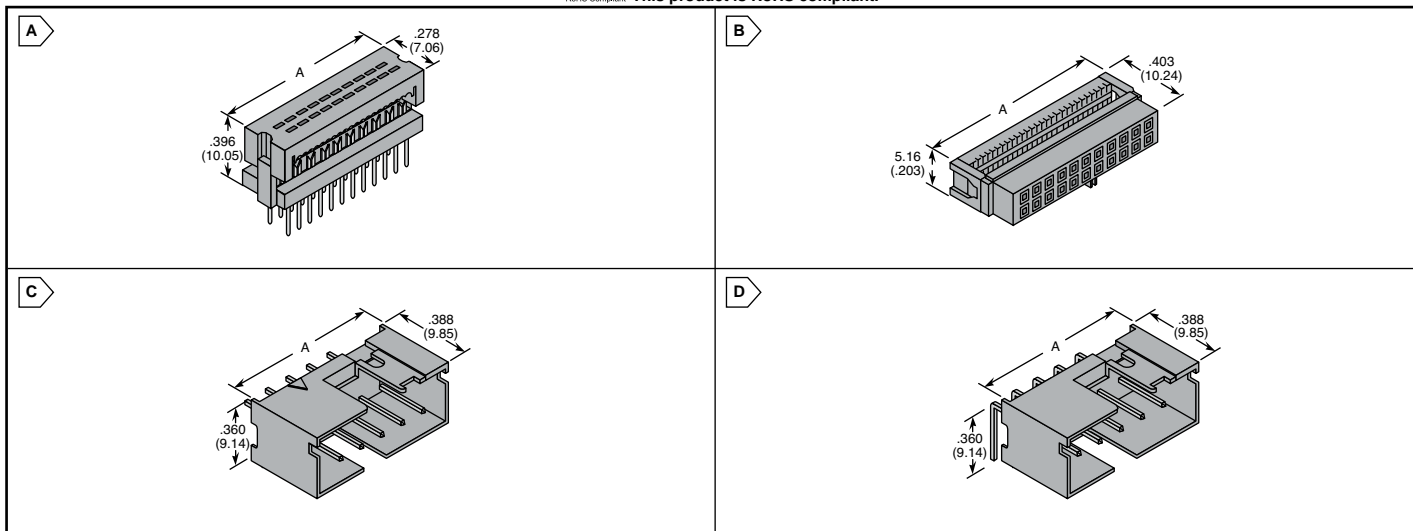

AMP-LATCH .050 CENTERLINE IDC DIP PLUGS

Specifications:

- .100 x .100 Footprint
- Tin Plated
- Black thermoplastic, UL 94V-0 rated



RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	No. of Pos.	Dim. A In. (mm)	Price Each		
					1	10	100
571-2-746610-1	2-746610-1	A	10	0.68 (17.27)			
571-2-746610-2	2-746610-2	A	14	0.88 (22.35)			
571-1-746610-4	1-746610-4	A	16	0.98 (24.89)			
571-1-746610-5	1-746610-5	A	20	1.18 (29.97)			
571-2-746610-3	2-746610-3	A	24	1.38 (35.05)			
571-1-746610-6	1-746610-6	A	26	1.48 (37.59)			
571-1-746610-7	1-746610-7	A	30	1.68 (42.67)			
571-1-746610-8	1-746610-8	A	34	1.88 (47.75)			
571-1-746610-9	1-746610-9	A	40	2.18 (55.37)			
571-2-746610-6	2-746610-6	A	44	2.38 (60.45)			
571-2-746610-0	2-746610-0	A	50	2.68 (68.07)			
571-2-746610-4	2-746610-4	A	60	3.18 (80.77)			
571-2-746610-5	2-746610-5	A	64	3.38 (85.85)			

AMP-LATCH 1MM CENTERLINE IDC RECEPTACLE ASSEMBLIES

Specifications:

- .2mm x 2mm Footprint
- 30µ" Plated
- Polarized
- Black Polyester, UL 94V-0 Rated



RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	No. of Pos.	Dim. A In. (mm)	Price Each		
					1	10	100
571-1-111623-8	1-111623-8	B	10	0.597 (15.16)			
571-1-111623-9	1-111623-9	B	14	0.755 (19.18)			
571-2-111623-0	2-111623-0	B	16	0.834 (21.18)			
571-2-111623-1	2-111623-1	B	20	0.991 (25.17)			
571-2-111623-7	2-111623-7	B	24	1.149 (29.18)			
571-2-111623-2	2-111623-2	B	26	1.227 (31.17)			
571-2-111623-3	2-111623-3	B	30	1.385 (35.18)			
571-2-111623-4	2-111623-4	B	40	1.779 (45.19)			
571-2-111623-5	2-111623-5	B	44	1.936 (49.17)			
571-2-111623-6	2-111623-6	B	50	2.172 (55.17)			

AMP-LATCH LOW PROFILE HEADER

Specifications:

- Center, Dual Polarizing Bar
- Black thermoplastic, UL 94V-0 rated
- Center, Dual Polarizing Bar
- Black thermoplastic, UL 94V-0 rated



RoHS Compliant

Vertical Headers, 15µ" Gold

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	No. of Pos.	Dim. A In. (mm)	Price Each		
					1	10	100
571-5103308-1	5103308-1	C	10	0.80 (20.32)			
571-5103308-2	5103308-2	C	14	1.00 (25.40)			
571-5103308-3	5103308-3	C	16	1.10 (27.94)			
571-5103308-5	5103308-5	C	20	1.30 (33.02)			
571-1-5103308-3	1-5103308-3	C	24	1.50 (38.10)			
571-5103308-6	5103308-6	C	26	1.60 (40.64)			
571-5103308-7	5103308-7	C	34	2.00 (50.80)			
571-5103308-8	5103308-8	C	40	2.30 (58.42)			
571-1-5103308-0	1-5103308-0	C	50	2.80 (71.12)			
571-1-5103308-2	1-5103308-2	C	60	3.30 (83.82)			

AMP-LATCH LOW PROFILE HEADERS

Specifications:

- Center, Dual Polarizing Bar
- Black thermoplastic, UL 94V-0 rated



RoHS Compliant

Vertical Headers, 30µ" Gold

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	No. of Pos.	Dim. A In. (mm)	Price Each		
					1	10	100
571-5103309-1	5103309-1	C	10	0.80 (20.32)			
571-5103309-2	5103309-2	C	14	1.00 (25.40)			
571-5103309-3	5103309-3	C	16	1.10 (27.94)			
571-5103309-5	5103309-5	C	20	1.30 (33.02)			
571-5103309-6	5103309-6	C	26	1.60 (40.64)			
571-5103309-7	5103309-7	C	34	2.00 (50.80)			
571-5103309-8	5103309-8	C	40	2.30 (58.42)			
571-1-5103309-0	1-5103309-0	C	50	2.80 (71.12)			

Right Angle Headers, 15µ" Gold

RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	No. of Pos.	Dim. A In. (mm)	Price Each		
					1	10	100
571-5103310-1	5103310-1	D	10	0.80 (20.32)			
571-5103310-2	5103310-2	D	14	1.00 (25.40)			
571-5103310-3	5103310-3	D	16	1.10 (27.94)			
571-5103310-5	5103310-5	D	20	1.30 (33.02)			
571-5103310-6	5103310-6	D	26	1.60 (40.64)			
571-5103310-7	5103310-7	D	34	2.00 (50.80)			
571-5103310-8	5103310-8	D	40	2.30 (58.42)			
571-1-5103310-0	1-5103310-0	D	50	2.80 (71.12)			

Right Angle Headers, 30µ" Gold

RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	No. of Pos.	Dim. A In. (mm)	Price Each		
					1	10	100
571-5103311-1	5103311-1	D	10	0.80 (20.32)			
571-5103311-2	5103311-2	D	14	1.00 (25.40)			
571-5103311-3	5103311-3	D	16	1.10 (27.94)			
571-5103311-5	5103311-5	D	20	1.30 (33.02)			
571-5103311-6	5103311-6	D	26	1.60 (40.64)			
571-5103311-7	5103311-7	D	34	2.00 (50.80)			
571-5103311-8	5103311-8	D	40	2.30 (58.42)			
571-1-5103311-0	1-5103311-0	D	60	3.30 (83.82)			