


AMP MTA .100" Series IDC Connectors

This product is RoHS compliant.

Authorized Distributor

Specifications:

- Voltage rating: 250VAC
- Current rating: 4 Amp max.
- Low-level resistance: 5mΩ max. initial
- Operating temp.: -55°C to +105°C
- Dielectric withstanding Voltage: 750VAC/1Min.
- Insulation resistance: 5000MΩ min. initial
- Pre-loaded with contacts

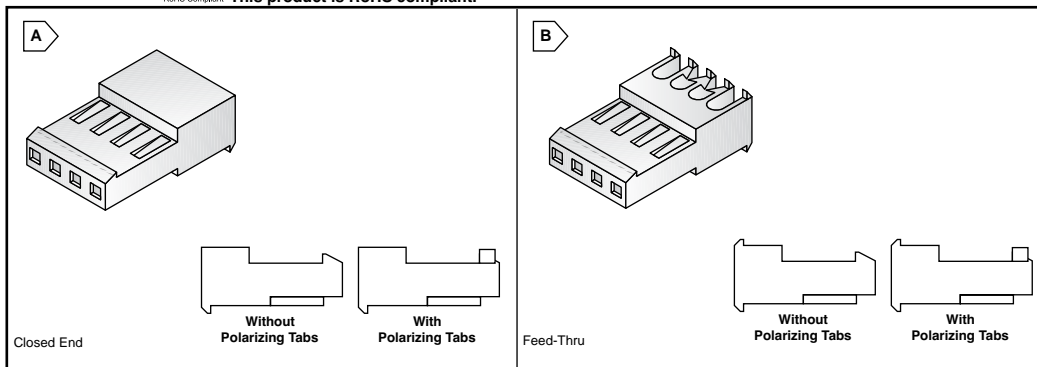

CLOSED END STYLE

* RoHS compliant per Tyco Electronics Documentation

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Number of Positions	Wire Size (AWG)	Color	Price Each		
						1	10	100
Closed End without Polarizing Tabs								
571-3-640440-2	3-640440-2	A	2	22	Red			
571-3-640440-3	3-640440-3	A	3	22	Red			
571-3-640440-4	3-640440-4	A	4	22	Red			
571-3-640440-5	3-640440-5	A	5	22	Red			
571-3-640440-6	3-640440-6	A	6	22	Red			
571-3-640440-7	3-640440-7	A	7	22	Red			
571-3-640440-8	3-640440-8	A	8	22	Red			
571-3-640440-9	3-640440-9	A	9	22	Red			
571-4-640440-0	4-640440-0	A	10	22	Red			
571-3-640441-2	3-640441-2	A	2	24	White			
571-3-640441-3	3-640441-3	A	3	24	White			
571-3-640441-4	3-640441-4	A	4	24	White			
571-3-640441-5	3-640441-5	A	5	24	White			
571-3-640441-6	3-640441-6	A	6	24	White			
571-3-640441-7	3-640441-7	A	7	24	White			
571-3-640441-8	3-640441-8	A	8	24	White			
571-3-640441-9	3-640441-9	A	9	24	White			
571-4-640441-0	4-640441-0	A	10	24	White			
571-3-640442-2	3-640442-2	A	2	26	Blue			
571-3-640442-3	3-640442-3	A	3	26	Blue			
571-3-640442-4	3-640442-4	A	4	26	Blue			
571-3-640442-5	3-640442-5	A	5	26	Blue			
571-3-640442-6	3-640442-6	A	6	26	Blue			
571-3-640442-7	3-640442-7	A	7	26	Blue			
571-3-640442-8	3-640442-8	A	8	26	Blue			
571-3-640442-9	3-640442-9	A	9	26	Blue			
571-4-640442-0	4-640442-0	A	10	26	Blue			
571-3-640443-2	3-640443-2	A	2	28	Green			
571-3-640443-3	3-640443-3	A	3	28	Green			
571-3-640443-4	3-640443-4	A	4	28	Green			
571-3-640443-5	3-640443-5	A	5	28	Green			
571-3-640443-6	3-640443-6	A	6	28	Green			
571-3-640443-7	3-640443-7	A	7	28	Green			
571-3-640443-8	3-640443-8	A	8	28	Green			
571-4-640443-0	4-640443-0	A	10	28	Green			

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Number of Positions	Wire Size (AWG)	Color	Price Each		
						1	10	100
Closed End with Polarizing Tabs								
571-3-643813-2	3-643813-2	A	2	22	Red			
571-3-643813-3	3-643813-3	A	3	22	Red			
571-3-643813-4	3-643813-4	A	4	22	Red			
571-3-643813-5	3-643813-5	A	5	22	Red			
571-3-643813-6	3-643813-6	A	6	22	Red			
571-3-643813-7	3-643813-7	A	7	22	Red			
571-3-643813-8	3-643813-8	A	8	22	Red			
571-3-643813-9	3-643813-9	A	9	22	Red			
571-4-643813-0	4-643813-0	A	10	22	Red			
571-3-643814-2	3-643814-2	A	2	24	White			
571-3-643814-3	3-643814-3	A	3	24	White			
571-3-643814-4	3-643814-4	A	4	24	White			
571-3-643814-5	3-643814-5	A	5	24	White			
571-3-643814-6	3-643814-6	A	6	24	White			
571-3-643814-7	3-643814-7	A	7	24	White			
571-3-643814-8	3-643814-8	A	8	24	White			
571-3-643814-9	3-643814-9	A	9	24	White			
571-4-643814-0	4-643814-0	A	10	24	White			
571-3-643815-2	3-643815-2	A	2	26	Blue			
571-3-643815-3	3-643815-3	A	3	26	Blue			
571-3-643815-4	3-643815-4	A	4	26	Blue			
571-3-643815-5	3-643815-5	A	5	26	Blue			
571-3-643815-6	3-643815-6	A	6	26	Blue			
571-3-643815-7	3-643815-7	A	7	26	Blue			
571-3-643815-8	3-643815-8	A	8	26	Blue			
571-3-643815-9	3-643815-9	A	9	26	Blue			
571-4-643815-0	4-643815-0	A	10	26	Blue			
571-3-643816-2	3-643816-2	A	2	28	Green			
571-3-643816-3	3-643816-3	A	3	28	Green			
571-3-643816-4	3-643816-4	A	4	28	Green			
571-3-643816-5	3-643816-5	A	5	28	Green			
571-3-643816-6	3-643816-6	A	6	28	Green			
571-3-643816-7	3-643816-7	A	7	28	Green			
571-3-643816-8	3-643816-8	A	8	28	Green			
571-4-643816-0	4-643816-0	A	10	28	Green			

FEED-THRU STYLE

* RoHS compliant per Tyco Electronics Documentation

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Number of Positions	Wire Size (AWG)	Color	Price Each		
						1	10	100
Feed-Thru without Polarizing Tabs								
571-3-640620-2	3-640620-2	B	2	22	Red			
571-3-640620-3	3-640620-3	B	3	22	Red			
571-3-640620-4	3-640620-4	B	4	22	Red			
571-3-640620-5	3-640620-5	B	5	22	Red			
571-3-640620-6	3-640620-6	B	6	22	Red			
571-3-640620-7	3-640620-7	B	7	22	Red			
571-3-640620-8	3-640620-8	B	8	22	Red			
571-3-640620-9	3-640620-9	B	9	22	Red			
571-4-640620-0	4-640620-0	B	10	22	Red			
571-3-640621-2	3-640621-2	B	2	24	White			
571-3-640621-3	3-640621-3	B	3	24	White			
571-3-640621-4	3-640621-4	B	4	24	White			
571-3-640621-5	3-640621-5	B	5	24	White			
571-3-640621-6	3-640621-6	B	6	24	White			
571-3-640621-8	3-640621-8	B	8	24	White			
571-4-640621-0	4-640621-0	B	10	24	White			
571-3-640622-2	3-640622-2	B	2	26	Blue			
571-3-640622-3	3-640622-3	B	3	26	Blue			
571-3-640622-4	3-640622-4	B	4	26	Blue			
571-3-640622-5	3-640622-5	B	5	26	Blue			
571-3-640622-6	3-640622-6	B	6	26	Blue			

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Number of Positions	Wire Size (AWG)	Color	Price Each		
						1	10	100
Feed-Thru without Polarizing Tabs (cont.)								
571-3-640622-8	3-640622-8	B	8	26	Blue			
571-3-640623-2	3-640623-2	B	2	28	Green			
571-3-640623-3	3-640623-3	B	3	28	Green			
571-3-640623-4	3-640623-4	B	4	28	Green			
571-3-640623-5	3-640623-5	B	5	28	Green			
571-3-640623-6	3-640623-6	B	6	28	Green			
Feed-Thru with Polarizing Tabs								
571-3-644540-2	3-644540-2	B	2	22	Red			
571-3-644540-3	3-644540-3	B	3	22	Red			
571-3-644540-4	3-644540-4	B	4	22	Red			
571-3-644540-5	3-644540-5	B	5	22	Red			
571-3-644540-6	3-644540-6	B	6	22	Red			
571-3-644540-8	3-644540-8	B	8	22	Red			
571-3-644563-2	3-644563-2	B	2	24	White			
571-3-644563-3	3-644563-3	B	3	24	White			
571-3-644563-4	3-644563-4	B	4	24	White			
571-3-644563-5	3-644563-5	B	5	24	White			
571-3-644563-6	3-644563-6	B	6	24	White			
571-3-644563-8	3-644563-8	B	8	24	White			
571-3-644563-9	3-644563-9	B	9	24	White			
571-3-644565-4	3-644565-4	B	4	28	Green			