

HARWIN L-Tek Connectors

HARWIN

 
L-TEK DATAMATE FEMALE PC TAIL CONNECTORS - VERTICAL

- Features:**
- Gold Plating
 - Fully Shrouded
 - Polarized Mouldings

For quantities of 50 and up, call for quote.


| MOUSER STOCK NO. | MOUSER NON-ROHS STOCK NO. | Harwin Part No. | Fig. | No. of Contacts | Price Each | | |
|-------------------|---------------------------|-----------------|------|-----------------|------------|----|----|
| | | | | | 1 | 10 | 25 |
| Single Row | | | | | | | |
| 855-M80-8400245 | 855-M80-8970205 | M80-8970205 | A | 2 | | | |
| 855-M80-8400445 | 855-M80-8970405 | M80-8970405 | A | 4 | | | |
| 855-M80-8400645 | 855-M80-8970605 | M80-8970605 | A | 6 | | | |
| Double Row | | | | | | | |
| 855-M80-8500445 | 855-M80-8870405 | M80-8870405 | A | 4 | | | |
| 855-M80-8500645 | 855-M80-8870605 | M80-8870605 | A | 6 | | | |
| 855-M80-8500845 | 855-M80-8870805 | M80-8870805 | A | 8 | | | |
| 855-M80-8501045 | 855-M80-8871005 | M80-8871005 | A | 10 | | | |
| 855-M80-8501245 | 855-M80-8871205 | M80-8871205 | A | 12 | | | |
| 855-M80-8501445 | 855-M80-8871405 | M80-8871405 | A | 14 | | | |
| 855-M80-8501645 | 855-M80-8871605 | M80-8871605 | A | 16 | | | |
| 855-M80-8502045 | 855-M80-8872005 | M80-8872005 | A | 20 | | | |
| 855-M80-8502645 | 855-M80-8872605 | M80-8872605 | A | 26 | | | |

3 AMP Four Finger Beryllium Copper Contact



Standard in all L & J Tek Female Connectors

A

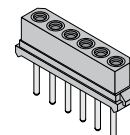

L-TEK DATAMATE FEMALE CRIMP CONNECTORS

- Features:**
- Gold Plating
 - Contacts included
 - Contacts rear insertable




RoHS Compliant


For quantities of 50 and up, call for quote.

| MOUSER STOCK NO. | Harwin Part No. | Fig. | No. of Contacts | AWG | Bore Size | Price Each | | |
|-----------------------------------|-----------------|------|-----------------|-------|-----------|------------|----|----|
| | | | | | | 1 | 10 | 25 |
| Single Row | | | | | | | | |
| 855-M80-8990205 | M80-8990205 | B | 2 | 22 | Large | | | |
| 855-M80-8990305 | M80-8990305 | B | 3 | 22 | Large | | | |
| 855-M80-8990405 | M80-8990405 | B | 4 | 22 | Large | | | |
| 855-M80-8990505 | M80-8990505 | B | 5 | 22 | Large | | | |
| 855-M80-8990605 | M80-8990605 | B | 6 | 22 | Large | | | |
| 855-M80-8990705 | M80-8990705 | B | 7 | 22 | Large | | | |
| 855-M80-8980205 | M80-8980205 | B | 2 | 24-28 | Small | | | |
| 855-M80-8980305 | M80-8980305 | B | 3 | 24-28 | Small | | | |
| 855-M80-8980405 | M80-8980405 | B | 4 | 24-28 | Small | | | |
| 855-M80-8980505 | M80-8980505 | B | 5 | 24-28 | Small | | | |
| 855-M80-8980605 | M80-8980605 | B | 6 | 24-28 | Small | | | |
| 855-M80-8980705 | M80-8980705 | B | 7 | 24-28 | Small | | | |
| Double Row | | | | | | | | |
| 855-M80-8890405 | M80-8890405 | B | 4 | 22 | Large | | | |
| 855-M80-8890605 | M80-8890605 | B | 6 | 22 | Large | | | |
| 855-M80-8890805 | M80-8890805 | B | 8 | 22 | Large | | | |
| 855-M80-8891005 | M80-8891005 | B | 10 | 22 | Large | | | |
| 855-M80-8891205 | M80-8891205 | B | 12 | 22 | Large | | | |
| 855-M80-8891405 | M80-8891405 | B | 14 | 22 | Large | | | |
| 855-M80-8891605 | M80-8891605 | B | 16 | 22 | Large | | | |
| 855-M80-8891805 | M80-8891805 | B | 18 | 22 | Large | | | |
| 855-M80-8892005 | M80-8892005 | B | 20 | 22 | Large | | | |
| 855-M80-8892605 | M80-8892605 | B | 26 | 22 | Large | | | |
| 855-M80-8893405 | M80-8893405 | B | 34 | 22 | Large | | | |
| 855-M80-8880405 | M80-8880405 | B | 4 | 24-28 | Small | | | |
| 855-M80-8880605 | M80-8880605 | B | 6 | 24-28 | Small | | | |
| 855-M80-8880805 | M80-8880805 | B | 8 | 24-28 | Small | | | |
| 855-M80-8881005 | M80-8881005 | B | 10 | 24-28 | Small | | | |
| 855-M80-8881205 | M80-8881205 | B | 12 | 24-28 | Small | | | |
| 855-M80-8881405 | M80-8881405 | B | 14 | 24-28 | Small | | | |
| 855-M80-8881605 | M80-8881605 | B | 16 | 24-28 | Small | | | |
| 855-M80-8881805 | M80-8881805 | B | 18 | 24-28 | Small | | | |
| 855-M80-8882005 | M80-8882005 | B | 20 | 24-28 | Small | | | |
| 855-M80-8882605 | M80-8882605 | B | 26 | 24-28 | Small | | | |
| 855-M80-8883405 | M80-8883405 | B | 34 | 24-28 | Small | | | |
| Spare Female Crimp Contact | | | | | | | | |
| 855-M80-0130005 | M80-0130005 | -- | -- | 24-28 | Small | | | |
| 855-M80-0110005 | M80-0110005 | -- | -- | 22 | Large | | | |

B

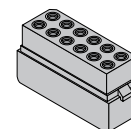

C

 

Harwin Rectangular Connectors

L-TEK HIGH RELIABILITY 2MM PRE-CRIMPED DATAMATE ASSEMBLIES WITH 18" LEADS

- Features:**
- Pre-assembled with 18" crimped leads inserted into the housing
 - Housings: Glass filled PPS UL94V-0, Black
 - Contact Plating: Gold
 - Current rating: 3.0 Amps
 - AWG: 26 and meets MIL-W-16878
 - Males supplied with Locking Latch
 - RoHS compliant per Harwin documentation
 - Different color wire for each contact




RoHS Compliant

For quantities of 50 and up, call for quote.

| MOUSER STOCK NO. | Harwin Part No. | Fig. | Contact Arrangement | Gender | Connector Housing | Lead Length | Price Each | | |
|------------------|-----------------|------|---------------------|--------|-------------------|-------------|------------|----|----|
| | | | | | | | 1 | 10 | 25 |
| 855-M80C108371C | M80C108371C | C | 2 x 2 | Female | 855-M80-8880405 | 18" | | | |
| 855-M80C108372C | M80C108372C | C | 2 x 4 | Female | 855-M80-8880805 | 18" | | | |
| 855-M80C108373C | M80C108373C | C | 2 x 5 | Female | 855-M80-8881005 | 18" | | | |
| 855-M80C108374C | M80C108374C | C | 2 x 6 | Female | 855-M80-8881205 | 18" | | | |
| 855-M80C108367C | M80C108367C | D | 2 x 2 | Male | 855-M80-8120405 | 18" | | | |
| 855-M80C108368C | M80C108368C | D | 2 x 4 | Male | 855-M80-8120805 | 18" | | | |
| 855-M80C108370C | M80C108370C | D | 2 x 6 | Male | 855-M80-8121205 | 18" | | | |

 D



DATAMATE TOOLS

For quantities of 5 and up, call for quote.

| MOUSER STOCK NO. | Harwin Part No. | Description | Price Each |
|------------------|-----------------|--------------------------|------------|
| 855-M22520/2-01 | M22520/2-01 | Crimp Tool | |
| 855-T5747 | T5747 | Positioner | |
| 855-T5746 | T5746 | Separator Tool | |
| 855-Z80-280 | Z80-280 | Insertion / Removal Tool | |