

HIROSE Wire-to-Board Connectors



HIROSE ELECTRIC CO., LTD.


DF13 SERIES- 1.25MM MINIATURE CRIMPING CONNECTORS

This product is RoHS compliant.

Housings-Single Row

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Positions	Dimensions: mm		Price Each		
				A	B	1	25	100
Crimp Receptacle Housings - Single Row								
798-DF13-2S-1.25C	DF13-2S-1.25C	A	2	4.15	1.25			
798-DF13-3S-1.25C	DF13-3S-1.25C	A	3	5.40	2.50			
798-DF13-4S-1.25C	DF13-4S-1.25C	A	4	6.65	3.75			
798-DF13-5S-1.25C	DF13-5S-1.25C	A	5	7.90	5.00			
798-DF13-6S-1.25C	DF13-6S-1.25C	A	6	9.15	6.25			
798-DF13-7S-1.25C	DF13-7S-1.25C	A	7	10.40	7.50			
798-DF13-8S-1.25C	DF13-8S-1.25C	A	8	11.65	8.75			
798-DF13-9S-1.25C	DF13-9S-1.25C	A	9	12.90	10.00			
798-DF13-10S-1.25C	DF13-10S-1.25C	A	10	14.15	11.25			
798-DF13-12S-1.25C	DF13-12S-1.25C	A	12	16.65	13.75			
798-DF13-14S-1.25C	DF13-14S-1.25C	A	14	19.15	16.25			
798-DF1315S125C	DF13-15S-1.25C	A	15	20.40	17.50			

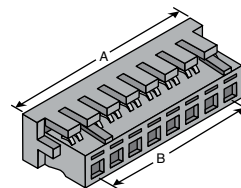


Headers-Single Row


For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Positions	Dimensions: mm		Price Each		
				A	B	1	25	100
Single Row - Vertical - Tin - Thru Hole - With Boss								
798-DF13-2P-1.25DSA	DF13-2P-1.25DSA	B	2	4.15	1.25			
798-DF13-3P-1.25DSA	DF13-3P-1.25DSA	B	3	5.40	2.50			
798-DF13-4P-1.25DSA	DF13-4P-1.25DSA	B	4	6.65	3.75			
798-DF13-5P-1.25DSA	DF13-5P-1.25DSA	B	5	7.90	5.00			
798-DF13-6P-1.25DSA	DF13-6P-1.25DSA	B	6	9.15	6.25			
798-DF13-7P-1.25DSA	DF13-7P-1.25DSA	B	7	10.40	7.50			
798-DF13-8P-1.25DSA	DF13-8P-1.25DSA	B	8	11.65	8.75			
798-DF13-9P-1.25DSA	DF13-9P-1.25DSA	B	9	12.90	10.00			
798-DF139P125DSA20	DF13-9P-1.25DSA(20)	B	9	12.90	10.00			
798-DF13-10P-1.25DSA	DF13-10P-1.25DSA	B	10	14.15	11.25			
798-DF13-11P-1.25DSA	DF13-11P-1.25DSA	B	11	15.40	12.50			
798-DF13-12P-1.25DSA	DF13-12P-1.25DSA	B	12	16.65	13.75			
798-DF13-13P-1.25DSA	DF13-13P-1.25DSA	B	13	17.90	15.00			
798-DF13-14P-1.25DSA	DF13-14P-1.25DSA	B	14	19.15	16.25			
798-DF13-15P-1.25DSA	DF13-15P-1.25DSA	B	15	20.40	17.50			
Single Row - Vertical - Gold - Thru Hole - With Boss								
798-DF132P125DSA50	DF13-2P-1.25DSA(50)	C	2	4.15	1.25			
798-DF134P125DSA50	DF13-4P-1.25DSA(50)	C	4	6.65	3.75			
798-DF135P125DSA50	DF13-5P-1.25DSA(50)	C	5	7.90	5.00			
798-DF136P125DSA50	DF13-6P-1.25DSA(50)	C	6	9.15	6.25			
798-DF138P125DSA50	DF13-8P-1.25DSA(50)	C	8	11.65	8.75			
Single Row - Right Angle - Tin - Thru Hole - With Boss								
798-DF13-2P-1.25DS20	DF13-2P-1.25DS(20)	C	2	4.15	1.25			
798-DF13-3P-1.25DS20	DF13-3P-1.25DS(20)	C	3	5.40	2.50			
798-DF13-4P-1.25DS20	DF13-4P-1.25DS(20)	C	4	6.65	3.75			
798-DF13-5P-1.25DS20	DF13-5P-1.25DS(20)	C	5	7.90	5.00			
798-DF13-6P-1.25DS20	DF13-6P-1.25DS(20)	C	6	9.15	6.25			
798-DF13-7P-1.25DS20	DF13-7P-1.25DS(20)	C	7	10.40	7.50			
798-DF13-8P-1.25DS20	DF13-8P-1.25DS(20)	C	8	11.65	8.75			
798-DF13-9P-1.25DS20	DF13-9P-1.25DS(20)	C	9	12.90	10.00			
798-DF13-10P-1.25DS20	DF13-10P-1.25DS(20)	C	10	14.15	11.25			
798-DF13-11P-1.25DS20	DF13-11P-1.25DS(20)	C	11	15.40	12.50			
798-DF13-12P-1.25DS20	DF13-12P-1.25DS(20)	C	12	16.65	13.75			
798-DF13-14P-1.25DS20	DF13-14P-1.25DS(20)	C	14	19.15	16.25			
798-DF13-15P-1.25DS20	DF13-15P-1.25DS(20)	C	15	20.40	17.50			
Single Row - Right Angle - Gold - Thru Hole - With Boss								
798-DF132P125DS50	DF13-2P-1.25DS(50)	C	2	4.15	1.25			
798-DF134P125DS50	DF13-4P-1.25DS(50)	C	4	6.65	3.75			
798-DF135P125DS50	DF13-5P-1.25DS(50)	C	5	7.90	5.00			
798-DF138P125DS50	DF13-8P-1.25DS(50)	C	8	11.65	8.75			
Single Row - Vertical - Tin - SMT - With Boss								
798-DF135P125V20	DF13-5P-1.25V(20)	D	5	10.90	5.00			
798-DF136P125V20	DF13-6P-1.25V(20)	D	6	9.15	6.25			
798-DF137P125V20	DF13-7P-1.25V(20)	D	7	13.40	7.50			
798-DF138P125V20	DF13-8P-1.25V(20)	D	8	14.65	8.75			
798-DF139P125V20	DF13-9P-1.25V(20)	D	9	15.90	10.00			
798-DF1312P125V20	DF13-12P-1.25V(20)	D	12	19.65	13.75			
798-DF1315P125V20	DF13-15P-1.25V(20)	D	15	20.40	17.50			
798-DF13B4P125V20	DF13B-4P-1.25V(20)	D	4	9.65	3.75			
Single Row - Vertical - Tin - SMT - Without Boss								
798-DF13C2P125V20	DF13C-2P-1.25V(20)	D	2	7.15	1.25			
798-DF13C-2P-1.25V21	DF13C-2P-1.25V(21)	D	2	7.15	1.25			
798-DF13C3P125V20	DF13C-3P-1.25V(20)	D	3	8.40	2.50			
798-DF13C-3P-1.25V21	DF13C-3P-1.25V(21)	D	3	8.40	2.50			
798-DF13C-4P-1.25V21	DF13C-4P-1.25V(21)	D	4	9.65	3.75			
798-DF13C5P125V20	DF13C-5P-1.25V(20)	D	5	10.90	5.00			
798-DF13C-5P-1.25V21	DF13C-5P-1.25V(21)	D	5	10.90	5.00			
798-DF13C6P125V20	DF13C-6P-1.25V(20)	D	6	12.15	6.25			
798-DF13C-6P-1.25V21	DF13C-6P-1.25V(21)	D	6	12.15	6.25			
798-DF13C-7P-1.25V21	DF13C-7P-1.25V(21)	D	7	13.40	7.50			
798-DF13C8P125V20	DF13C-8P-1.25V(20)	D	8	14.65	8.75			
798-DF13C-8P-1.25V21	DF13C-8P-1.25V(21)	D	8	14.65	8.75			
798-DF13C-9P-1.25V21	DF13C-9P-1.25V(21)	D	9	15.90	10.00			
798-DF13C10P125V20	DF13C-10P-1.25V(20)	D	10	17.15	11.25			
798-DF13C-10P-1.25V21	DF13C-10P-1.25V(21)	D	10	17.15	11.25			
798-DF13C-11P-1.25V21	DF13C-11P-1.25V(21)	D	11	18.40	12.50			
798-DF13C-12P-1.25V21	DF13C-12P-1.25V(21)	D	12	19.65	13.75			
798-DF13C14P125V20	DF13C-14P-1.25V(20)	D	14	22.15	16.25			
798-DF13C-14P-1.25V21	DF13C-14P-1.25V(21)	D	14	22.15	16.25			
798-DF13C-15P-1.25V21	DF13C-15P-1.25V(21)	D	15	23.40	17.50			
Single Row - Vertical - Gold - SMT - With Boss								
798-DF133P125V50	DF13-3P-1.25V(50)	D	3	8.40	2.50			
798-DF134P125V50	DF13-4P-1.25V(50)	D	4	9.65	3.75			
798-DF135P125V50	DF13-5P-1.25V(50)	D	5	10.90	5.00			
798-DF137P125V50	DF13-7P-1.25V(50)	D	7	13.40	7.50			
798-DF138P125V50	DF13-8P-1.25V(50)	D	8	14.65	8.75			
798-DF139P125V50	DF13-9P-1.25V(50)	D	9	15.90	10.00			
798-DF1310P125V50	DF13-10P-1.25V(50)	D	10	17.15	11.25			
798-DF1312P125V50	DF13-12P-1.25V(50)	D	12	19.65	13.75			


B

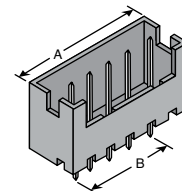

C

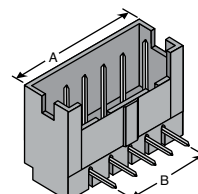

D

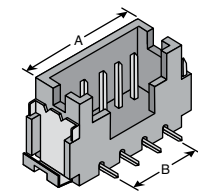

NEW FROM HIROSE

Rectangular Connectors

Hirose

NEW FROM HIROSE

NEW FROM HIROSE