


HIROSE 2.00mm Double Row Connectors



HIROSE ELECTRIC CO., LTD.

This product is RoHS compliant.

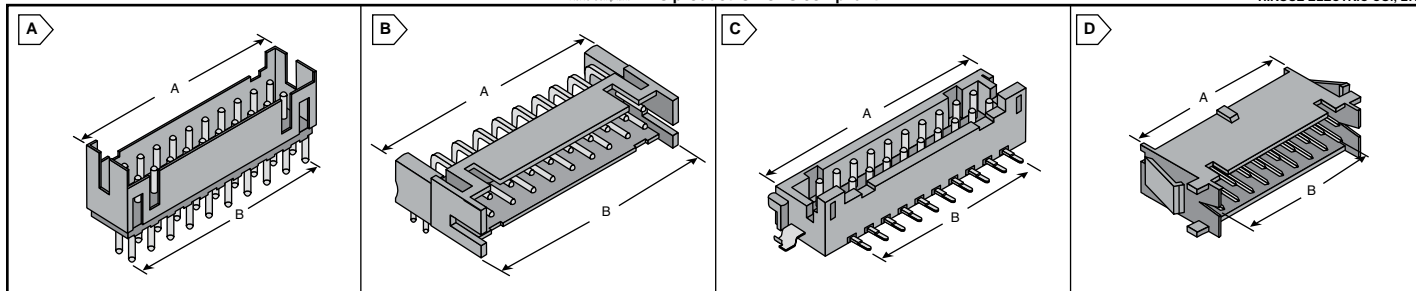

DF11 SERIES DOUBLE ROW CONNECTORS

Headers

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Circuits	Dim.		Price Each		
				A	B	1	25	100
Vertical - Tin - Thru-Hole								
798-DF11-4DP-2DSA08	DF11-4DP-2DSA(08)	A	4	6	2			
798-DF11-4DP-2DSA24	DF11-4DP-2DSA(24)	A	4	6	2			
798-DF11-6DP-2DSA08	DF11-6DP-2DSA(08)	A	6	8	4			
798-DF11-6DP-2DSA24	DF11-6DP-2DSA(24)	A	6	8	4			
798-DF11-8DP-2DSA08	DF11-8DP-2DSA(08)	A	8	10	6			
798-DF11-8DP-2DSA24	DF11-8DP-2DSA(24)	A	8	10	6			
798-DF11-10DP-2DSA08	DF11-10DP-2DSA(08)	A	10	12	8			
798-DF11-10DP-2DSA24	DF11-10DP-2DSA(24)	A	10	12	8			
798-DF11-12DP-2DSA08	DF11-12DP-2DSA(08)	A	12	14	10			
798-DF11-12DP-2DSA24	DF11-12DP-2DSA(24)	A	12	14	10			
798-DF11-14DP-2DSA08	DF11-14DP-2DSA(08)	A	14	16	12			
798-DF11-14DP-2DSA24	DF11-14DP-2DSA(24)	A	14	16	12			
798-DF11-16DP-2DSA08	DF11-16DP-2DSA(08)	A	16	18	14			
798-DF11-16DP-2DSA24	DF11-16DP-2DSA(24)	A	16	18	14			
798-DF11-18DP-2DSA08	DF11-18DP-2DSA(08)	A	18	20	16			
798-DF11-18DP-2DSA24	DF11-18DP-2DSA(24)	A	18	20	16			
798-DF11-20DP-2DSA08	DF11-20DP-2DSA(08)	A	20	22	18			
798-DF11-20DP-2DSA24	DF11-20DP-2DSA(24)	A	20	22	18			
798-DF11-22DP-2DSA08	DF11-22DP-2DSA(08)	A	22	24	20			
798-DF11-22DP-2DSA24	DF11-22DP-2DSA(24)	A	22	24	20			
798-DF11-24DP-2DSA08	DF11-24DP-2DSA(08)	A	24	26	22			
798-DF11-24DP-2DSA24	DF11-24DP-2DSA(24)	A	24	26	22			
798-DF11-26DP-2DSA08	DF11-26DP-2DSA(08)	A	26	28	24			
798-DF11-26DP-2DSA24	DF11-26DP-2DSA(24)	A	26	28	24			
798-DF11-28DP-2DSA08	DF11-28DP-2DSA(08)	A	28	30	26			
798-DF11-28DP-2DSA24	DF11-28DP-2DSA(24)	A	28	30	26			
798-DF11-30DP-2DSA08	DF11-30DP-2DSA(08)	A	30	32	28			
798-DF11-30DP-2DSA24	DF11-30DP-2DSA(24)	A	30	32	28			
798-DF11-32DP-2DSA08	DF11-32DP-2DSA(08)	A	32	34	30			
798-DF11-32DP-2DSA24	DF11-32DP-2DSA(24)	A	32	34	30			
Vertical - Gold - Thru-Hole								
798-DF11-4DP-2DSA01	DF11-4DP-2DSA(01)	A	4	6	2			
798-DF11-6DP-2DSA01	DF11-6DP-2DSA(01)	A	6	8	4			
798-DF11-8DP-2DSA01	DF11-8DP-2DSA(01)	A	8	10	6			
798-DF11-10DP-2DSA01	DF11-10DP-2DSA(01)	A	10	12	8			
798-DF11-12DP-2DSA01	DF11-12DP-2DSA(01)	A	12	14	10			
798-DF11-14DP-2DSA01	DF11-14DP-2DSA(01)	A	14	16	12			
798-DF11-16DP-2DSA01	DF11-16DP-2DSA(01)	A	16	18	14			
798-DF11-18DP-2DSA01	DF11-18DP-2DSA(01)	A	18	20	16			
798-DF11-20DP-2DSA01	DF11-20DP-2DSA(01)	A	20	22	18			
798-DF11-22DP-2DSA01	DF11-22DP-2DSA(01)	A	22	24	20			
798-DF11-24DP-2DSA01	DF11-24DP-2DSA(01)	A	24	26	22			
798-DF11-26DP-2DSA01	DF11-26DP-2DSA(01)	A	26	28	24			
798-DF11-28DP-2DSA01	DF11-28DP-2DSA(01)	A	28	30	26			
798-DF11-30DP-2DSA01	DF11-30DP-2DSA(01)	A	30	32	28			
798-DF11-32DP-2DSA01	DF11-32DP-2DSA(01)	A	32	34	30			
Right Angle - Tin - Thru-Hole								
798-DF11-4DP-2DS24	DF11-4DP-2DS(24)	B	4	6	2			
798-DF11-6DP-2DS24	DF11-6DP-2DS(24)	B	6	8	4			
798-DF11-8DP-2DS24	DF11-8DP-2DS(24)	B	8	10	6			
798-DF11-10DP-2DS24	DF11-10DP-2DS(24)	B	10	12	8			
798-DF11-12DP-2DS24	DF11-12DP-2DS(24)	B	12	14	10			
798-DF11-14DP-2DS24	DF11-14DP-2DS(24)	B	14	16	12			
798-DF11-16DP-2DS24	DF11-16DP-2DS(24)	B	16	18	14			
798-DF11-18DP-2DS24	DF11-18DP-2DS(24)	B	18	20	16			
798-DF11-20DP-2DS24	DF11-20DP-2DS(24)	B	20	22	18			
798-DF11-22DP-2DS24	DF11-22DP-2DS(24)	B	22	24	20			
798-DF11-24DP-2DS24	DF11-24DP-2DS(24)	B	24	26	22			
798-DF11-26DP-2DS24	DF11-26DP-2DS(24)	B	26	28	24			
798-DF11-28DP-2DS24	DF11-28DP-2DS(24)	B	28	30	26			
798-DF11-30DP-2DS24	DF11-30DP-2DS(24)	B	30	32	28			
798-DF11-32DP-2DS24	DF11-32DP-2DS(24)	B	32	34	30			

Headers (Cont.)

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Circuits	Dim.		Price Each		
				A	B	1	25	100
Right Angle - Gold - Thru-Hole								
798-DF11-4DP-2DS52	DF11-4DP-2DS(52)	B	4	6	2			
798-DF11-6DP-2DS52	DF11-6DP-2DS(52)	B	6	8	4			
798-DF11-8DP-2DS52	DF11-8DP-2DS(52)	B	8	10	6			
798-DF11-10DP-2DS52	DF11-10DP-2DS(52)	B	10	12	8			
798-DF11-12DP-2DS52	DF11-12DP-2DS(52)	B	12	14	10			
798-DF11-14DP-2DS52	DF11-14DP-2DS(52)	B	14	16	12			
798-DF11-16DP-2DS52	DF11-16DP-2DS(52)	B	16	18	14			
798-DF11-18DP-2DS52	DF11-18DP-2DS(52)	B	18	20	16			
798-DF11-20DP-2DS52	DF11-20DP-2DS(52)	B	20	22	18			
798-DF11-22DP-2DS52	DF11-22DP-2DS(52)	B	22	24	20			
798-DF11-24DP-2DS52	DF11-24DP-2DS(52)	B	24	26	22			
798-DF11-26DP-2DS52	DF11-26DP-2DS(52)	B	26	28	24			
798-DF11-28DP-2DS52	DF11-28DP-2DS(52)	B	28	30	26			
798-DF11-30DP-2DS52	DF11-30DP-2DS(52)	B	30	32	28			
798-DF11-32DP-2DS52	DF11-32DP-2DS(52)	B	32	34	30			
Vertical - Tin - SMT								
798-DF11GZ-4DP-2V20	DF11GZ-4DP-2V(20)	C	4	8.5	2			
798-DF11GZ-6DP-2V20	DF11GZ-6DP-2V(20)	C	6	10.5	4			
798-DF11GZ-8DP-2V20	DF11GZ-8DP-2V(20)	C	8	12.5	6			
798-DF11GZ-10DP-2V20	DF11GZ-10DP-2V(20)	C	10	14.5	8			
798-DF11GZ-12DP-2V20	DF11GZ-12DP-2V(20)	C	12	16.5	10			
798-DF11GZ-14DP-2V20	DF11GZ-14DP-2V(20)	C	14	18.5	12			
798-DF11GZ-16DP-2V20	DF11GZ-16DP-2V(20)	C	16	20.5	14			
798-DF11GZ-18DP-2V20	DF11GZ-18DP-2V(20)	C	18	22.5	16			
798-DF11GZ-20DP-2V20	DF11GZ-20DP-2V(20)	C	20	24.5	18			
798-DF11GZ-22DP-2V20	DF11GZ-22DP-2V(20)	C	22	26.5	20			
798-DF11GZ-24DP-2V20	DF11GZ-24DP-2V(20)	C	24	28.5	22			
798-DF11GZ-26DP-2V20	DF11GZ-26DP-2V(20)	C	26	30.5	24			
798-DF11GZ-28DP-2V20	DF11GZ-28DP-2V(20)	C	28	32.5	26			
798-DF11GZ-30DP-2V20	DF11GZ-30DP-2V(20)	C	30	34.5	28			
798-DF11GZ-32DP-2V20	DF11GZ-32DP-2V(20)	C	32	36.5	30			
798-DF11GZ-40DP-2V20	DF11GZ-40DP-2V(20)	C	40	44.5	38			
Vertical - Gold - SMT								
798-DF11G-4DP-2V50	DF11G-4DP-2V(50)	C	4	8.5	2			
798-DF11G-6DP-2V50	DF11G-6DP-2V(50)	C	6	10.5	4			
798-DF11G-8DP-2V50	DF11G-8DP-2V(50)	C	8	12.5	6			
798-DF11G-10DP-2V50	DF11G-10DP-2V(50)	C	10	14.5	8			
798-DF11G-12DP-2V50	DF11G-12DP-2V(50)	C	12	16.5	10			
798-DF11G-14DP-2V50	DF11G-14DP-2V(50)	C	14	18.5	12			
798-DF11G-16DP-2V50	DF11G-16DP-2V(50)	C	16	20.5	14			
798-DF11G-18DP-2V50	DF11G-18DP-2V(50)	C	18	22.5	16			
798-DF11G-20DP-2V50	DF11G-20DP-2V(50)	C	20	24.5	18			
798-DF11G-22DP-2V50	DF11G-22DP-2V(50)	C	22	26.5	20			
798-DF11G-24DP-2V50	DF11G-24DP-2V(50)	C	24	28.5	22			
798-DF11G-26DP-2V50	DF11G-26DP-2V(50)	C	26	30.5	24			
798-DF11G-28DP-2V50	DF11G-28DP-2V(50)	C	28	32.5	26			
798-DF11G-30DP-2V50	DF11G-30DP-2V(50)	C	30	34.5	28			
798-DF11G-32DP-2V50	DF11G-32DP-2V(50)	C	32	36.5	30			
798-DF11G-40DP-2V50	DF11G-40DP-2V(50)	C	40	44.5	38			
Adapter - Male-Male - Panel Locks								
798-DF11-4DEP-2A	DF11-4DEP-2A	D	4	11	2			
798-DF11-6DEP-2A	DF11-6DEP-2A	D	6	13	4			
798-DF11-8DEP-2A	DF11-8DEP-2A	D	8	15	6			
798-DF11-10DEP-2A	DF11-10DEP-2A	D	10	17	8			
798-DF11-12DEP-2A	DF11-12DEP-2A	D	12	19	10			
798-DF11-14DEP-2A	DF11-14DEP-2A	D	14	21	12			
798-DF11-16DEP-2A	DF11-16DEP-2A	D	16	23	14			
798-DF11-18DEP-2A	DF11-18DEP-2A	D	18	25	16			
798-DF11-20DEP-2A	DF11-20DEP-2A	D	20	27	18			
798-DF11-22DEP-2A	DF11-22DEP-2A	D	22	29	20			
798-DF11-24DEP-2A	DF11-24DEP-2A	D	24	31	22			
798-DF11-26DEP-2A	DF11-26DEP-2A	D	26	33	24			
798-DF11-28DEP-2A	DF11-28DEP-2A	D	28	35	26			
798-DF11-30DEP-2A	DF11-30DEP-2A	D	30	37	28			
798-DF11-32DEP-2A	DF11-32DEP-2A							