


# HIROSE 2.0mm for Double Row Connections



HIROSE ELECTRIC CO., LTD.

RoHS Compliant This product is RoHS compliant.

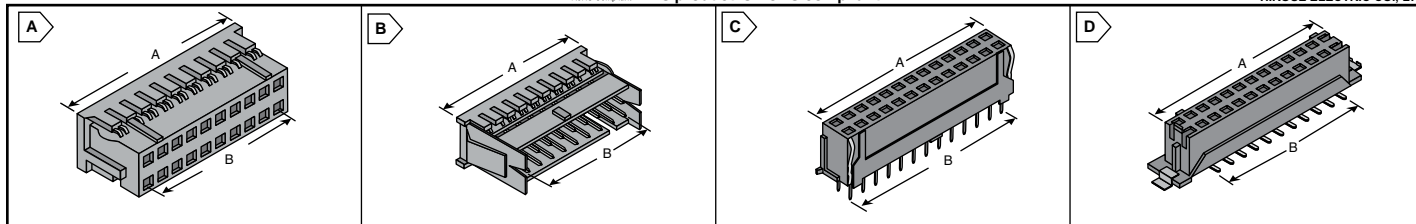

## DF11 SERIES DOUBLE ROW CONNECTORS

### Housings

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Circuits	Dim.		Price Each		
				A	B	1	25	100
<b>Crimp Receptacle Housings</b>								
798-DF11-4DS-2C	DF11-4DS-2C	A	4	6	2			
798-DF11-6DS-2C	DF11-6DS-2C	A	6	8	4			
798-DF11-8DS-2C	DF11-8DS-2C	A	8	10	6			
798-DF11-10DS-2C	DF11-10DS-2C	A	10	12	8			
798-DF11-12DS-2C	DF11-12DS-2C	A	12	14	10			
798-DF11-14DS-2C	DF11-14DS-2C	A	14	16	12			
798-DF11-16DS-2C	DF11-16DS-2C	A	16	18	14			
798-DF11-18DS-2C	DF11-18DS-2C	A	18	20	16			
798-DF11-20DS-2C	DF11-20DS-2C	A	20	22	18			
798-DF11-22DS-2C	DF11-22DS-2C	A	22	24	20			
798-DF11-24DS-2C	DF11-24DS-2C	A	24	26	22			
798-DF11-26DS-2C	DF11-26DS-2C	A	26	28	24			
798-DF11-28DS-2C	DF11-28DS-2C	A	28	30	26			
798-DF11-30DS-2C	DF11-30DS-2C	A	30	32	28			
798-DF11-32DS-2C	DF11-32DS-2C	A	32	34	30			
<b>Crimp Plug Housings</b>								
798-DF11-4DEP-2C	DF11-4DEP-2C	B	4	11	2			
798-DF11-6DEP-2C	DF11-6DEP-2C	B	6	13	4			
798-DF11-8DEP-2C	DF11-8DEP-2C	B	8	15	6			
798-DF11-10DEP-2C	DF11-10DEP-2C	B	10	17	8			
798-DF11-12DEP-2C	DF11-12DEP-2C	B	12	19	10			
798-DF11-14DEP-2C	DF11-14DEP-2C	B	14	21	12			
798-DF11-16DEP-2C	DF11-16DEP-2C	B	16	23	14			
798-DF11-18DEP-2C	DF11-18DEP-2C	B	18	25	16			
798-DF11-20DEP-2C	DF11-20DEP-2C	B	20	27	18			
798-DF11-22DEP-2C	DF11-22DEP-2C	B	22	29	20			
798-DF11-24DEP-2C	DF11-24DEP-2C	B	24	31	22			
798-DF11-26DEP-2C	DF11-26DEP-2C	B	26	33	24			
798-DF11-28DEP-2C	DF11-28DEP-2C	B	28	35	26			
798-DF11-30DEP-2C	DF11-30DEP-2C	B	30	37	28			
798-DF11-32DEP-2C	DF11-32DEP-2C	B	32	39	30			

### Crimp Contacts

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	Plating	AWG	Price Each		
					1	25	100
<b>Female</b>							
798-DF11-22SC	DF11-22SC	-	Tin	22			
798-DF11-2428SC	DF11-2428SC	-	Tin	24-28			
798-DF11-30SC	DF11-30SC	-	Tin	30			
798-DF11-22SCA	DF11-22SCA	-	Gold	22			
798-DF11-2428SCA	DF11-2428SCA	-	Gold	24-28			
798-DF11-30SCA	DF11-30SCA	-	Gold	30			
<b>Male</b>							
798-DF11-EP2428PC	DF11-EP2428PC	-	Tin	24-28			
798-DF11-EP2428PCA	DF11-EP2428PCA	-	Gold	24-28			

### Crimp Contacts (Reels)

MOUSER STOCK NO.	Hirose Part No.	Fig.	Plating	AWG	Reel Qty.	Price Each
798-DF11-22SCF	DF11-22SCF	-	Tin	22	10000	
798-DF11-2428SCF	DF11-2428SCF	-	Tin	24-28	10000	
798-DF11-30SCF	DF11-30SCF	-	Tin	30	10000	
798-DF11-22SCFA	DF11-22SCFA	-	Gold	22	10000	
798-DF11-2428SCFA	DF11-2428SCFA	-	Gold	24-28	10000	
798-DF11-2428SCFA04	DF11-2428SCFA(04)	-	Gold	24-28	10000	
798-DF11-30SCFA	DF11-30SCFA	-	Gold	30	10000	
<b>Male</b>						
798-DF11-EP2428PCF	DF11-EP2428PCF	-	Tin	24-28	10000	
798-DF11-EP2428PCFA	DF11-EP2428PCFA	-	Gold	24-28	10000	

### Crimp Contacts (Tooling)

For quantities of 5 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Description	Price Each
798-DF11EPTA2428HCUS	DF11EP-TA2428HC/US	Tool w/Die 24-28AWG Male	
798-DF11TA2428HC	DF11-TA2428HC	Tool w/Die 24-28 AWG	
798-DF11-TA30HC	DF11-TA30HC	Tool 30AWG Fem	

### Receptacles

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Circuits	Dim.		Price Each		
				A	B	1	25	100
<b>PCB Receptacles - Vertical - Tin - Thru-Hole</b>								
798-DF11-6DS-2DSA05	DF11-6DS-2DSA(05)	C	6	8	4			
798-DF11-8DS-2DSA05	DF11-8DS-2DSA(05)	C	8	10	6			
798-DF11-10DS-2DSA05	DF11-10DS-2DSA(05)	C	10	12	8			
798-DF11-12DS-2DSA05	DF11-12DS-2DSA(05)	C	12	14	10			
798-DF11-14DS-2DSA05	DF11-14DS-2DSA(05)	C	14	16	12			
798-DF11-16DS-2DSA05	DF11-16DS-2DSA(05)	C	16	18	14			
798-DF11-18DS-2DSA05	DF11-18DS-2DSA(05)	C	18	20	16			
798-DF11-20DS-2DSA05	DF11-20DS-2DSA(05)	C	20	22	18			
798-DF11-22DS-2DSA05	DF11-22DS-2DSA(05)	C	22	24	20			
798-DF11-24DS-2DSA05	DF11-24DS-2DSA(05)	C	24	26	22			
798-DF11-26DS-2DSA05	DF11-26DS-2DSA(05)	C	26	28	24			
798-DF11-28DS-2DSA05	DF11-28DS-2DSA(05)	C	28	30	26			
798-DF11-32DS-2DSA05	DF11-32DS-2DSA(05)	C	32	34	30			
<b>PCB Receptacles - Vertical - Gold - Thru-Hole</b>								
798-DF11-6DS-2DSA06	DF11-6DS-2DSA(06)	C	6	8	4			
798-DF11-8DS-2DSA06	DF11-8DS-2DSA(06)	C	8	10	6			
798-DF11-10DS-2DSA06	DF11-10DS-2DSA(06)	C	10	12	8			
798-DF11-12DS-2DSA06	DF11-12DS-2DSA(06)	C	12	14	10			
798-DF11-14DS-2DSA06	DF11-14DS-2DSA(06)	C	14	16	12			
798-DF11-16DS-2DSA06	DF11-16DS-2DSA(06)	C	16	18	14			
798-DF11-18DS-2DSA06	DF11-18DS-2DSA(06)	C	18	20	16			
798-DF11-20DS-2DSA06	DF11-20DS-2DSA(06)	C	20	22	18			
798-DF11-24DS-2DSA06	DF11-24DS-2DSA(06)	C	24	26	22			
798-DF11-26DS-2DSA06	DF11-26DS-2DSA(06)	C	26	28	24			
798-DF11-32DS-2DSA06	DF11-32DS-2DSA(06)	C	32	34	30			
<b>PCB Receptacles - Vertical - Tin - SMT</b>								
798-DF11Z-4DS-2V20	DF11Z-4DS-2V(20)	D	4	8.5	2			
798-DF11Z-6DS-2V20	DF11Z-6DS-2V(20)	D	6	10.5	4			
798-DF11Z-8DS-2V20	DF11Z-8DS-2V(20)	D	8	12.5	6			
798-DF11Z-10DS-2V20	DF11Z-10DS-2V(20)	D	10	14.5	8			
798-DF11Z-12DS-2V20	DF11Z-12DS-2V(20)	D	12	16.5	10			
798-DF11Z-14DS-2V20	DF11Z-14DS-2V(20)	D	14	18.5	12			
798-DF11Z-16DS-2V20	DF11Z-16DS-2V(20)	D	16	20.5	14			
798-DF11Z-20DS-2V20	DF11Z-20DS-2V(20)	D	20	24.5	18			
798-DF11Z-22DS-2V20	DF11Z-22DS-2V(20)	D	22	26.5	20			
798-DF11Z-24DS-2V20	DF11Z-24DS-2V(20)	D	24	28.5	22			
798-DF11Z-26DS-2V20	DF11Z-26DS-2V(20)	D	26	30.5	24			
798-DF11Z-28DS-2V20	DF11Z-28DS-2V(20)	D	28	32.5	26			
798-DF11Z-30DS-2V20	DF11Z-30DS-2V(20)	D	30	34.5	28			
798-DF11Z-32DS-2V20	DF11Z-32DS-2V(20)	D	32	34	30			
798-DF11Z-40DS-2V20	DF11Z-40DS-2V(20)	D	40	44.5	38			
<b>PCB Receptacles - Vertical - Gold - SMT</b>								
798-DF11Z-4DS-2V50	DF11Z-4DS-2V(50)	D	4	8.5	2			
798-DF11Z-6DS-2V50	DF11Z-6DS-2V(50)	D	6	10.5	4			
798-DF11Z-8DS-2V50	DF11Z-8DS-2V(50)	D	8	12.5	6			
798-DF11Z-10DS-2V50	DF11Z-10DS-2V(50)	D	10	14.5	8			
798-DF11Z-12DS-2V50	DF11Z-12DS-2V(50)	D	12	16.5	10			
798-DF11Z-14DS-2V50	DF11Z-14DS-2V(50)	D	14	18.5	12			
798-DF11Z-16DS-2V50	DF11Z-16DS-2V(50)	D	16	20.5	14			
798-DF11Z-18DS-2V50	DF11Z-18DS-2V(50)	D	18	22.5	16			
798-DF11Z-20DS-2V50	DF11Z-20DS-2V(50)	D	20	24.5	18			
798-DF11Z-22DS-2V50	DF11Z-22DS-2V(50)	D	22	26.5	20			
798-DF11Z-24DS-2V50	DF11Z-24DS-2V(50)	D	24	28.5	22			
798-DF11Z-26DS-2V50	DF11Z-26DS-2V(50)	D	26	30.5	24			
798-DF11Z-28DS-2V50	DF11Z-28DS-2V(50)	D	28	32.5	26			
798-DF11Z-30DS-2V50	DF11Z-30DS-2V(50)	D	30	34.5	28			
798-DF11Z-40DS-2V50	DF11Z-40DS-2V(50)	D	40	44.5	38			

Rectangular Connectors Hirose