


MOLEX KK® Series Headers (.100")

molex
one company a world of innovation

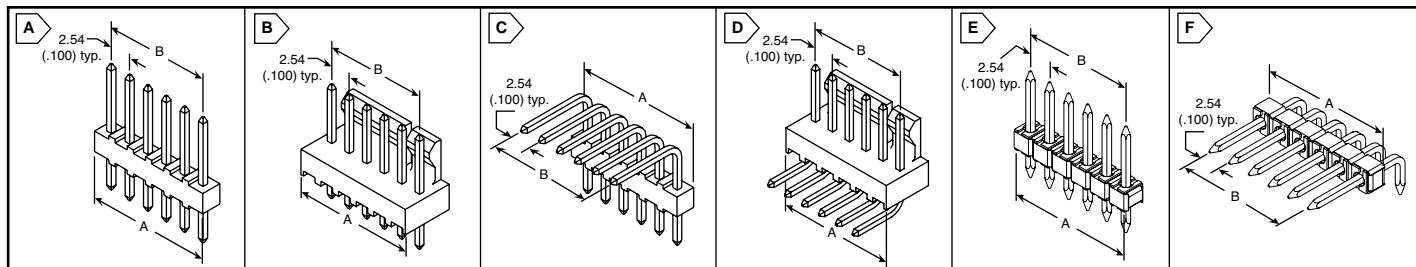

.100" PCB HEADERS

• Contact: Brass, 0.64mm (.025") square pins • UL94V-0, White Nylon • Voltage: 250V • Current: 4.0A • RoHS compliant per Molex documentation



For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	No. of Circuits	Dimen.: mm		Price Each			
				A	B	1	10	100	500
Vertical, Tin Plating									
538-22-03-2021	22-03-2021	A	2	4.83	2.54				
538-22-03-2031	22-03-2031	A	3	7.37	5.08				
538-22-03-2041	22-03-2041	A	4	9.91	7.62				
538-22-03-2051	22-03-2051	A	5	12.45	10.16				
538-22-03-2061	22-03-2061	A	6	14.99	12.7				
538-22-03-2071	22-03-2071	A	7	17.53	15.24				
538-22-03-2081	22-03-2081	A	8	20.07	17.78				
538-22-03-2091	22-03-2091	A	9	22.61	20.32				
538-22-03-2101	22-03-2101	A	10	25.15	22.86				
538-22-03-2111	22-03-2111	A	11	27.69	25.4				
538-22-03-2121	22-03-2121	A	12	30.23	27.94				
Vertical, Gold Plating									
538-22-10-2021	22-10-2021	A	2	4.83	2.54				
538-22-10-2031	22-10-2031	A	3	7.37	5.08				
538-22-10-2041	22-10-2041	A	4	9.91	7.62				
538-22-10-2051	22-10-2051	A	5	12.45	10.16				
538-22-10-2061	22-10-2061	A	6	14.99	12.7				
538-22-10-2071	22-10-2071	A	7	17.53	15.24				
538-22-10-2081	22-10-2081	A	8	20.07	17.78				
538-22-10-2091	22-10-2091	A	9	22.61	20.32				
538-22-10-2101	22-10-2101	A	10	25.15	22.86				
538-22-10-2111	22-10-2111	A	11	27.69	25.4				
538-22-10-2121	22-10-2121	A	12	30.23	27.94				
Vertical Friction Lock, Tin Plating									
538-22-23-2021	22-23-2021	B	2	5.08	2.54				
538-22-23-2031	22-23-2031	B	3	7.62	5.08				
538-22-23-2041	22-23-2041	B	4	10.16	7.62				
538-22-23-2051	22-23-2051	B	5	12.7	10.16				
538-22-23-2061	22-23-2061	B	6	15.24	12.7				
538-22-23-2071	22-23-2071	B	7	17.78	15.24				
538-22-23-2081	22-23-2081	B	8	20.32	17.78				
538-22-23-2091	22-23-2091	B	9	22.86	20.32				
538-22-23-2101	22-23-2101	B	10	25.4	22.86				
538-22-23-2111	22-23-2111	B	11	27.94	25.4				
538-22-23-2121	22-23-2121	B	12	30.48	27.94				
Vertical Friction Lock, Gold Plating									
538-22-11-2022	22-11-2022	B	2	5.08	2.54				
538-22-11-2032	22-11-2032	B	3	7.62	5.08				
538-22-11-2042	22-11-2042	B	4	10.16	7.62				
538-22-11-2052	22-11-2052	B	5	12.7	10.16				
538-22-11-2062	22-11-2062	B	6	15.24	12.7				
538-22-11-2072	22-11-2072	B	7	17.78	15.24				
538-22-11-2082	22-11-2082	B	8	20.32	17.78				
538-22-11-2092	22-11-2092	B	9	22.86	20.32				
538-22-11-2102	22-11-2102	B	10	25.4	22.86				
538-22-11-2112	22-11-2112	B	11	27.94	25.4				
538-22-11-2122	22-11-2122	B	12	30.48	27.94				

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	No. of Circuits	Dimen.: mm		Price Each			
				A	B	1	10	100	500
Right Angle, Tin Plating									
538-22-05-2021	22-05-2021	C	2	4.83	2.54				
538-22-05-2031	22-05-2031	C	3	7.37	5.08				
538-22-05-2041	22-05-2041	C	4	9.91	7.62				
538-22-05-2051	22-05-2051	C	5	12.45	10.16				
538-22-05-2061	22-05-2061	C	6	14.99	12.7				
538-22-05-2071	22-05-2071	C	7	17.53	15.24				
538-22-05-2081	22-05-2081	C	8	20.07	17.78				
538-22-05-2091	22-05-2091	C	9	22.61	20.32				
538-22-05-2101	22-05-2101	C	10	25.15	22.86				
538-22-05-2111	22-05-2111	C	11	27.69	25.4				
538-22-05-2121	22-05-2121	C	12	30.23	27.94				
Right Angle, Gold Plating									
538-22-12-2021	22-12-2021	C	2	4.83	2.54				
538-22-12-2031	22-12-2031	C	3	7.37	5.08				
538-22-12-2041	22-12-2041	C	4	9.91	7.62				
538-22-12-2051	22-12-2051	C	5	12.45	10.16				
538-22-12-2061	22-12-2061	C	6	14.99	12.7				
538-22-12-2071	22-12-2071	C	7	17.53	15.24				
538-22-12-2081	22-12-2081	C	8	20.07	17.78				
538-22-12-2101	22-12-2101	C	10	25.15	22.86				
538-22-12-2121	22-12-2121	C	12	30.23	27.94				
Right Angle Friction Lock, Tin Plating									
538-22-05-3021	22-05-3021	D	2	5.08	2.54				
538-22-05-3031	22-05-3031	D	3	7.62	5.08				
538-22-05-3041	22-05-3041	D	4	10.16	7.62				
538-22-05-3051	22-05-3051	D	5	12.7	10.16				
538-22-05-3061	22-05-3061	D	6	15.24	12.7				
538-22-05-3071	22-05-3071	D	7	17.78	15.24				
538-22-05-3081	22-05-3081	D	8	20.32	17.78				
538-22-05-3091	22-05-3091	D	9	22.86	20.32				
538-22-05-3101	22-05-3101	D	10	25.4	22.86				
538-22-05-3111	22-05-3111	D	11	27.94	25.4				
538-22-05-3121	22-05-3121	D	12	30.48	27.94				
Right Angle Friction Lock, Gold Plating									
538-22-12-2024	22-12-2024	D	2	5.08	2.54				
538-22-12-2034	22-12-2034	D	3	7.62	5.08				
538-22-12-2044	22-12-2044	D	4	10.16	7.62				
538-22-12-2054	22-12-2054	D	5	12.7	10.16				
538-22-12-2064	22-12-2064	D	6	15.24	12.7				
538-22-12-2074	22-12-2074	D	7	17.78	15.24				
538-22-12-2084	22-12-2084	D	8	20.32	17.78				
538-22-12-2094	22-12-2094	D	9	22.86	20.32				
538-22-12-2104	22-12-2104	D	10	25.4	22.86				
538-22-12-2114	22-12-2114	D	11	27.94	25.4				
538-22-12-2124	22-12-2124	D	12	30.48	27.94				

Rectangular Connectors Molex

.100" BREAKAWAY HEADERS - PCB

• Voltage: 250V • Current: 4.0A • RoHS compliant per Molex documentation

RoHS Compliant

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	No. of Circuits	Dimen.: mm		Price Each			
				A	B	1	10	100	500
Vertical, Tin Plating									
538-22-28-4020	22-28-4020	E	2	5.08	2.54				
538-22-28-4030	22-28-4030	E	3	7.62	5.08				
538-22-28-4040	22-28-4040	E	4	10.16	7.62				
538-22-28-4050	22-28-4050	E	5	12.7	10.16				
538-22-28-4060	22-28-4060	E	6	15.24	12.7				
538-22-28-4070	22-28-4070	E	7	17.78	15.24				
538-22-28-4080	22-28-4080	E	8	20.32	17.78				
538-22-28-4090	22-28-4090	E	9	22.86	20.32				
538-22-28-4100	22-28-4100	E	10	25.4	22.86				
538-22-28-4360	22-28-4360	E	36	91.44	88.9				
Vertical, Gold Plating									
538-22-28-4023	22-28-4023	E	2	5.08	2.54				
538-22-28-4033	22-28-4033	E	3	7.62	5.08				
538-22-28-4043	22-28-4043	E	4	10.16	7.62				
538-22-28-4053	22-28-4053	E	5	12.7	10.16				
538-22-28-4063	22-28-4063	E	6	15.24	12.7				

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	No. of Circuits	Dimen.: mm		Price Each			
				A	B	1	10	100	500
Vertical, Gold Plating (Cont.)									
538-22-28-4073	22-28-4073	E	7	17.78	15.24				
538-22-28-4083	22-28-4083	E	8	20.32	17.78				
538-22-28-4093	22-28-4093	E	9	22.86	20.32				
538-22-28-4103	22-28-4103	E	10	25.4	22.86				
538-22-28-4363	22-28-4363	E	36	91.44	88.9				
Right Angle, Tin Plating									
538-22-28-8020	22-28-8020	F	2	5.08	2.54				
538-22-28-8030	22-28-8030	F	3	7.62	5.08				
538-22-28-8040	22-28-8040	F	4	10.16	7.62				
538-22-28-8050	22-28-8050	F	5	12.7	10.16				
538-22-28-8060	22-28-8060	F	6	15.24	12.7				
538-22-28-8070	22-28-8070	F	7	17.78	15.24				
538-22-28-8080	22-28-8080	F	8	20.32	17.78				
538-22-28-8090	22-28-8090	F	9	22.86	20.32				
538-22-28-8100	22-28-8100	F	10	25.4	22.86				
538-22-28-8360	22-28-8360	F	36	91.44	88.9				