


# MILL-MAX In-line Sockets and Headers

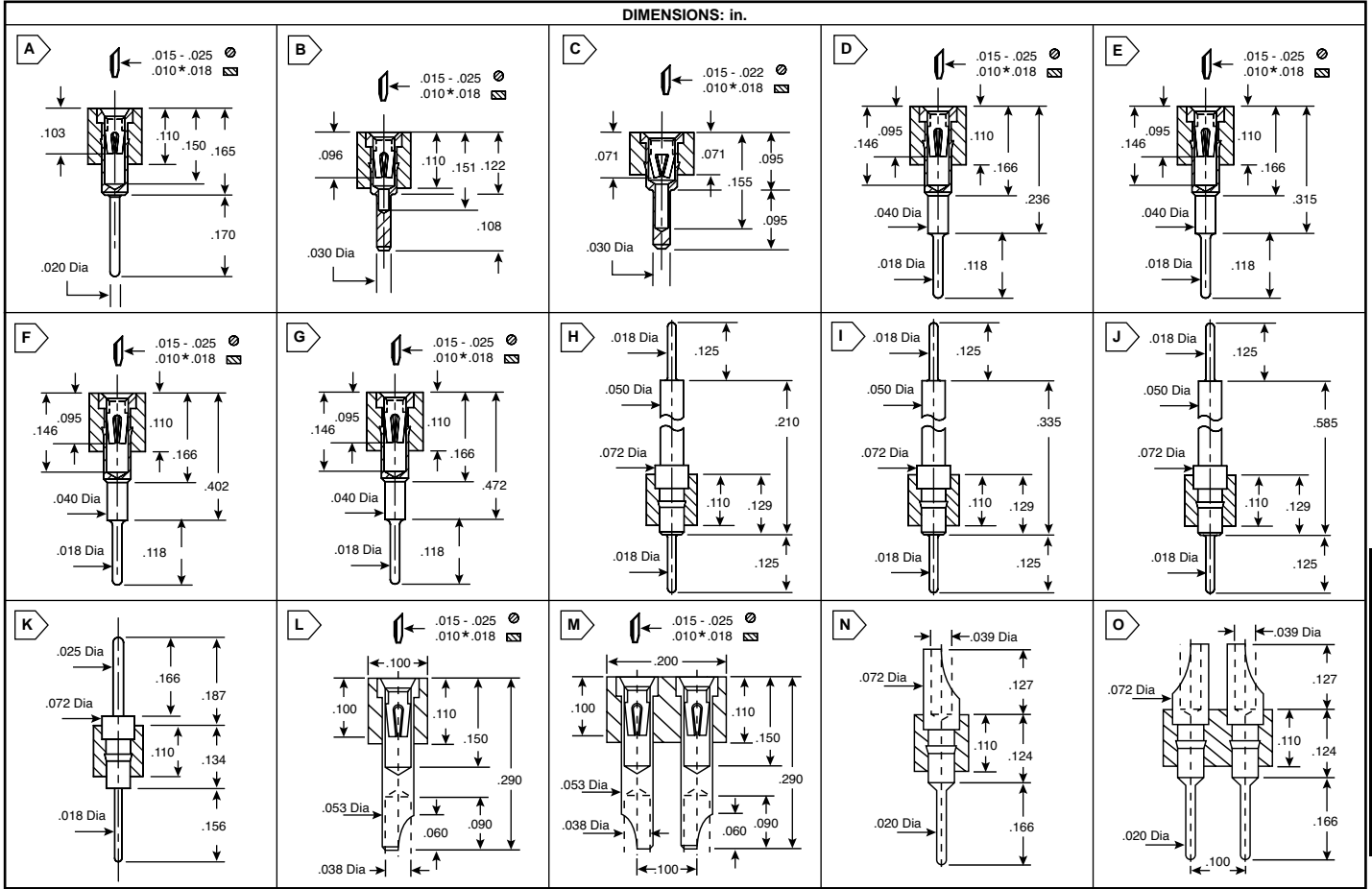

## .100" SINGLE-IN-LINE CONNECTORS

Plating		
Code	Shell	Inner Contact
43	200µ" Tin (Matte Fin.)	30µ" Gold
93	200µ" Tin/Lead	30µ" Gold
10	10µ" Gold	100µ" Nickel

### Sockets

• 64 positions (can be cut down) • High-Rel 4-finger contacts are rated at 3A • Sockets accept .015-.025" dia. pins and standard IC leads

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Mill-Max Part No.	Fig.	Description	Tail Type	Sleeve Plating	Price Each			
						1	10	100	500
<b>RoHS Compliant</b>									
575-31143164	311-43-164-41-001000	A	Long Solder Tail	Solder	Tin				
575-31543164	315-43-164-41-001000	B	Very Low Profile	Solder	Tin				
575-315431643	315-43-164-41-003000	C	Ultra Low Profile	Solder	Tin				
575-316431646	316-43-164-41-006000	D	Elevated	Solder	Tin				
575-316431643	316-43-164-41-003000	E	Elevated	Solder	Tin				
575-316431647	316-43-164-41-007000	F	Elevated	Solder	Tin				
575-316431648	316-43-164-41-008000	G	Elevated	Solder	Tin				
<b>Non-RoHS Compliant</b>									
575-641101	311-93-164-41-001000	A	Long Solder Tail	Solder	Tin				
575-641501	315-93-164-41-001000	B	Very Low Profile	Solder	Tin				
575-641503	315-93-164-41-003000	C	Ultra Low Profile	Solder	Tin				
575-643166	316-93-164-41-006000	D	Elevated	Solder	Tin				
575-643163	316-93-164-41-003000	E	Elevated	Solder	Tin				
575-643167	316-93-164-41-007000	F	Elevated	Solder	Tin				
575-643168	316-93-164-41-008000	G	Elevated	Solder	Tin				

### Headers

• .018" Pin / .018" Tails \* .025" Pin / .018" Tail

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Mill-Max Part No.	Fig.	No. of Positions	Tail Type	Sleeve Plating	Price Each			
						1	10	100	500
<b>RoHS Compliant</b>									
575-641591	342-10-164-00-591000	H	64	Solder	10µ" Gold				
575-641592	342-10-164-00-592000	I	64	Solder	10µ" Gold				
575-641593	342-10-164-00-593000	J	64	Solder	10µ" Gold				
*575-101641	350-10-164-00-001000	K	64	Solder	10µ" Gold				

## SOLDER CUP INTERCONNECTS

• 64 positions (can be cut down) • Thru-hole • .100 Grid • RoHS Compliant per Mill-Max documentation



For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Mill-Max Part No.	Fig.	Description	Sleeve Plating	Price Each			
					1	10	100	500
<b>Sockets</b>								
575-32943164	329-43-164-41-540000	L	Single Row Solder Cup Sockets	Tin				
575-42943264	429-43-264-41-540000	M	Double Row Solder Cup Sockets	Tin				
<b>Headers</b>								
575-38010164	380-10-164-00-001000	N	Single Row Solder Cup/Solder Tail	10µ" Gold				
575-48010264	480-10-264-00-001000	O	Double Row Solder Cup/Solder Tail	10µ" Gold				