


# MILL-MAX In-line Sockets and Headers



DIMENSIONS: in.

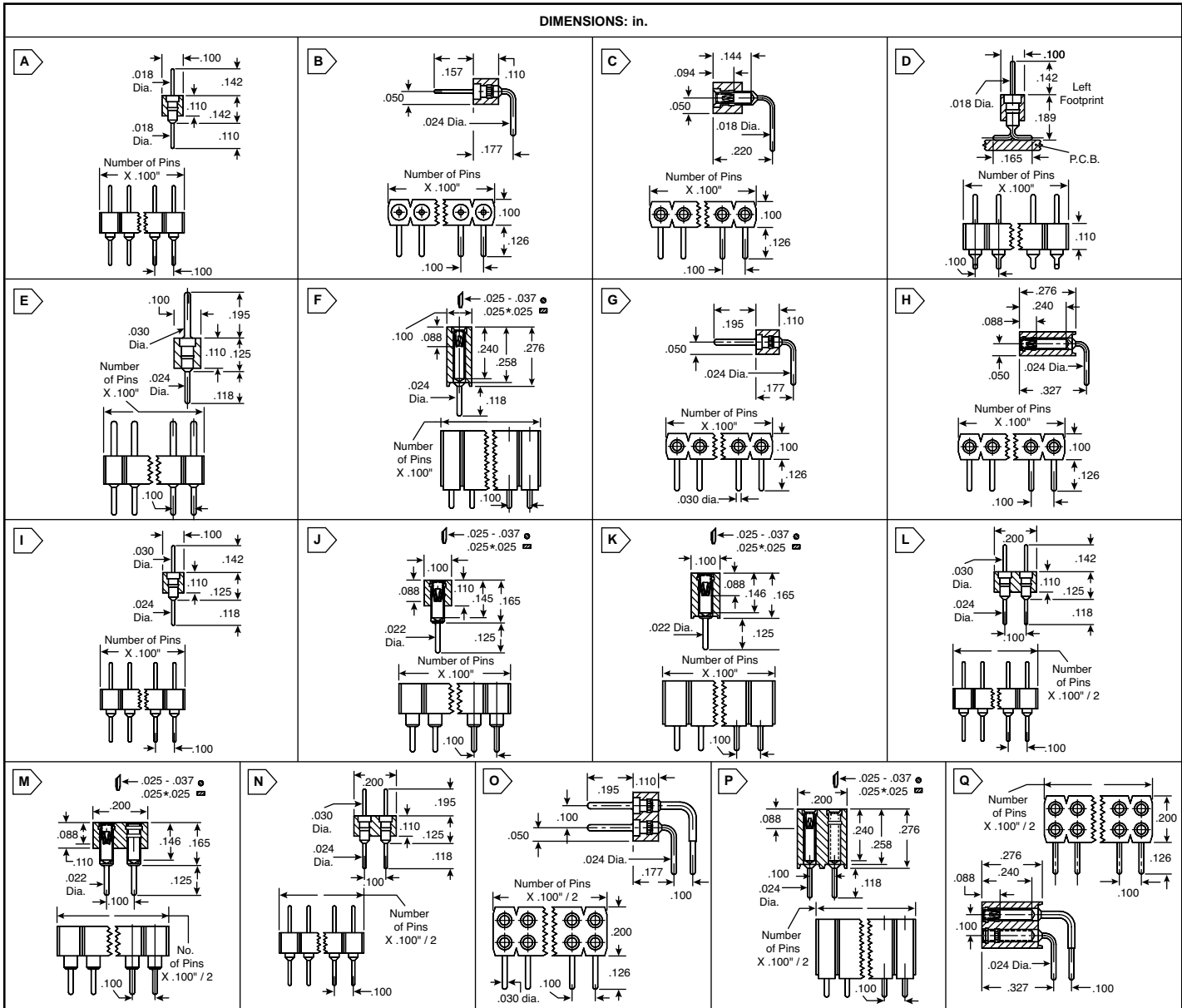

Sockets

Mill-Max

## .100" INTERCONNECTS

Plating		
Code	Shell	Inner Contact
10	10µ" Gold	n/a
43	200µ" Tin (Matte Fin.)	30µ" Gold
93	200µ" Tin/Lead	30µ" Gold

- May be cut to length
- Tail Type: Solder



RoHS Compliant

\*: Not RoHS Compliant

### Single Row

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Mill-Max Part No.	Fig.	Description	No. of Cont.	Price Each		
					1	10	100
<b>.018" Dia. Pins, 3A</b>							
575-010064	350-10-164-00-006000	A	Straight Header	64			
575-643909	399-10-164-10-009000	B	Rt. Angle Header	64			
*575-643903	399-93-164-10-003000	C	Rt. Angle Socket	64			
575-39943164	399-43-164-10-003000	C	Rt. Angle Socket	64			
575-640006	350-10-164-00-106000	D	Surf. Mt. Header	64			
<b>.030" Dia. Pins, 4.5A</b>							
575-010064	800-10-064-10-001000	E	Straight Header	64			
*575-093050	801-93-050-10-001000	F	Straight Socket	50			
575-8014305010	801-43-050-10-001000	F	Straight Socket	50			
575-642001	800-10-064-20-001000	G	Rt. Angle Header	64			
*575-502001	801-93-050-20-001000	H	Rt. Angle Socket	50			
575-8014305020	801-43-050-20-001000	H	Rt. Angle Socket	50			
575-641002	800-10-064-10-002000	I	Low Prof. Header	64			
*575-641012	801-93-064-10-002000	J	Low Prof. Socket	64			
575-8014306410	801-43-064-10-002000	J	Low Prof. Socket	64			

### Single Row (Cont.)

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Mill-Max Part No.	Fig.	Description	No. of Cont.	Price Each		
					1	10	100
<b>.030" Dia. Pins, 4.5A (cont.)</b>							
*575-361012	801-93-036-10-012000	K	Low Prof. Socket	36			
575-80143036	801-43-036-10-012000	K	Low Prof. Socket	36			

### Double Row

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Mill-Max Part No.	Fig.	Description	No. of Cont.	Price Each		
					1	10	100
<b>.030" Dia. Pins, 4.5A</b>							
575-641022	802-10-064-10-002000	L	Low Prof. Header	2x32			
*575-721022	803-93-072-10-002000	M	Low Prof. Socket	2x36			
575-80343072102	803-43-072-10-002000	M	Low Prof. Socket	2x36			
575-641001	802-10-064-10-001000	N	Straight Header	2x32			
575-642201	802-10-064-20-001000	O	Rt. Angle Header	2x32			
*575-072101	803-93-072-10-001000	P	Straight Socket	2x36			
575-80343072101	803-43-072-10-001000	P	Straight Socket	2x36			
*575-100201	803-93-100-20-001000	Q	Rt. Angle Socket	2x50			
575-8034310020	803-43-100-20-001000	Q	Rt. Angle Socket	2x50			

