


# AMP Terminals

**Tyco Electronics**

RoHS Compliant This product is RoHS compliant.

Authorized Distributor

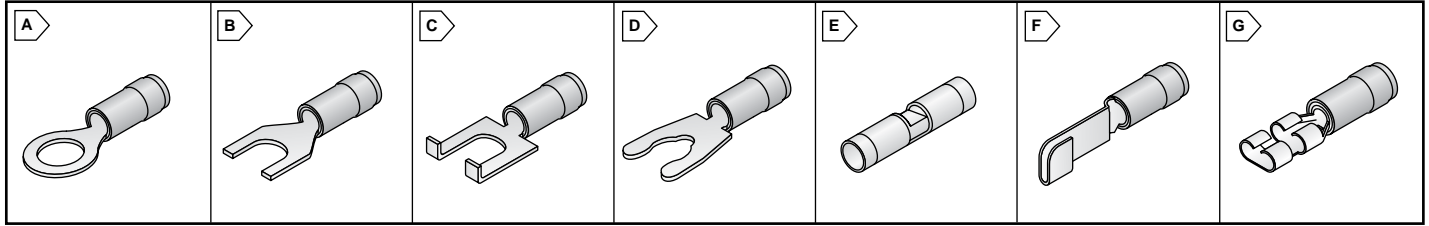

## PIDG NYLON (PRE-INSULATED DIAMOND GRIP) TERMINALS

Designed for complete and uniform reliability in the most difficult circuit environments. These nylon terminals feature a tin plated copper body with a special designed copper sleeve that is fitted over the terminal barrel to provide maximum circumferential insulation support to the wire.

### Features:

- High dielectric strength
- Temperature rating: 105°C
- Funnel ramp entry
- Meet or exceed requirements of MIL-T-7928, Type II, Class 1 & 2
- Copper support sleeve for insulation
- RoHS Compliant per Tyco Electronics documentation



\*26-22 splices are 26-24 range in accordance with MIL-T-7928.

† 22-16 splices are 22-18 range in accordance with MIL-T-7928.

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each		
						1	100	500
<b>Ring Tongue Terminals</b>								
571-323912	323912	A	Yellow	#2	26 - 22			
571-323914	323914	A	Yellow	#4	26 - 22			
571-323915	323915	A	Yellow	#6	26 - 22			
571-323916	323916	A	Yellow	#8	26 - 22			
571-324075	324075	A	Yellow	#10	26 - 22			
571-328657	328657	A	Red	#2	22 - 16			
571-31880	31880	A	Red	#4	22 - 16			
571-36152	36152	A	Red	#6	22 - 16			
571-31890	31890	A	Red	#8	22 - 16			
571-36154	36154	A	Red	#10	22 - 16			
571-31894	31894	A	Red	1/4"	22 - 16			
571-31895	31895	A	Red	5/16"	22 - 16			
571-31897	31897	A	Red	3/8"	22 - 16			
571-320619	320619	A	Blue	#6	16 - 14			
571-320565	320565	A	Blue	#8	16 - 14			
571-36160	36160	A	Blue	#10	16 - 14			
571-321045	321045	A	Blue	1/4"	16 - 14			
571-328998	328998	A	Blue	5/16"	16 - 14			
571-328999	328999	A	Blue	3/8"	16 - 14			
571-35149	35149	A	Yellow	#6	12 - 10			
571-35108	35108	A	Yellow	#8	12 - 10			
571-35109	35109	A	Yellow	#10	12 - 10			
571-35110	35110	A	Yellow	1/4"	12 - 10			
571-35111	35111	A	Yellow	5/16"	12 - 10			
571-35112	35112	A	Yellow	3/8"	12 - 10			
571-35151	35151	A	Yellow	1/2"	12 - 10			
<b>Spade Tongue Terminals</b>								
571-328394	328394	B	Red	#2	22 - 16			
571-327717	327717	B	Red	#4	22 - 16			
571-34541	34541	B	Red	#6	22 - 16			
571-32053	32053	B	Red	#8	22 - 16			
571-32054	32054	B	Red	#10	22 - 16			
571-35559	35559	B	Blue	#6	16 - 14			
571-32059	32059	B	Blue	#8	16 - 14			
571-321233	321233	B	Blue	#8	16 - 14			
571-32060	32060	B	Blue	#10	16 - 14			
571-32589	32589	B	Yellow	#10	12 - 10			
<b>Flanged Spade Tongue Terminals</b>								
571-324608	324608	C	Red	#2	22 - 16			
571-32562	32562	C	Red	#6	22 - 16			
571-320861	320861	C	Blue	#6	16 - 14			
571-320862	320862	C	Blue	#8	16 - 14			
571-325150	325150	C	Yellow	#6	12 - 10			
<b>Short Spring Spade Tongue Terminals</b>								
571-52927	52927	D	Red	#4	22 - 16			
571-52929	52929	D	Red	#6	22 - 16			
571-52930	52930	D	Red	#8	22 - 16			
571-52931	52931	D	Red	#10	22 - 16			
571-52935	52935	D	Blue	#6	16 - 14			
571-52936	52936	D	Blue	#8	16 - 14			
571-52937	52937	D	Blue	#10	16 - 14			
571-52941	52941	D	Yellow	#6	12 - 10			
571-52942	52942	D	Yellow	#8	12 - 10			
571-52943	52943	D	Yellow	#10	12 - 10			
<b>Butt Splices</b>								
*571-323994	323994	E	Yellow	---	26 - 22			
† 571-320559	320559	E	Red	---	22 - 16			
571-320562	320562	E	Blue	---	16 - 14			
571-320570	320570	E	Yellow	---	12 - 10			
<b>Knife Disconnect Splices</b>								
571-32446	32446	F	Red	---	22 - 16			
571-32448	32448	F	Blue	---	16 - 14			

## PIDG FASTON RECEPTACLES

### Features:

- Tin-plated brass
- No dimple with wire stop
- RoHS Compliant per Tyco Electronics documentation



For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Color	Size (In.)	Wire Size (AWG)	Price Each		
						1	100	500
571-6409231	640923-1	G	Red	.110" x .020"	22 - 18			
571-6409291	640929-1	G	Blue	.110" x .020"	16 - 14			
571-428441	42844-1	G	Green	.250" x .032"	14 - 12			
571-6409171	640917-1	G	Red	.187" x .020"	22 - 18			
*571-6409111	640911-1	G	Red	.205" x .032"	22 - 18			
*571-6409151	640915-1	G	Blue	.205" x .032"	16 - 14			
*571-608941	60894-1	G	Natural	.110" x .032"	22 - 18			
571-6409191	640919-1	G	Blue	.187" x .020"	16 - 14			
*571-6409091	640909-1	G	Red	.205" x .020"	22 - 18			
571-6409031	640903-1	G	Red	.250" x .032"	22 - 18			
571-6409051	640905-1	G	Blue	.250" x .032"	16 - 14			
571-6409071	640907-1	G	Yellow	.250" x .032"	12 - 10			

\*Dimple with wire stop

## PLASTI-GRIP VINYL PRE-INSULATED TERMINALS

22-16 terminals and splices are stamped 22-18 in accordance with MIL-T-7928 commercial wire, range is 22-16.

### Features:

 
- Tin-plated copper
- Vinyl insulation
- Temperature rating: 90°C
- RoHS Compliant per Tyco Electronics documentation



For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each		
						1	100	500
<b>Ring Tongue Terminals</b>								
571-34141	34141	A	Red	#4	22 - 16			
571-34142	34142	A	Red	#6	22 - 16			
571-34148	34148	A	Red	#8	22 - 16			
571-34149	34149	A	Red	#10	22 - 16			
571-34151	34151	A	Red	5/16"	22 - 16			
571-34160	34160	A	Blue	#8	16 - 14			
571-34161	34161	A	Blue	#10	16 - 14			
571-34163	34163	A	Blue	5/16"	16 - 14			
571-34853	34853	A	Yellow	#8	12 - 10			
571-34854	34854	A	Yellow	#10	12 - 10			
571-34173	34173	A	Yellow	3/8"	12 - 10			
<b>Spade Tongue Terminals</b>								
571-320665	320665	B	Red	#6	22 - 16			
571-34156	34156	B	Red	#10	22 - 16			
571-322994	322994	B	Blue	#6	16 - 14			
571-34166	34166	B	Blue	#8	16 - 14			
571-34176	34176	B	Yellow	#10	12 - 10			
<b>Flanged Spade Tongue Terminals</b>								
571-322249	322249	C	Red	#6	22 - 16			
571-328516	328516	C	Red	#10	22 - 16			
571-324165	324165	C	Blue	#6	16 - 14			
<b>Short Spring Spade Tongue Terminal</b>								
571-52949	52949	D	Red	#6	22 - 16			
<b>Butt Splices</b>								
571-34070	34070	E	Red	---	22 - 16			
571-34071	34071	E	Blue	---	16 - 14			
571-34072	34072	E	Yellow	---	12 - 10			

## CRIMP TOOL FOR SOLDERLESS TERMINALS



Heavy duty or small task tool designed with crimper, cutter, and stripper all in one.

For quantities of 5 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Description	Price Each
571-3549401	354940-1	Procrimper III without dies	
571-584231	58423-1	Die set for Procrimper III	

Terminals

AMP