

AMP Terminals, Splices and Wire Caps

RoHS Compliant **This product is RoHS compliant.**

SOLISTRAND UNINSULATED TERMINALS

• RoHS Compliant per Tyco Electronics documentation

Short Spring Spade Tongue Terminals

For quantities of 5,000 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Stud Size	Wire Size (AWG)	Dimensions L x W	Price Each			
						1	100	500	1000
571-531751	53175-1	A	4	22-16	.576 x .203				
571-531201	53120-1	A	6	22-16	.576 x .250				
571-531231	53123-1	A	6	16-14	.576 x .250				
571-531261	53126-1	A	6	12-10	.636 x .250				

DIAMOND GRIP UNISULATED TERMINALS

• RoHS Compliant per Tyco Electronics documentation

Ring Tongue Terminals

For quantities of 5,000 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Stud Size	Wire Size (AWG)	Dimensions L x W	Price Each			
						1	100	500	1000
571-31518	31518	B	2	26-22	.464 x .140				
571-31094	31094	B	4	22-16	.603 x .218				
571-30996	30996	B	8	22-16	.775 x .312				
571-30927	30927	B	8	16-14	.790 x .343				

RING TONGUE RADIATION RESISTANT TERMINALS

• RoHS Compliant per Tyco Electronics documentation

For quantities of 5,000 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
						1	100	500	1000
571-696422-3	696422-3	C	Red	6	22-16				
571-696422-5	696422-5	C	Red	8	22-16				
571-696422-6	696422-6	C	Red	10	22-16				

PIDG RING TONGUE INSULATION RESTRICTING TERMINALS

• RoHS Compliant per Tyco Electronics documentation

For quantities of 5,000 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
						1	100	500	1000
571-13205513	1-320551-3	D	Red/Red	8	22-16				
571-13205514	1-320551-4	D	Red/White	8	22-16				
571-2361535	2-36153-4	D	Red/White	10	22-16				
571-518649	51864-9	D	Blue/Green	10	16-14				
571-23205634	2-320563-4	D	Blue/Green	1/4	14				
571-2361614	2-36161-4	D	Yellow/Brown	10	10				

PIDG OFFSET AND SLOTTED RING TONGUE TERMINALS

• RoHS Compliant per Tyco Electronics documentation

For quantities of 5,000 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
						1	100	500	1000
571-323011	323011	E	Yellow	6	26-22				
571-36954	36954	E	Red	8	22-16				

PIDG SPARE WIRE CAPS

• Not sealed
• RoHS Compliant per Tyco Electronics documentation

For quantities of 5,000 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Cap Insulation Color	Wire Size (AWG)	Price Each			
					1	100	500	1000
Unstripped Wire								
571-324484	324485	F	Red	- - -				
Stripped Wire								
571-328307	328307	G	Red	22-18				

CLOSED END SPLICES


Splice Marking

- VS 300V, 90°C
- ECN 300V 105°C
- ECV 600V max. Building wiring 1000V max.
- EC 600V max. Building wiring 1000V max; Fixtures and signs, 105°C
- Fixtures and signs, 105°C UL, 90°C CSA
- RoHS Compliant per Tyco Electronics documentation

* Max. recommended operating temperature, 150°C

For quantities of 5,000 and up, call for quote.

MOUSER STOCK NO.	AMP Part No.	Fig.	Material	Color	Length	Wire Size (AWG)	Splice Marking	Price Each			
								1	100	500	1000
Vinyl BOMB-TAIL Splices											
571-34306	34306	H	Copper	Blue	0.750	22-16	VS				
571-34864	34864	H	Copper	Blue	0.800	22-16	VS				
571-23283753	2-328375-3	H	Copper	Purple	0.775	22-14	VS				
571-532341	53234-1	H	Copper	Transparent	1.500	22-12	ECV				
Nylon Molded Splices											
571-35115	35115	I	Copper	Transparent	0.680	22-14	ECN				
*571-559271	55927-1	I	Copper	Black	0.680	22-14	ECN				
571-35653	35653	I	Copper	Transparent	0.775	22-10	ECN				
*571-559291	55929-1	I	Copper	Black	0.970	22-10	EC				
571-328730	328730	I	Copper	Transparent	0.720	22-10	EC				

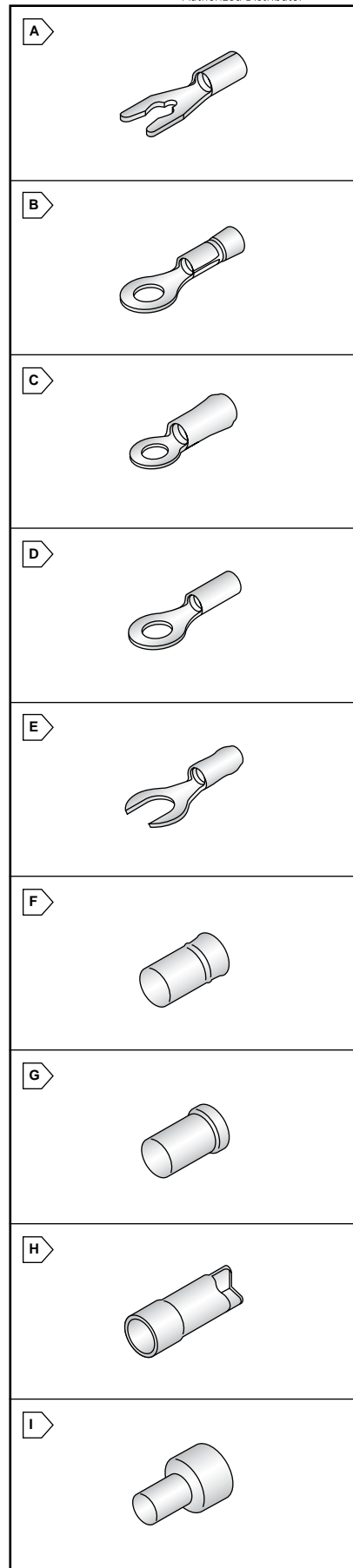

AMP Terminals