

MOLEX Terminals and Splices

RING TONGUE TERMINALS

• Material: Copper




RoHS Compliant

Krimptite®, Non Insulated

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	Wire Size (AWG)	Stud Size	Price Each			
					1	100	500	1000
538-19069-0042	19069-0042	A	18-22	1/4				
538-19069-0049	19069-0049	A	18-22	3/8				
538-19069-0107	19069-0107	A	14-16	1/4				
538-19069-0109	19069-0109	A	14-16	5/16				

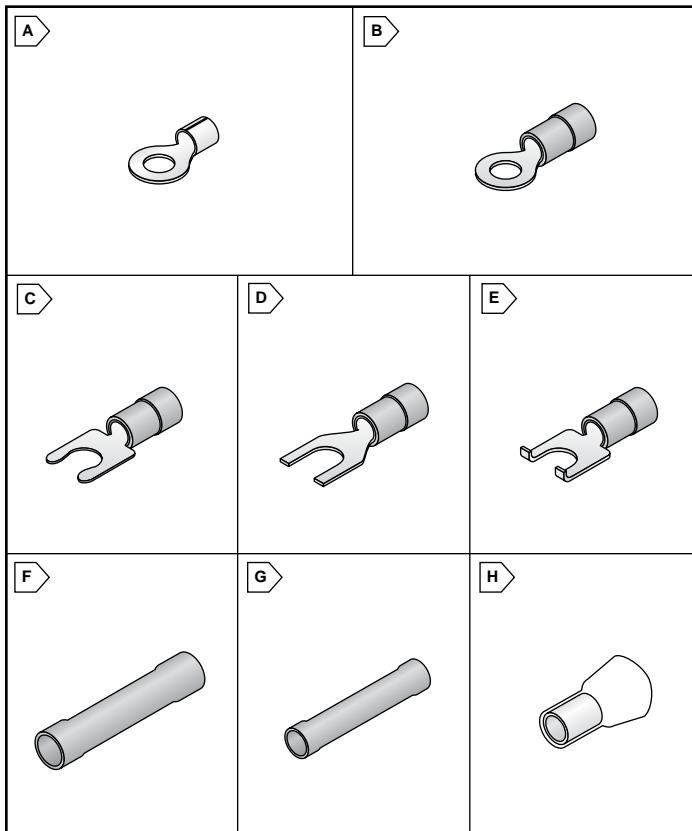

Insulkrimp®, PVC Insulated

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	Wire Size (AWG)	Stud Size	Price Each			
					1	100	500	1000
538-19070-0040	19070-0040	B	18-22	5-6				
538-19070-0013	19070-0013	B	18-22	8				
538-19070-0015	19070-0015	B	18-22	10				
538-19070-0023	19070-0023	B	18-22	1/4				
538-19070-0067	19070-0067	B	14-16	3-4				
538-19070-0069	19070-0069	B	14-16	5-6				
538-19070-0086	19070-0086	B	14-16	8				
538-19070-0090	19070-0090	B	14-16	10				
538-19070-0075	19070-0075	B	14-16	1/4				
538-19070-0059	19070-0059	B	14-16	3/8				
538-19070-0143	19070-0143	B	10-12	5-6				
538-19070-0123	19070-0123	B	10-12	10				
538-19070-0132	19070-0132	B	10-12	1/4				
538-19070-0155	19070-0155	B	10-12	5/16				
538-19070-0153	19070-0153	B	10-12	3/8				

Avikrimp®, Nylon Insulated

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	Wire Size (AWG)	Stud Size	Price Each			
					1	100	500	1000
538-19073-0005	19073-0005	B	18-22	1-2				
538-19073-0007	19073-0007	B	18-22	3-4				
538-19073-0038	19073-0038	B	18-22	5-6				
538-19073-0013	19073-0013	B	18-22	8				
538-19073-0017	19073-0017	B	18-22	10				
538-19073-0024	19073-0024	B	18-22	1/4				
538-19073-0027	19073-0027	B	18-22	5/16				
538-19073-0032	19073-0032	B	18-22	3/8				
538-19073-0067	19073-0067	B	14-16	5-6				
538-19073-0083	19073-0083	B	14-16	5-6				
538-19073-0085	19073-0085	B	14-16	8				
538-19073-0087	19073-0087	B	14-16	10				
538-19073-0076	19073-0076	B	14-16	1/4				
538-19073-0079	19073-0079	B	14-16	5/16				
538-19073-0059	19073-0059	B	14-16	3/8				
538-19073-0170	19073-0170	B	10-12	10				
538-19073-0236	19073-0236	B	10-12	3/8				
538-19073-0145	19073-0145	B	10-12	1/2				

SNAP SPADE TERMINALS

• Material: Copper



RoHS Compliant

Insulkrimp®, PVC Insulated

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	Wire Size (AWG)	Stud Size	Price Each			
					1	100	500	1000
538-19099-0009	19099-0009	C	18-22	5-6				
538-19099-0013	19099-0013	C	18-22	8				
538-19099-0015	19099-0015	C	18-22	10				
538-19099-0034	19099-0034	C	14-16	10				
538-19099-0044	19099-0044	C	10-12	5-6				
538-19099-0048	19099-0048	C	10-12	8				

SPADE TONGUE TERMINALS

• Material: Copper

Insulkrimp®, PVC Insulated

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	Wire Size (AWG)	Stud Size	Price Each			
					1	100	500	1000
538-19144-0001	19144-0001	D	18-22	5-6				
538-19144-0003	19144-0003	D	18-22	8				
538-19144-0005	19144-0005	D	18-22	10				
538-19144-0018	19144-0018	D	14-16	5-6				
538-19144-0020	19144-0020	D	14-16	8				
538-19144-0026	19144-0026	D	14-16	10				
538-19144-0037	19144-0037	D	10-12	5-6				
538-19144-0039	19144-0039	D	10-12	8				

Avikrimp®, Nylon Insulated

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	Wire Size (AWG)	Stud Size	Price Each			
					1	100	500	1000
538-19198-0070	19198-0070	D	18-22	5-6				
538-19198-0004	19198-0004	D	18-22	8				
538-19198-0006	19198-0006	D	18-22	10				
538-19198-0016	19198-0016	D	14-16	5-6				
538-19198-0025	19198-0025	D	14-16	10				
538-19198-0044	19198-0044	D	10-12	5-6				
538-19198-0047	19198-0047	D	10-12	8				

FLANGED SPADE TERMINALS

Insulkrimp®, PVC Insulated

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	Wire Size (AWG)	Stud Size	Price Each			
					1	100	500	1000
538-19121-0005	19121-0005	E	22-18	5-6				
538-19121-0007	19121-0007	E	22-18	8				
538-19121-0009	19121-0009	E	22-18	10				
538-19121-0028	19121-0028	E	16-14	8				
538-19121-0030	19121-0030	E	14-16	10				
538-19121-0053	19121-0053	E	10-12	8				
538-19121-0056	19121-0056	E	10-12	10				

Avikrimp®, Nylon Insulated

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	Wire Size (AWG)	Stud Size	Price Each			
					1	100	500	1000
538-19127-0007	19127-0007	E	22-18	5-6				
538-19127-0012	19127-0012	E	22-18	10				
538-19127-0042	19127-0042	E	16-14	8				
538-19127-0086	19127-0086	E	10-12	8				
538-19127-0089	19127-0089	E	10-12	10				

SPLICES

Step Down Butt Splices, Insulated

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	Wire Size (AWG)	Color	Price Each			
					1	100	500	1000
538-19154-0022	19154-0022	F	14/16-18/22	Blue w/red stripe				
538-19154-0035	19154-0035	F	10/12-14/16	Yel. w/blue stripe				

Butt Splices - Insulkrimp®, PVC Insulated

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	Wire Size (AWG)	Color	Price Each			
					1	100	500	1000
538-19154-0004	19154-0004	G	18-22	---				
538-19154-0015	19154-0015	G	14-16	---				
538-19154-0028	19154-0028	G	10-12	---				

Closed End Splices, Nylon-Insulated

Two piece construction. A translucent nylon-molded insulation is adhered to the metal connector insert. The connector's insert is annealed, Tin-plated, seamless, pure electrolytic, tough pitch copper. Individual design and performance requirements dictate the use of copper inserts. These connectors are all rated for a maximum of 600V.

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	Wire Size (AWG)	Color	Price Each			
					1	100	500	1000
538-19160-0012	19160-0012	H	14-22	---				
538-19160-0009	19160-0009	H	12-22	---				
538-19160-0002	19160-0002	H	10-16	---				