


PANDUIT Terminals



RoHS Compliant This product is RoHS compliant.

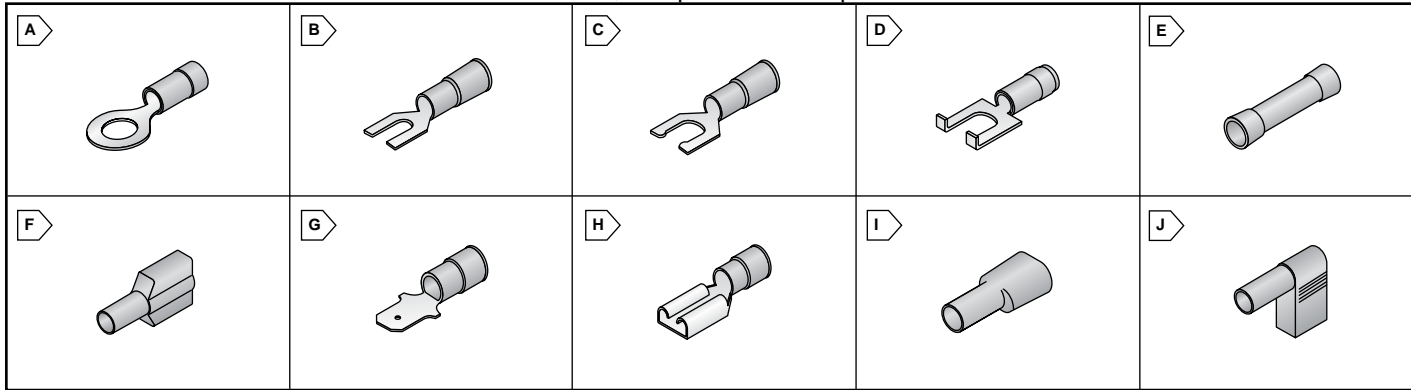

SOLDERLESS TERMINALS

- Price each is per terminal
- All terminals feature brazed seam construction

Stock No. Suffix Denotes Standard Package Quantity:
L = 50, C = 100, D = 500, M = 1000



RoHS Compliant

For quantities of 5000 and up, call for quote.



RoHS Compliant

For quantities of 5000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Wire Size	Stud Size	Color	Price Each			
					1	100	500	1000
Vinyl Ring - Funnel Entry - Insulated								
644-PV18-6R-MY	A	22-18	6	Red				
644-PV18-8R-MY	A	22-18	8	Red				
644-PV18-4RX-MY	A	22-18	4	Red				
644-PV18-6RX-MY	A	22-18	6	Red				
644-PV18-8RX-MY	A	22-18	8	Red				
644-PV18-10RX-MY	A	22-18	10	Red				
644-PV14-6R-M	A	16-14	6	Blue				
644-PV14-8R-M	A	16-14	8	Blue				
644-PV14-10R-M	A	16-14	10	Blue				
644-PV14-14R-M	A	16-14	1/4	Blue				
644-PV14-4RX-C	A	16-14	4	Blue				
644-PV14-6RX-M	A	16-14	6	Blue				
644-PV14-8RX-M	A	16-14	8	Blue				
644-PV14-10RX-M	A	16-14	10	Blue				
644-PV14-14RX-M	A	16-14	1/4	Blue				
644-PV10-8R-D	A	12-10	8	Yellow				
644-PV10-10R-D	A	12-10	10	Yellow				
644-PV10-14R-D	A	12-10	1/4	Yellow				
644-PV10-6RX-L	A	12-10	6	Yellow				
644-PV10-8RX-L	A	12-10	8	Yellow				
644-PV10-10RX-L	A	12-10	10	Yellow				
644-PV10-14RX-L	A	12-10	1/4	Yellow				
Nylon Ring - Insulated								
644-PN18-14R-M	A	22-18	1/4	Red				
644-PN18-4R-M	A	22-18	4	Red				
644-PN18-10R-M	A	22-18	10	Red				
644-PN18-4RN-M	A	22-18	4	Red				
644-PN18-6RN-M	A	22-18	6	Red				
644-PN18-8R-M	A	22-18	8	Red				
644-PN14-4R-M	A	16-14	4	Blue				
644-PN14-56R-M	A	16-14	5/16	Blue				
644-PN14-6R-M	A	16-14	6	Blue				
644-PN14-8R-M	A	16-14	8	Blue				
644-PN14-6RX-C	A	16-14	6	Blue				
644-PN14-8RX-C	A	16-14	8	Blue				
644-PN14-10RX-C	A	16-14	10	Blue				
644-PN10-6R-D	A	12-10	6	Yellow				
644-PN10-8R-L	A	12-10	8	Yellow				
644-PN10-14R-L	A	12-10	1/4	Yellow				
644-PN10-6RX-L	A	12-10	6	Yellow				
644-PN10-8RX-L	A	12-10	8	Yellow				
644-PN10-10RX-L	A	12-10	10	Yellow				
644-PN10-56R-D	A	12-10	5/16	Yellow				
644-PN10-38R-D	A	12-10	3/8	Yellow				
Vinyl Fork - Insulated								
644-PV18-6F-MY	B	22-18	6	Red				
644-PV18-8F-MY	B	22-18	8	Red				
644-PV18-6FX-MY	B	22-18	6	Red				
644-PV18-6FN-MY	B	22-18	6	Red				
644-PV18-8FX-MY	B	22-18	8	Red				
644-PV18-10F-MY	B	22-18	10	Red				
644-PV14-8F-M	B	16-14	8	Blue				
644-PV14-10F-M	B	16-14	10	Blue				
644-PV14-6FX-M	B	16-14	6	Blue				
644-PV14-6FN-M	B	16-14	6	Blue				
644-PV14-8FX-M	B	16-14	8	Blue				
644-PV14-10FX-M	B	16-14	10	Blue				

MOUSER STOCK NO.	Fig.	Wire Size	Stud Size	Color	Price Each			
					1	100	500	1000
Vinyl Fork (Cont.)								
644-PV14-14F-M	B	16-14	1/4	Blue				
644-PV10-6F-D	B	12-10	6	Yellow				
644-PV10-10F-D	B	12-10	10	Yellow				
644-PV10-14F-D	B	12-10	1/4	Yellow				
644-PV10-14FX-L	B	12-10	1/4	Yellow				
Nylon Fork Insulated								
644-PNF18-6F-M	B	22-18	6	Red				
644-PNF18-8F-M	B	22-18	8	Red				
644-PNF18-10F-M	B	22-18	10	Red				
644-PNF18-14F-C	B	22-18	1/4	Red				
644-PNF14-6F-M	B	16-14	6	Blue				
644-PNF14-8F-M	B	16-14	8	Blue				
644-PNF14-10F-M	B	16-14	10	Blue				
644-PNF10-6F-L	B	12-10	6	Yellow				
644-PNF10-10F-L	B	12-10	10	Yellow				
Vinyl Locking Fork								
644-PV18-6LF-MY	C	22-18	6	Red				
Nylon Locking Fork								
644-PN18-8LF-M	C	22-18	8	Red				
644-PN14-6LF-M	C	16-14	6	Blue				
644-PN14-8LF-M	C	16-14	8	Blue				
644-PN14-10LF-M	C	16-14	10	Blue				
Vinyl Flanged Fork								
644-PN18-6LF-M	D	22-18	6	Red				
644-PN18-8FF-M	D	22-18	8	Red				
644-PN18-10FF-M	D	22-18	10	Red				
644-PN14-6FF-M	D	16-14	6	Blue				
Vinyl Flanged Fork								
644-PN14-8FF-M	D	16-14	8	Blue				
Vinyl Butt Splice								
644-BSV18X-MY	E	22-18	---	Red				
644-BSV14X-M	E	16-14	---	Blue				
644-BSV10X-D	E	12-10	---	Yellow				
Nylon Butt Splice								
644-BSN14-M	E	16-14	---	Blue				
Disconnect (Male)								
644-DNF18-250FIM-M	F	22-18	.250x.032	Red				
644-DNF18-250FIMB-L	F	22-18	.250x.032	Red				
644-DNF14-250FIMB-L	F	16-14	.250x.032	Blue				
644-DNF14-250M-M	G	16-14	.250x.032	Blue				
644-DV14-250MB-M	G	16-14	.250x.032	Blue				
644-DNF10-250M-D	G	12-10	.250x.032	Yellow				
Disconnect (Female)								
644-DNF18-110-M	H	22-18	.110x.032	Red				
644-DNF18-187-M	H	22-18	.187x.032	Red				
644-DNF18-250-M	H	22-18	.250x.032	Red				
644-DNF18-250FIB-M	I	22-18	.250x.032	Red				
644-DNF14-110-M	H	16-14	.110x.032	Blue				
644-DNF14-187-M	H	16-14	.187x.032	Blue				
644-DNF14-250-M	H	16-14	.250x.032	Blue				
644-DV14-250B-M	H	16-14	.250x.032	Blue				
644-DNF14-250FIB-M	I	16-14	.250x.032	Blue				
644-DNF10-250FI-D	I	12-10	.250x.032	Yellow				
Right Angle Disconnect (Female) Tab Width								
644-DNFR14-250B-M	J	16-14	.250x.032	Blue				

Terminals Panduit