

TYCO ELECTRONICS Barrier Terminal Blocks

RoHS Compliant This product is RoHS compliant.

.325" PITCH, DUAL BARRIER, INTERLOCKING

Modular Interlocking design; Create terminal blocks up to 16 positions without losing centerline spacing

- #6-32 Screws on .325" Centers
- Single Row PCB Mount
- Wire Range 16-22 AWG
- 15A UL Rating
- 300V UL Rating
- Housing: UL94V-0; Color: Black




For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Tyco Electronics Part No.	No. of Positions	Length (in.)	Price Each			
				1	25	50	100
571-1977477-2	1977477-2	2	0.649				
571-1977477-3	1977477-3	3	0.974				

.325" PITCH, DUAL BARRIER, SINGLE ROW

- #6-32 screws on .325" centers
- UL94V-0
- Housing Material: Thermoplastic Polyamide
- Printed Circuit Pin
- 14-22 AWG
- 20A rating
- Color: Black

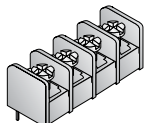


For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Tyco Electronics Part No.	No. of Positions	Length (in.)	Price Each			
				1	25	50	100
Steel Binding Combo Head Screws							
571-14376676	1437667-6	2	.325				
571-114376670	1-1437667-0	4	.975				
571-114376672	1-1437667-2	6	1.625				
571-114376675	1-1437667-5	8	2.275				
571-114376679	1-1437667-9	12	3.575				
Steel Wire Clamp Combo Head Screws							
571-214376674	2-1437667-4	2	0.325				
571-214376675	2-1437667-5	3	0.650				
571-214376676	2-1437667-6	4	0.975				
571-214376678	2-1437667-8	5	1.300				
571-214376679	2-1437667-9	6	1.625				
571-314376671	3-1437667-1	8	2.275				
571-314376672	3-1437667-2	9	2.600				
571-314376673	3-1437667-3	10	2.925				

.375" PITCH, LOW PROFILE, DUAL BARRIER, SINGLE ROW

- Flat, all positions filled
- Housing Material: Thermoplastic Polyamide
- #6-32 screws on .375" centers
- UL94V-0
- Printed Circuit Pin
- 12-22 AWG
- 20A rating
- Color: Black

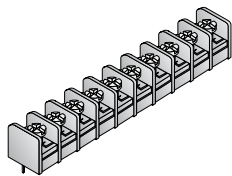

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Tyco Electronics Part No.	No. of Positions	Length (in.)	Price Each			
				1	25	50	100
Steel Binding Combo Head Screws							
571-14376644	1437664-4	2	.815				
571-14376645	1437664-5	3	1.19				
571-14376646	1437664-6	4	1.565				
571-14376647	1437664-7	5	1.94				
571-14376649	1437664-9	7	2.315				
571-114376640	1-1437664-0	6	2.69				
571-114376641	1-1437664-1	8	3.065				
571-114376643	1-1437664-3	9	3.44				
571-114376644	1-1437664-4	10	3.82				
571-114376647	1-1437664-7	12	4.57				
Steel Clamp-Plate Combo Head Screws							
571-314376640	3-1437664-0	2	0.815				
571-314376641	3-1437664-1	3	1.190				
571-314376643	3-1437664-3	4	1.565				
571-314376645	3-1437664-5	5	1.940				
571-314376648	3-1437664-8	6	2.315				
571-414376640	4-1437664-0	7	2.690				
571-414376641	4-1437664-1	8	3.065				
571-414376642	4-1437664-2	9	3.440				

DUAL BARRIER STRIPS, DOUBLE-ROW

Double row, dual barrier strips for wire-to-wire applications. These parts also allow end users to complete the wiring to a separate screw without disturbing the factory wiring. Closed bottom design allows for mounting direct to sheet metal panel.

- Specifications:**
- Insulator body: UL 94V-0 Thermoplastic, Black
 - Terminal: Brass, Tin Plated
 - Screw: #6-32 Steel, Nickel Plated
 - Molded to Length

.374 Dual Barrier Strips, Double Row with Binding Head Screws


- Electrical:**
- Current rating: 20A, 300VAC
 - Wire range: 12-22 AWG
 - Withstanding voltage: 2000 VAC min.
 - Temperature: -40°C to +105°C

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Tyco Electronics Part No.	No. of Positions	Length (in.)	Price Each			
				1	25	50	100
571-15463062	1546306-2	2	1.42				
571-15463063	1546306-3	3	1.80				
571-15463064	1546306-4	4	2.17				
571-15463065	1546306-5	5	2.55				
571-15463066	1546306-6	6	2.92				
571-15463067	1546306-7	7	3.30				
571-15463068	1546306-8	8	3.67				
571-115463060	1-1546306-0	10	4.41				
571-115463062	1-1546306-2	12	5.16				
571-115463064	1-1546306-4	14	5.91				
571-115463066	1-1546306-6	16	6.65				
571-215463060	2-1546306-0	20	8.15				

.250" PITCH, TRI-BARRIER, SINGLE ROW

- Housing Material: Polypropylene
- 10A rating
- 18-22 AWG wire range
- UL94V-0
- #3-48 screws on .250" centers
- Printed Circuit Pin, Vertical
- Phil-slot Head
- Color: Black

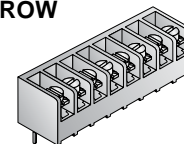

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Tyco Electronics Part No.	No. of Positions	Length (in.)	Price Each			
				1	25	50	100
571-314376463	3-1437646-3	2	.57				
571-314376469	3-1437646-9	3	.82				
571-414376462	4-1437646-2	4	1.07				
571-414376465	4-1437646-5	5	1.32				
571-514376460	5-1437646-0	6	1.57				
571-514376464	5-1437646-4	7	1.82				
571-514376467	5-1437646-7	8	2.07				
571-514376469	5-1437646-9	9	2.32				
571-614376462	6-1437646-2	10	2.57				

.325" PITCH, TRI-BARRIER, SINGLE ROW

- 20A rating
- 14-22 AWG
- Housing Material: Polyamide
- Color: Black
- #4-40 screws on .325" centers
- Printed Circuit Pin, Vertical
- UL94V-0
- Phil-Slot Head

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Tyco Electronics Part No.	No. of Positions	Length (in.)	Price Each			
				1	25	50	100
571-514376487	5-1437648-7	2	.705				
571-614376481	6-1437648-1	3	1.03				
571-614376487	6-1437648-7	4	1.35				
571-714376484	7-1437648-4	5	1.68				
571-814376480	8-1437648-0	6	2.00				
571-814376486	8-1437648-6	7	2.33				
571-914376481	9-1437648-1	8	2.65				
571-14376491	1437649-1	9	2.98				
571-14376495	1437649-5	10	3.30				

.375" PITCH, TRI-BARRIER, SINGLE ROW

- UL94V-0
- 25A rating
- 12-22 AWG
- Housing Material: Polypropylene
- #6-32 screws on .375" centers
- Printed Circuit Pin, Vertical
- Phil-slot head

For quantities of 200 and up, call for quote.

MOUSER STOCK NO.	Tyco Electronics Part No.	No. of Positions	Length (in.)	Price Each			
				1	25	50	100
571-314376529	3-1437652-9	2	.815				
571-514376524	5-1437652-4	3	1.19				
571-614376527	6-1437652-7	4	1.56				
571-814376522	8-1437652-2	5	1.94				
571-914376525	9-1437652-5	6	2.31				
571-114376533	1-1437653-3	8	3.06				
571-214376535	2-1437653-5	9	3.44				
571-314376535	3-1437653-5	10	3.81				
571-514376531	5-1437653-1	12	4.56				
571-614376538	6-1437653-8	14	5.31				
571-814376530	8-1437653-0	16	6.06				