


Pushbutton Switches

RoHS Compliant This product is RoHS compliant.

DIMENSIONS: in.

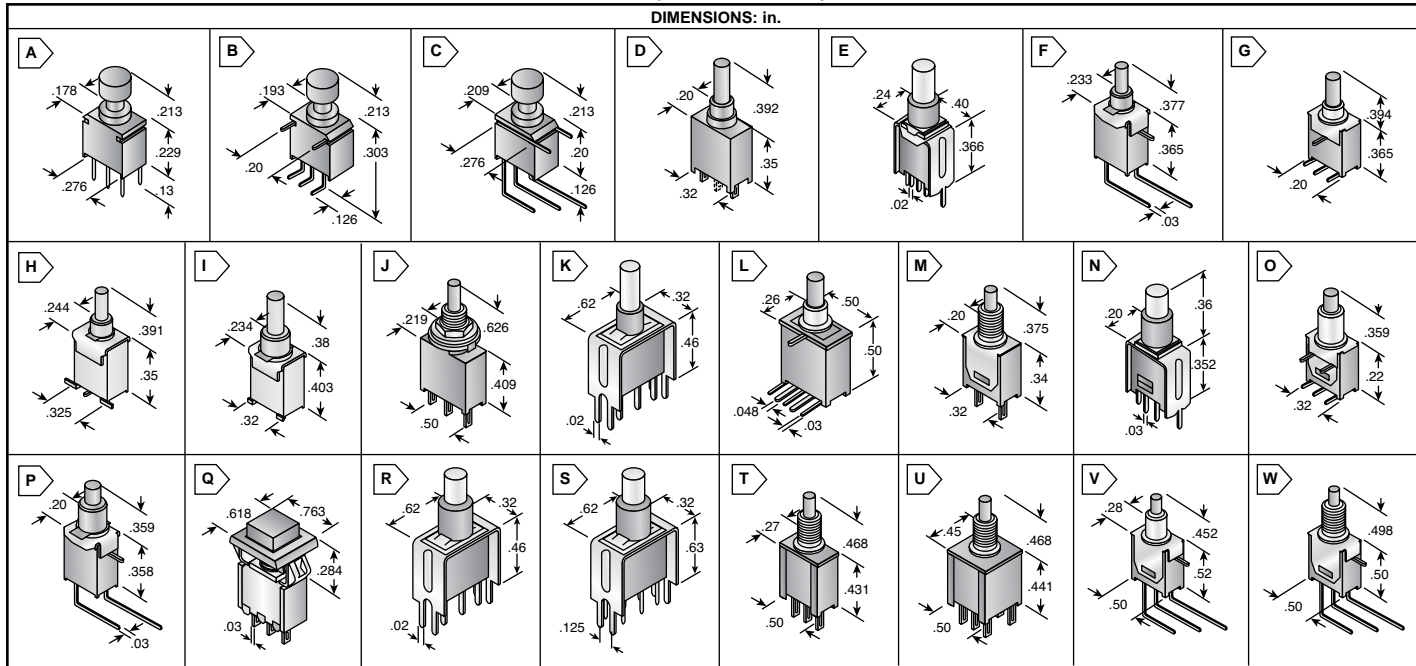

MOUNTAIN SWITCH SEALED PUSHBUTTON SWITCHES

Ultra-Miniature

- Rating: 0.4 Volt-Amp (VA) max. / 20V max. (AC or DC)



RoHS Compliant

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Type	Circuit	Contact Resistance	Price Each			
					1	50	100	500
107-8219-EV	A	SPDT	On-(On)	100mΩ Max.				
107-8214-EV	A	DPDT	On-(On)	100mΩ Max.				
107-8216-EV	B	SPDT	On-(On)	100mΩ Max.				
107-8215-EV	B	DPDT	On-(On)	100mΩ Max.				
107-8217-EV	C	SPDT	On-(On)	100mΩ Max.				
107-8218-EV	C	DPDT	On-(On)	100mΩ Max.				

Sub-Miniature

- Rating: 0.4 Volt-Amps (VA) max. / 20V max. (AC or DC)

For quantities of 1000 and up, call for quote.

PC Mount					
MOUSER STOCK NO.	Fig.	Type	Circuit	Contact Resistance	Price Each
107-3013-EVX	D	SPST	Off-(On)	20mΩ Max.	
107-3015-EVX	D	SPDT	On-(On)	20mΩ Max.	
107-3017-EVX	E	SPDT	On-(On)	20mΩ Max.	
107-3014-EVX	F	SPST	Off-(On)	20mΩ Max.	
107-3016-EVX	G	SPDT	On-(On)	20mΩ Max.	
Surface Mount					
107-3018-EVX	H	SPDT	On-(On)	20mΩ Max.	
107-3020-EVX	H	SPDT	Off-(On)	20mΩ Max.	
107-3019-EVX	I	SPDT	On-(On)	20mΩ Max.	
107-3021-EVX	I	SPST	Off-(On)	20mΩ Max.	

Snap Acting

- Rating: 1A/250VAC; 3A/120VAC or 28VDC

For quantities of 1000 and up, call for quote.


MOUSER STOCK NO.	Fig.	Type	Circuit	Contact Resistance	Price Each			
					1	50	100	500
107-3001-EVX	J	SPDT	On-(On)	20mΩ Max.				
107-3003-EVX	K	SPDT	On-(On)	20mΩ Max.				
107-3002-EVX	L	SPDT	On-(On)	20mΩ Max.				

MOUNTAIN SWITCH LP12 SERIES ILLUMINATED PUSHBUTTON SWITCHES

- Rating: 50mA/12VDC
- Contact resistance: 100mΩ
- Operating force: 250gf max.
- Type: SPST momentary
- Bounce: 10msec. max
- LED: 15mA/4.2V



RoHS Compliant

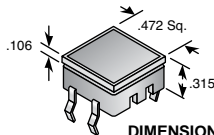

DIMENSIONS: in.

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	LED Color	Price Each			
		1	50	100	500
107-LP12-7-EV	Green				
107-LP12-5-EV	Red				
107-LP12-3-EV	Yellow				

ALPHA FOOT SWITCHES

Specifications:


- Rating: 6A/125VAC, 3A/250VAC, 4A/30VDC
- Contact resistance: 50mΩ silver contacts
- Insulation resistance: 500VDC-100MΩ min.
- Dielectric strength: 1000VAC for 1 minute
- Operating life: 30,000 cycles



RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Alpha Part No.	Type	Terminals	Operating Force	Price Each			
					1	25	50	100
107-SF12011F-L	SF12011F-0202-20R-L-011	DPDT Latching	PC	1.6 ± 0.5Kgf				
107-SF12011F-M	SF12011F-0202-20R-M-011	DPDT Momentary	PC	2.8 ± 0.8Kgf				
107-SF12020F-L	SF12020F-0202-20R-L-011	DPDT Latching	Solder Solder	1.6 ± 0.5Kgf				
107-SF12020F-M	SF12020F-0202-20R-M-011	DPDT Momentary	Solder Solder	2.8 ± 0.8Kgf				

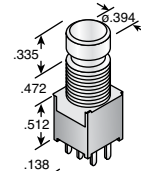

DIMENSIONS: in.

Pushbutton Switches