


WELL BUYING Pushbutton Switches



RoHS Compliant This product is RoHS compliant.

DIMENSIONS: in.

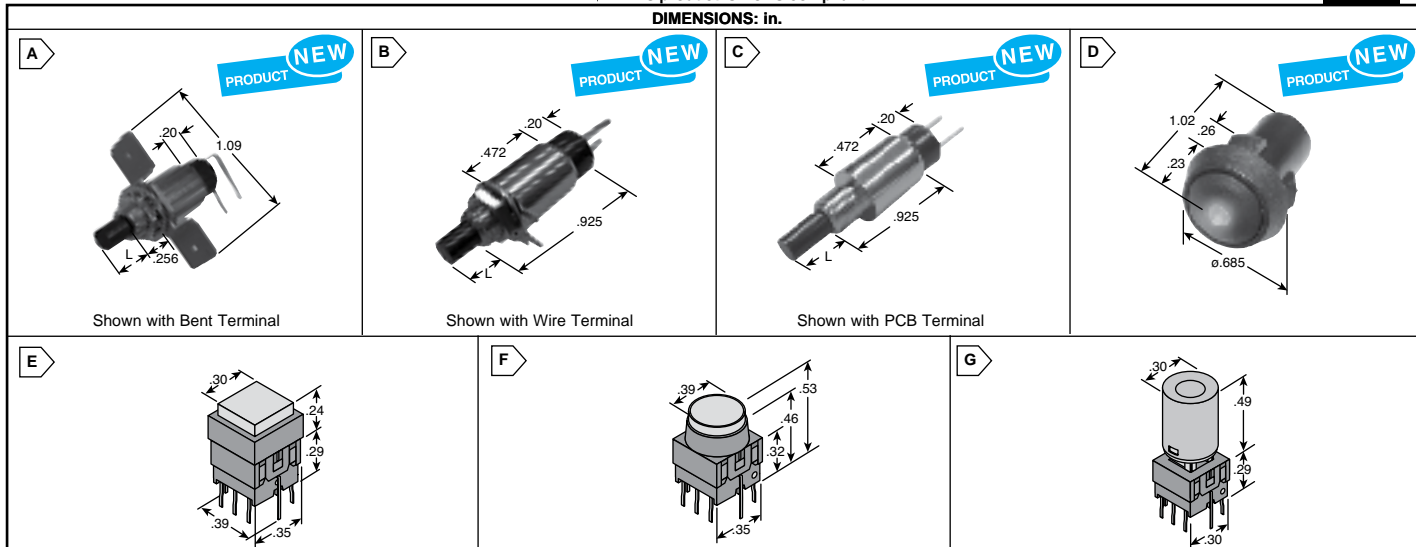

WELL BUYING PUSHBUTTON SWITCHES

DIMENSIONS: in.

RP Series

Specifications:

- Rating: 1A/120VAC or 28VDC
- Operating force: 650±150gf

RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Well Buying Part No.	Fig.	Circuit	Terminal Type	Knob (L) length (in)	Price Each		
						1	50	100
107-RP-MBNS	RP-MBNS	A	Off-(On)	B	0.20			
107-RP-MWLL	RP-MWLL	A	Off-On	W	0.26			
107-RP-MWNL	RP-MWNL	A	Off-(On)	W	0.26			
107-RP-MWNS	RP-MWNS	A	Off-(On)	W	0.20			
107-RP-PBLS	RP-PBLS	B	Off-On	B	0.20			
107-RP-PBNS	RP-PBNS	B	Off-(On)	B	0.20			
107-RP-PPLS	RP-PPLS	B	Off-On	P	0.20			
107-RP-SBLS	RP-SBLS	C	Off-On	B	0.20			
107-RP-SBNS	RP-SBNS	C	Off-(On)	B	0.20			
107-RP-SPLS	RP-SPLS	C	Off-On	P	0.20			
107-RP-SPNL	RP-SPNL	C	Off-(On)	P	0.26			
107-RP-SPNS	RP-SPNS	C	Off-(On)	P	0.20			
107-RP-SWLL	RP-SWLL	C	Off-On	W	0.26			
107-RP-SWLS	RP-SWLS	C	Off-On	W	0.20			
107-RP-SWNL	RP-SWNL	C	Off-(On)	W	0.26			
107-RP-SWNS	RP-SWNS	C	Off-(On)	W	0.20			

PS001W Series

Specifications:

- Rating: 0.1A/30VDC
- Operating force: 400±100gf
- Circuit: Off-(On)

Applications:

- Automotive Industry
- Office Appliance
- Communication Equipment

For quantities of 500 and up, call for quote.

RoHS Compliant

MOUSER STOCK NO.	Well Buying Part No.	Fig.	LED Color	Cable and Connector	Water Proof Rating	Price Each		
						1	50	100
107-PS001W-KWUBXX	PS001W-N11NAKWUBXX	D	Ultra Blue	without	IP65			
107-PS001W-KWUBXX-W2	PS001W-N11NAKWUBXX-W200	D	Ultra Blue	with	IP67			
107-PS001W-KWUGXX	PS001W-N11NAKWUGXX	D	Ultra Green	without	IP65			
107-PS001W-KWUGXX-W2	PS001W-N11NAKWUGXX-W200	D	Ultra Green	with	IP67			
107-PS001W-KWURXX	PS001W-N11NAKWURXX	D	Ultra Red	without	IP65			
107-PS001W-KWURXX-W2	PS001W-N11NAKWURXX-W200	D	Ultra Red	with	IP67			
107-PS001W-KWUWXX	PS001W-N11NAKWUWXX	D	Ultra White	without	IP65			
107-PS001W-KWUWXX-W2	PS001W-N11NAKWUWXX-W200	D	Ultra White	with	IP67			
107-PS001W-KWUYXX	PS001W-N11NAKWUYXX	D	Ultra Yellow	without	IP65			
107-PS001W-KWUYXX-W2	PS001W-N11NAKWUYXX-W200	D	Ultra Yellow	with	IP67			
107-PS001W-KWXXXX	PS001W-N11NAKWXXXX	D	-	without	IP65			
107-PS001W-KWXXXX-W2	PS001W-N11NAKWXXXX-W200	D	-	with	IP67			

PS004 Series

Specifications:

- Rating: 0.1A/30VDC max; 0.1mA/5VDC min
- Operating force: 250±100gf
- Type: DPDT

Applications:

- Instrumentation
- Communication products
- Computer products

For quantities of 500 and up, call for quote.

RoHS Compliant

MOUSER STOCK NO.	Well Buying Part No.	Fig.	Circuit	LED Color	Cap Color	Price Each		
						1	50	100
107-PS522SUR-EV	PS004-N22NPS1KTURXX	E	On-(On)	Ultra Red	Transparent			
107-PS522SUG-EV	PS004-N22NPS1KTUGXX	E	On-(On)	Ultra Green	Transparent			
107-PS522SUY-EV	PS004-N22NPS1KTUYXX	E	On-(On)	Ultra Yellow	Transparent			
107-PS322SUR-EV	PS004-L22NPS1KTURXX	E	On-On	Ultra Red	Transparent			
107-PS322SUG-EV	PS004-L22NPS1KTUGXX	E	On-On	Ultra Green	Transparent			
107-PS322SUY-EV	PS004-L22NPS1KTUYXX	E	On-On	Ultra Yellow	Transparent			
107-PS522RUG-EV	PS004-N22NPR1KTUGXX	E	On-(On)	Ultra Green	Transparent			
107-PS522RUY-EV	PS004-N22NPR1XTUYXX	F	On-(On)	Ultra Yellow	Transparent			
107-PS522RUR-EV	PS004-N22NPR1AXTURUG	G	On-(On)	Ultra Red/Ultra Grn	Transparent			
107-PS522RURX-EV	PS004-N22NPR1AXRURXX	G	On-(On)	Ultra Red	Red			
107-PS522RUB-EV	PS004-N22NPR1AXBUBXX	G	On-(On)	Ultra Blue	Blue			
107-PS322RUR-EV	PS004-L22NPR1AXTURXX	G	On-On	Ultra Red	Transparent			
107-PS322RUG-EV	PS004-L22NPR1AXTUGXX	G	On-On	Ultra Green	Transparent			
107-PS322RUY-EV	PS004-L22NPR1AXTUYXX	G	On-On	Ultra Yellow	Transparent			