


HONEYWELL Limit Switches

 This product is RoHS compliant.

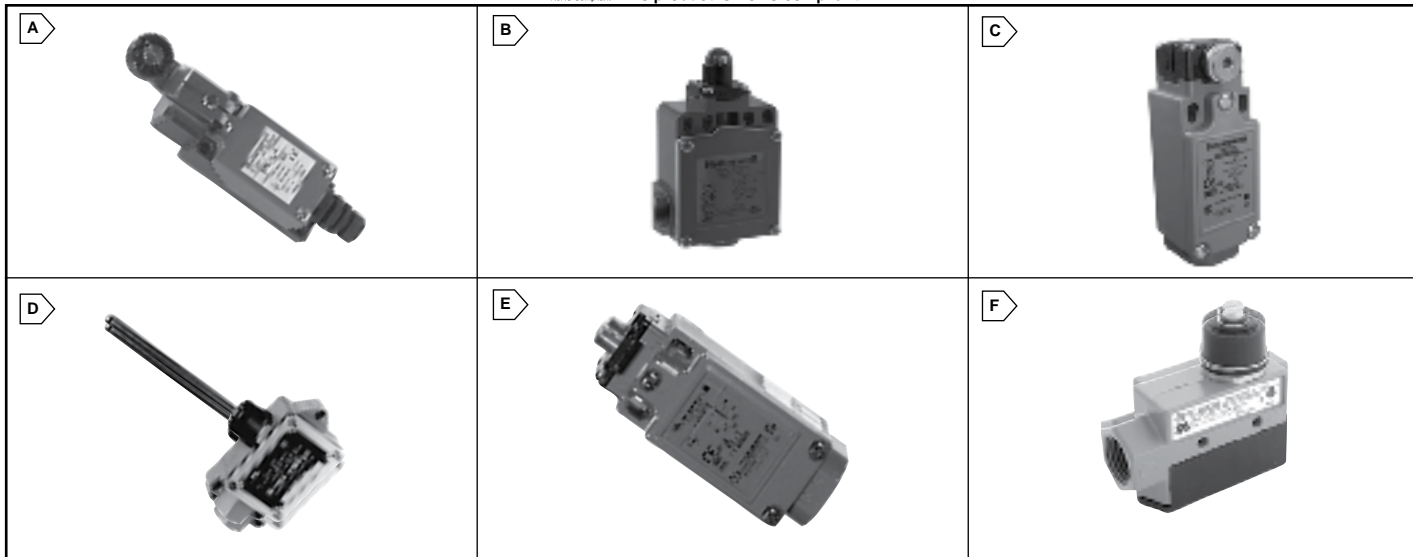

MICRO SWITCH™ GLOBAL LIMIT SWITCHES

Designed to IEC standard for world-wide acceptance. These metal or plastic switches are available with a wide variety of actuators, electrical specifications, terminations, circuitry and sealing ratings.



* Part is UL only.

MOUSER STOCK NO.	Honeywell Part No.	Fig.	Contact Form	Circuitry	Actuator Type	Operating Force (max.)	Lever Style	Price Each		
								1	10	50
*785-SZL-VL-H	SZL-VL-H	A	SPDT	1 NC 1 NO	Roller Plunger	8.83 N	None			
*785-SZL-VL-G	SZL-VL-G	A	SPDT	1 NC 1 NO	Wobble-Coil Spring	0.88 N	None			
*785-SZL-VL-F	SZL-VL-F	A	SPDT	1 NC 1 NO	Wobble-Plastic Rod	0.88 N	None			
*785-SZL-VL-D	SZL-VL-D	A	SPDT	1 NC 1 NO	Top Plunger	8.83 N	None			
*785-SZL-VL-C	SZL-VL-C	A	SPDT	1 NC 1 NO	Side Rotary	2.0-7.84N	None			
*785-SZL-VL-B	SZL-VL-B	A	SPDT	1 NC 1 NO	Side Rotary	3.35-7.84 N	None			
*785-SZL-VL-A	SZL-VL-A	A	SPDT	1 NC 1 NO	Side Rotary	5.88 N	None			
785-GLEA24C	GLEA24C	B	DPDT	2 NC 2 NO	Top Roller Plunger	13.0 N	None			
785-GLEA24A1B	GLEA24A1B	B	DPDT	2 NC 2 NO	Side Rotary	0.165 N	Roller-Std			
785-GLDA01A4J	GLDA01A4J	C	SPDT	1 NC 1 NO	Side Rotary	0.120 N	Rod-adj.			
785-GLDA01A2A	GLDA01A2A	C	SPDT	1 NC 1 NO	Side Rotary	0.120 N	Roller-adj.			
785-GLDA01A1B	GLDA01A1B	C	SPDT	1 NC 1 NO	Side Rotary	0.120 N	Roller-Std, Steel			
785-GLDA01A1A	GLDA01A1A	C	SPDT	1 NC 1 NO	Side Rotary	0.120 N	Roller-Std, Plastic			
785-GLCA01C	GLCA01C	D	SPDT	1 NC 1 NO	Top Roller Plunger	16.0 N	None			
785-GLCA01B	GLCA01B	E	SPDT	1 NC 1 NO	Top Plunger	16.0 N	None			
785-GLCA01A4J	GLCA01A4J	E	SPDT	1 NC 1 NO	Side Rotary	0.120 N	Rod-adj.			
785-GLCA01A2B	GLCA01A2B	E	SPDT	1 NC 1 NO	Side Rotary	0.120 N	Roller-adj., Steel			
785-GLCA01A2A	GLCA01A2A	E	SPDT	1 NC 1 NO	Side Rotary	0.120 N	Roller-adj., Plastic			
785-GLCA01A1B	GLCA01A1B	E	SPDT	1 NC 1 NO	Side Rotary	0.120 N	Roller-Std, Steel			
785-GLCA01A1A	GLCA01A1A	E	SPDT	1 NC 1 NO	Side Rotary	0.120 N	Roller-Std, Plastic			
785-GLAA01B	GLAA01B	E	SPDT	1 NC 1 NO	Top Plunger	16.0 N	None			

Honeywell

Limit Switches

MICRO SWITCH™ MEDIUM-DUTY LIMIT SWITCHES

Application-proven enclosed switches (precision snap-acting switches sealed in rugged metal housing). Honeywell Sensing and Control's (S&C) limit switches offer superior flexibility and performance.



* Part is UL only.

785-BAF1-2RN-RH	BAF1-2RN-RH	D	SPDT	1 NC 1 NO	Top Plunger	11.2 N	None			
785-BAF1-2RN18-LH	BAF1-2RN18-LH	D	SPDT	1 NC 1 NO	Wobble-Coil Spring, LH	--	None			
785-BAF1-2RN18-RH	BAF1-2RN18-RH	D	SPDT	1 NC 1 NO	Wobble-Coil Spring, RH	--	None			
785-BAF1-2RN2-LH	BAF1-2RN2-LH	D	SPDT	1 NC 1 NO	Top Roller Arm	8.90 N	Roller-adj.			
785-BAF1-2RQ9-RH	BAF1-2RQ9-RH	D	SPDT	1 NC 1 NO	Top Roller Plunger	11.1 N	None			
785-BAF1-3RNX1	BAF1-3RNX1	D	SPDT	1 NC 1 NO	Top Plunger	7.79 N	None			
785-BZE6-2RN	BZE6-2RN	F	SPDT	1 NC 1 NO	Top Plunger	2.50 N	None			
*785-BZE6-2RN-S	BZE6-2RN-S	F	SPDT	1 NC 1 NO	Top Plunger	2.50 N	None			
785-BZE6-2RN18	BZE6-2RN18	F	SPDT	1 NC 1 NO	Wobble-Coil Spring	1.95 N	None			
785-BZE6-2RN2	BZE6-2RN2	F	SPDT	1 NC 1 NO	Top Roller Arm	5.56 N	Roller-adj.			
785-BZE6-2RN4	BZE6-2RN4	F	SPDT	1 NC 1 NO	Manual Palm Button	5.56 N	None			
785-BZE6-2RN7	BZE6-2RN7	F	SPDT	1 NC 1 NO	Top Plunger	6.67 N	None			
785-BZE6-2RN72	BZE6-2RN72	F	SPDT	1 NC 1 NO	Top Plunger	6.67 N	None			
785-BZE6-2RN80	BZE6-2RN80	F	SPDT	1 NC 1 NO	Top Roller Plunger	6.67 N	None			
785-BZE6-2RQ	BZE6-2RQ	F	SPDT	1 NC 1 NO	Top Plunger	3.61 N	None			
785-BZE6-2RQ62	BZE6-2RQ62	F	SPDT	1 NC 1 NO	Low Force Rod	1.39 N	Rod-Low Force			
785-BZE6-2RQ8	BZE6-2RQ8	F	SPDT	1 NC 1 NO	Top Roller Plunger	3.61 N	None			
785-BZE6-2RQ81	BZE6-2RQ81	F	SPDT	1 NC 1 NO	Cross Roller Plunger	3.61 N	None			
785-BZE6-RNX1	BZE6-RNX1	F	SPDT	1 NC 1 NO	Top Plunger	5.56 N	None			
*785-BZG1-2RN	BZG1-2RN	F	SPDT	1 NC 1 NO	Top Plunger	6.67 N	None			
*785-BZG1-2RN2	BZG1-2RN2	F	SPDT	1 NC 1 NO	Top Roller Arm	5.56 N	Roller-adj.			
785-BZV6-2RN	BZV6-2RN	F	SPDT	1 NC 1 NO	Top Plunger	6.67 N	None			
785-BZV6-2RN18	BZV6-2RN18	F	SPDT	1 NC 1 NO	Wobble - Coil Spring	1.95 N	None			
785-BZV6-2RN2	BZV6-2RN2	F	SPDT	1 NC 1 NO	Top Roller Arm	5.56 N	Roller-adj.			
785-BZV6-2RQ2	BZV6-2RQ2	F	SPDT	1 NC 1 NO	Top Roller Arm	5.00 N	Roller-adj.			
785-BZV6-2RQ8	BZV6-2RQ8	F	SPDT	1 NC 1 NO	Top Roller Plunger	3.61 N	None			
785-DTE6-2RN	DTE6-2RN	F	SPDT	2 NC 2 NO	Top Plunger	16.4 N	None			
785-DTE6-2RN2	DTE6-2RN2	F	SPDT	2 NC 2 NO	Top Roller Arm	13.34 N	Roller-adj.			
785-DTE6-2RN80	DTE6-2RN80	F	SPDT	2 NC 2 NO	Top Roller Plunger	13.34 N	None			
785-DTE6-2RQ2	DTE6-2RQ2	F	SPDT	2 NC 2 NO	Top Roller Arm	5.57 N	Roller-adj.			
785-DTE6-2RQ9	DTE6-2RQ9	F	SPDT	2 NC 2 NO	Top Roller Plunger	13.34 N	None			
785-DTV6-2RN	DTV6-2RN	F	SPDT	2 NC 2 NO	Top Plunger	16.4 N	None			