

# ON SEMICONDUCTOR Zener Diodes


ON Semiconductor®



RoHS Compliant This product is RoHS compliant.

Diodes & Rectifiers

ON Semiconductor

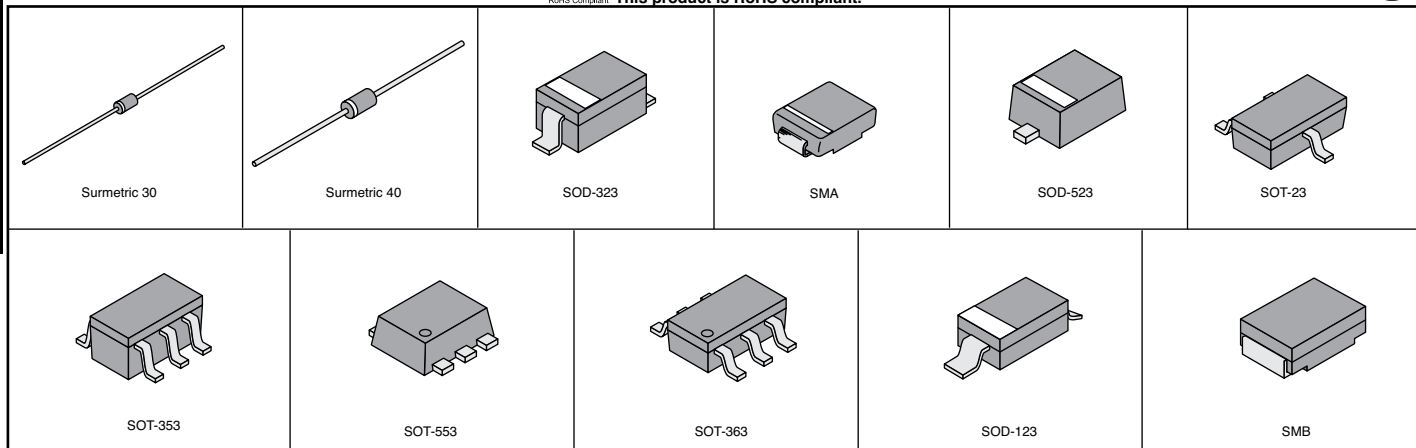

ON Semiconductor®



## ZENER DIODES

For quantities of 1000 and up, call for quote.



RoHS Compliant

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	ON Semi Part No.	Package	P Max (W)	VZ Typ. (V)	Price Each			
					1	25	100	500
<b>Axial Lead</b>								
863-1N5920BG	1N5920BG	Surmetic 30	3	6.2				
863-1N5929BG	1N5929BG	Surmetic 30	3	15				
863-1N5934BG	1N5934BG	Surmetic 30	3	24				
863-1N5953BG	1N5953BG	Surmetic 30	3	150				
863-1N5956BG	1N5956BG	Surmetic 30	3	200				
863-1N5333BG	1N5333BG	Surmetic 40	5	3.3				
863-1N5335BG	1N5335BG	Surmetic 40	5	3.9				
863-1N5337BG	1N5337BG	Surmetic 40	5	4.7				
863-1N5338BG	1N5338BG	Surmetic 40	5	5.1				
863-1N5339BG	1N5339BG	Surmetic 40	5	5.6				
863-1N5340BG	1N5340BG	Surmetic 40	5	6				
863-1N5341BG	1N5341BG	Surmetic 40	5	6.2				
863-1N5342BG	1N5342BG	Surmetic 40	5	6.8				
863-1N5343BG	1N5343BG	Surmetic 40	5	7.5				
863-1N5344BG	1N5344BG	Surmetic 40	5	8.2				
863-1N5346BG	1N5346BG	Surmetic 40	5	9.1				
863-1N5347BG	1N5347BG	Surmetic 40	5	10				
863-1N5348BG	1N5348BG	Surmetic 40	5	11				
863-1N5349BG	1N5349BG	Surmetic 40	5	12				
863-1N5350BG	1N5350BG	Surmetic 40	5	13				
863-1N5351BG	1N5351BG	Surmetic 40	5	14				
863-1N5352BG	1N5352BG	Surmetic 40	5	15				
863-1N5353BG	1N5353BG	Surmetic 40	5	16				
863-1N5355BG	1N5355BG	Surmetic 40	5	18				
863-1N5357BG	1N5357BG	Surmetic 40	5	20				
863-1N5358BG	1N5358BG	Surmetic 40	5	22				
863-1N5359BG	1N5359BG	Surmetic 40	5	24				
863-1N5360BG	1N5360BG	Surmetic 40	5	25				
863-1N5361BG	1N5361BG	Surmetic 40	5	27				
863-1N5362BG	1N5362BG	Surmetic 40	5	28				
863-1N5363BG	1N5363BG	Surmetic 40	5	30				
863-1N5364BG	1N5364BG	Surmetic 40	5	33				
863-1N5365BG	1N5365BG	Surmetic 40	5	36				
863-1N5366BG	1N5366BG	Surmetic 40	5	39				
863-1N5368BG	1N5368BG	Surmetic 40	5	47				
863-1N5373BG	1N5373BG	Surmetic 40	5	68				
863-1N5374BG	1N5374BG	Surmetic 40	5	75				
863-1N5378BG	1N5378BG	Surmetic 40	5	100				
863-1N5384BG	1N5384BG	Surmetic 40	5	160				
863-1N5386BG	1N5386BG	Surmetic 40	5	180				
<b>Surface Mount</b>								
863-MM3Z12VT1G	MM3Z12VT1G	SOD-323	0.2	12				
863-MM3Z4V7T1G	MM3Z4V7T1G	SOD-323	0.2	4.7				
863-MM3Z5V6T1G	MM3Z5V6T1G	SOD-323	0.2	5.6				
863-1SMA5921BT3G	1SMA5921BT3G	SMA	1.5	6.8				
863-1SMB5939BT3G	1SMB5939BT3G	SMB	3	39				
863-BZX84C10LT1G	BZX84C10LT1G	SOT-23	0.225	10				
863-BZX84C13LT1G	BZX84C13LT1G	SOT-23	0.225	13				
863-BZX84C15LT1G	BZX84C15LT1G	SOT-23	0.225	15				
863-BZX84C16LT1G	BZX84C16LT1G	SOT-23	0.225	16				
863-BZX84C27LT3G	BZX84C27LT3G	SOT-23	0.225	27				
863-BZX84C2V4LT1G	BZX84C2V4LT1G	SOT-23	0.225	2.4				
863-BZX84C33LT1G	BZX84C33LT1G	SOT-23	0.225	33				
863-BZX84C3V3LT1G	BZX84C3V3LT1G	SOT-23	0.225	3.3				
863-BZX84C3V9LT1G	BZX84C3V9LT1G	SOT-23	0.225	3.9				
863-BZX84C47LT1G	BZX84C47LT1G	SOT-23	0.225	47				
863-BZX84C4V3LT1G	BZX84C4V3LT1G	SOT-23	0.225	4.3				

MOUSER STOCK NO.	ON Semi Part No.	Package	P Max (W)	VZ Typ. (V)	Price Each			
					1	25	100	500
<b>Surface Mount (cont.)</b>								
863-BZX84C51LT1G	BZX84C51LT1G	SOT-23	0.225	51				
863-BZX84C6V8LT1G	BZX84C6V8LT1G	SOT-23	0.225	6.8				
863-BZX84C7V5LT1G	BZX84C7V5LT1G	SOT-23	0.225	7.5				
863-BZX84C8V2LT1G	BZX84C8V2LT1G	SOT-23	0.225	8.2				
863-MMBZ5238BLT1G	MMBZ5238BLT1G	SOT-23	0.225	8.7				
863-MMBZ5244BLT1G	MMBZ5244BLT1G	SOT-23	0.225	14				
863-MMBZ5247BLT1G	MMBZ5247BLT1G	SOT-23	0.225	17				
863-MSQA6V1W5T2G	MSQA6V1W5T2G	SOT-353	0.385	6.6				
863-DF6A6.8FUT1G	DF6A6.8FUT1G	SOT-363	0.385	6.8				
863-MMBZ18VALT1G	MMBZ18VALT1G	SOT-23	0.225	18				
863-MMBZ5V6ALT1G	MMBZ5V6ALT1G	SOT-23	0.225	5.6				
863-MMSZ15T1G	MMSZ15T1G	SOD-123	0.5	15				
863-MMSZ43T1G	MMSZ43T1G	SOD-123	0.5	43				
863-MMSZ5231BT1G	MMSZ5231BT1G	SOD-123	0.5	5.1				
863-MMSZ5248BT1G	MMSZ5248BT1G	SOD-123	0.5	18				
863-MMSZ5252BT1G	MMSZ5252BT1G	SOD-123	0.5	24				
863-MMSZ5256BT1G	MMSZ5256BT1G	SOD-123	0.5	30				
863-MMSZ5258BT1G	MMSZ5258BT1G	SOD-123	0.5	36				
863-MMSZ5V6T1G	MMSZ5V6T1G	SOD-123	0.5	5.6				
863-MMSZ4678T1G	MMSZ4678T1G	SOD-123	0.5	1.8				
863-MMSZ4679T1G	MMSZ4679T1G	SOD-123	0.5	2				
863-MMSZ4683T1G	MMSZ4683T1G	SOD-123	0.5	3				
863-MMSZ4685T1G	MMSZ4685T1G	SOD-123	0.5	3.6				
863-MMSZ4687T1G	MMSZ4687T1G	SOD-123	0.5	4.3				
863-MMSZ4689ET1G	MMSZ4689ET1G	SOD-123	0.5	5.1				
863-MMSZ4690T1G	MMSZ4690T1G	SOD-123	0.5	5.6				
863-MMSZ4691T1G	MMSZ4691T1G	SOD-123	0.5	6.2				
863-MMSZ4692T1G	MMSZ4692T1G	SOD-123	0.5	6.8				
863-MMSZ4693T1G	MMSZ4693T1G	SOD-123	0.5	7.5				
863-MMSZ4694T1G	MMSZ4694T1G	SOD-123	0.5	8.2				
863-MMSZ4696T1G	MMSZ4696T1G	SOD-123	0.5	9.1				
863-MMSZ4697T1G	MMSZ4697T1G	SOD-123	0.5	10				
863-MMSZ4698T1G	MMSZ4698T1G	SOD-123	0.5	11				
863-MMSZ4699T1G	MMSZ4699T1G	SOD-123	0.5	12				
863-MMSZ4703T1G	MMSZ4703T1G	SOD-123	0.5	16				
863-MMSZ4704T1G	MMSZ4704T1G	SOD-123	0.5	17				
863-MMSZ4711T1G	MMSZ4711T1G	SOD-123	0.5	27				
863-MMSZ5233BT1G	MMSZ5233BT1G	SOD-123	0.5	6				
863-MMSZ5255BT1G	MMSZ5255BT1G	SOD-123	0.5	28				
863-MMSZ5261BT1G	MMSZ5261BT1G	SOD-123	0.5	47				
863-MMSZ5262BT1G	MMSZ5262BT1G	SOD-123	0.5	51				
863-MMSZ5267BT1G	MMSZ5267BT1G	SOD-123	0.5	75				
863-MMSZ5270BT1G	MMSZ5270BT1G	SOD-123	0.5	91				
863-1SMA5919BT3G	1SMA5919BT3G	SMA	1.5	5.6				
863-1SMB5914BT3G	1SMB5914BT3G	SMB	3	3.6				
863-1SMB5915BT3G	1SMB5915BT3G	SMB	3	3.9				
863-1SMB5916BT3G	1SMB5916BT3G	SMB	3	4.3				
863-1SMB5917BT3G	1SMB5917BT3G	SMB	3	4.7				
863-1SMB5918BT3G	1SMB5918BT3G	SMB	3	5.1				
863-1SMB5922BT3G	1SMB5922BT3G	SMB	3	7.5				
863-1SMB5923BT3G	1SMB5923BT3G	SMB	3	8.2				
863-1SMB5925BT3G	1SMB5925BT3G	SMB	3	10				
863-1SMB5928BT3G	1SMB5928BT3G	SMB	3	13				
863-1SMB5930BT3G	1SMB5930BT3G	SMB	3	16				
863-1SMB5932BT3G	1SMB5932BT3G	SMB	3	20				
863-1SMB5933BT3G	1SMB5933BT3G	SMB	3	22				
863-1SMB5943BT3G	1SMB5943BT3G	SMB	3	56				
863-1SMB5949BT3G	1SMB5949BT3G	SMB	3	100				