

VISHAY Diodes

Products may be RoHS compliant.
Check mouser.com for RoHS status.

VISHAY STANDARD RECOVERY DIODES

12 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Vishay Part No.	Package	Polarity	V _{RMM} (V)	I _{F(RMS)} (A)	Price Each			
						1	10	100	500
844-1N1206A	1N1206A	DO-203AA (DO-4)	Cathode-to-Stud	600	800				

16 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

844-16F120	16F120	DO-203AA (DO-4)	Cathode-to-Stud	1200	25				
------------	--------	-----------------	-----------------	------	----	--	--	--	--

35 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

844-1N1183	1N1183	DO-203AB (DO-5)	Cathode-to-Stud	50	500				
844-1N1184A	1N1184A	DO-203AB (DO-5)	Cathode-to-Stud	100	500				
844-1N3768	1N3768	DO-203AB (DO-5)	Cathode-to-Stud	1000	380				

40 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

844-40HF60	40HF60	DO-203AB (DO-5)	Cathode-to-Stud	600	62				
844-40HFR60	40HFR60	DO-203AB (DO-5)	Anode-to-Stud	600	62				
844-40HF120	40HF120	DO-203AB (DO-5)	Cathode-to-Stud	1200	62				

70 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

844-70HF40	70HF40	DO-203AB (DO-5)	Cathode-to-Stud	400	1200				
844-70HF60	70HF60	DO-203AB (DO-5)	Cathode-to-Stud	600	1200				
844-70HFR60	70HFR60	DO-203AB (DO-5)	Anode-to-Stud	600	1200				
844-70HF120	70HF120	DO-203AB (DO-5)	Cathode-to-Stud	1200	1200				
844-70HFR120	70HFR120	DO-203AB (DO-5)	Anode-to-Stud	1200	1200				

85 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

844-85HF40	85HF40	DO-203AB (DO-5)	Cathode-to-Stud	400	133				
844-85HF60	85HF60	DO-203AB (DO-5)	Cathode-to-Stud	600	133				
844-85HFR60	85HFR60	DO-203AB (DO-5)	Anode-to-Stud	600	133				
844-85HF120	85HF120	DO-203AB (DO-5)	Cathode-to-Stud	1200	133				
844-85HFR120	85HFR120	DO-203AB (DO-5)	Anode-to-Stud	1200	133				

150 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

844-150K40A	150K40A	DO-205AA (DO-8)	Cathode-to-Stud	400	235				
844-150K60A	150K60A	DO-205AA (DO-8)	Cathode-to-Stud	600	235				
844-150KR60A	150KR60A	DO-205AA (DO-8)	Anode-to-Stud	600	235				

300 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

844-300U40A	300U40A	DO-205AB (DO-9)	Cathode-to-Stud	400	500				
844-300U60A	300U60A	DO-205AB (DO-9)	Cathode-to-Stud	600	700				
844-300UR40A	300UR40A	DO-205AB (DO-9)	Anode-to-Stud	400	500				
844-300UR60A	300UR60A	DO-205AB (DO-9)	Anode-to-Stud	600	700				

475 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

844-40EPS08PBF	40EPS08PBF	TO-247AC	Cathode-to-Stud	800	900				
----------------	------------	----------	-----------------	-----	-----	--	--	--	--

VISHAY HYPERFAST RECOVERY DIODES

8.0 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Vishay Part No.	Package	I _{FSM} (V)	V _{RMM} (V)	trr (Max) (ns)	Price Each			
						1	10	100	500
8.0 Amp - Thru Hole									
844-8ETH06PBF	8ETH06PBF	TO-220AC	90	600	22				
844-8ETH06PPPBF	8ETH06PPPBF	TO-220 FullPak (2L)	100	600	22				
844-8S2TH06FP	8S2TH06FP	TO-220 FullPak (2L)	100	600	25				
844-8STH06FP	8STH06FP	TO-220 FullPak (3L)	100	600	25				

15 Amp - Surface Mount

844-15ETH06SPBF	15ETH06SPBF	D2PAK	120	600	35				
-----------------	-------------	-------	-----	-----	----	--	--	--	--

15 Amp - Thru Hole

844-15S2TH06FP	15S2TH06FP	TO-220 FullPak (2L)	115	600	28				
844-15STH06FP	15STH06FP	TO-220 FullPak (3L)	115	600	28				
844-15ETH06PBF	15ETH06PBF	TO-220AC	120	600	35				
844-15ETH06PPPBF	15ETH06PPPBF	TO-220 FullPak (2L)	180	600	35				

30 Amp - Thru Hole

844-30ETH06PBF	30ETH06PBF	TO-220AC	200	600	35				
----------------	------------	----------	-----	-----	----	--	--	--	--

VISHAY ULTRA FAST RECOVERY DIODES

15 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Vishay Part No.	Package	I _{FSM} (V)	V _{RMM} (V)	trr (Max) (ns)	Price Each			
						1	10	100	500
844-MUR1520PBF	MUR1520PBF	TO-220AC	200	200	35				

20 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

844-MUR2020CTPBF	MUR2020CTPBF	TO-220AB	100/per leg	200	35				
------------------	--------------	----------	-------------	-----	----	--	--	--	--

30 Amp - Thru Hole


For quantities of 1000 and up, call for quote.

844-30CPU04PBF	30CPU04PBF	TO-247AC	200	400	60				
844-30EPH06PBF	30EPH06PBF	TO-247AC	300	600	35				

60 Amp - Thru Hole

For quantities of 1000 and up, call for quote.

844-60APU06PBF	30CPU04PBF	TO-247AC	600	600	45				
----------------	------------	----------	-----	-----	----	--	--	--	--

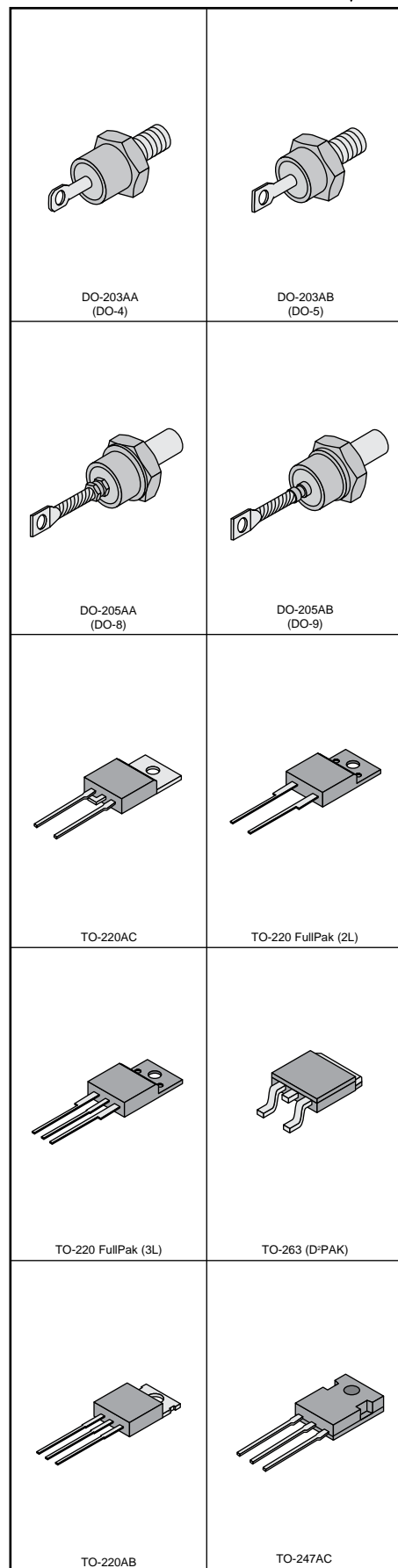

Diodes & Rectifiers
Vishay Semiconductors