

ON SEMICONDUCTOR Transistors



This product is RoHS compliant.

ON Semiconductor®




Transistors

ON Semiconductor

ON SEMICONDUCTOR GENERAL PURPOSE BIPOLAR TRANSISTORS (CONT.)

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	ON Semi Part No.	Package	VCE0 Min (V)	IC Max (A)	hFE Min	hFE Max	Price Each			
							1	25	100	500
PNP (Cont.)										
863-BC856ALT1G	BC856ALT1G	SOT-23	80	0.1	125	250				
863-BC856BLT1G	BC856BLT1G	SOT-23	80	0.1	220	475				
863-MMBTA56LT1G	MMBTA56LT1G	SOT-23	80	0.5	100	-				
863-MPSA56RLRAG	MPSA56RLRAG	TO-92	80	0.5	100	-				
863-BD140G	BD140G	Case 77	80	1.5	40	250				
863-2N4920G	2N4920G	Case 77	80	3	-	150				
863-MJE172G	MJE172G	Case 77	80	3	-	250				
863-2N5195G	2N5195G	Case 77	80	4	-	80				
863-MJD45H11G	MJD45H11G	DKPAK	80	8	60	-				
863-MJF45H11G	MJF45H11G	TO-220 FP	80	10	-	-				
863-D45H11G	D45H11G	TO-220	80	10	40	-				
863-2N6491G	2N6491G	TO-220	80	15	20	150				
863-D45VH10G	D45VH10G	TO-220	80	15	20	-				
863-2N5884G	2N5884G	TO-3	80	25	-	100				
863-2N5684G	2N5684G	TO-3	80	50	-	60				
863-TIP30CG	TIP30CG	TO-220	100	1	15	75				
863-BCP53-16T1G	BCP53-16T1G	SOT-223	100	1.5	100	250				
863-BCP53T1G	BCP53T1G	SOT-223	100	1.5	40	250				
863-MJD32CG	MJD32CG	DKPAK	100	3	10	50				
863-TIP32CG	TIP32CG	TO-220	100	3	10	50				
863-MJE253G	MJE253G	Case77	100	4	40	180				
863-TIP42CG	TIP42CG	TO-220	100	6	15	75				
863-TIP36CG	TIP36CG	TO-218	100	25	15	75				
863-MJF15031G	MJF15031G	TO-220 FP	150	8	40	-				
863-MJE4353G	MJE4353G	TO-218	160	16	-	-				
863-MJE15033G	MJE15033G	TO-220	250	8	50	-				
863-MJE350G	MJE350G	Case 77	300	0.5	30	240				
863-MMBTA92LT1G	MMBTA92LT1G	SOT-23	300	0.5	25	-				
863-MPSA92G	MPSA92G	TO-92	300	0.5	25	-				
863-PZTA92T1G	PZTA92T1G	SOT-223	300	0.5	25	-				
863-MJE5730G	MJE5730G	TO-220	300	1	-	150				
863-MJE5850G	MJE5850G	TO-220	300	8	-	-				
863-MMBT6520LT1G	MMBT6520LT1G	SOT-23	350	0.5	15	-				
863-MJE5851G	MJE5851G	TO-220	350	8	-	-				
863-MJE5852G	MJE5852G	TO-220	400	8	-	-				
Complementary										
863-MBT3946DW1T1G	MBT3946DW1T1G	SOT-363	40	0.2	100	300				
863-BC847BPDW1T1G	BC847BPDW1T1G	SOT-363	50	0.1	200	450				

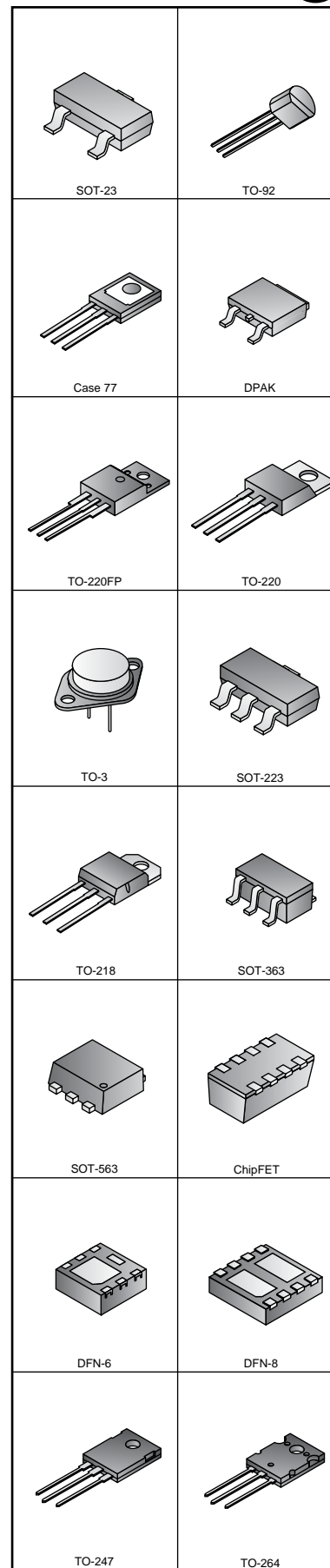

ON SEMICONDUCTOR LOW VCE BIPOLAR TRANSISTORS - PNP

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	ON Semi Part No.	Package	VCE0 Min (V)	IC Max (A)	hFE Min	hFE Max	Price Each			
							1	25	100	500
863-NSS12100XV6T1G	NSS12100XV6T1G	SOT 563	12	2	150	-				
863-NSS12200LT1G	NSS12200LT1G	SOT-23	-12	4	250	-				
863-NSS20200LT1G	NSS20200LT1G	SOT-23	20	4	250	-				
863-NSS40200LT1G	NSS40200LT1G	SOT-23	40	4	250	-				
863-NSS40200UW6T1G	NSS40200UW6T1G	DFN 6	-	4	150	-				
863-NSS40600CF8T1G	NSS40600CF8T1G	ChipFET	40	6	250	-				
863-NUS5530MNR2G	NUS5530MNR2G	DFN 8	35	2	100	400				

ON SEMICONDUCTOR AUDIO BIPOLAR TRANSISTORS

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	ON Semi Part No.	Package	VCE0 Min (V)	IC Max (A)	hFE Min	hFE Max	Price Each			
							1	25	100	500
NPN										
863-MJ15003G	MJ15003G	TO-3	140	20	25	150				
863-MJ15024G	MJ15024G	TO-3	250	16	15	60				
863-MJ21196G	MJ21196G	TO-3	250	16	25	75				
863-MJE15034G	MJE15034G	TO-220	350	4	100	-				
863-MJE15028G	MJE15028G	TO-220	120	8	40	-				
863-MJ15015G	MJ15015G	TO-3	120	15	20	70				
863-MJE15030G	MJE15030G	TO-220	150	8	40	-				
863-MJW21192G	MJW21192G	TO-247	150	8	15	100				
863-MJ15022G	MJ15022G	TO-3	200	16	15	60				
863-MJW3281AG	MJW3281AG	TO-247	230	15	50	200				
863-MJE15032G	MJE15032G	TO-220	250	8	50	-				
863-MJ15011G	MJ15011G	TO-3	250	10	20	100				
863-MJ15024G	MJ15024G	TO-3	250	16	15	60				
863-MJ21194G	MJ21194G	TO-3	250	16	25	75				
863-MJL21194G	MJL21194G	TO-264	250	16	25	75				
863-MJL21196G	MJL21196G	TO-264	250	16	25	100				
863-MJW21194G	MJW21194G	TO-247	250	16	20	70				
863-MJL3281AG	MJL3281AG	TO-264	260	15	75	150				
863-MJE15034G	MJE15034G	TO-220	350	4	100	-				
863-MJL4281AG	MJL4281AG	TO-264	350	15	80	250				