

ON SEMICONDUCTOR MOSFETS


ON Semiconductor®



RoHS Compliant This product is RoHS compliant.

MOSFETS

ON Semiconductor

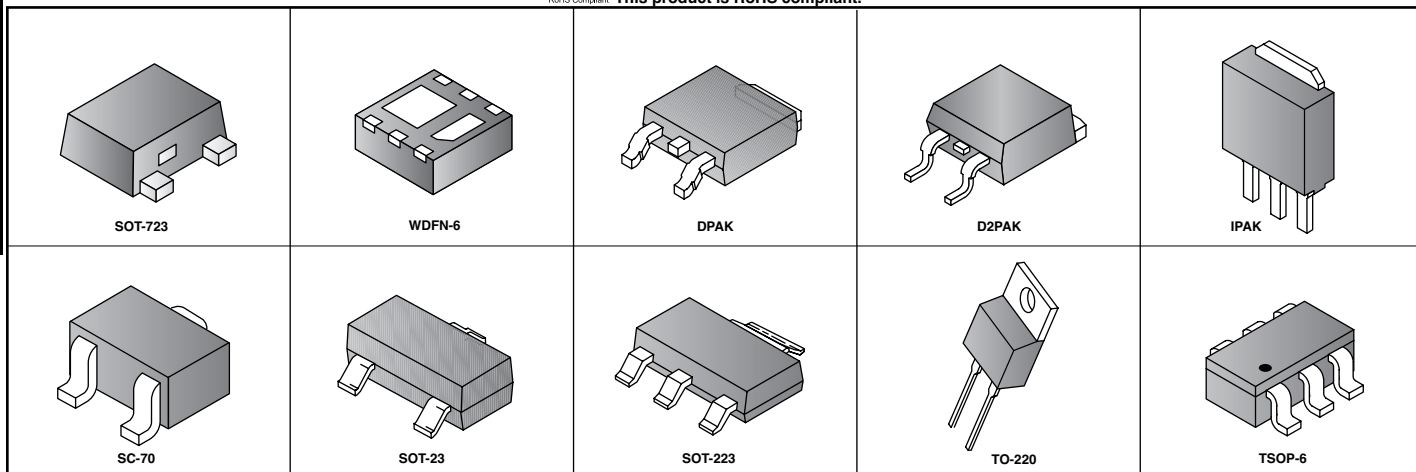

N-CHANNEL & P-CHANNEL POWER MOSFETS

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	ON Semiconductor Part No.	Package	V(BR) DSS Min (V)	rDS(on) Max (mΩ)	PD Max (W)	ID Max (A)	Price Each			
							1	25	100	500
N-Channel										
863-NTK3134NT1G	NTK3134NT1G	SOT-723	20	350	0.55	0.89				
863-NTK3134NT5G	NTK3134NT5G	SOT-723	20	350	0.55	0.89				
863-NTLJS4114NT1G	NTLJS4114NT1G	WDFN-6	30	35	3.3	7.8				
863-NTK3134NT1G	NTK3134NT1G	SOT-723	20	350	0.55	0.89				
863-NTK3134NT5G	NTK3134NT5G	SOT-723	20	350	0.55	0.89				
863-NTGS3446T1G	NTGS3446T1G	TSOP-6	20	45	2	5.1				
863-NTR4501NT1G	NTR4501NT1G	SOT-23	20	80	1.25	3.2				
863-MGSF2N02ELT1G	MGSF2N02ELT1G	SOT-23	20	85	1.25	2.8				
863-MGSF1N02LT1G	MGSF1N02LT1G	SOT-23	20	90	0.4	0.75				
863-MMBF0201NLT1G	MMBF0201NLT1G	SOT-23	20	1000	0.225	0.3				
863-NTP125N02RG	NTP125N02RG	TO-220	24	4.6	113.6	125				
863-NTP65N02RG	NTP65N02RG	TO-220	24	10.5	62.5	65				
863-NTB75N03RT4G	NTB75N03RT4G	D2PAK	25	8	62.5	72				
863-NTD70N03R-1G	NTD70N03R-1G	DPAK	25	8	62.5	72				
863-NTD65N03R-35G	NTD65N03R-35G	IPAK	25	8.4	50	65				
863-NTD20N03L27G	NTD20N03L27G	DPAK	30	27	74	20				
863-BSS138LT1G	BSS138LT1G	SOT-23	50	3500	0.225	0.2				
863-NTB75N06G	NTB75N06G	D2PAK	60	9.5	214	75				
863-NTB45N06T4G	NTB45N06T4G	D2PAK	60	26	125	45				
863-NTB45N06LT4G	NTB45N06LT4G	D2PAK	60	28	125	45				
863-NTD20N06G	NTD20N06G	DPAK	60	46	60	20				
863-NTB30N06LT4G	NTB30N06LT4G	D2PAK	60	46	88.2	30				
863-NTD3055-094T4G	NTD3055-094T4G	DPAK	60	94	48	12				
863-NTF3055-100T1G	NTF3055-100T1G	SOT-223	60	100	2.1	3				
863-NTB18N06LT4G	NTB18N06LT4G	D2PAK	60	100	48.4	15				
863-NTP18N06LG	NTP18N06LG	TO-220	60	100	48.4	15				
863-NTD3055L104G	NTD3055L104G	DPAK	60	104	48	12				
863-NTD3055L104T4G	NTD3055L104T4G	DPAK	60	104	48	12				
863-NTF3055L108T1G	NTF3055L108T1G	SOT-223	60	120	2.1	3				
863-NTD3055-150-1G	NTD3055-150-1G	DPAK	60	150	28.8	9				
863-MMF960T1G	MMF960T1G	SOT-223	60	1700	0.8	0.3				
863-MMBF170LT1G	MMBF170LT1G	SOT-23	60	5000	0.225	0.5				
863-NTB52N10G	NTB52N10G	D2PAK	100	30	178	52				
863-BSS123LT1G	BSS123LT1G	SOT-23	100	6000	0.225	0.17				
863-NTP35N15G	NTP35N15G	TO-220	150	50	178	37				
P-Channel										
863-NTLJD3119CTAG	NTLJD3119CTAG	WDFN-6	20	65	2.3	4.6				
863-NTLJD3119CTBG	NTLJD3119CTBG	WDFN-6	20	65	2.3	4.6				
863-NTGS3443T1G	NTGS3443T1G	TSOP-6	20	65	2	2				
863-NTGS3441T1G	NTGS3441T1G	TSOP-6	20	90	1	2.35				
863-NTS4101PT1G	NTS4101PT1G	SC-70	20	120	0.329	1.37				
863-NTR1P02T1G	NTR1P02T1G	SOT-23	20	180	0.4	1				
863-NTR1P02LT1G	NTR1P02LT1G	SOT-23	20	220	0.4	1.3				
863-NTR0202PLT1G	NTR0202PLT1G	SOT-23	20	800	0.225	0.4				
863-NTD25P03LG	NTD25P03LG	DPAK	30	72	75	25				
863-NTR4502PT1G	NTR4502PT1G	SOT-23	30	200	1.25	1.95				