

Fast Acting and Slow Blow Fuses





SINGLE BLOW SURFACE MOUNT FUSES

RoHS Compliant This product is RoHS compliant.

- Features:**
- Single blow fuse for over current protection
 - UL certified
 - Surface mount packaging for automated assembly
 - RoHS compliant and halogen free



Case Size	DIMENSIONS: mm			
	L	W	H	a
0402	1.0 ±0.1	0.52 ±0.05	0.35 ±0.05	0.25 ±0.1
0603	1.6 ±0.1	0.8 ±0.1	0.45 ±0.1	0.35 ±0.2
1206	3.2 ±0.1	1.55 ±0.1	0.6 ±0.1	0.5 ±0.2

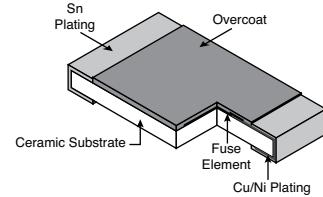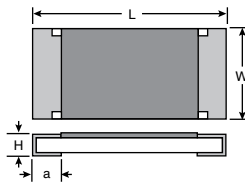

Fuses & Fuse Holders

Fast Acting Fuses

For quantities greater than listed, call for quote.


MOUSER STOCK NO.	Bourns Part No.	Rated Current (Amps)	Rated Voltage	Package Size	Price Each				Reel Qty.	Price Per Piece
					1	10	100	250		
652-SF-0402F050-2	SF-0402F050-2	0.5A	24V	0402					10000	
652-SF-0402F200-2	SF-0402F200-2	2.0A	24V	0402					10000	
652-SF-0603F050-2	SF-0603F050-2	0.5A	50V	0603					5000	
652-SF-0603F100-2	SF-0603F100-2	1.0A	32V	0603					5000	
652-SF-0603F150-2	SF-0603F150-2	1.5A	32V	0603					5000	
652-SF-0603F200-2	SF-0603F200-2	2.0A	32V	0603					5000	
652-SF-0603F250-2	SF-0603F250-2	2.5A	24V	0603					5000	
652-SF-0603F300-2	SF-0603F300-2	3.0A	24V	0603					5000	
652-SF-0603F315-2	SF-0603F315-2	3.15A	24V	0603					5000	
652-SF-0603F500-2	SF-0603F500-2	5.0A	32V	0603					5000	
652-SF-1206F050-2	SF-1206F050-2	0.5A	63V	1206					5000	
652-SF-1206F080-2	SF-1206F080-2	0.8A	63V	1206					5000	
652-SF-1206F100-2	SF-1206F100-2	1.0A	63V	1206					5000	
652-SF-1206F125-2	SF-1206F125-2	1.25A	63V	1206					5000	
652-SF-1206F150-2	SF-1206F150-2	1.5A	63V	1206					5000	
652-SF-1206F200-2	SF-1206F200-2	2.0A	63V	1206					5000	
652-SF-1206F250-2	SF-1206F250-2	2.5A	32V	1206					5000	
652-SF-1206F300-2	SF-1206F300-2	3.0A	32V	1206					5000	
652-SF-1206F400-2	SF-1206F400-2	4.0A	24V	1206					5000	
652-SF-1206F500-2	SF-1206F500-2	5.0A	24V	1206					5000	
652-SF-1206F700-2	SF-1206F700-2	7.0A	24V	1206					5000	

Slow Blow Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bourns Part No.	Rated Current (Amps)	Rated Voltage	Package Size	Price Each				Reel Qty.	Price Per Piece
					1	10	100	250		
652-SF-0402S200-2	SF-0402S200-2	2.0A	24V	0402					10000	
652-SF-0603S125-2	SF-0603S125-2	1.25A	32V	0603					5000	
652-SF-0603S160-2	SF-0603S160-2	1.6A	32V	0603					5000	
652-SF-0603S200-2	SF-0603S200-2	2.0A	32V	0603					5000	
652-SF-0603S250-2	SF-0603S250-2	2.5A	32V	0603					5000	
652-SF-0603S300-2	SF-0603S300-2	3.0A	32V	0603					5000	
652-SF-1206S050-2	SF-1206S050-2	0.5A	63V	1206					5000	
652-SF-1206S100-2	SF-1206S100-2	1.0A	63V	1206					5000	
652-SF-1206S150-2	SF-1206S150-2	1.5A	63V	1206					5000	
652-SF-1206S200-2	SF-1206S200-2	2.0A	63V	1206					5000	
652-SF-1206S250-2	SF-1206S250-2	2.5A	32V	1206					5000	
652-SF-1206S300-2	SF-1206S300-2	3.0A	32V	1206					5000	
652-SF-1206S400-2	SF-1206S400-2	4.0A	24V	1206					5000	
652-SF-1206S500-2	SF-1206S500-2	5.0A	24V	1206					5000	
652-SF-1206S700-2	SF-1206S700-2	7.0A	24V	1206					5000	

 
Littelfuse 209 SERIES 2AG, SLO-BLO (TIME-LAG) FUSES



For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Amp Rating	Voltage Rating	Price Each		
				1	10	100
576-0209.500MXEP	0209.500MXEP	0.5	350			
576-0209.750MXEP	0209.750MXEP	0.75	350			
576-0209001.MXEP	0209001.MXEP	1	350			

 Littelfuse 208 SERIES 2AG, FAST-ACTING FUSES




For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Amp Rating	Voltage Rating	Price Each		
				1	10	100
576-0208002.MXEP	0208002.MXEP	2	350			
576-0208003.MXEP	0208003.MXEP	3	350			
576-0208004.MXEP	0208004.MXEP	4	350			
576-0208005.MXEP	0208005.MXEP	5	350			
576-0208007.MXEP	0208007.MXEP	7	350			

Littelfuse 875 AND 877 SERIES SLO-BLO 3.6X10MM PIGTAIL FUSES

 - Features:**
- Slo-Blo ceramic body fuse in compact package
 - Single pigtail axial
 - Lead format



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Amp Rating	Voltage Rating	Price Each				
				1	10	100	250	
875 Series								
576-0875.100MXEP	0875.100MXEP	0.1	250					
576-0875.125MXEP	0875.125MXEP	0.125	250					
576-0875.200MXEP	0875.200MXEP	0.2	250					
576-0875.250MXEP	0875.250MXEP	0.25	250					
576-0875.300MXEP	0875.300MXEP	0.3	250					
576-0875.400MXEP	0875.400MXEP	0.4	250					
576-0875.500MXEP	0875.500MXEP	0.5	250					
576-0875.600MXEP	0875.600MXEP	0.6	250					
576-0875.800MXEP	0875.800MXEP	0.8	250					
576-0875001.MXEP	0875001.MXEP	1	250					
576-0875002.MXEP	0875002.MXEP	2	250					
576-0875003.MXEP	0875003.MXEP	3	250					
576-0875004.MXEP	0875004.MXEP	4	250					
576-0875005.MXEP	0875005.MXEP	5	250					
576-087501.5MXEP	087501.5MXEP	1.5	250					
576-087501.6MXEP	087501.6MXEP	1.6	250					
576-087502.5MXEP	087502.5MXEP	2.5	250					
877 Series								
576-0877002.MXEP	0877002.MXEP	2	250					
576-0877004.MXEP	0877004.MXEP	4	250					
576-087706.3MXEP	087706.3MXEP	6.3	250					
576-08773.15MXEP	08773.15MXEP	3.15	250					