


# COOPER/BUSSMANN Fuses

Products may be RoHS compliant. Check mouser.com for RoHS status.

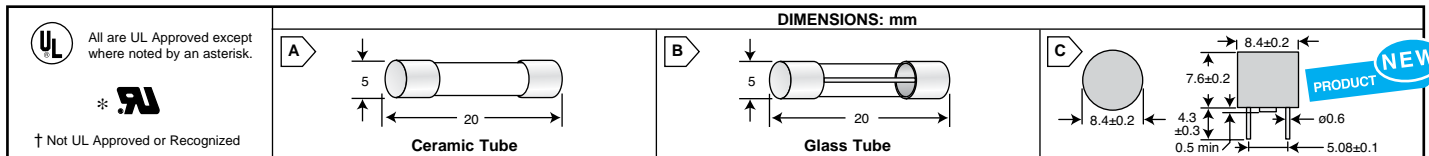

## 5MM X 20MM FUSES

### GDA Series Fast-Acting/High Breaking Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-GDA-50MA	A	.05	250			
504-GDA-100MA	A	.1	250			
504-GDA-160MA	A	.16	250			
504-GDA-200MA	A	.2	250			
504-GDA-250MA	A	.25	250			
504-GDA-315MA	A	.315	250			
504-GDA-500MA	A	0.5	250			
504-GDA-630MA	A	.63	250			
504-GDA-800MA	A	.8	250			
504-GDA-1A	A	1	250			
504-GDA-1.25A	A	1.25	250			
504-GDA-1.6A	A	1.6	250			
504-GDA-2A	A	2	250			
504-GDA-2.5A	A	2.5	250			
504-GDA-3.15A	A	3.15	250			
504-GDA-4A	A	4	250			
504-GDA-5A	A	5	250			
504-GDA-6.3A	A	6.3	250			

### GDB Series Fast-Acting/Low Breaking Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-GDB-80MA	B	.08	250			
504-GDB-100MA	B	.1	250			
504-GDB-125MA	B	.125	250			
504-GDB-160MA	B	.16	250			
504-GDB-315MA	B	.315	250			
504-GDB-400MA	B	.4	250			
504-GDB-500MA	B	.5	250			
504-BK/S500-630-R	B	.63	250			
504-GDB-800MA	B	.8	250			
504-GDB-1A	B	1	250			
504-GDB-1.25A	B	1.25	250			
504-GDB-2A	B	2	250			
504-GDB-2.5A	B	2.5	250			
504-GDB-3.15A	B	3.15	250			
504-GDB-4A	B	4	250			
504-GDB-5A	B	5	250			
504-GDB-6.3A	B	6.3	250			
504-GDB-10	B	10	250			

### GMC Series Medium Time-Delay Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-GMC-125MA	B	1/8	250			
504-GMC-1/4	B	1/4	250			
504-GMC-1/2	B	1/2	250			
504-GMC-3/4	B	3/4	250			
504-GMC-8/10	B	8/10	250			
504-GMC-1	B	1	250			
504-GMC-2	B	2	250			
504-GMC-2-1/2	B	2 1/2	250			
504-GMC-3	B	3	250			
504-GMC-3.15	B	3-15/100	250			
504-GMC-3-1/2	B	3 1/2	125			
504-GMC-4	B	4	125			
504-GMC-5	B	5	125			
504-GMC-6	B	6	125			
504-GMC-7	B	7	125			
504-GMC-8	B	8	125			
504-GMC-10	B	10	125			

### GDC Series Time-Delay/Low Breaking Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-GDC-V-50MA	B	.05	250			
504-GDC-63MA	B	.063	250			
504-GDC-100MA	B	.1	250			
504-GDC-V-100MA	B	0.1	250			
504-GDC-125MA	B	.125	250			
504-GDC-V-160MA	B	0.16	250			
504-GDC-200MA	B	.2	250			
504-GDC-250MA	B	.25	250			
504-GDC-500MA	B	.5	250			
504-GDC-630MA	B	.63	250			
504-GDC-800MA	B	.8	250			
504-GDC-1A	B	1	250			
504-GDC-1.25A	B	1.25	250			
504-GDC-1.6A	B	1.6	250			
504-GDC-2A	B	2	250			
504-GDC-2.5A	B	2.5	250			
504-GDC-3.15A	B	3.15	250			
504-GDC-4A	B	4	250			
504-GDC-5A	B	5	250			
504-GDC-6.3A	B	6.3	250			

### GMA Series Fast-Acting Fuses

\* Accepted worldwide \* Recommended for new designs

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-GMA-63MA	B	.063	250			
504-GMA-1/10	B	1/10	250			
504-GMA-1/8	B	1/8	250			
504-GMA-2/10	B	2/10	250			
504-GMA-1/4	B	1/4	250			
504-GMA-1/2	B	1/2	250			
504-GMA-3/4	B	3/4	250			
504-GMA-8/10	B	8/10	250			
504-GMA-1	B	1	250			
504-GMA-1-1/4	B	1-1/4	250			
504-GMA-1-1/2	B	1 1/2	250			
504-GMA-1.6	B	1-6/10	250			
504-GMA-2	B	2	250			
504-GMA-2-1/2	B	2 1/2	250			
504-GMA-3	B	3	250			
504-GMA-3.15	B	3-15/100	125			
504-GMA-3.5	B	3-1/2	125			
504-GMA-4	B	4	125			
504-GMA-5	B	5	125			
504-GMA-6	B	6	125			
504-GMA-7	B	7	125			
504-GMA-8	B	8	125			
504-GMA-10	B	10	125			
504-GMA-15	B	15	125			

### GMD Series Time-Delay/Low Breaking Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-GMD-125MA	B	0.125	250			
504-GMD-150MA	B	0.15	250			
504-GMD-200MA	B	0.2	250			
504-GMD-250MA	B	0.25	250			
504-GMD-300	B	0.3	250			
504-GMD-315MA	B	0.315	250			
504-GMD-400MA	B	0.4	250			
504-GMD-500MA	B	0.5	250			
504-GMD-600MA	B	0.6	250			
504-GMD-630MA	B	0.63	250			
504-GMD-750MA	B	0.75	250			
504-GMD-800MA	B	0.8	250			
504-GMD-1A	B	1	250			
504-GMD-1.2A	B	1.2	250			
504-GMD-1.25A	B	1.25	250			
504-GMD-1.5A	B	1.5	250			
504-GMD-1.6A	B	1.6	250			
504-GMD-2A	B	2	250			
504-GMD-2.5A	B	2.5	250			
504-GMD-3A	B	3	250			
504-GMD-4A	B	4	250			

## SUBMINIATURE SR-5 AND SR-5F SERIES OF FUSES

- Accepted for primary and secondary overcurrent protection
- Place directly into PCB or plug into BK/PCS holder
- Compatible with leaded & lead-free reflow and wave solder
- Radial leaded thru-hole fuse
- Base/Cap is Nylon #66, UL 94V0
- Pines are tin plated copper



RoHS Compliant

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each				Reel Qty.	Price Each	MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each			
				1	25	50	100							1	25	50	100
<b>SR-5 Series Time Lag Fuses</b>																	
504-SR-5-1.6A-AP	C	1.6	250					1000		504-SR-5-1.6A-BK	C	1.6	250				
504-SR-5-100MA-AP	C	0.1	250					1000		504-SR-5-100MA-BK	C	0.1	250				
504-SR-5-125MA-AP	C	0.125	250					1000		504-SR-5-125MA-BK	C	0.125	250				
504-SR-5-160MA-AP	C	0.16	250					1000		504-SR-5-160MA-BK	C	0.16	250				
504-SR-5-1A-AP	C	1.0	250					1000		504-SR-5-1A-BK	C	1.0	250				
504-SR-5-2.5A-AP	C	2.5	250					1000		504-SR-5-2.5A-BK	C	2.5	250				
504-SR-5-200MA-AP	C	0.2	250					1000		504-SR-5-200MA-BK	C	0.2	250				
504-SR-5-250MA-AP	C	0.25	250					1000		504-SR-5-250MA-BK	C	0.25	250				
504-SR-5-2A-AP	C	2.0	250					1000		504-SR-5-2A-BK	C	2.0	250				
504-SR-5-3.15A-AP	C	3.15	250					1000		504-SR-5-3.15A-BK	C	3.15	250				
504-SR-5-315MA-AP	C	0.315	250					1000		504-SR-5-315MA-BK	C	0.315	250				
504-SR-5-40MA-AP	C	0.04	250					1000		504-SR-5-40MA-BK	C	0.04	250				
504-SR-5-4A-AP	C	4.0	250					1000		504-SR-5-4A-BK	C	4.0	250				
504-SR-5-500MA-AP	C	0.5	250					1000		504-SR-5-500MA-BK	C	0.5	250				
504-SR-5-50MA-AP	C	0.05	250					1000		504-SR-5-50MA-BK	C	0.05	250				
504-SR-5-5A-AP	C	5.0	250					1000		504-SR-5-5A-BK	C	5.0	250				
504-SR-5-630MA-AP	C	0.63	250					1000		504-SR-5-630MA-BK	C	0.63	250				
504-SR-5-63MA-AP	C	0.063	250					1000		504-SR-5-63MA-BK	C	0.063	250				
504-SR-5-800MA-AP	C	0.8	250					1000		504-SR-5-800MA-BK	C	0.8	250				
<b>SR-5 Series Fast Acting Fuses</b>																	
504-SR-5F-800MA-AP	C	0.8	250					1000		504-SR-5F-800MA-BK	C	0.8	250				
504-SR-5F-1A-AP	C	1	250					1000		504-SR-5F-1A-BK	C	1	250				
504-SR-5F-1.6A-AP	C	1.6	250					1000		504-SR-5F-1.6A-BK	C	1.6	250				
504-SR-5F-2A-AP	C	2	250					1000		504-SR-5F-2A-BK	C	2	250				
504-SR-5F-2.5A-AP	C	2.5	250					1000		504-SR-5F-2.5A-BK	C	2.5	250				
504-SR-5F-3.15A-AP	C	3.15	250					1000		504-SR-5F-3.15A-BK	C	3.15	250				
504-SR-5F-4A-AP	C	4	250					1000		504-SR-5F-4A-BK	C	4	250				
504-SR-5F-5A-AP	C	5	250					1000		504-SR-5F-5A-BK	C	5	250				
504-SR-5F-6.3A-AP	C	6.3	125					1000		504-SR-5F-6.3A-BK	C	6.3	125				
504-SR-5F-7A-AP	C	7	125					1000		504-SR-5F-7A-BK	C	7	125				