


LITTELFUSE Fuses



RoHS Compliant This product is RoHS compliant.

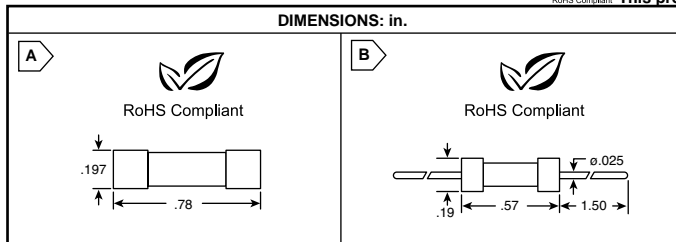

LITTELFUSE 5MM X 20MM FUSES (CONT.)

218 Series SLO-BLO® Fuses

*35 amp interrupting rating



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0218.032HXP	0218.032HXP	A	0.032	250				
576-0218.040HXP	0218.040HXP	A	0.04	250				
576-0218.050HXP	0218.050HXP	A	0.05	250				
576-0218.063HXP	0218.063HXP	A	0.063	250				
576-0218.080HXP	0218.080HXP	A	0.08	250				
576-0218.100HXP	0218.100HXP	A	0.1	250				
576-0218.125HXP	0218.125HXP	A	0.125	250				
576-0218.160HXP	0218.160HXP	A	0.16	250				
576-0218.200HXP	0218.200HXP	A	0.2	250				
576-0218.250HXP	0218.250HXP	A	0.25	250				
576-0218.315HXP	0218.315HXP	A	0.315	250				
576-0218.400HXP	0218.400HXP	A	0.4	250				
576-0218.500HXP	0218.500HXP	A	0.5	250				
576-0218.630HXP	0218.630HXP	A	0.63	250				
576-0218.800HXP	0218.800HXP	A	0.8	250				
576-0218001.HXP	0218001.HXP	A	1	250				
576-02181.25HXP	02181.25HXP	A	1.25	250				
576-021801.6HXP	021801.6HXP	A	1.6	250				
576-0218002.HXP	0218002.HXP	A	2	250				
576-021802.5HXP	021802.5HXP	A	2.5	250				
576-02183.15HXP	02183.15HXP	A	3.15	250				
576-0218004.HXP	0218004.HXP	A	4	250				
576-0218005.HXP	0218005.HXP	A	5	250				
576-021806.3HXP	021806.3HXP	A	6.3	250				
576-0218008.HXP	0218008.HXP	A	8	250				
576-0218010.HXP	0218010.HXP	A	10	250				
576-0218015.HXP	0218015.HXP	A	15	250				

Littelfuse Fuses & Fuse Holders

LITTELFUSE 5MM X 20MM FUSES

*The interrupting rating is the maximum current, at the rated voltage, that the fuse can safely open without the possibility of rupturing.

215 Series-SLO-BLO® Fuses



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0215.200HXP	0215.200HXP	A	0.2	250				
576-0215.315HXP	0215.315HXP	A	0.315	250				
576-0215.500HXP	0215.500HXP	A	0.5	250				
576-0215.800HXP	0215.800HXP	A	0.8	250				
576-0215001.HXP	0215001.HXP	A	1	250				
576-02151.25HXP	02151.25HXP	A	1.25	250				
576-021501.6HXP	021501.6HXP	A	1.6	250				
576-0215002.HXP	0215002.HXP	A	2	250				
576-021502.5HXP	021502.5HXP	A	2.5	250				
576-02153.15HXP	02153.15HXP	A	3.15	250				
576-0215004.HXP	0215004.HXP	A	4	250				
576-0215005.HXP	0215005.HXP	A	5	250				
576-021506.3HXP	021506.3HXP	A	6.3	250				
576-0215008.HXP	0215008.HXP	A	8	250				
576-0215010.HXP	0215010.HXP	A	10	250				

216 Series Fast Acting Fuses



*1500 amp interrupting rating

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0216.050HXP	0216.050HXP	A	0.05	250				
576-0216.100HXP	0216.100HXP	A	0.1	250				
576-0216.125HXP	0216.125HXP	A	0.125	250				
576-0216.200HXP	0216.200HXP	A	0.2	250				
576-0216.250HXP	0216.250HXP	A	0.25	250				
576-0216.315HXP	0216.315HXP	A	0.315	250				
576-0216.400HXP	0216.400HXP	A	0.4	250				
576-0216.500HXP	0216.500HXP	A	0.5	250				
576-0216.630HXP	0216.630HXP	A	0.63	250				
576-0216001.HXP	0216001.HXP	A	1	250				
576-02161.25HXP	02161.25HXP	A	1.25	250				
576-021601.6HXP	021601.6HXP	A	1.6	250				
576-0216002.HXP	0216002.HXP	A	2	250				
576-021602.5HXP	021602.5HXP	A	2.5	250				
576-02163.15HXP	02163.15HXP	A	3.15	250				
576-0216004.HXP	0216004.HXP	A	4	250				
576-0216005.HXP	0216005.HXP	A	5	250				
576-021606.3HXP	021606.3HXP	A	6.3	250				
576-0216008.HXP	0216008.HXP	A	8	250				
576-0216010.HXP	0216010.HXP	A	10	250				

217 Series Fast Acting Fuses



*35 amp interrupting rating

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0217.032HXP	0217.032HXP	A	0.032	250				
576-0217.063HXP	0217.063HXP	A	0.063	250				
576-0217.100HXP	0217.100HXP	A	0.1	250				
576-0217.125HXP	0217.125HXP	A	0.125	250				
576-0217.200HXP	0217.200HXP	A	0.2	250				
576-0217.250HXP	0217.250HXP	A	0.25	250				
576-0217.400HXP	0217.400HXP	A	0.4	250				
576-0217.500HXP	0217.500HXP	A	0.5	250				
576-0217.630HXP	0217.630HXP	A	0.63	250				
576-0217.800HXP	0217.800HXP	A	0.8	250				
576-0217001.HXP	0217001.HXP	A	1	250				
576-02171.25HXP	02171.25HXP	A	1.25	250				
576-021701.6HXP	021701.6HXP	A	1.6	250				
576-0217002.HXP	0217002.HXP	A	2	250				
576-021702.5HXP	021702.5HXP	A	2.5	250				
576-02173.15HXP	02173.15HXP	A	3.15	250				
576-0217004.HXP	0217004.HXP	A	4	250				
576-0217005.HXP	0217005.HXP	A	5	250				
576-021706.3HXP	021706.3HXP	A	6.3	250				
576-0217008.HXP	0217008.HXP	A	8	250				
576-0217010.HXP	0217010.HXP	A	10	250				


235 Series Fast-Acting Fuses



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0235.100HXP	0235.100HXP	A	0.1	250				
576-0235.125HXP	0235.125HXP	A	0.125	250				
576-0235.200HXP	0235.200HXP	A	0.2	250				
576-0235.250HXP	0235.250HXP	A	0.25	250				
576-0235.300HXP	0235.300HXP	A	0.3	250				
576-0235.400HXP	0235.400HXP	A	0.4	250				
576-0235.500HXP	0235.500HXP	A	0.5	250				
576-0235.600HXP	0235.600HXP	A	0.6	250				
576-0235.700HXP	0235.700HXP	A	0.7	250				
576-0235.800HXP	0235.800HXP	A	0.8	250				
576-0235001.HXP	0235001.HXP	A	1	250				
576-02351.25HXP	02351.25HXP	A	1.25	250				
576-023501.6HXP	023501.6HXP	A	1.6	250				
576-0235002.HXP	0235002.HXP	A	2	250				
576-023502.5HXP	023502.5HXP	A	2.5	250				
576-0235003.HXP	0235003.HXP	A	3	250				
576-0235004.HXP	0235004.HXP	A	4	125				
576-0235005.HXP	0235005.HXP	A	5	125				
576-0235006.HXP	0235006.HXP	A	6	125				

 
239 Series Slo-Blo® Fuses



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0239.200HXP	0239.200HXP	A	0.2	250				
576-0239.250HXP	0239.250HXP	A	0.25	250				
576-0239.300HXP	0239.300HXP	A	0.3	250				
576-0239.400HXP	0239.400HXP	A	0.4	250				
576-0239.500HXP	0239.500HXP	A	0.5	250				
576-0239.600HXP	0239.600HXP	A	0.6	250				
576-0239.750HXP	0239.750HXP	A	0.75	250				
576-0239.800HXP	0239.800HXP	A	0.8	250				
576-0239001.HXP	0239001.HXP	A	1	250				
576-02391.25HXP	02391.25HXP	A	1.25	250				
576-023901.6HXP	023901.6HXP	A	1.6	250				
576-0239002.HXP	0239002.HXP	A	2	250				
576-023902.5HXP	023902.5HXP	A	2.5	250				
576-0239003.HXP	0239003.HXP	A	3	250				
576-0239004.HXP	0239004.HXP	A	4	125				
576-0239005.HXP	0239005.HXP	A	5	125				

 2AG FUSES



224 Series (Axial Lead) Fast-Acting Fuses

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0224.250HXP	0224.250HXP	B	0.25	250				
576-0224.375HXP	0224.375HXP	B	0.375	250				
576-0224.500HXP	0224.500HXP	B	0.5	250				
576-0224.750HXP	0224.750HXP	B	0.75	250				
576-0224001.HXP	0224001.HXP	B	1	250				
576-022401.5HXP	022401.5HXP	B	1.5	250				
576-0224002.HXP	0224002.HXP	B	2	25				