


LITTELFUSE Fuses



Products may be RoHS compliant. Check mouser.com for RoHS status.

DIMENSIONS: mm (in.)

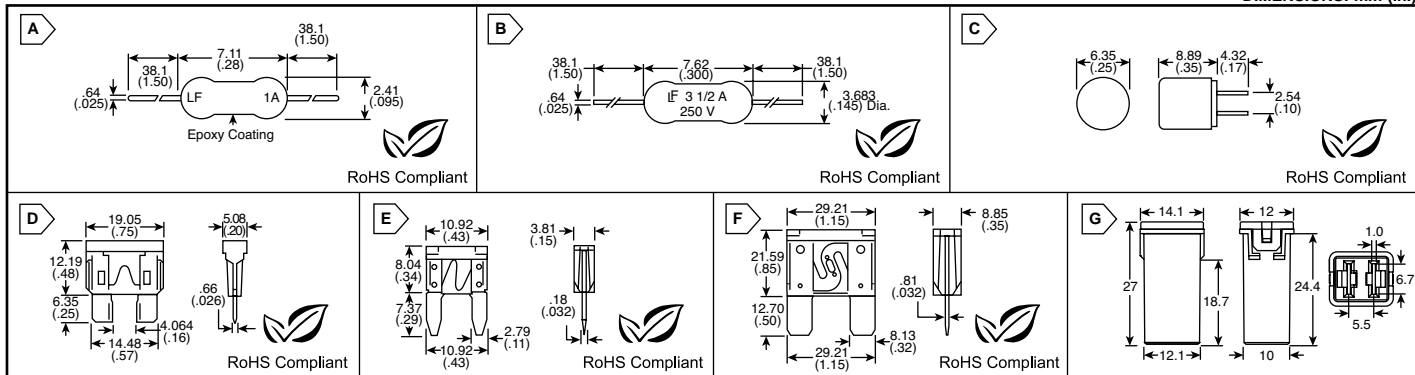

251L SERIES PICO® II FAST-ACTING SUBMINIATURE FUSES, AXIAL LEAD



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0251.062MXL	0251.062MXL	A	0.062	125				
576-0251.125MXL	0251.125MXL	A	0.125	125				
576-0251.250MXL	0251.250MXL	A	0.25	125				
576-0251.375MXL	0251.375MXL	A	0.375	125				
*576-0251.500MAT1L	0251.500MAT1L	A	0.5	125				
*576-0251.750MAT1L	0251.750MAT1L	A	0.75	125				
576-0251001.MXL	0251001.MXL	A	1	125				
576-02511.25MXL	02511.25MXL	A	1.25	125				
576-025101.5MXL	025101.5MXL	A	1.5	125				
576-0251002.MXL	0251002.MXL	A	2	125				
576-025102.5MXL	025102.5MXL	A	2.5	125				
576-0251003.MXL	0251003.MXL	A	3	125				
576-025103.5MXL	025103.5MXL	A	3.5	125				
*576-0251004.MRT1L	0251004.MRT1L	A	4	125				
576-0251005.MXL	0251005.MXL	A	5	125				
576-0251007.MXL	0251007.MXL	A	7	125				
576-0251010.MXL	0251010.MXL	A	10	125				
*576-0251012.MRT1L	0251012.MRT1L	A	12	125				
*576-0251015.MRT1L	0251015.MRT1L	A	15	125				

* Tape and Reel

263 SERIES PICO® II VERY FAST-ACTING SUBMINIATURE FUSES



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	1	10	100	250
576-0263.062MXL	0263.062MXL	B	0.062	250				
576-0263.125MXL	0263.125MXL	B	0.125	250				
576-0263.250MXL	0263.250MXL	B	0.25	250				
576-0263.375MXL	0263.375MXL	B	0.375	250				
576-0263.500MXL	0263.500MXL	B	0.5	250				
576-0263.750MXL	0263.750MXL	B	0.75	250				
576-0263001.MXL	0263001.MXL	B	1	250				
576-026301.5MXL	026301.5MXL	B	1.5	250				
576-0263002.MXL	0263002.MXL	B	2	250				
576-026302.5MXL	026302.5MXL	B	2.5	250				
576-0263003.MXL	0263003.MXL	B	3	250				
576-026303.5MXL	026303.5MXL	B	3.5	250				
576-0263004.MXL	0263004.MXL	B	4	250				
576-0263005.MXL	0263005.MXL	B	5	250				

473 SERIES PICO® II SLO-BLO SUBMINIATURE FUSES



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	1	10	100	250
*576-0473.375MRT1L	0473.375MRT1L	A	0.375	125				
*576-0473.500MRT1L	0473.500MRT1L	A	0.5	125				
*576-0473.750MRT1L	0473.750MRT1L	A	0.75	125				
*576-0473001.MRT1L	0473001.MRT1L	A	1	125				
*576-047301.5MRT1L	047301.5MRT1L	A	1.5	125				
*576-0473002.MRT1L	0473002.MRT1L	A	2	125				
*576-04732.25MRT1L	04732.25MRT1L	A	2.25	125				
*576-047302.5MRT1L	047302.5MRT1L	A	2.5	125				
*576-0473003.MRT1L	0473003.MRT1L	A	3	125				
*576-047303.5MRT1L	047303.5MRT1L	A	3.5	125				
*576-0473004.MRT1L	0473004.MRT1L	A	4	125				
*576-0473005.MRT1L	0473005.MRT1L	A	5	125				
*576-0473007.MRT1L	0473007.MRT1L	A	7	125				

* Tape and Reel

273 SERIES MICRO™ FUSE VERY FAST-ACTING SUBMINIATURE FUSES



Developed originally for the U.S. Space Program, MICRO fuse provides reliability in a compact design.

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	1	10	100	250
576-0273.031V	273.031	C	0.031	125				
576-0273.050H	273.050	C	0.05	125				
576-0273.062V	273.062	C	0.062	125				
576-0273.125H	273.125	C	0.125	125				
576-0273.250H	273.250	C	0.25	125				
576-0273.500H	273.500	C	0.5	125				
576-0273001.H	273001	C	1	125				
576-027301.5H	27301.5	C	1.5	125				
576-0273002.H	273002	C	2	125				
576-0273003.H	273003	C	3	125				
576-0273004.H	273004	C	4	125				
576-0273005.H	273005	C	5	125				

© Copyright 2011 Mouser Electronics

257 SERIES AUTOFUSE ATO® FAST-ACTING BLADE FUSES

Designed and originated by Littelfuse for the automotive industry, the ATO® fuse has become the original equipment circuit protection standard for foreign and domestic automobiles and trucks. Readily identifiable and easily replaced, this fuse can be specified for a variety of low voltage electronic applications. The ATO® series is rated to 85°C ambient.



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0257001.PXPV	257001	D	1	32				
576-0257002.PXPV	257002	D	2	32				
576-0257003.PXPV	257003	D	3	32				
576-0257004.PXPV	257004	D	4	32				
576-0257005.PXPV	257005	D	5	32				
576-025707.5PXPV	25707.5	D	7.5	32				
576-0257010.PXPV	257010	D	10	32				
576-0257015.PXPV	257015	D	15	32				
576-0257020.PXPV	257020	D	20	32				
576-0257025.PXPV	257025	D	25	32				
576-0257030.PXPV	257030	D	30	32				
576-0257040.PXPV	257040	D	40	32				

297 SERIES AUTOFUSE MINI® FAST-ACTING

The MINI® fuse has become the industry standard blade fuse for engine compartment locations requiring a 125°C temperature rating.



- Materials: plastic body, silver plated terminals
- Voltage rating: 32V

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	1	10	100	250
576-0297002.WXNV	297002	E	2	32				
576-0297003.WXNV	297003	E	3	32				
576-0297004.WXNV	297004	E	4	32				
576-0297005.WXNV	297005	E	5	32				
576-029707.5WXNV	29707.5	E	7.5	32				
576-0297010.WXNV	297010	E	10	32				
576-0297015.WXNV	297015	E	15	32				
576-0297020.WXNV	297020	E	20	32				
576-0297025.WXNV	297025	E	25	32				
576-0297030.WXNV	297030	E	30	32				

299 SERIES MAXI® SLO-BLO® AUTOMOTIVE BLADE FUSES

Designed and originated by Littelfuse for the automotive industry, the MAXI® fuse has become the original equipment circuit protection standard for foreign and domestic automobiles and trucks. The MAXI® series is rated to 125°C ambient.



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	1	10	100	250
576-0299020.ZXNV	299020	F	20	32				
576-0299025.ZXNV	299025	F	25	32				
576-0299030.ZXNV	299030	F	30	32				
576-0299035.ZXNV	299035	F	35	32				
576-0299040.ZXNV	299040	F	40	32				
576-0299050.ZXNV	299050	F	50	32				
576-0299060.ZXNV	299060	F	60	32				
576-0299070.ZXNV	299070	F	70	32				
576-0299080.ZXNV	299080	F	80	32				

495 SERIES JCASE® SLO-BLO® AUTOMOTIVE CARTRIDGE FUSE



The JCASE® cartridge fuse is the new global standard for Slo-Blo fuses for automotive applications. They are designed to increase the reliability of customer's modules by putting the box-contact in the fuse, instead of in the module. The JCASE® Series is rated to 125°C ambient.

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Color	Amp (A)	Volts (V)	Price Each			
						1	10	100	250
576-495020.Z	495020.Z	G	Blue	20	32				
576-495025.Z	495025.Z	G	White	25	32				
576-495030.Z	495030.Z	G	Pink	30	32				
576-495040.Z	495040.Z	G	Green	40	32				
576-495050.Z	495050.Z	G	Red	50	32				
576-495060.Z	495060.Z	G	Yellow	60	32				

© Copyright 2011 Mouser Electronics