

BOURNS Multi-Turn Cermet Trimmer Potentiometers

BOURNS

RoHS Compliant This product is RoHS compliant.


BOURNS 3296 SERIES 3/8" SQUARE / 25 TURN / SEALED

- Features:**
- 5 terminal styles
 - Chevron seal design

- Specifications:**
- Resistance tolerance: ±10% standard
 - Power rating: 70°C - 0.5W; 125°C - 0W
 - Temperature range: -55°C to +150°C
 - Temperature coefficient: ±100ppm/°C

Series No.	Price Each					
	1	10	50	100	500	1000
3296P, 3296Z 3296W, X, Y						

Value (Ω)	3296P Series	3296W Series	3296X Series	3296Y Series	3296Z Series
	MOUSER STOCK NO.				
10	652-3296P-1-100LF	652-3296W-1-100LF	652-3296X-1-100LF	652-3296Y-1-100LF	652-3296Z-1-100LF
20	652-3296P-1-200LF	652-3296W-1-200LF	652-3296X-1-200LF	652-3296Y-1-200LF	652-3296Z-1-200LF
50	652-3296P-1-500LF	652-3296W-1-500LF	652-3296X-1-500LF	652-3296Y-1-500LF	652-3296Z-1-500LF
100	652-3296P-1-101LF	652-3296W-1-101LF	652-3296X-1-101LF	652-3296Y-1-101LF	652-3296Z-1-101LF
200	652-3296P-1-201LF	652-3296W-1-201LF	652-3296X-1-201LF	652-3296Y-1-201LF	652-3296Z-1-201LF
500	652-3296P-1-501LF	652-3296W-1-501LF	652-3296X-1-501LF	652-3296Y-1-501LF	652-3296Z-1-501LF
1K	652-3296P-1-102LF	652-3296W-1-102LF	652-3296X-1-102LF	652-3296Y-1-102LF	652-3296Z-1-102LF
2K	652-3296P-1-202LF	652-3296W-1-202LF	652-3296X-1-202LF	652-3296Y-1-202LF	652-3296Z-1-202LF
5K	652-3296P-1-502LF	652-3296W-1-502LF	652-3296X-1-502LF	652-3296Y-1-502LF	652-3296Z-1-502LF
10K	652-3296P-1-103LF	652-3296W-1-103LF	652-3296X-1-103LF	652-3296Y-1-103LF	652-3296Z-1-103LF
20K	652-3296P-1-203LF	652-3296W-1-203LF	652-3296X-1-203LF	652-3296Y-1-203LF	652-3296Z-1-203LF
25K	652-3296P-1-253LF	652-3296W-1-253LF	652-3296X-1-253LF	652-3296Y-1-253LF	652-3296Z-1-253LF
50K	652-3296P-1-503LF	652-3296W-1-503LF	652-3296X-1-503LF	652-3296Y-1-503LF	652-3296Z-1-503LF
100K	652-3296P-1-104LF	652-3296W-1-104LF	652-3296X-1-104LF	652-3296Y-1-104LF	652-3296Z-1-104LF
200K	652-3296P-1-204LF	652-3296W-1-204LF	652-3296X-1-204LF	652-3296Y-1-204LF	652-3296Z-1-204LF
250K	652-3296P-1-254LF	652-3296W-1-254LF	652-3296X-1-254LF	652-3296Y-1-254LF	652-3296Z-1-254LF
500K	652-3296P-1-504LF	652-3296W-1-504LF	652-3296X-1-504LF	652-3296Y-1-504LF	652-3296Z-1-504LF
1M	652-3296P-1-105LF	652-3296W-1-105LF	652-3296X-1-105LF	652-3296Y-1-105LF	652-3296Z-1-105LF
2M	652-3296P-1-205LF	652-3296W-1-205LF	652-3296X-1-205LF	652-3296Y-1-205LF	652-3296Z-1-205LF

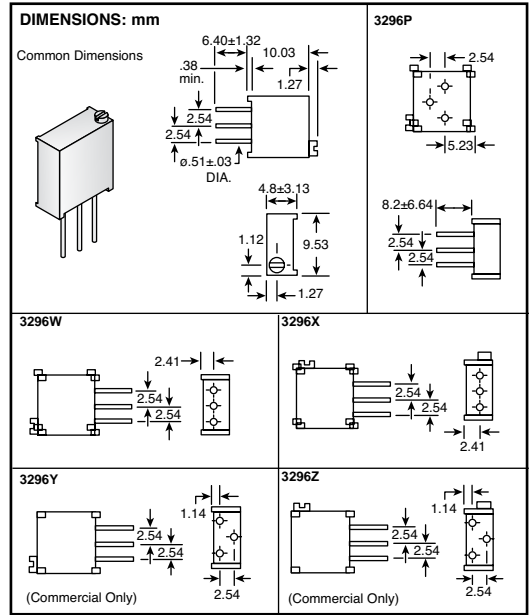

Multi-Turn Trimmers Bourns


BOURNS 3006 SERIES 3/4" RECTANGULAR / 15 TURN / SEALED

- Features:**
- Low PC board profile - only 1/4" high

- Specifications:**
- Resistance tolerance: ±10% standard
 - Power rating: 70°C - 0.75W; 125°C - 0W
 - Temperature range: -55°C to +125°C
 - Temperature coefficient: ±100ppm/°C

Series No.	Price Each					
	1	10	50	100	500	1000
3006P 3006W, 3006Y						


Value (Ω)	3006P Series	3006W Series	3006Y Series
	MOUSER STOCK NO.		
100	652-3006P-1-101-LF	652-3006W-1-101-LF	652-3006Y-1-101-LF
200	652-3006P-1-201-LF	652-3006W-1-201-LF	652-3006Y-1-201-LF
500	652-3006P-1-501-LF	652-3006W-1-501-LF	652-3006Y-1-501-LF
1K	652-3006P-1-102-LF	652-3006W-1-102-LF	652-3006Y-1-102-LF
2K	652-3006P-1-202-LF	652-3006W-1-202-LF	652-3006Y-1-202-LF
5K	652-3006P-1-502-LF	652-3006W-1-502-LF	652-3006Y-1-502-LF
10K	652-3006P-1-103-LF	652-3006W-1-103-LF	652-3006Y-1-103-LF
20K	652-3006P-1-203-LF	652-3006W-1-203-LF	652-3006Y-1-203-LF
25K	652-3006P-1-253-LF	652-3006W-1-253-LF	652-3006Y-1-253-LF
50K	652-3006P-1-503-LF	652-3006W-1-503-LF	652-3006Y-1-503-LF
100K	652-3006P-1-104-LF	652-3006W-1-104-LF	652-3006Y-1-104-LF
200K	652-3006P-1-204-LF	652-3006W-1-204-LF	652-3006Y-1-204-LF
250K	652-3006P-1-254-LF	652-3006W-1-254-LF	652-3006Y-1-254-LF
500K	652-3006P-1-504-LF	652-3006W-1-504-LF	652-3006Y-1-504-LF
1M	652-3006P-1-105-LF	652-3006W-1-105-LF	652-3006Y-1-105-LF

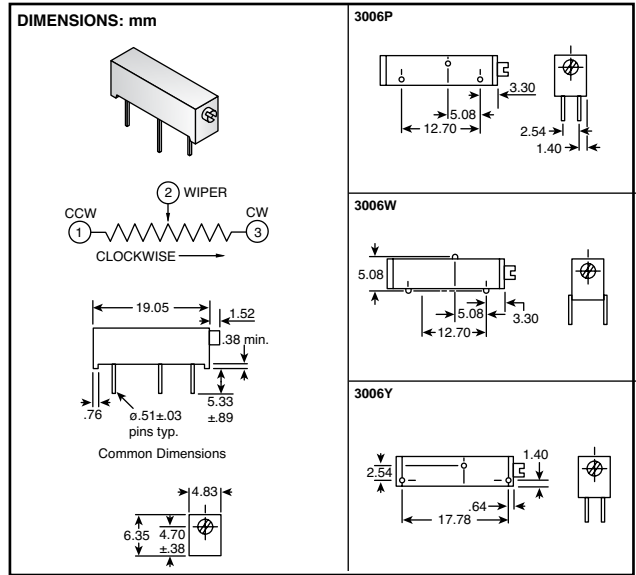

BOURNS 3059 SERIES 1-1/4" RECTANGULAR / 22 TURN / SEALED

- Specifications:**
- Resistance tolerance: ±10% standard
 - Power rating: 70°C - 1.0W; 150°C - 0W
 - Temperature range: -55°C to +150°C
 - Temperature coefficient: ±100ppm/°C

DIMENSIONS: mm

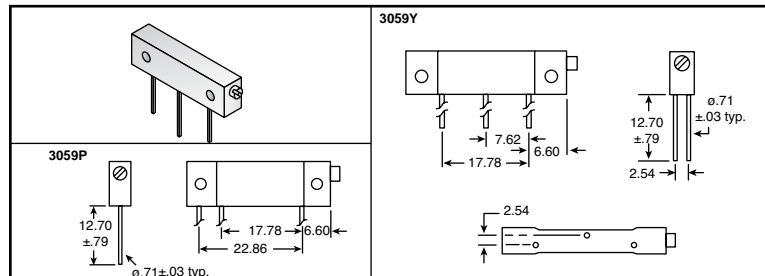

Series No.	Price Each					
	1	25	50	100	500	1000
3059P, 3059Y						

Value (Ω)	3059P Series	3059Y Series
	MOUSER STOCK NO.	
100	652-3059P-1-101LF	652-3059Y-1-101LF
200	652-3059P-1-201LF	652-3059Y-1-201LF
500	652-3059P-1-501LF	652-3059Y-1-501LF
1K	652-3059P-1-102LF	652-3059Y-1-102LF
2K	652-3059P-1-202LF	652-3059Y-1-202LF
5K	652-3059P-1-502LF	652-3059Y-1-502LF
10K	652-3059P-1-103LF	652-3059Y-1-103LF
20K	652-3059P-1-203LF	652-3059Y-1-203LF
50K	652-3059P-1-503LF	652-3059Y-1-503LF
100K	652-3059P-1-104LF	652-3059Y-1-104LF
200K	652-3059P-1-204LF	652-3059Y-1-204LF
500K	652-3059P-1-504LF	652-3059Y-1-504LF
1M	652-3059P-1-105LF	652-3059Y-1-105LF