

KEMET Ceramic Chip Capacitors

The Capacitance Company
KEMET
CHARGED™


CASE SIZE 0805 (CONT.)



RoHS Compliant

Please call a Mouser representative for information of product not listed.

MOUSER STOCK NO.	KEMET Part No.	Value (pF)	Volt (DC)	Tol.±	Price Each		7" Reel Qty.	Price Per Piece
					1	100		
Temperature Coefficient: C0G								
80-C0805C169C1G	C0805C169C1GACTU	1.6	100	.25pF			4,000	
80-C0805C189C5G	C0805C189C5GACTU	1.8	50	.25pF			4,000	
80-C0805C209C5G	C0805C209C5GACTU	2.0	50	.25pF			4,000	
80-C0805C229C5G	C0805C229C5GACTU	2.2	50	.25pF			4,000	
80-C0805C229C1G	C0805C229C1GACTU	2.2	100	.25pF			4,000	
80-C0805C229D1G	C0805C229D1GACTU	2.2	100	.5pF			4,000	
80-C0805C279C5G	C0805C279C5GACTU	2.7	50	.25pF			4,000	
80-C0805C279D5G	C0805C279D5GACTU	2.7	50	.5pF			4,000	
80-C0805C279C1G	C0805C279C1GACTU	2.7	100	.25pF			4,000	
80-C0805C309C5G	C0805C309C5GACTU	3.0	50	.25pF			4,000	
80-C0805C339C5G	C0805C339C5GACTU	3.3	50	.25pF			4,000	
80-C0805C339D1G	C0805C339D1GACTU	3.3	100	.5pF			4,000	
80-C0805C399C5G	C0805C399C5GACTU	3.9	50	.25pF			4,000	
80-C0805C399D1G	C0805C399D1GACTU	3.9	100	.5pF			4,000	
80-C0805C479C5G	C0805C479C5GACTU	4.7	50	.25pF			4,000	
80-C0805C479D5G	C0805C479D5GACTU	4.7	50	.5pF			4,000	
80-C0805C569J5G	C0805C569J5GACTU	5.6	50	5%			4,000	
80-C0805C569C5G	C0805C569C5GACTU	5.6	50	.25pF			4,000	
80-C0805C569D5G	C0805C569D5GACTU	5.6	50	.5pF			4,000	
80-C0805C569C1G	C0805C569C1GACTU	5.6	100	.25pF			4,000	
80-C0805C689C5G	C0805C689C5GACTU	6.8	50	.25pF			4,000	
80-C0805C689D1G	C0805C689D1GACTU	6.8	100	.5pF			4,000	
80-C0805C829C5G	C0805C829C5GACTU	8.2	50	.25pF			4,000	
80-C0805C829C1G	C0805C829C1GACTU	8.2	100	.25pF			4,000	
80-C0805C100J5G	C0805C100J5GACTU	10	50	5%			4,000	
80-C0805C100K5G	C0805C100K5GACTU	10	50	10%			4,000	
80-C0805C100C5G	C0805C100C5GACTU	10	50	.25pF			4,000	
80-C0805C100J1G	C0805C100J1GACTU	10	100	5%			4,000	
80-C0805C100K1G	C0805C100K1GACTU	10	100	10%			4,000	
80-C0805C100C1G	C0805C100C1GACTU	10	100	.25pF			4,000	
80-C0805C100D1G	C0805C100D1GACTU	10	100	.5pF			4,000	
80-C0805C120J5G	C0805C120J5GACTU	12	50	5%			4,000	
80-C0805C120C5G	C0805C120C5GACTU	12	50	.25pF			4,000	
80-C0805C150J5G	C0805C150J5GACTU	15	50	5%			4,000	
80-C0805C150K5G	C0805C150K5GACTU	15	50	10%			4,000	
80-C0805C150G1G	C0805C150G1GACTU	15	100	2%			4,000	
80-C0805C150J1G	C0805C150J1GACTU	15	100	5%			4,000	
80-C0805C150K1G	C0805C150K1GACTU	15	100	10%			4,000	
80-C0805C180G5G	C0805C180G5GACTU	18	50	2%			4,000	
80-C0805C180J5G	C0805C180J5GACTU	18	50	5%			4,000	
80-C0805C180K5G	C0805C180K5GACTU	18	50	10%			4,000	
80-C0805C180J1G	C0805C180J1GACTU	18	100	5%			4,000	
80-C0805C200G5G	C0805C200G5GACTU	20	50	2%			4,000	
80-C0805C200J5G	C0805C200J5GACTU	20	50	5%			4,000	
80-C0805C220G5G	C0805C220G5GACTU	22	50	2%			4,000	
80-C0805C220J5G	C0805C220J5GACTU	22	50	5%			4,000	
80-C0805C220K5G	C0805C220K5GACTU	22	50	10%			4,000	
80-C0805C220G1G	C0805C220G1GACTU	22	100	2%			4,000	
80-C0805C220J1G	C0805C220J1GACTU	22	100	5%			4,000	
80-C0805C220K1G	C0805C220K1GACTU	22	100	10%			4,000	
80-C0805C220J2G	C0805C220J2GACTU	22	200	5%			4,000	
80-C0805C240J5G	C0805C240J5GACTU	24	50	5%			4,000	
80-C0805C270G5G	C0805C270G5GACTU	27	50	2%			4,000	
80-C0805C270J5G	C0805C270J5GACTU	27	50	5%			4,000	
80-C0805C270K5G	C0805C270K5GACTU	27	50	10%			4,000	
80-C0805C270D1G	C0805C270D1GACTU	27	100	.5pF			4,000	
80-C0805C300J5G	C0805C300J5GACTU	30	50	5%			4,000	
80-C0805C300J1G	C0805C300J1GACTU	30	100	5%			4,000	
80-C0805C330F5G	C0805C330F5GACTU	33	50	1%			4,000	
80-C0805C330G5G	C0805C330G5GACTU	33	50	2%			4,000	
80-C0805C330J5G	C0805C330J5GACTU	33	50	5%			4,000	
80-C0805C330K5G	C0805C330K5GACTU	33	50	10%			4,000	
80-C0805C330G1G	C0805C330G1GACTU	33	100	2%			4,000	
80-C0805C330J1G	C0805C330J1GACTU	33	100	5%			4,000	
80-C0805C390G5G	C0805C390G5GACTU	39	50	2%			4,000	
80-C0805C390J5G	C0805C390J5GACTU	39	50	5%			4,000	
80-C0805C390K1G	C0805C390K1GACTU	39	100	10%			4,000	
80-C0805C390J2G	C0805C390J2GACTU	39	200	5%			4,000	
80-C0805C470G5G	C0805C470G5GACTU	47	50	2%			4,000	
80-C0805C470J5G	C0805C470J5GACTU	47	50	5%			4,000	
80-C0805C470K5G	C0805C470K5GACTU	47	50	10%			4,000	
80-C0805C470J1G	C0805C470J1GACTU	47	100	5%			4,000	
80-C0805C510J5G	C0805C510J5GACTU	51	50	5%			4,000	
80-C0805C560G5G	C0805C560G5GACTU	56	50	2%			4,000	
80-C0805C560J5G	C0805C560J5GACTU	56	50	5%			4,000	
80-C0805C560K5G	C0805C560K5GACTU	56	50	10%			4,000	
80-C0805C560G1G	C0805C560G1GACTU	56	100	2%			4,000	
80-C0805C560J1G	C0805C560J1GACTU	56	100	5%			4,000	
80-C0805C560K1G	C0805C560K1GACTU	56	100	10%			4,000	
80-C0805C680G5G	C0805C680G5GACTU	68	50	2%			4,000	
80-C0805C680J5G	C0805C680J5GACTU	68	50	5%			4,000	
80-C0805C680J1G	C0805C680J1GACTU	68	100	5%			4,000	
80-C0805C680K2G	C0805C680K2GACTU	68	200	10%			4,000	

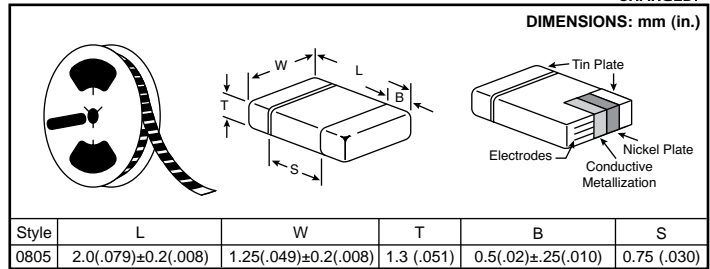

CASE SIZE 0805 (CONT.)

Please call a Mouser representative for information of product not listed.

MOUSER STOCK NO.	KEMET Part No.	Value (pF)	Volt (DC)	Tol.±	Price Each		7" Reel Qty.	Price Per Piece
					1	100		
Temperature Coefficient: C0G (Cont.)								
80-C0805C750J5G	C0805C750J5GACTU	75	50	5%			4,000	
80-C0805C820G5G	C0805C820G5GACTU	82	50	2%			4,000	
80-C0805C820J5G	C0805C820J5GACTU	82	50	5%			4,000	
80-C0805C820K5G	C0805C820K5GACTU	82	50	10%			4,000	
80-C0805C820J1G	C0805C820J1GACTU	82	100	5%			4,000	
80-C0805C820K1G	C0805C820K1GACTU	82	100	10%			4,000	
80-C0805C910G5G	C0805C910G5GACTU	91	50	2%			4,000	
80-C0805C910J1G	C0805C910J1GACTU	91	100	5%			4,000	
80-C0805C101G5G	C0805C101G5GACTU	100	50	2%			4,000	
80-C0805C101J5G	C0805C101J5GACTU	100	50	5%			4,000	
80-C0805C101K5G	C0805C101K5GACTU	100	50	10%			4,000	
80-C0805C101G1G	C0805C101G1GACTU	100	100	2%			4,000	
80-C0805C101J1G	C0805C101J1GACTU	100	100	5%			4,000	
80-C0805C101K1G	C0805C101K1GACTU	100	100	10%			4,000	
80-C0805C101J2G	C0805C101J2GACTU	100	200	5%			4,000	
80-C0805C121G5G	C0805C121G5GACTU	120	50	2%			4,000	
80-C0805C121J5G	C0805C121J5GACTU	120	50	5%			4,000	
80-C0805C121J1G	C0805C121J1GACTU	120	100	5%			4,000	
80-C0805C121K1G	C0805C121K1GACTU	120	100	10%			4,000	
80-C0805C151G5G	C0805C151G5GACTU	150	50	2%			4,000	
80-C0805C151J5G	C0805C151J5GACTU	150	50	5%			4,000	
80-C0805C151J1G	C0805C151J1GACTU	150	100	5%			4,000	
80-C0805C181G5G	C0805C181G5GACTU	180	50	2%			4,000	
80-C0805C181J5G	C0805C181J5GACTU	180	50	5%			4,000	
80-C0805C181J1G	C0805C181J1GACTU	180	100	5%			4,000	
80-C0805C181K1G	C0805C181K1GACTU	180	100	10%			4,000	
80-C0805C201J5G	C0805C201J5GACTU	200	50	5%			4,000	
80-C0805C221J5G	C0805C221J5GACTU	220	50	5%			4,000	
80-C0805C221K5G	C0805C221K5GACTU	220	50	10%			4,000	
80-C0805C221G1G	C0805C221G1GACTU	220	100	2%			4,000	
80-C0805C221J1G	C0805C221J1GACTU	220	100	5%			4,000	
80-C0805C221K1G	C0805C221K1GACTU	220	100	10%			4,000	
80-C0805C271G5G	C0805C271G5GACTU	270	50	2%			4,000	
80-C0805C271J5G	C0805C271J5GACTU	270	50	5%			4,000	
80-C0805C271J1G	C0805C271J1GACTU	270	100	5%			4,000	
80-C0805C301J5G	C0805C301J5GACTU	300	50	5%			4,000	
80-C0805C301K2G	C0805C301K2GACTU	300	200	10%			4,000	
80-C0805C331G5G	C0805C331G5GACTU	330	50	2%			4,000	
80-C0805C331J5G	C0805C331J5GACTU	330	50	5%			4,000	
80-C0805C331K5G	C0805C331K5GACTU	330	50	10%			4,000	
80-C0805C331J1G	C0805C331J1GACTU	330	100	5%			4,000	
80-C0805C331K1G	C0805C331K1GACTU	330	100	10%			4,000	
80-C0805C391J5G	C0805C391J5GACTU	390	50	5%			4,000	
80-C0805C471G5G	C0805C471G5GACTU	470	50	2%			4,000	
80-C0805C471J5G	C0805C471J5GACTU	470	50	5%			4,000	
80-C0805C471K5G	C0805C471K5GACTU	470	50	10%			4,000	
80-C0805C471J1G	C0805C471J1GACTU	470	100	5%			4,000	
80-C0805C471J2G	C0805C471J2GACTU	470	200	5%			4,000	
80-C0805C561G5G								