

# KEMET Ceramic Chip Capacitors

The Capacitance Company  
**KEMET**  
CHARGED™


## CASE SIZE 0805 (CONT.)



RoHS Compliant

Please call a Mouser representative for information of product not listed.

MOUSER STOCK NO.	KEMET Part No.	Value (pF)	Volt (DC)	Tol.±	Price Each		7" Reel Qty.	Price Per Piece
					1	100		
<b>Temperature Coefficient: X7R</b>								
80-C0805C221K5R	C0805C221K5RACTU	220	50	10%			4,000	
80-C0805C221K1R	C0805C221K1RACTU	220	100	10%			4,000	
80-C0805C221K2R	C0805C221K2RACTU	220	200	10%			4,000	
80-C0805C271K5R	C0805C271K5RACTU	270	50	10%			4,000	
80-C0805C331K5R	C0805C331K5RACTU	330	50	10%			4,000	
80-C0805C331K1R	C0805C331K1RACTU	330	100	10%			4,000	
80-C0805C391K5R	C0805C391K5RACTU	390	50	10%			4,000	
80-C0805C471K5R	C0805C471K5RACTU	470	50	10%			4,000	
80-C0805C471K1R	C0805C471K1RACTU	470	100	10%			4,000	
80-C0805C561K5R	C0805C561K5RACTU	560	50	10%			4,000	
80-C0805C681K5R	C0805C681K5RACTU	680	50	10%			4,000	
80-C0805C681K1R	C0805C681K1RACTU	680	100	10%			4,000	
80-C0805C821K5R	C0805C821K5RACTU	820	50	10%			4,000	
80-C0805C102J5R	C0805C102J5RACTU	1000	50	5%			4,000	
80-C0805C102K5R	C0805C102K5RACTU	1000	50	10%			4,000	
80-C0805C102M5R	C0805C102M5RACTU	1000	50	20%			4,000	
80-C0805C102J1R	C0805C102J1RACTU	1000	100	5%			4,000	
80-C0805C102K1R	C0805C102K1RACTU	1000	100	10%			4,000	
80-C0805C102K2R	C0805C102K2RACTU	1000	200	10%			4,000	
80-C0805C122K5R	C0805C122K5RACTU	1200	50	10%			4,000	
80-C0805C122K2R	C0805C122K2RACTU	1200	200	10%			4,000	
80-C0805C152J5R	C0805C152J5RACTU	1500	50	5%			4,000	
80-C0805C152K5R	C0805C152K5RACTU	1500	50	10%			4,000	
80-C0805C152K1R	C0805C152K1RACTU	1500	100	10%			4,000	
80-C0805C202K5R	C0805C202K5RACTU	2000	50	10%			4,000	
80-C0805C222J5R	C0805C222J5RACTU	2200	50	5%			4,000	
80-C0805C222K5R	C0805C222K5RACTU	2200	50	10%			4,000	
80-C0805C222K1R	C0805C222K1RACTU	2200	100	10%			4,000	
80-C0805C222K2R	C0805C222K2RACTU	2200	200	10%			4,000	
80-C0805C272K5R	C0805C272K5RACTU	2700	50	10%			4,000	
80-C0805C272K1R	C0805C272K1RACTU	2700	100	10%			4,000	
80-C0805C332J5R	C0805C332J5RACTU	3300	50	5%			4,000	
80-C0805C332K5R	C0805C332K5RACTU	3300	50	10%			4,000	
80-C0805C332J1R	C0805C332J1RACTU	3300	100	5%			4,000	
80-C0805C332K1R	C0805C332K1RACTU	3300	100	10%			4,000	
80-C0805C392J5R	C0805C392J5RACTU	3900	50	5%			4,000	
80-C0805C392K5R	C0805C392K5RACTU	3900	50	10%			4,000	
80-C0805C472J5R	C0805C472J5RACTU	4700	50	5%			4,000	
80-C0805C472K5R	C0805C472K5RACTU	4700	50	10%			4,000	
80-C0805C472J1R	C0805C472J1RACTU	4700	100	5%			4,000	
80-C0805C472K1R	C0805C472K1RACTU	4700	100	10%			4,000	
80-C0805C472K2R	C0805C472K2RACTU	4700	200	10%			4,000	
80-C0805C562J5R	C0805C562J5RACTU	5600	50	5%			4,000	
80-C0805C562K5R	C0805C562K5RACTU	5600	50	10%			4,000	
80-C0805C562K1R	C0805C562K1RACTU	5600	100	10%			4,000	
80-C0805C682J5R	C0805C682J5RACTU	6800	50	5%			4,000	
80-C0805C682K5R	C0805C682K5RACTU	6800	50	10%			4,000	
80-C0805C822J5R	C0805C822J5RACTU	8200	50	5%			4,000	
80-C0805C822K5R	C0805C822K5RACTU	8200	50	10%			4,000	
80-C0805C123K5R	C0805C123K5RACTU	.012µF	50	10%			4,000	
80-C0805C153J5R	C0805C153J5RACTU	.015µF	50	5%			4,000	
80-C0805C153K5R	C0805C153K5RACTU	.015µF	50	10%			4,000	
80-C0805C153K1R	C0805C153K1RACTU	.015µF	100	10%			4,000	
80-C0805C183K5R	C0805C183K5RACTU	.018µF	50	10%			4,000	
80-C0805C103J5R	C0805C103J5RACTU	.01µF	50	5%			4,000	
80-C0805C103K5R	C0805C103K5RACTU	.01µF	50	10%			4,000	
80-C0805C103M5R	C0805C103M5RACTU	.01µF	50	20%			4,000	
80-C0805C103J1R	C0805C103J1RACTU	.01µF	100	5%			4,000	
80-C0805C103K1R	C0805C103K1RACTU	.01µF	100	10%			4,000	
80-C0805C223J5R	C0805C223J5RACTU	.022µF	50	5%			4,000	
80-C0805C223K5R	C0805C223K5RACTU	.022µF	50	10%			4,000	
80-C0805C223K1R	C0805C223K1RACTU	.022µF	100	10%			4,000	
80-C0805C273K5R	C0805C273K5RACTU	.027µF	50	10%			4,000	
80-C0805C333J5R	C0805C333J5RACTU	.033µF	50	5%			4,000	
80-C0805C333K5R	C0805C333K5RACTU	.033µF	50	10%			4,000	
80-C0805C393J5R	C0805C393J5RACTU	.039µF	50	5%			4,000	
80-C0805C473K5R	C0805C473K5RACTU	.047µF	50	10%			4,000	
80-C0805C563J5R	C0805C563J5RACTU	.056µF	50	5%			4,000	
80-C0805C563K5R	C0805C563K5RACTU	.056µF	50	10%			4,000	
80-C0805C683J5R	C0805C683J5RACTU	.068µF	50	5%			4,000	
80-C0805C683K5R	C0805C683K5RACTU	.068µF	50	10%			4,000	
80-C0805C823K5R	C0805C823K5RACTU	.082µF	50	10%			4,000	
80-C0805C154K4R	C0805C154K4RACTU	.15µF	16	10%			4,000	
80-C0805C154K3R	C0805C154K3RACTU	.15µF	25	10%			4,000	
80-C0805C184K4R	C0805C184K4RACTU	.18µF	16	10%			4,000	
80-C0805C104K4R	C0805C104K4RACTU	0.1µF	16	10%			4,000	
80-C0805C104K3R	C0805C104K3RACTU	0.1µF	25	10%			4,000	
80-C0805C104J5R	C0805C104J5RACTU	0.1µF	50	5%			4,000	

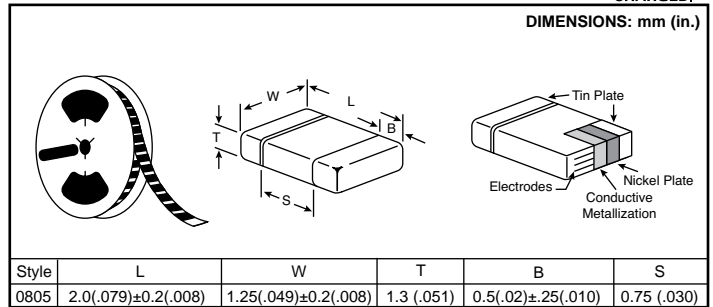

## CASE SIZE 0805 (CONT.)

Please call a Mouser representative for information of product not listed.

MOUSER STOCK NO.	KEMET Part No.	Value (pF)	Volt (DC)	Tol.±	Price Each		7" Reel Qty.	Price Per Piece
					1	100		
<b>Temperature Coef: X7R (cont.)</b>								
80-C0805C104K5R	C0805C104K5RACTU	0.1µF	50	10%			4,000	
80-C0805C104M5R	C0805C104M5RACTU	0.1µF	50	20%			4,000	
80-C0805C224J4R	C0805C224J4RACTU	.22µF	16	5%			4,000	
80-C0805C224K4R	C0805C224K4RACTU	.22µF	16	10%			4,000	
80-C0805C224J3R	C0805C224J3RACTU	.22µF	25	5%			4,000	
80-C0805C224K3R	C0805C224K3RACTU	.22µF	25	10%			4,000	
80-C0805C274K4R	C0805C274K4RACTU	.27µF	16	10%			4,000	
80-C0805C274K3R	C0805C274K3RACTU	.27µF	25	10%			4,000	
80-C0805C334K8R	C0805C334K8RACTU	.33µF	10	10%			2,500	
80-C0805C334J4R	C0805C334J4RACTU	.33µF	16	5%			2,500	
80-C0805C334K4R	C0805C334K4RACTU	.33µF	16	10%			2,500	
80-C0805C334K3R	C0805C334K3RACTU	.33µF	25	10%			2,500	
80-C0805C394K4R	C0805C394K4RACTU	.39µF	16	10%			2,500	
80-C0805C474J4R	C0805C474J4RACTU	.47µF	16	5%			2,500	
80-C0805C474K4R	C0805C474K4RACTU	.47µF	16	10%			2,500	
80-C0805C474J3R	C0805C474J3RACTU	.47µF	25	5%			2,500	
80-C0805C474K3R	C0805C474K3RACTU	.47µF	25	10%			2,500	
80-C0805C564K8R	C0805C564K8RACTU	.56µF	10	10%			2,500	
80-C0805C684K8R	C0805C684K8RACTU	.68µF	10	10%			2,500	
80-C0805C105K8R	C0805C105K8RACTU	1.0µF	10	10%			4,000	
80-C0805C125K9R	C0805C125K9RACTU	1.2µF	6.3	10%			2,500	
80-C0805C125K8R	C0805C125K8RACTU	1.2µF	10	10%			2,500	
80-C0805C125K4R	C0805C125K4RACTU	1.2µF	16	10%			2,500	
80-C0805C155K9R	C0805C155K9RACTU	1.5µF	6.3	10%			2,500	
80-C0805C155K8R	C0805C155K8RACTU	1.5µF	10	10%			2,500	
80-C0805C155K4R	C0805C155K4RACTU	1.5µF	16	10%			2,500	
80-C0805C185K9R	C0805C185K9RACTU	1.8µF	6.3	10%			2,500	
80-C0805C185K8R	C0805C185K8RACTU	1.8µF	10	10%			2,500	
80-C0805C185K4R	C0805C185K4RACTU	1.8µF	16	10%			2,500	
<b>Temperature Coef: X5R</b>								
80-C0805C125K9P	C0805C125K9PACTU	1.2µF	6.3	10%			4,000	
80-C0805C125K8P	C0805C125K8PACTU	1.2µF	10	10%			4,000	
80-C0805C155K9P	C0805C155K9PACTU	1.5µF	6.3	10%			2,500	
80-C0805C155K8P	C0805C155K8PACTU	1.5µF	10	10%			2,500	
80-C0805C185K9P	C0805C185K9PACTU	1.8µF	6.3	10%			2,500	
80-C0805C185K8P	C0805C185K8PACTU	1.8µF	10	10%			2,500	
80-C0805C275K8P	C0805C275K8PACTU	2.7µF	10	10%			4,000	
80-C0805C335K9P	C0805C335K9PACTU	3.3µF	6.3	10%			2,500	
80-C0805C335K8P	C0805C335K8PACTU	3.3µF	10	10%			2,500	
80-C0805C395K9P	C0805C395K9PACTU	3.9µF	6.3	10%			2,500	
80-C0805C395K8P	C0805C395K8PACTU	3.9µF	10	10%			2,500	
80-C0805C685K9P	C0805C685K9PACTU	6.8µF	6.3	10%			2,500	
<b>Temperature Coef: Z5U</b>								
80-C0805C103M5U	C0805C103M5UACTU	.01µF	50	20%			4,000	
80-C0805C103Z5U	C0805C103Z5UACTU	.01µF	50	+80, -20			4,000	
80-C0805C104M5U	C0805C104M5UACTU	0.1µF	50	20%			4,000	
80-C0805C104Z5U	C0805C104Z5UACTU	0.1µF	50	+80, -20			4,000	
<b>Temperature Coef: Y5V</b>								
80-C0805C104Z3V	C0805C104Z3VACTU	0.1µF	25	+80, -20			4,000	
80-C0805C104M5V	C0805C104M5VACTU	0.1µF	50	+80, -20			4,000	
80-C0805C104Z5V	C0805C104Z5VACTU	0.1µF	50	+80, -20			4,000	
80-C0805C224M3V	C0805C224M3VACTU	.22µF	25	+80, -20			4,000	
80-C0805C224Z3V	C0805C224Z3VACTU	.22µF	25	+80, -20			4,000	
80-C0805C334Z4V	C0805C334Z4VACTU	.33µF	16	+80, -20				