

KEMET Ceramic Chip Capacitors


The Capacitance Company
KEMET
CHARGED™

CASE SIZE 1206



Please call a Mouser representative for information of product not listed.

MOUSER STOCK NO.	KEMET Part No.	Value (pF)	Volt (DC)	Tol.±	Price Ea.		7" Reel Qty.	Price Per Piece
					1	100		
Temperature Coef: C0G								
80-C1206C109C5G	C1206C109C5GACTU	1.0	50	.25pF			4000	
80-C1206C109D5G	C1206C109D5GACTU	1.0	50	.5pF			4,000	
80-C1206C159C5G	C1206C159C5GACTU	1.5	50	.25pF			4,000	
80-C1206C189C5G	C1206C189C5GACTU	1.8	50	.25pF			4,000	
80-C1206C209C5G	C1206C209C5GACTU	2.0	50	.25pF			4,000	
80-C1206C229C5G	C1206C229C5GACTU	2.2	50	.25pF			4,000	
80-C1206C279C5G	C1206C279C5GACTU	2.7	50	.25pF			4,000	
80-C1206C309D5G	C1206C309D5GACTU	3.0	50	.5pF			4,000	
80-C1206C339C5G	C1206C339C5GACTU	3.3	50	.25pF			4,000	
80-C1206C399C5G	C1206C399C5GACTU	3.9	50	.25pF			4,000	
80-C1206C479K5G	C1206C479K5GACTU	4.7	50	10%			4,000	
80-C1206C479C5G	C1206C479C5GACTU	4.7	50	.25pF			4,000	
80-C1206C509D5G	C1206C509D5GACTU	5.0	50	.5pF			4,000	
80-C1206C519C5G	C1206C519C5GACTU	5.1	50	.25pF			4,000	
80-C1206C569J5G	C1206C569J5GACTU	5.6	50	5%			4,000	
80-C1206C569C5G	C1206C569C5GACTU	5.6	50	.25pF			4,000	
80-C1206C689C5G	C1206C689C5GACTU	6.8	50	.25pF			4,000	
80-C1206C689D5G	C1206C689D5GACTU	6.8	50	.5pF			4,000	
80-C1206C759C5G	C1206C759C5GACTU	7.5	50	.25pF			4,000	
80-C1206C759D5G	C1206C759D5GACTU	7.5	50	.5pF			4,000	
80-C1206C829J5G	C1206C829J5GACTU	8.2	50	5%			4,000	
80-C1206C829C5G	C1206C829C5GACTU	8.2	50	.5pF			4,000	
80-C1206C919D5G	C1206C919D5GACTU	9.1	50	.5pF			4,000	
80-C1206C100J5G	C1206C100J5GACTU	10	50	5%			4,000	
80-C1206C100C5G	C1206C100C5GACTU	10	50	.25pF			4,000	
80-C1206C100J1G	C1206C100J1GACTU	10	100	5%			4,000	
80-C1206C100D1G	C1206C100D1GACTU	10	100	.5pF			4,000	
80-C1206C110C5G	C1206C110C5GACTU	11	50	.25pF			4,000	
80-C1206C120J5G	C1206C120J5GACTU	12	50	5%			4,000	
80-C1206C120J1G	C1206C120J1GACTU	12	100	5%			4,000	
80-C1206C150J5G	C1206C150J5GACTU	15	50	5%			4,000	
80-C1206C150K5G	C1206C150K5GACTU	15	50	10%			4,000	
80-C1206C150K1G	C1206C150K1GACTU	15	100	10%			4,000	
80-C1206C180J5G	C1206C180J5GACTU	18	50	5%			4,000	
80-C1206C200J5G	C1206C200J5GACTU	20	50	5%			4,000	
80-C1206C200J1G	C1206C200J1GACTU	20	100	5%			4,000	
80-C1206C220J5G	C1206C220J5GACTU	22	50	5%			4,000	
80-C1206C220K5G	C1206C220K5GACTU	22	50	10%			4,000	
80-C1206C220K1G	C1206C220K1GACTU	22	100	10%			4,000	
80-C1206C240J1G	C1206C240J1GACTU	24	100	5%			4,000	
80-C1206C270J5G	C1206C270J5GACTU	27	50	5%			4,000	
80-C1206C270K5G	C1206C270K5GACTU	27	50	10%			4,000	
80-C1206C270J1G	C1206C270J1GACTU	27	100	5%			4,000	
80-C1206C330G5G	C1206C330G5GACTU	33	50	2%			4,000	
80-C1206C330J5G	C1206C330J5GACTU	33	50	5%			4,000	
80-C1206C330K5G	C1206C330K5GACTU	33	50	10%			4,000	
80-C1206C330J1G	C1206C330J1GACTU	33	100	5%			4,000	
80-C1206C330K1G	C1206C330K1GACTU	33	100	10%			4,000	
80-C1206C330K2G	C1206C330K2GACTU	33	200	10%			4,000	
80-C1206C390J5G	C1206C390J5GACTU	39	50	5%			4,000	
80-C1206C390K5G	C1206C390K5GACTU	39	50	10%			4,000	
80-C1206C390J1G	C1206C390J1GACTU	39	100	5%			4,000	
80-C1206C470G5G	C1206C470G5GACTU	47	50	2%			4,000	
80-C1206C470J5G	C1206C470J5GACTU	47	50	5%			4,000	
80-C1206C470K5G	C1206C470K5GACTU	47	50	10%			4,000	
80-C1206C470J1G	C1206C470J1GACTU	47	100	5%			4,000	
80-C1206C470K2G	C1206C470K2GACTU	47	200	5%			4,000	
80-C1206C470K2G	C1206C470K2GACTU	47	200	10%			4,000	
80-C1206C510J5G	C1206C510J5GACTU	51	50	5%			4,000	
80-C1206C560J5G	C1206C560J5GACTU	56	50	5%			4,000	
80-C1206C620J1G	C1206C620J1GACTU	62	100	5%			4,000	
80-C1206C680G5G	C1206C680G5GACTU	68	50	2%			4,000	
80-C1206C680J5G	C1206C680J5GACTU	68	50	5%			4,000	
80-C1206C680M5G	C1206C680M5GACTU	68	50	20%			4,000	
80-C1206C680J1G	C1206C680J1GACTU	68	100	5%			4,000	
80-C1206C820J5G	C1206C820J5GACTU	82	50	5%			4,000	
80-C1206C101G5G	C1206C101G5GACTU	100	50	2%			4,000	
80-C1206C101J5G	C1206C101J5GACTU	100	50	5%			4,000	
80-C1206C101K5G	C1206C101K5GACTU	100	50	10%			4,000	
80-C1206C101J1G	C1206C101J1GACTU	100	100	5%			4,000	
80-C1206C101K1G	C1206C101K1GACTU	100	100	10%			4,000	
80-C1206C101K2G	C1206C101K2GACTU	100	200	10%			4,000	
80-C1206C121G5G	C1206C121G5GACTU	120	50	2%			4,000	
80-C1206C121J5G	C1206C121J5GACTU	120	50	5%			4,000	
80-C1206C121J1G	C1206C121J1GACTU	120	100	5%			4,000	
80-C1206C151G5G	C1206C151G5GACTU	150	50	2%			4,000	
80-C1206C151J5G	C1206C151J5GACTU	150	50	5%			4,000	
80-C1206C151K5G	C1206C151K5GACTU	150	50	10%			4,000	
80-C1206C151J1G	C1206C151J1GACTU	150	100	5%			4,000	
80-C1206C151J2G	C1206C151J2GACTU	150	200	5%			4,000	

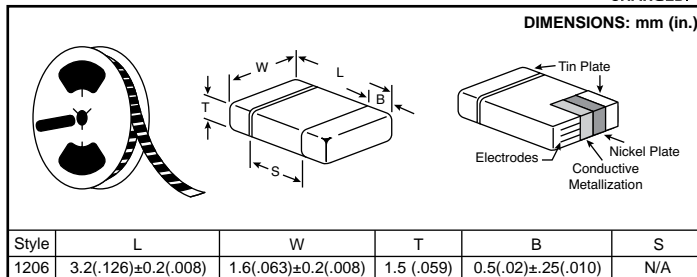

CASE SIZE 1206 (CONT.)

Please call a Mouser representative for information of product not listed.

MOUSER STOCK NO.	KEMET Part No.	Value (pF)	Volt (DC)	Tol.±	Price Ea.		7" Reel Qty.	Price Per Piece
					1	100		
Temperature Coef: C0G (Cont.)								
80-C1206C181J5G	C1206C181J5GACTU	180	50	5%			4,000	
80-C1206C181K5G	C1206C181K5GACTU	180	50	10%			4,000	
80-C1206C181J1G	C1206C181J1GACTU	180	100	5%			4,000	
80-C1206C201J1G	C1206C201J1GACTU	200	100	5%			4,000	
80-C1206C221G5G	C1206C221G5GACTU	220	50	2%			4,000	
80-C1206C221J5G	C1206C221J5GACTU	220	50	5%			4,000	
80-C1206C221K5G	C1206C221K5GACTU	220	50	10%			4,000	
80-C1206C221J2G	C1206C221J2GACTU	220	200	5%			4,000	
80-C1206C271J5G	C1206C271J5GACTU	270	50	5%			4,000	
80-C1206C271K5G	C1206C271K5GACTU	270	50	10%			4,000	
80-C1206C271J1G	C1206C271J1GACTU	270	100	5%			4,000	
80-C1206C271J2G	C1206C271J2GACTU	270	200	5%			4,000	
80-C1206C331G5G	C1206C331G5GACTU	330	50	2%			4,000	
80-C1206C331J5G	C1206C331J5GACTU	330	50	5%			4,000	
80-C1206C331K5G	C1206C331K5GACTU	330	50	10%			4,000	
80-C1206C331J1G	C1206C331J1GACTU	330	100	5%			4,000	
80-C1206C331K1G	C1206C331K1GACTU	330	100	10%			4,000	
80-C1206C331J2G	C1206C331J2GACTU	330	200	5%			4,000	
80-C1206C361J5G	C1206C361J5GACTU	360	50	5%			4,000	
80-C1206C391G5G	C1206C391G5GACTU	390	50	2%			4,000	
80-C1206C391J5G	C1206C391J5GACTU	390	50	5%			4,000	
80-C1206C391K5G	C1206C391K5GACTU	390	50	10%			4,000	
80-C1206C391J2G	C1206C391J2GACTU	390	200	5%			4,000	
80-C1206C471G5G	C1206C471G5GACTU	470	50	2%			4,000	
80-C1206C471J5G	C1206C471J5GACTU	470	50	5%			4,000	
80-C1206C471K5G	C1206C471K5GACTU	470	50	10%			4,000	
80-C1206C471J1G	C1206C471J1GACTU	470	100	5%			4,000	
80-C1206C471K1G	C1206C471K1GACTU	470	100	10%			4,000	
80-C1206C471K2G	C1206C471K2GACTU	470	200	10%			4,000	
80-C1206C561G5G	C1206C561G5GACTU	560	50	2%			4,000	
80-C1206C561J5G	C1206C561J5GACTU	560	50	5%			4,000	
80-C1206C561K5G	C1206C561K5GACTU	560	50	10%			4,000	
80-C1206C561J1G	C1206C561J1GACTU	560	100	5%			4,000	
80-C1206C621J5G	C1206C621J5GACTU	620	50	5%			4,000	
80-C1206C681J5G	C1206C681J5GACTU	680	50	5%			4,000	
80-C1206C681K5G	C1206C681K5GACTU	680	50	10%			4,000	
80-C1206C681K1G	C1206C681K1GACTU	680	100	10%			4,000	
80-C1206C751J5G	C1206C751J5GACTU	750	50	5%			4,000	
80-C1206C821G5G	C1206C821G5GACTU	820	50	2%			4,000	
80-C1206C821J5G	C1206C821J5GACTU	820	50	5%			4,000	
80-C1206C821K5G	C1206C821K5GACTU	820	50	10%			4,000	
80-C1206C102G5G	C1206C102G5GACTU	1000	50	2%			4,000	
80-C1206C102J5G	C1206C102J5GACTU	1000	50	5%			4,000	
80-C1206C102K5G	C1206C102K5GACTU	1000	50	10%			4,000	
80-C1206C102G1G	C1206C102G1GACTU	1000	100	2%			4,000	
80-C1206C102J1G	C1206C102J1GACTU	1000	100	5%			4,000	
80-C1206C102K1G	C1206C102K1GACTU	1000	100	10%			4,000	
80-C1206C102K2G	C1206C102K2GACTU	1000	200	10%			2,500	
80-C1206C122J5G	C1206C122J5GACTU	1200	50	5%			4,000	
80-C1206C122K5G	C1206C122K5GACTU	1200	50	10%			4,000	
80-C1206C122J1G	C1206C122J1GACTU	1200	100	5%			4,000	
80-C1206C152J5G	C1206C152J5GACTU	1500	50	5%</				