

CITIZEN SMD Programmable, XO and VCXO Oscillators CITIZEN

RoHS Compliant This product is RoHS compliant.

CITIZEN CSX-750F SERIES CERAMIC CRYSTAL CLOCK OSCILLATORS 7 X 5 X 1.6



RoHS Compliant

3.3 Volt

For quantities of 2,000 and up, call for quote.

MOUSER STOCK NO.	Citizen Part Number	Frequency (MHz)	Price Each				
			1	10	50	100	500
695-CSX750FBC-184	CSX750FBC1.8432MUT	1.84320					
695-CSX750FBC-368	CSX750FBC3.6864MUT	3.68640					
695-CSX750FBC-4	CSX750FBC4.0000MUT	4.00000					
695-CSX750FBC-8	CSX750FBC8.0000MUT	8.00000					
695-CSX750FBC-10	CSX750FBC10.0000MUT	10.00000					
695-CSX750FBC-12	CSX750FBC12.0000MUT	12.00000					
695-CSX750FBC-147	CSX750FBC14.7456MUT	14.74560					
695-CSX750FBC-16	CSX750FBC16.0000MUT	16.00000					
695-CSX750FBC-18.4	CSX750FBC18.432MUT	18.43200					
695-CSX750FBC-20	CSX750FBC20.0000MUT	20.00000					
695-CSX750FBC-24	CSX750FBC24.0000MUT	24.00000					
695-CSX750FBC-245	CSX750FBC24.576MUT	24.57600					
695-CSX750FBC-25	CSX750FBC25.0000MUT	25.00000					
695-CSX750FBC-32	CSX750FBC32.0000MUT	32.00000					
695-CSX750FBC-333	CSX750FBC33.333MUT	33.33300					
695-CSX750FJC-40	CSX750FJC40.0000MUT	40.00000					
695-CSX750FJC-48	CSX750FJC48.0000MUT	48.00000					
695-CSX750FJC-50	CSX750FJC50.0000MUT	50.00000					
695-CSX750FJC-60	CSX750FJC60.0000MUT	60.00000					
695-CSX750FJC-64	CSX750FJC64.0000MUT	64.00000					



RoHS Compliant

5.0 Volt

For quantities of 2,000 and up, call for quote.

MOUSER STOCK NO.	Citizen Part Number	Frequency (MHz)	Price Each				
			1	10	50	100	500
695-CSX750FCC-184	CSX750FCC1.8432M-UT	1.84320					
695-CSX750FCC-4	CSX750FCC4.0000M-UT	4.00000					
695-CSX750FCC-8	CSX750FCC8.0000M-UT	8.00000					
695-CSX750FCC-10	CSX750FCC10.0000M-UT	10.00000					
695-CSX750FCC-143	CSX750FCC14.31818M-UT	14.31818					
695-CSX750FCC-16	CSX750FCC16.0000M-UT	16.00000					
695-CSX750FCC-20	CSX750FCC20.0000M-UT	20.00000					
695-CSX750FCC-40	CSX750FCC40.0000M-UT	40.00000					
695-CSX750FCC-48	CSX750FCC48.0000M-UT	48.00000					
695-CSX750FCC-50	CSX750FCC50.0000M-UT	50.00000					

PART NUMBERING GUIDE:

695-CSX750 - -FREQ

Product Family: 695-CSX750

Frequency: Numerical Value - Max. characters as follows:
XXX.XXXXXX
Followed by "M" for MHz

Programmable Frequency:

	Voltage	Load Condition
PT	5V	TTL
PC	5V	CMOS
PB	3.3V	CMOS

Packaging Method:
UT = Tape & Reel (2000 pcs min.)
UB = Bulk

Frequency Tolerance (at Operating Temp.):
B = ±50ppm (-20°C to +70°C)
C = ±100ppm (-20°C to +70°C) (Std)
F = ±100ppm (-40°C to +85°C)
G = ±200ppm (-40°C to +85°C)

CITIZEN CSX750 SERIES PROGRAMMABLE CRYSTAL OSCILLATORS 7.0 X 5.0MM

Features:

- Wide range of output frequency by PLL technology

Specifications:


- Frequency Range: CSX750PT - 1.000MHz to 125.000MHz
CSX750PC - 1.000MHz to 125.000MHz
CSX750PB - 1.000MHz to 100.000MHz

Applications:

- Communication Devices
- AV Devices
- Automotive Devices
- Measuring Instruments



RoHS Compliant

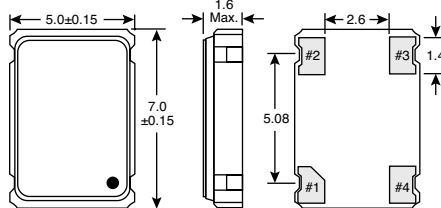




DIMENSIONS: mm

Pin Assignment	
Pin No.	Connection
#1	OE or Stand By
#2	GND
#3	OUT
#4	Vdd

MOUSER STOCK NO.	Price Each	
	1	10
695-CSX750XXX-XX-Freq	3,90	3,32


Function	
#1 Input	#3 Output Condition
H	Oscillation Out
Open	Oscillation Out
L	Oscillation Stop

CITIZEN CSX-750V SERIES VOLTAGE CONTROLLED CRYSTAL OSCILLATORS 7.0 X 5.0MM

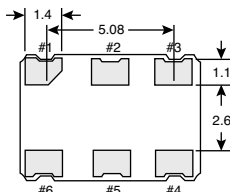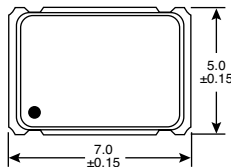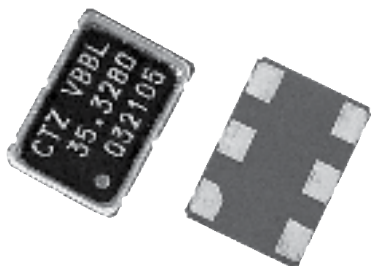

Pin Assignment	
Pin No.	Connection
#1	VC
#2	NC
#3	GND
#4	OUT
#5	OE
#6	Vdd

Function	
#5	#4 Output Condition
H	Oscillation out
Open	Oscillation out
L	Oscillation stop

 

Features:

- Available to supply voltage 5.0V or 3.3V
- Automatic mounting and reflowable type
- Most appropriate for communication devices and other equipment
- Output enable function (OE) can be used for low power consumption



RoHS Compliant

For quantities of 1,000 and up, call for quote.

MOUSER STOCK NO.	Citizen Part Number	Frequency (MHz)	Voltage	Pull (ppm)	Temp. °C	Price Each				
						1	10	50	100	500
695-CSX750VKB-122	CSX750VKB-12.288M-UT	12.288	3.3	±90	-20 + 70					
695-CSX750VKB-25	CSX750VKB-25.00M-UT	25.00	3.3	±90	-20 + 70					
695-CSX750VKB-327	CSX750VKB-32.768M-UT	32.768	3.3	±90	-20 + 70					
695-CSX750VJB-20	CSX750VJB-20.00M-UT	20.00	5.0	±100	-20 + 70					
695-CSX750VJB-27	CSX750VJB-27.00M-UT	27.00	5.0	±100	-20 + 70					