


# AVX Medium Power Film Capacitors

## FB SERIES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Volts (V)	Value (μf)	Irms (A)	Dimensions: mm (in.)				Price Each	
Mfr.	Mfr. Part No.				L	W	H	LS	1	5
581	FB37M6A0306KC	700	30	16.0	30	42.5	45	37.5	12.40	10.91
581	FB37H6C0106KC	900	10	8.5	22	42.5	33.5	37.5	8.33	7.33
581	FB37M6C0206KC	900	20	14.0	30	42.5	45	37.5	11.37	10.01
581	FB37L6L0106KC	1.1K	10	14.0	24	42.5	44	37.5	8.66	7.62
581	FB37M6P0106KC	1.2K	10	11.0	30	42.5	45	37.5	9.43	8.29

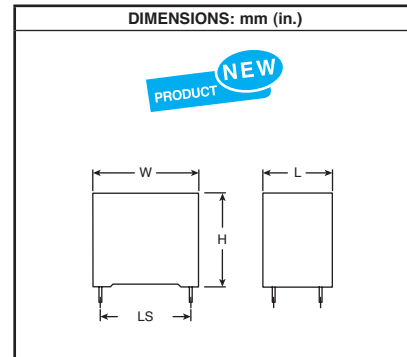

## FE SERIES


For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Volts (V)	Value (μf)	Irms (A)	Dimensions: mm (in.)				Price Each	
Mfr.	Mfr. Part No.				L	W	H	LS	1	5
581	FE37M6C0206KB	900	20	15.0	30	42.5	45	37.5	12.65	11.13
581	FE52N6L0206KB	1.1K	20	15.0	30	57.5	45	52.5	13.40	11.79
581	FE37M6P0106KB	1.2K	10	12.0	30	42.5	45	37.5	11.55	10.16

## FFVS SERIES

For quantities greater than listed, call for quote.


MOUSER STOCK NO.		Volts (V)	Value (μf)	Height mm (in.)	Irms (A)	Price Each	
Mfr.	Mfr. Part No.					1	5
581	FFVS6K0226K	600	22	34 (1.339)	78	160.78	145.44
581	FFVS6K0147K	600	140	51 (2.008)	82	212.68	193.86
581	FFVS6B0586K	800	58	40 (1.575)	83	170.45	152.77
581	FFVS6B1286K	800	128	64 (2.520)	84	199.98	170.66
581	FFVS6C0306K	900	30	34 (1.339)	56	159.13	146.12
581	FFVS6C0656K	900	65	51 (2.520)	86	167.05	155.00
581	FFVS6L0956K	1000	95	51 (2.008)	63	173.18	158.58
581	FFVS6U0656K	1200	65	51 (2.520)	57	171.10	158.58
581	FFVS6U0656K	1900	22	51 (2.520)	68	171.10	158.58

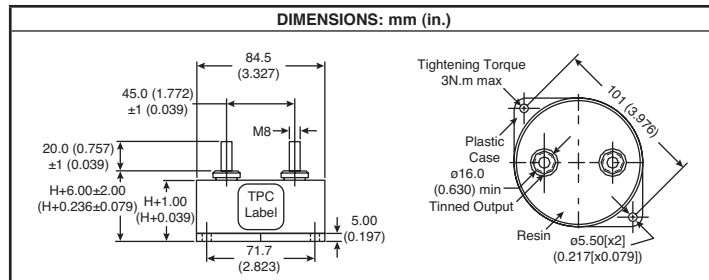

## FFB SERIES

For quantities greater than listed, call for quote.


MOUSER STOCK NO.		Volts (V)	Value (μf)	Irms (A)	Dimensions: mm (in.)				Price Each	
Mfr.	Mfr. Part No.				L	W	H	LS	1	5
581	FFB14D0336K	75	33	3	31.1	13.0	22.4	27.5	11.05	10.04
581	FFB34D0686K	75	68	46.2	31.1	17.3	29.8	27.5	17.27	15.70
581	FFB54D0117K	75	110	10	32.0	22.0	37.0	27.5	33.73	32.50
581	FFB14E0206K	100	20	2.6	31.1	13.0	22.4	27.5	8.90	8.09
581	FFB44E0476K	100	47	6	31.1	20.8	31.3	27.5	16.95	15.40
581	FFB54E0686K	100	68	9	32.0	22.0	37.0	27.5	28.12	25.56
581	FFB14H0755K	300	7.5	2.4	31.1	13.0	22.4	27.5	4.92	4.47
581	FFB44H0186K	300	18	6	31.1	20.8	31.3	27.5	10.30	9.36
581	FFB54H0276K	300	27	9	32.0	22.0	37.0	27.5	14.42	13.11
581	FFB14I0625K	400	6.2	2.5	31.1	13.0	22.4	27.5	6.80	6.05
581	FFB44I0156K	400	15	6.2	31.1	20.8	31.3	27.5	10.92	9.93
581	FFB54I0206K	400	20	8.2	32.0	22.0	37.0	27.5	22.27	20.25
581	FFB16J0395K	525	3.9	5.1	31.1	13.0	22.4	27.5	5.45	5.01
581	FFB46J0106K	525	10	12	31.1	20.8	31.3	27.5	13.45	12.22
581	FFB56J0136K	525	13	12	32.0	22.0	37.0	27.5	21.45	19.50
581	FFB16A0335K	720	3.3	5	31.1	13.0	22.4	27.5	5.20	4.72
581	FFB46A0755K	720	7.5	11.4	31.1	20.8	31.3	27.5	9.72	8.84
581	FFB56A0106K	720	10	12	32.0	22.0	37.0	27.5	21.05	19.13
581	FFB16C0205K	900	2	3.6	31.1	13.0	22.4	27.5	4.95	4.50
581	FFB46C0515K	900	5.1	9.3	31.1	20.8	31.3	27.5	10.70	9.72
581	FFB16L0155K	1100	1.5	3.3	31.1	13.0	22.4	27.5	6.87	6.25
581	FFB46L0305K	1100	3	6.6	31.1	20.8	31.3	27.5	8.55	7.77
581	FFB56L0475K	1100	4.7	10.3	32.0	22.0	37.0	27.5	13.40	12.18

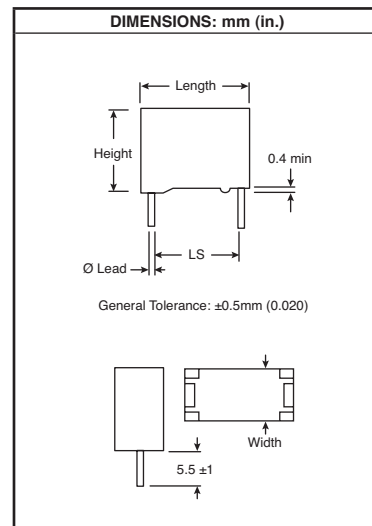

## FFLI SERIES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Volts (V)	Value (μF)	Irms (A)	Dimensions: mm (in.)			Terminal	Price Each	
Mfr.	Mfr. Part No.				D	H	LS		1	5
581	FFLI6B0687KJE	800	680	53	85	155	32	Female	128.04	123.69
581	FFLI6B1607KJE	800	1600	72	116	180	50	Female	220.96	215.18
581	FFLI6B3007KJE	800	3000	100	116	340	50	Female	387.70	366.47
581	FFLI6L0657KJE	1000	650	60	100	155	50	Female	138.48	133.47
581	FFLI6L0267KJE	1000	260	56	85	105	32	Female	89.61	86.12
581	FFLI6U0157KJE	1150	150	44	75	105	32	Female	80.64	76.80
581	FFLI6U0437KJE	1150	430	43	85	180	32	Female	110.20	106.80
581	FFLI6U0867KJE	1150	860	64	116	180	50	Female	162.66	159.12
581	FFLI6Q0257KJE	1400	250	42	85	155	32	Female	93.53	89.79
581	FFLI6Q0607KJE	1400	600	60	116	180	50	Female	143.14	140.77

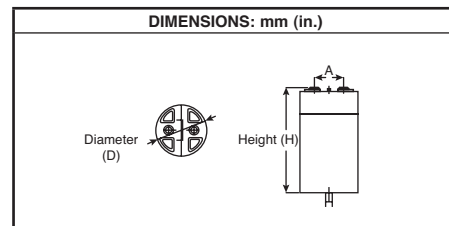

## FFV3 SERIES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Volts (V)	Value (μF)	Irms (A)	Price Each	
Mfr.	Mfr. Part No.				1	5
581	FFV34D0167K	75	160	23	41.58	37.10
581	FFV34E0107K	100	100	24	34.66	32.49
581	FFV34H0506K	300	50	26	30.10	28.12
581	FFV34I0406K	400	40	23	30.70	28.26
581	FFV36J0206K	500	20	27	22.40	21.57
581	FFV36A0206K	700	20	30	23.44	22.10
581	FFV36C0136K	900	13	25	22.44	21.57
581	FFV36L0905K	1100	9	20	21.80	20.10

