

PANASONIC Metallized Polyester Film Capacitors Panasonic

RoHS Compliant This product is RoHS compliant.


ECQEB AND ECQEF SERIES

Features:

- Small size
- Excellent electrical characteristics
- Flame retardant epoxy resin coating
- Tolerance: 10%
- Small size (ECQEB series)
- Self-healing property (ECQEF series)

Applications:

- 250VDC: High frequency and current circuits
- 450VDC: Active filter circuits

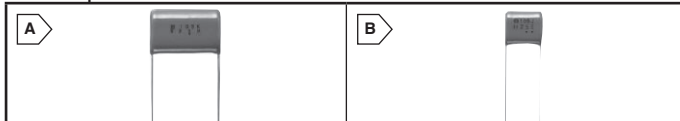

For quantities greater than listed, call for quote.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Value (uF)	Rated Volt	Price Each			
				1	25	100	250
ECQEB							
667-ECQ-E2153JB	A	0.015	250	.40	.192	.164	.144
667-ECQ-E2103JB	A	0.010	250	.40	.192	.164	.144
667-ECQ-E2123JB	A	0.012	250	.40	.192	.164	.144
667-ECQ-E2183JB	A	0.018	250	.40	.192	.164	.144
667-ECQ-E2223JB	A	0.022	250	.40	.192	.164	.144
667-ECQ-E2273JB	A	0.027	250	.40	.192	.164	.144
667-ECQ-E2333JB	A	0.033	250	.40	.192	.164	.144
667-ECQ-E2393JB	A	0.039	250	.40	.192	.164	.144
667-ECQ-E2473JB	A	0.047	250	.40	.192	.164	.144
667-ECQ-E2563JB	A	0.056	250	.40	.192	.164	.144
667-ECQ-E2683JB	A	0.068	250	.40	.192	.164	.144
667-ECQ-E2823JB	A	0.082	250	.44	.214	.183	.16
667-ECQ-E2104JB	A	0.10	250	.40	.192	.164	.144
667-ECQ-E2124JB	A	0.12	250	.56	.338	.295	.232
667-ECQ-E2154JB	A	0.15	250	.43	.232	.202	.175
667-ECQ-E2184JB	A	0.18	250	.82	.494	.432	.339
667-ECQ-E2224JB	A	0.22	250	.48	.255	.222	.193
667-ECQ-E2274JB	A	0.27	250	.82	.496	.433	.34
667-ECQ-E2334JB	A	0.33	250	.95	.486	.40	.353
667-ECQ-E2394JB	A	0.39	250	.92	.587	.528	.455
667-ECQ-E2474JB	A	0.47	250	.85	.511	.447	.351
667-ECQ-E2564JB	A	0.56	250	.63	.369	.316	.283
667-ECQ-E2684JB	A	0.68	250	.69	.404	.347	.31
667-ECQ-E2824JB	A	0.82	250	.92	.589	.53	.456
667-ECQ-E2105JB	A	1.0	250	.37	.348	.318	.295
667-ECQ-E2125JB	A	1.2	250	1.11	.75	.681	.592
667-ECQ-E2155JB	A	1.5	250	1.02	.645	.555	.492
667-ECQ-E2185JB	A	1.8	250	1.21	.899	.825	.728
667-ECQ-E2225JB	A	2.2	250	1.01	.939	.707	.678
667-ECQ-E2275JB	A	2.7	250	1.76	1.27	1.16	1.01
667-ECQ-E2335JB	A	3.3	250	1.97	1.43	1.30	1.14
667-ECQ-E2395JB	A	3.9	250	2.83	2.18	1.33	1.14
667-ECQ-E2475JB	A	4.7	250	2.51	1.93	1.83	1.71

MOUSER STOCK NO.	Fig.	Value (uF)	Rated Volt	Price Each			
				1	25	100	250
ECQEF							
667-ECQ-E2153JF	B	0.0015	250	.40	.192	.164	.144
667-ECQ-E2153JF	B	0.0015	250	.56	.321	.268	.20
667-ECQ-E4153JF	B	0.0015	400	.63	.361	.301	.226
667-ECQ-E6152JF	B	0.0015	630	.59	.316	.275	.239
667-ECQ-E6153JF	B	0.0015	630	.99	.507	.417	.369
667-ECQ-E6392JF	B	0.0039	630	.75	.451	.394	.31
667-ECQ-E2103JF	B	0.010	250	.40	.192	.164	.144
667-ECQ-E2103JF	B	0.010	250	.56	.321	.268	.20
667-ECQ-E4103JF	B	0.010	400	.63	.361	.301	.226
667-ECQ-E6103JF	B	0.010	630	.49	.264	.23	.20
667-ECQ-E2123JF	B	0.012	250	.40	.192	.164	.144
667-ECQ-E2123JF	B	0.012	250	.56	.321	.268	.20
667-ECQ-E4123JF	B	0.012	400	.63	.361	.301	.226
667-ECQ-E6123JF	B	0.012	630	.75	.453	.396	.311
667-ECQ-E2183JF	B	0.018	250	.40	.192	.164	.144
667-ECQ-E2183JF	B	0.018	250	.56	.321	.268	.20
667-ECQ-E4183JF	B	0.018	400	.63	.361	.301	.226
667-ECQ-E6183JF	B	0.018	630	.55	.293	.255	.222
667-ECQ-E2223JF	B	0.022	250	.40	.192	.164	.144
667-ECQ-E2223JF	B	0.022	250	.56	.321	.268	.20
667-ECQ-E4223JF	B	0.022	400	.63	.361	.301	.226
667-ECQ-E6223JF	B	0.022	630	.86	.517	.452	.355
667-ECQ-E2273JF	B	0.027	250	.40	.192	.164	.144
667-ECQ-E2273JF	B	0.027	250	.56	.321	.268	.20
667-ECQ-E4273JF	B	0.027	400	.63	.361	.301	.226
667-ECQ-E6273JF	B	0.027	630	.59	.315	.274	.238
667-ECQ-E2333JF	B	0.033	250	.40	.192	.164	.144
667-ECQ-E2333JF	B	0.033	250	.56	.321	.268	.20
667-ECQ-E4333JF	B	0.033	400	.63	.361	.301	.226
667-ECQ-E6333JF	B	0.033	630	.95	.486	.40	.353
667-ECQ-E2393JF	B	0.039	250	.40	.192	.164	.144
667-ECQ-E2393JF	B	0.039	250	.56	.321	.268	.20
667-ECQ-E4393JF	B	0.039	400	.63	.361	.301	.226
667-ECQ-E6393JF	B	0.039	630	.88	.529	.463	.364
667-ECQ-E1473JF	B	0.047	100	.61	.266	.197	.167
667-ECQ-E2473JF	B	0.047	250	.40	.192	.164	.144
667-ECQ-E2473JF	B	0.047	250	.56	.321	.268	.20
667-ECQ-E4473JF	B	0.047	400	.63	.361	.301	.226
667-ECQ-E6473JF	B	0.047	630	.88	.563	.507	.436
667-ECQ-E2563JF	B	0.056	250	.40	.192	.164	.144
667-ECQ-E2563JF	B	0.056	250	.66	.38	.317	.238
667-ECQ-E4563JF	B	0.056	400	.88	.529	.463	.364
667-ECQ-E6563JF	B	0.056	630	1.05	.561	.491	.435
667-ECQ-E2683JF	B	0.068	250	.40	.192	.164	.144
667-ECQ-E2683JF	B	0.068	250	.68	.387	.322	.241
667-ECQ-E4683JF	B	0.068	400	.92	.553	.484	.38
667-ECQ-E6683JF	B	0.068	630	1.35	.72	.63	.558
667-ECQ-E1823JF	B	0.082	100	.61	.266	.197	.167
667-ECQ-E2823JF	B	0.082	250	.44	.214	.183	.16
667-ECQ-E2823JF	B	0.082	250	.68	.387	.322	.241
667-ECQ-E4823JF	B	0.082	400	.35	.323	.295	.274
667-ECQ-E6823JF	B	0.082	630	.97	.618	.556	.479
667-ECQ-E2104JF	B	0.10	250	.40	.192	.164	.144
667-ECQ-E2104JF	B	0.10	250	.68	.387	.322	.241
667-ECQ-E4104JF	B	0.10	400	.96	.578	.505	.397
667-ECQ-E6104JF	B	0.10	630	1.10	.708	.637	.549
667-ECQ-E1124JF	B	0.12	100	.52	.276	.24	.209
667-ECQ-E2124JF	B	0.12	250	.56	.338	.295	.232

MOUSER STOCK NO.	Fig.	Value (uF)	Rated Volt	Price Each			
				1	25	100	250
ECQEF Cont.							
667-ECQ-E2124JF	B	0.12	250	.48	.235	.201	.176
667-ECQ-E4124JF	B	0.12	400	.63	.369	.316	.283
667-ECQ-E6124JF	B	0.12	630	1.01	.747	.686	.606
667-ECQ-E2154JF	B	0.15	250	.43	.232	.202	.175
667-ECQ-E2154JF	B	0.15	250	.58	.347	.304	.238
667-ECQ-E4154JF	B	0.15	400	.69	.404	.347	.31
667-ECQ-E6154JF	B	0.15	630	1.43	.761	.666	.589
667-ECQ-E2184JF	B	0.18	250	.82	.494	.432	.339
667-ECQ-E2184JF	B	0.18	250	.70	.419	.367	.288
667-ECQ-E4184JF	B	0.18	400	1.12	.603	.528	.467
667-ECQ-E6184JF	B	0.18	630	1.04	.705	.64	.557
667-ECQ-E2224JF	B	0.22	250	.48	.255	.222	.193
667-ECQ-E2224JF	B	0.22	250	.82	.495	.432	.339
667-ECQ-E4224JF	B	0.22	400	1.03	.66	.593	.51
667-ECQ-E6224JF	B	0.22	630	1.14	.772	.701	.61
667-ECQ-E2274JF	B	0.27	250	.82	.496	.433	.34
667-ECQ-E2274JF	B	0.27	250	.86	.517	.452	.355
667-ECQ-E4274JF	B	0.27	400	1.05	.714	.648	.563
667-ECQ-E6274JF	B	0.27	630	1.24	.841	.764	.665
667-ECQ-E2334JF	B	0.33	250	.95	.486	.40	.353
667-ECQ-E2334JF	B	0.33	250	.84	.506	.443	.348
667-ECQ-E6334JF	B	0.33	400	.95	.71	.653	.576
667-ECQ-E2394JF	B	0.39	250	1.21	.899	.825	.728
667-ECQ-E2394JF	B	0.39	250	.92	.587	.528	.455
667-ECQ-E4394JF	B	0.39	400	.96	.582	.508	.40
667-ECQ-E6394JF	B	0.39	630	1.30	.88	.799	.694
667-ECQ-E2474JF	B	0.47	250	1.43	1.03	.943	.829
667-ECQ-E2474JF	B	0.47	250	.85	.511	.447	.351
667-ECQ-E4474JF	B	0.47	400	.97	.583	.509	.40
667-ECQ-E6474JF	B	0.47	630	1.16	.855	.786	.693
667-ECQ-E1564JF	B	0.56	100	1.17	.805	.696	.611
667-ECQ-E2564JF	B	0.56	250	1.08	.695	.626	.539
667-ECQ-E2564JF	B	0.56	250	.63	.369	.316	.283
667-ECQ-E4564JF	B	0.56	400	.92	.586	.527	.454
667-ECQ-E6564JF	B	0.56	630	1.06	.674	.581	.515
667-ECQ-E1684JF	B	0.68	100	1.73	1.25	1.14	1.00
667-ECQ-E268							