

# TXC SMD CMOS CXO Oscillators

RoHS Compliant This product is RoHS compliant.


 
 


NEW SUPPLIER

## 7C SERIES 5 X 3.2MM

### Features:

- Operating Temperature Range: -10°C to 70°C
- Ultra small SMD seam sealed clock crystal oscillator units
- Designed for automatic mounting and reflow soldering
- Optionable stand-by function for output: Tri-state output
- High stability, low jitter, low power consumption
- High precision characteristic covering up to wide frequency range

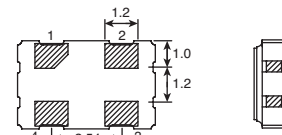

### Applications:

- Wireless communication set, PDA and DSC

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TXC Part No.	Freq. (MHz)	Price Each			Price Per Reel of 1000 ea.
			1	10	100	
<b>2.5 Volts</b>						
717-7C-20.000MCB-T	7C-20.000MCB-T	20.000	2.40	2.00	1.60	1.12
717-7C-25.000MCB-T	7C-25.000MCB-T	25.000	2.40	2.00	1.60	1.12
717-7C-40.000MCB-T	7C-40.000MCB-T	40.000	2.40	2.00	1.60	1.12
<b>3.3 Volts</b>						
717-7C-16.000MBA-T	717-7C-16.000MBA-T	16.000	3.33	2.85	1.90	1.33
717-7C-16.000MBA-T	717-7C-16.000MBA-T	16.000	3.00	2.60	1.80	1.12
717-7C-20.000MBA-T	717-7C-20.000MBA-T	20.000	3.33	2.85	1.90	1.33
717-7C-20.000MBA-T	717-7C-20.000MBA-T	20.000	3.00	2.60	1.80	1.12



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TXC Part No.	Freq. (MHz)	Price Each			Price Per Reel of 1000 ea.
			1	10	100	
<b>3.3 Volts</b>						
717-7C-24.000MBA-T	7C-24.000MBA-T	24.000	3.33	2.85	1.90	1.33
717-7C-24.000MBA-T	7C-24.000MBA-T	24.000	3.00	2.60	1.80	1.12
717-7C-25.000MBA-T	7C-25.000MBA-T	25.000	3.33	2.85	1.90	1.33
717-7C-25.000MBA-T	7C-25.000MBA-T	25.000	3.00	2.60	1.80	1.12
717-7C-40.000MBA-T	7C-40.000MBA-T	40.000	3.33	2.85	1.90	1.33
717-7C-40.000MBA-T	7C-40.000MBA-T	40.000	3.00	2.60	1.80	1.12
717-7C-50.000MBA-T	7C-50.000MBA-T	50.000	3.33	2.85	1.90	1.33
717-7C-50.000MBA-T	7C-50.000MBA-T	50.000	3.00	2.60	1.80	1.12

## 7W SERIES 7 X 5MM

### Features:

- Operating Temperature Range: -10°C to 70°C
- Small SMD seam sealed clock crystal oscillator units
- High stability, low jitter, low power consumption
- Designed for automatic mounting and reflow soldering
- Optionable stand-by function for output: Tri-state output
- High precision characteristic covering up to wide frequency range

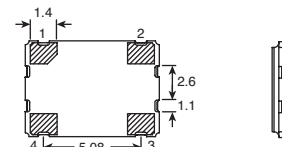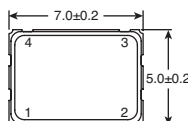

### Applications:

- Wireless communication, PC and LCDM.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TXC Part No.	Freq. (MHz)	Price Each			Price Per Reel of 1000 ea.
			1	10	100	
<b>2.5 Volts</b>						
717-7W-1.544MBA-T	7W-1.544MBA-T	1.5440	2.98	2.55	1.70	1.19
717-7W-1.544MBA-T	7W-1.544MBA-T	1.5440	2.63	2.27	1.57	.98
717-7W-1.8432MBA-T	7W-1.8432MBA-T	1.8432	2.98	2.55	1.70	1.19
717-7W-1.8432MBA-T	7W-1.8432MBA-T	1.8432	2.63	2.27	1.57	.98
717-7W-3.6864MBA-T	7W-3.6864MBA-T	3.6864	2.98	2.55	1.70	1.19
717-7W-3.6864MBA-T	7W-3.6864MBA-T	3.6864	2.63	2.27	1.57	.98
717-7W-4.000MBA-T	7W-4.000MBA-T	4.0000	2.98	2.55	1.70	1.19
717-7W-4.000MBA-T	7W-4.000MBA-T	4.0000	2.63	2.27	1.57	.98
717-7W-7.3728MBA-T	7W-7.3728MBA-T	7.3728	2.98	2.55	1.70	1.19
717-7W-7.3728MBA-T	7W-7.3728MBA-T	7.3728	2.63	2.27	1.57	.98
717-7W-8.000MBA-T	7W-8.000MBA-T	8.0000	2.98	2.55	1.70	1.19
717-7W-8.000MBA-T	7W-8.000MBA-T	8.0000	2.63	2.27	1.57	.98
717-7W-10.000MBA-T	7W-10.000MBA-T	10.0000	2.98	2.55	1.70	1.19
717-7W-10.000MBA-T	7W-10.000MBA-T	10.0000	2.63	2.27	1.57	.98
717-7W-12.000MBA-T	7W-12.000MBA-T	12.0000	2.98	2.55	1.70	1.19
717-7W-12.000MBA-T	7W-12.000MBA-T	12.0000	2.63	2.27	1.57	.98
717-7W-12.288MBA-T	7W-12.288MBA-T	12.2880	2.98	2.55	1.70	1.19
717-7W-12.288MBA-T	7W-12.288MBA-T	12.2880	2.63	2.27	1.57	.98
717-7W-14.7456MBA-T	7W-14.7456MBA-T	14.7456	2.98	2.55	1.70	1.19
717-7W-14.7456MBA-T	7W-14.7456MBA-T	14.7456	2.63	2.27	1.57	.98
717-7W-16.000MBA-T	7W-16.000MBA-T	16.0000	2.98	2.55	1.70	1.19
717-7W-16.000MBA-T	7W-16.000MBA-T	16.0000	2.63	2.27	1.57	.98
717-7W-18.432MBA-T	7W-18.432MBA-T	18.4320	2.98	2.55	1.70	1.19
717-7W-18.432MBA-T	7W-18.432MBA-T	18.4320	2.63	2.27	1.57	.98
717-7W-20.000MBA-T	7W-20.000MBA-T	20.0000	2.98	2.55	1.70	1.19
717-7W-20.000MBA-T	7W-20.000MBA-T	20.0000	2.63	2.27	1.57	.98
717-7W-24.000MBA-T	7W-24.000MBA-T	24.0000	2.98	2.55	1.70	1.19
717-7W-24.000MBA-T	7W-24.000MBA-T	24.0000	2.63	2.27	1.57	.98
717-7W-24.576MBA-T	7W-24.576MBA-T	24.5760	2.98	2.55	1.70	1.19
717-7W-24.576MBA-T	7W-24.576MBA-T	24.5760	2.63	2.27	1.57	.98
717-7W-25.000MBA-T	7W-25.000MBA-T	25.0000	2.98	2.55	1.70	1.19
717-7W-25.000MBA-T	7W-25.000MBA-T	25.0000	2.63	2.27	1.57	.98

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TXC Part No.	Freq. (MHz)	Price Each			Price Per Reel of 1000 ea.
			1	10	100	
<b>3.3 Volts</b>						
717-7W-27.000MBA-T	7W-27.000MBA-T	27.0000	2.98	2.55	1.70	1.19
717-7W-27.000MBA-T	7W-27.000MBA-T	27.0000	2.63	2.27	1.57	.98
717-7W-30.000MBA-T	7W-30.000MBA-T	30.0000	2.98	2.55	1.70	1.19
717-7W-30.000MBA-T	7W-30.000MBA-T	30.0000	2.63	2.27	1.57	.98
717-7W-32.000MBA-T	7W-32.000MBA-T	32.0000	2.98	2.55	1.70	1.19
717-7W-32.000MBA-T	7W-32.000MBA-T	32.0000	2.63	2.27	1.57	.98
717-7W-40.000MBA-T	7W-40.000MBA-T	40.0000	2.98	2.55	1.70	1.19
717-7W-40.000MBA-T	7W-40.000MBA-T	40.0000	2.63	2.27	1.57	.98
717-7W-48.000MBA-T	7W-48.000MBA-T	48.0000	2.98	2.55	1.70	1.19
717-7W-48.000MBA-T	7W-48.000MBA-T	48.0000	2.63	2.27	1.57	.98
717-7W-49.152MBA-T	7W-49.152MBA-T	49.1520	2.98	2.55	1.70	1.19
717-7W-49.152MBA-T	7W-49.152MBA-T	49.1520	2.63	2.27	1.57	.98
717-7W-50.000MBA-T	7W-50.000MBA-T	50.0000	2.98	2.55	1.70	1.19
717-7W-50.000MBA-T	7W-50.000MBA-T	50.0000	2.63	2.27	1.57	.98
717-7W-66.6666MBA-T	7W-66.6666MBA-T	66.6666	2.80	2.40	1.60	1.12
717-7W-75.000MBA-T	7W-75.000MBA-T	75.0000	2.80	2.40	1.60	1.12
717-7W-80.000MBA-T	7W-80.000MBA-T	80.0000	2.80	2.40	1.60	1.12
717-7W-100.000MBA-T	7W-100.000MBA-T	100.0000	4.69	4.06	2.81	1.75
717-7W-125.000MBA-T	7W-125.000MBA-T	125.0000	5.63	4.87	3.37	2.10
<b>5 Volts</b>						
717-7W-3.6864MAB-T	7W-3.6864MAB-T	3.6864	1.80	1.50	1.20	.84
717-7W-4.000MAB-T	7W-4.000MAB-T	4.0000	1.80	1.50	1.20	.84
717-7W-8.000MAB-T	7W-8.000MAB-T	8.0000	1.80	1.50	1.20	.84
717-7W-10.000MAB-T	7W-10.000MAB-T	10.0000	1.80	1.50	1.20	.84
717-7W-20.000MAB-T	7W-20.000MAB-T	20.0000	1.80	1.50	1.20	.84
717-7W-24.000MAB-T	7W-24.000MAB-T	24.0000	1.80	1.50	1.20	.84
717-7W-25.000MAB-T	7W-25.000MAB-T	25.0000	1.80	1.50	1.20	.84
717-7W-27.000MAB-T	7W-27.000MAB-T	27.0000	1.80	1.50	1.20	.84
717-7W-30.000MAB-T	7W-30.000MAB-T	30.0000	1.80	1.50	1.20	.84
717-7W-40.000MAB-T	7W-40.000MAB-T	40.0000	1.80	1.50	1.20	.84
717-7W-48.000MAB-T	7W-48.000MAB-T	48.0000	1.80	1.50	1.20	.84
717-7W-50.000MAB-T	7W-50.000MAB-T	50.0000	1.80	1.50	1.20	.84

## 7W SERIES 7 X 5MM

### Features:

 


- Operating Temperature Range: -10°C to 70°C
- Tri-state function available
- Ultra small SMD seam sealed clock crystal oscillator units

### Applications:

- WLAN, Bluetooth, DSC, DSL and other IT product

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TXC Part No.	Freq. (MHz)	Price Each			Price Per Reel of 1000 ea.
			1	10	100	
<b>3.3 Volts</b>						
717-7X-25.000MBA-T	7X-25.000MBA-T	25.000	3.85	3.30	2.20	1.54
717-7X-25.000MBA-T	7X-25.000MBA-T	25.000	3.56	3.08	2.13	1.42
717-7X-26.000MBA-T	7X-26.000MBA-T	26.000	3.85	3.30	2.20	1.54
717-7X-26.000MBA-T	7X-26.000MBA-T	26.000	3.56	3.08	2.13	1.42

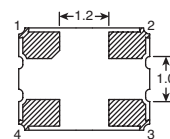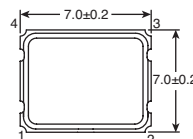

Frequency Control

TXC

NEW SUPPLIER

NEW SUPPLIER

NEW SUPPLIER