

# TXC SMD, DIP and Tuning Fork Crystals



This product is RoHS compliant.



## 9HT10 & 9H12 SERIES SMD CRYSTALS

**Features:**

- 2 pads surface mount package
- High reliable environmental performance
- Application for NB, Smart Phone, variety of compact portable consumer products reference clocks



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TXC Part No.	Freq. (MHz)	Price Each			Price Per Reel of 3000 ea.
			1	10	100	
<b>3.2 x 1.5 x 0.75, ±10ppm</b>						
717-9HT10-32.768KEZF	9HT10-32.768KEZF-T	32.768	1.50	1.25	1.00	.66
<b>3.2 x 1.5 x 0.75, ±20ppm</b>						
717-9HT10-32.768KDZF	9HT10-32.768KDZF-T	32.768	1.35	1.13	.90	.60
<b>1.6 x 1.0 x 0.5, ±20ppm</b>						
717-9HT1232.768KDZFT	9HT12-32.768KDZF-T	32.768	2.00	1.80	1.44	1.08
<b>1.6 x 1.0 x 0.5, ±30ppm</b>						
717-9HT1232.768KAZFT	9HT12-32.768KAZF-T	32.768	1.88	1.69	1.35	1.01



## 9C SERIES SMD CYRSTALS, HC-49S

**Features:**


- Operating Temperature Range: -20°C to 70°C
- High frequency pullability and low equivalent series resistance.
- Highly mass production capability

**Applications:**

- PC
- STB
- LCDM
- Cable Modem

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TXC Part No.	Freq. (MHz)	Price Each			Price Per Reel of 1000 ea.
			1	10	100	
717-9C-3.6864MAAJ-T	9C-3.6864MAAJ-T	3.68640	.53	.45	.32	.23
717-9C-4.000MAAJ-T	9C-4.000MAAJ-T	4.00000	.53	.45	.32	.23
717-9C-4.9152MAAJ-T	9C-4.9152MAAJ-T	4.91520	.53	.45	.32	.23
717-9C-6.000MAAJ-T	9C-6.000MAAJ-T	6.00000	.53	.45	.32	.23
717-9C-7.3728MAAJ-T	9C-7.3728MAAJ-T	7.37280	.53	.45	.32	.23
717-9C-8.000MEEJ-T	9C-8.000MEEJ-T	8.00000	.68	.58	.40	.25
717-9C-8.000MAAJ-T	9C-8.000MAAJ-T	8.00000	.53	.45	.32	.23
717-9C-8.192MEEJ-T	9C-8.192MEEJ-T	8.19200	.68	.58	.40	.25
717-9C-8.192MAAJ-T	9C-8.192MAAJ-T	8.19200	.53	.45	.32	.23
717-9C-10.000MEEJ-T	9C-10.000MEEJ-T	10.00000	.68	.58	.40	.25
717-9C-10.000MAAJ-T	9C-10.000MAAJ-T	10.00000	.53	.45	.32	.23
717-9C-11.0592MEEJ-T	9C-11.0592MEEJ-T	11.05920	.68	.58	.40	.25
717-9C-11.0592MAAJ-T	9C-11.0592MAAJ-T	11.05920	.53	.45	.32	.23
717-9C-12.000MEEJ-T	9C-12.000MEEJ-T	12.00000	.68	.58	.40	.25
717-9C-12.000MAAJ-T	9C-12.000MAAJ-T	12.00000	.53	.45	.32	.23
717-9C-12.288MEEJ-T	9C-12.288MEEJ-T	12.28800	.68	.58	.40	.25
717-9C-12.288MAAJ-T	9C-12.288MAAJ-T	12.28800	.53	.45	.32	.23
717-9C-13.560MEEJ-T	9C-13.560MEEJ-T	13.56000	.68	.58	.40	.25
717-9C-13.560MAAJ-T	9C-13.560MAAJ-T	13.56000	.53	.45	.32	.23
717-9C-14.31818MEEJT	9C-14.31818MEEJT	14.31818	.68	.58	.40	.25
717-9C-14.31818MAAJT	9C-14.31818MAAJT	14.31818	.53	.45	.32	.23
717-9C-14.7456MEEJ-T	9C-14.7456MEEJ-T	14.74560	.68	.58	.40	.25

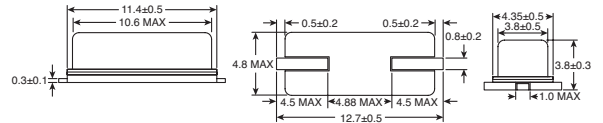

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TXC Part No.	Freq. (MHz)	Price Each			Price Per Reel of 1000 ea.
			1	10	100	
717-9C-14.7456MAAJ-T	9C-14.7456MAAJ-T	14.74560	.53	.45	.32	.23
717-9C-16.000MEEJ-T	9C-16.000MEEJ-T	16.00000	.68	.58	.40	.25
717-9C-16.000MAAJ-T	9C-16.000MAAJ-T	16.00000	.53	.45	.32	.23
717-9C-18.432MEEJ-T	9C-18.432MEEJ-T	18.43200	.68	.58	.40	.25
717-9C-18.432MAAJ-T	9C-18.432MAAJ-T	18.43200	.53	.45	.32	.23
717-9C-20.000MEEJ-T	9C-20.000MEEJ-T	20.00000	.68	.58	.40	.25
717-9C-20.000MAAJ-T	9C-20.000MAAJ-T	20.00000	.53	.45	.32	.23
717-9C-22.1184MEEJ-T	9C-22.1184MEEJ-T	22.11840	.68	.58	.40	.25
717-9C-22.1184MAAJ-T	9C-22.1184MAAJ-T	22.11840	.53	.45	.32	.23
717-9C-24.000MEEJ-T	9C-24.000MEEJ-T	24.00000	.68	.58	.40	.25
717-9C-24.000MAAJ-T	9C-24.000MAAJ-T	24.00000	.53	.45	.32	.23
717-9C-25.000MEEJ-T	9C-25.000MEEJ-T	25.00000	.68	.58	.40	.25
717-9C-25.000MAAJ-T	9C-25.000MAAJ-T	25.00000	.53	.45	.32	.23
717-9C-26.000MEEJ-T	9C-26.000MEEJ-T	26.00000	.68	.58	.40	.25
717-9C-26.000MAAJ-T	9C-26.000MAAJ-T	26.00000	.53	.45	.32	.23
717-9C-27.000MEEJ-T	9C-27.000MEEJ-T	27.00000	.68	.58	.40	.25
717-9C-27.000MAAJ-T	9C-27.000MAAJ-T	27.00000	.53	.45	.32	.23
717-9C-30.000MEEJ-T	9C-30.000MEEJ-T	30.00000	.68	.58	.40	.25
717-9C-30.000MAAJ-T	9C-30.000MAAJ-T	30.00000	.53	.45	.32	.23
717-9C-48.000MEEJ-T	9C-48.000MEEJ-T	48.00000	.77	.66	.44	.31
717-9C-48.000MAAJ-T	9C-48.000MAAJ-T	48.00000	.53	.45	.32	.23

## 9B SERIES DIP CRYSTALS, LEADED, HC-49S

**Features:**


- Operating Temperature Range: -20° to 70°C
- Resistance welded type crystal units.
- High frequency pullability and low equivalent series resistance.
- Lower cost and highly mass production capability.

**Applications:**

- TV
- STB
- LCDM
- Cable Modem

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TXC Part No.	Freq. (MHz)	Price Each			Price Per Reel of 1000 ea.
			1	10	100	
717-9B-3.579545MAAJB	9B-3.579545MAAJB	3.579545	.46	.39	.26	.18
717-9B-3.6864MAAJ-B	9B-3.6864MAAJ-B	3.686400	.46	.39	.26	.18
717-9B-4.000MAAJ-B	9B-4.000MAAJ-B	4.000000	.46	.39	.26	.18
717-9B-4.096MAAJ-B	9B-4.096MAAJ-B	4.096000	.46	.39	.26	.18
717-9B-4.9152MAAJ-B	9B-4.9152MAAJ-B	4.915200	.46	.39	.26	.18
717-9B-6.000MAAJ-B	9B-6.000MAAJ-B	6.000000	.46	.39	.26	.18
717-9B-7.3728MAAJ-B	9B-7.3728MAAJ-B	7.372800	.46	.39	.26	.18
717-9B-8.000MEEJ-B	9B-8.000MEEJ-B	8.000000	.56	.48	.32	.22
717-9B-8.000MAAJ-B	9B-8.000MAAJ-B	8.000000	.46	.39	.26	.18
717-9B-8.192MEEJ-B	9B-8.192MEEJ-B	8.192000	.56	.48	.32	.22
717-9B-8.192MAAJ-B	9B-8.192MAAJ-B	8.192000	.46	.39	.26	.18
717-9B-10.000MEEJ-B	9B-10.000MEEJ-B	10.000000	.56	.48	.32	.22
717-9B-10.000MAAJ-B	9B-10.000MAAJ-B	10.000000	.46	.39	.26	.18
717-9B-11.0592MEEJ-B	9B-11.0592MEEJ-B	11.059200	.56	.48	.32	.22
717-9B-11.0592MAAJ-B	9B-11.0592MAAJ-B	11.059200	.46	.39	.26	.18
717-9B-12.000MEEJ-B	9B-12.000MEEJ-B	12.000000	.56	.48	.32	.22
717-9B-12.000MAAJ-B	9B-12.000MAAJ-B	12.000000	.46	.39	.26	.18
717-9B-14.31818MEEJB	9B-14.31818MEEJB	14.318180	.56	.48	.32	.22
717-9B-14.31818MAAJB	9B-14.31818MAAJB	14.318180	.46	.39	.26	.18
717-9B-14.7456MEEJ-B	9B-14.7456MEEJ-B	14.745600	.56	.48	.32	.22

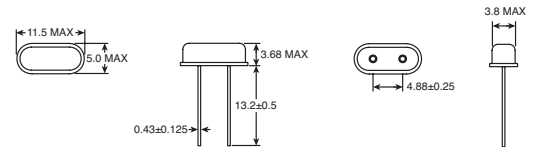

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TXC Part No.	Freq. (MHz)	Price Each			Price Per Reel of 1000 ea.
			1	10	100	
717-9B-14.7456MAAJ-B	9B-14.7456MAAJ-B	14.745600	.46	.39	.26	.18
717-9B-16.000MEEJ-B	9B-16.000MEEJ-B	16.000000	.56	.48	.32	.22
717-9B-16.000MAAJ-B	9B-16.000MAAJ-B	16.000000	.46	.39	.26	.18
717-9B-18.432MEEJ-B	9B-18.432MEEJ-B	18.432000	.56	.48	.32	.22
717-9B-18.432MAAJ-B	9B-18.432MAAJ-B	18.432000	.46	.39	.26	.18
717-9B-20.000MEEJ-B	9B-20.000MEEJ-B	20.000000	.56	.48	.32	.22
717-9B-20.000MAAJ-B	9B-20.000MAAJ-B	20.000000	.46	.39	.26	.18
717-9B-22.1184MEEJ-B	9B-22.1184MEEJ-B	22.118400	.56	.48	.32	.22
717-9B-22.1184MAAJ-B	9B-22.1184MAAJ-B	22.118400	.46	.39	.26	.18
717-9B-24.000MEEJ-B	9B-24.000MEEJ-B	24.000000	.67	.57	.38	.26
717-9B-24.000MAAJ-B	9B-24.000MAAJ-B	24.000000	.46	.39	.26	.18
717-9B-24.576MEEJ-B	9B-24.576MEEJ-B	24.576000	.56	.48	.32	.22
717-9B-24.576MAAJ-B	9B-24.576MAAJ-B	24.576000	.46	.39	.26	.18
717-9B-25.000MEEJ-B	9B-25.000MEEJ-B	25.000000	.56	.48	.32	.22
717-9B-25.000MAAJ-B	9B-25.000MAAJ-B	25.000000	.46	.39	.26	.18
717-9B-27.000MEEJ-B	9B-27.000MEEJ-B	27.000000	.56	.48	.32	.22
717-9B-27.000MAAJ-B	9B-27.000MAAJ-B	27.000000	.46	.39	.26	.18
717-9B-48.000MEEJ-B	9B-48.000MEEJ-B	48.000000	.67	.57	.38	.27
717-9B-48.000MAAJ-B	9B-48.000MAAJ-B	48.000000	.46	.39	.26	.18

## 9HT11 SERIES SMD TUNING FORK CRYSTALS

**Features:**


- Operating Temperature Range: -40°C to 85°C
- Frequency Tolerance: ±20ppm
- Load Capacitance: 12.5pF
- Ceramic surface mount package.

**Applications:**

- Mobile phone
- Notebook
- DSC

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TXC Part No.	Freq. (MHz)	Price Each			Price Per Reel of 1000 ea.
			1	10	100	
717-9HT11-32.7KDZC-T	9HT11-32.7KDZC-T	32.768	2.65	2.43	1.68	1.12
717-9HT11-32.7KDZF-T	9HT11-32.7KDZF-T	32.768	2.65	2.43	1.68	1.12

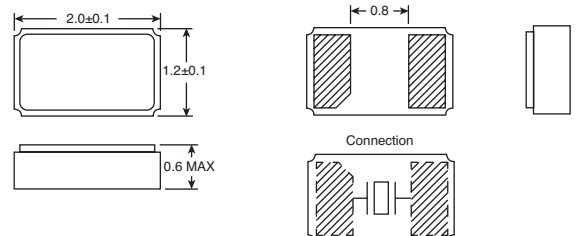

NEW SUPPLIER

Frequency Control

TXC

NEW SUPPLIER

NEW SUPPLIER

NEW SUPPLIER