


CHICAGO MINIATURE Incandescent Replacements

Chicago Miniature Lighting, LLC
Lighting the world since 1910

RoHS Compliant **This product is RoHS compliant.**

LED Indication

Chicago Miniature

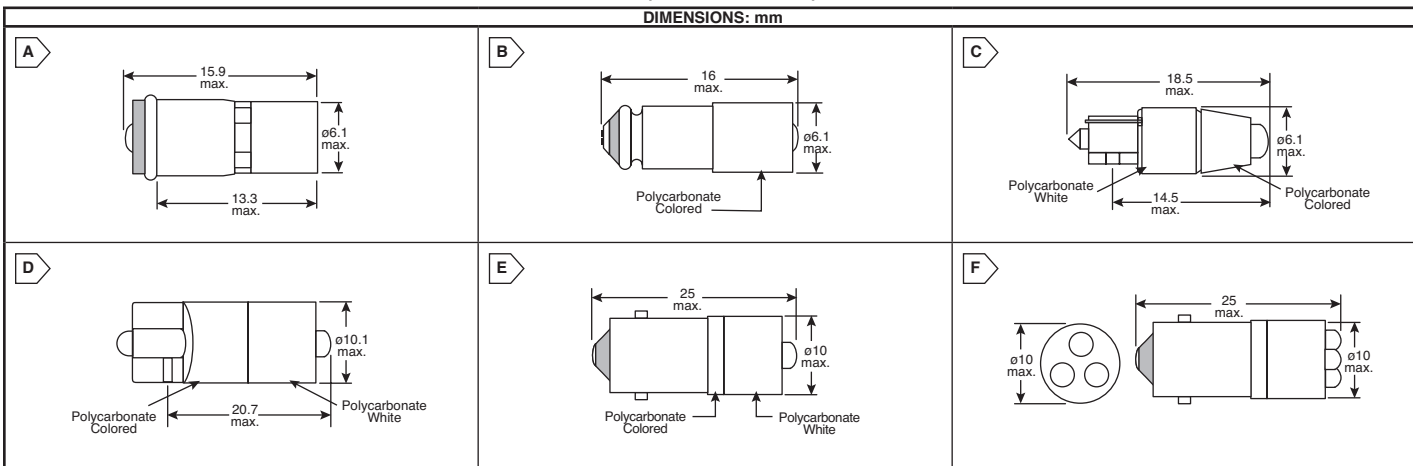

INCANDESCENT REPLACEMENTS

Features:

- Extremely High Brightness with Low Current Draw
- Low Heat Generation
- Shock and Vibration Proof
- Five Standard Colors

Specification:

- Long Life: 100K Hours vs. 10K Hours
- Storage Temperature: -25°C to +80°C
- Ambient Temperature: -20°C to +60°C

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Chicago Miniature Part No.	Fig.	Color	Voltage	Current (mA)	Luminous Intensity (mcd)	Wavelength (nm)	Replaces Incandescent No.	Price Each			
									1	10	100	500
15101 Series												
606-1510125UR3	1510125UR3	A	Red	12DC	14	330	630		8.04	5.63	4.82	4.27
606-1510125UG3	1510125UG3	A	Green	12DC	14	910	525	394, 330, 382	12.01	8.40	7.21	6.38
606-1510125W3	1510125W3	A	White Clear	12DC	14	700	—		12.01	8.40	7.21	6.38
606-1510125W3D	1510125W3D	A	White Diffused	12DC	14	350	—		12.01	8.40	7.21	6.38
606-1510135UR3	1510135UR3	A	Red	24DC	14	330	630	327, 376, 385, 387	7.99	5.60	4.80	4.25
606-1510135UG3	1510135UG3	A	Green	24DC	14	910	525		12.01	8.40	7.21	6.38
606-1510135W3D	1510135W3D	A	White Diffused	24DC	14	350	—		12.01	8.40	7.21	6.38
15121 Series												
606-1512125W3D	1512125W3D	B	White Diffused	12DC	7/14	350	—		10.31	7.21	6.19	5.53
606-1512135UG3	1512135UG3	B	Green	24DC	7/14	910	525		10.32	7.22	6.19	5.54
606-1512135W3D	1512135W3D	B	White Diffused	24DC	7/14	350	—	276, 334, 388	10.32	7.22	6.19	5.54
1511A Series												
606-1511A25W3	1511A25W3	C	White Clear	12AC/DC	6/12	600	—	18, 37, 70,	11.46	8.02	6.88	6.09
606-1511A25W3D	1511A25W3D	C	White Diffused	12AC/DC	6/12	300	—	73, 74	11.46	8.02	6.88	6.09
1511B Series												
606-1511B25W3	1511B25W3	D	White Clear	12AC/DC	7/14	700	—	192, 124, 158	11.46	8.02	6.88	6.09
606-1511B25W3D	1511B25W3D	D	White Diffused	12AC/DC	7/14	350	—	161, 168, 184	11.46	8.02	6.88	6.09
606-1511B35W3	1511B35W3	D	White Clear	24AC/DC	7/14	700	—	585, 655, 656,	11.46	8.02	6.88	6.09
18602 Series												
606-18602250	18602250	E	Red	12AC/DC	15	350	630	12MB, 181, 756,	8.16	5.70	4.90	4.33
606-18602252	18602252	E	Yellow	12AC/DC	15	300	587	1488, 1815,	9.01	6.30	5.41	4.79
606-18602257	18602257	E	Blue	12AC/DC	15	400	470	1894, 1889,	11.15	7.81	6.69	5.99
606-1860225W3	1860225W3	E	White Clear	12AC/DC	15	750	—	7191, 1893, 1898	11.15	7.81	6.69	5.99
606-18602350	18602350	E	Red	24AC/DC	15	350	630	24MB, 1437,	8.16	5.70	4.90	4.33
606-18602351	18602351	E	Green	24AC/DC	15	1000	525	1818	11.15	7.81	6.69	5.99
606-18602450	18602450	E	Red	28AC/DC	15	350	630	313, 757	8.16	5.70	4.90	4.33
606-18602451	18602451	E	Green	28AC/DC	15	1000	525	1437, 1819,	11.15	7.81	6.69	5.99
606-1860245W3	1860245W3	E	White Clear	28AC/DC	15	750	—	1820, 1929, 1843, 1864, 1873	11.15	7.81	6.69	5.99
18620 Series												
606-1862045W3	1862045W3	F	White Clear	28AC/DC	9/17	3 x 850	—	1843, 1864	25.53	17.87	15.32	13.71
606-1862045W3D	1862045W3D	F	White Diffused	28AC/DC	9/17	3 x 425	—	1873	25.53	17.87	15.32	13.71