


# CHICAGO MINIATURE INDICATORS and Lamp Holders

**Chicago Miniature Lighting, LLC**  
Lighting the world since 1910

Products may be RoHS compliant. Check mouser.com for RoHS status.

**Chicago Miniature Lighting, LLC**  
Lighting the world since 1910

## GEMLITE SUBMIDGET INDICATORS

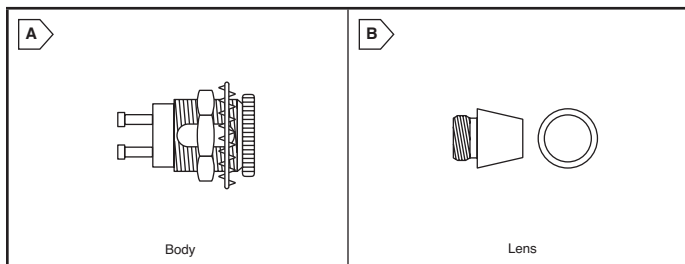

### Specifications:


- Mounting hole: .313"
- Mounting centers: .469" min.
- Panel thickness: .218" max.
- Lock washer: nickel plated bronze
- Hex nut: nickel plated brass
- Lens: high temperature lexan
- Lens shank: nickel plated brass
- Housing material: black nickel plated brass
- Electrical rating: up to 30V, up to 1W

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each		
			1	10	100
606-5160-458	A	T-1 sub-midget flange base indicator, body	9.99	8.66	8.33
606-160A-604R	B	Translucent red lens for 5160-48, lens	1.49	1.29	1.24
606-160A-604G	B	Translucent green lens for 5160-48, lens	1.49	1.29	1.24
606-160A-604Y	B	Translucent yellow lens for 5160-48, lens	2.14	1.85	1.78
606-160A-604W	B	Translucent white lens for 5160-48, lens	1.49	1.29	1.24

**Chicago Miniature Lighting, LLC**  
Lighting the world since 1910

## MIDGET FLANGE RELAMPABLE INDICATORS

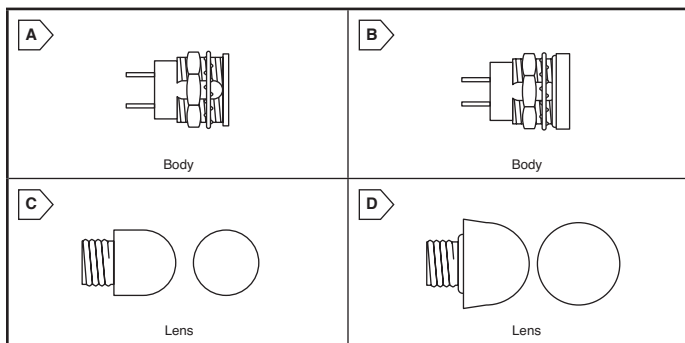

### Specifications:

- Mounting hole: .484"
- Mounting centers: .750" min.
- Panel thickness: standard=.265" watertight=.188"
- Terminals: tin plated brass
- Housing material: black anodized aluminum
- Hex nut/lock washer: chrome treated steel
- O-rings (5139 only): neoprene
- Electrical rating: up to 30V, up to 2W
- Lens: high temperature lexan

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each		
			1	10	100
606-5131-038	A	T-1 3/4 midget flange standard indicator	4.52	3.97	3.85
606-5139-038	B	T-1 3/4 midget flange watertight indicator	6.17	5.35	5.14
606-131A-303R	C	Transparent red lens for 5131-038	3.15	2.73	2.63
606-131A-303A	C	Transparent amber lens for 5131-038	3.15	2.73	2.63
606-131A-303G	C	Transparent green lens for 5131-038	3.15	2.73	2.63
606-131A-304R	C	Translucent red lens for 5131-038	3.15	2.73	2.63
606-131A-304G	C	Translucent green lens for 5131-038	3.15	2.73	2.63
606-131A-304Y	C	Translucent yellow lens for 5131-038	3.15	2.73	2.63
606-139A-404G	D	Translucent green lens for 5139-038	5.78	5.02	4.84
606-139A-404R	D	Translucent red lens for 5139-038	4.93	4.50	4.20
606-139A-404Y	D	Translucent yellow lens for 5139-038	5.78	5.02	4.84

**Chicago Miniature Lighting, LLC**  
Lighting the world since 1910

## RELAMPABLE INDICATOR HOLDERS




For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Description	Price Each		
		1	10	100
606-CM21-2	T-1 3/4 bi-pin base lamp socket	9.54	8.26	7.95

**Chicago Miniature Lighting, LLC**  
Lighting the world since 1910

## GLO-LITE NEON INDICATORS

DIMENSIONS: in.

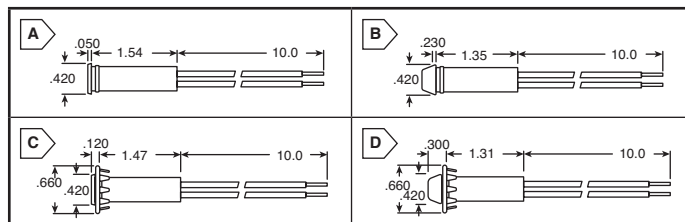

### Specifications:

- Mounting hole: 6063 Series - .375"/6073 Series - .500"
- Mounting centers: 6063 Series -.500"/6073 Series -.688"
- Panel thickness: 6063 Series - 1.25"/6073 Series -.078"
- Bezel (6073 only): chrome plated brass
- Wire leads: 22AWG stranded black 105°C PVC
- Electrical: 125VAC, built-in 30KΩ 1/4W resistor
- UL Recognized, CSA Certified


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Description	Price Each		
				1	10	100
606-6063-001-534R	A	Red	Flat face with no bezel	2.91	2.52	2.43
606-6063-001-634R	B	Red	Conical face with no bezel	2.91	2.52	2.43
606-6073-001-534R	C	Red	Flat face with chrome bezel	4.03	3.49	3.36
606-6073-001-634R	D	Red	Conical face with chrome bezel	4.03	3.49	3.36
606-6073-001-634W	D	White	Conical face with chrome bezel	4.03	3.49	3.36

**Chicago Miniature Lighting, LLC**  
Lighting the world since 1910

## T-2 AND T-3 1/4 MINIATURE RELAMPABLE INDICATORS

(For use with Bayonet Incandescent and Neon Lamps)

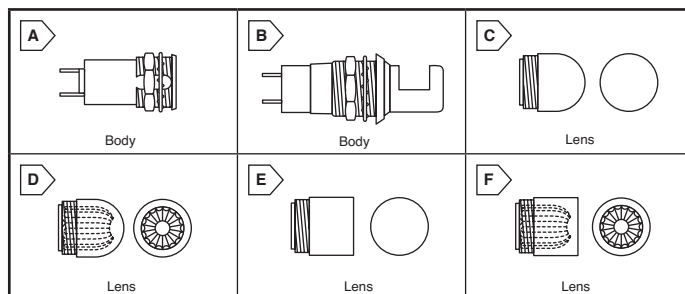

### Specifications:

- Mounting hole: .688"
- Mounting centers: .969" min.
- Panel thickness: .406" max.
- Lock washer: chromate treated steel
- Housing material: 5100 Series - glass filled polyester  
5200 Series - phenolic  
900-200 Series - black anodized aluminum
- Hex nut: zinc plated steel
- Lens (5100 and 5200 Series): high temperature lexan

### Body

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each		
			1	10	100
606-5100-822	A	Solder lug terminals, no resistor	6.76	6.09	5.41
606-5100-823	A	Screw type terminals, no resistor	5.64	4.92	4.73
606-5100-824	A	.250" quick connect terminals, no resistor	5.41	4.68	4.50
606-900-200	B	Instrument lite, solder lug terminals	28.30	22.80	20.50

### Lenses (for 606-5100 and 606-5200 series, shown above)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each		
			1	10	100
606-25P-306R	C	Transparent red dome	.87	.67	.48
606-25P-306A	C	Transparent amber dome	.87	.67	.48
606-25P-306G	C	Transparent green dome	.87	.67	.48
606-25P-306C	C	Transparent clear dome	.87	.67	.48
606-25P-307R	C	Translucent red dome	.87	.67	.48
606-25P-307G	C	Translucent green dome	.87	.67	.48
606-25P-307Y	C	Translucent yellow dome	.87	.67	.48
606-25P-307W	C	Translucent white dome	.87	.67	.48
606-25P-326R	D	Transparent red fluted dome	.87	.67	.48
606-25P-326A	D	Transparent amber fluted dome	.87	.67	.48
606-25P-326G	D	Transparent green fluted dome	.87	.67	.48
606-25P-326C	D	Transparent clear fluted dome	.87	.67	.48
606-25P-606A	E	Transparent amber cylindrical	.87	.67	.48
606-25P-606R	E	Transparent red cylindrical	.87	.67	.48
606-25P-606G	E	Transparent green cylindrical	.87	.67	.48
606-25P-606C	E	Transparent clear cylindrical	.87	.67	.48
606-25P-607R	E	Translucent red cylindrical	.87	.67	.48
606-25P-607G	E	Translucent green cylindrical	.87	.67	.48
606-25P-607Y	E	Translucent yellow cylindrical	.87	.67	.48
606-25P-607W	E	Translucent white cylindrical	.87	.67	.48
606-25P-626R	F	Transparent red fluted cylindrical	.87	.67	.48
606-25P-626A	F	Transparent amber fluted cylindrical	.87	.67	.48
606-25P-626G	F	Transparent green fluted cylindrical	.87	.67	.48
606-25P-626C	F	Transparent clear fluted cylindrical	.87	.67	.48