

AVERY DENNISON Cable Mounting Ties



RoHS Compliant This product is RoHS compliant.

SCREW MOUNT TIES

Screw Mount Ties are preferred when position is critical or the operation requires the product to be pre-mounted to a surface before final assembly. For an added dimension of security, Avery Dennison Screw Mount Cable Ties are easily applied to keep your application secure and positioned exactly where it needs to be.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Avery Dennison Part No.	Fig.	Color	Dimensions: in.			Bundle Dia min-max.	Min Loop Tensile Strength	Price Each		
				Length	Width	Thickness			1	100	1000
514-08415	08415	A	Natural	7.5	0.177	0.055	1/16"-1-3/4"	50lbs.	.43	.262	.178
514-08443	08443	A	Black	7.5	0.177	0.055	1/16"-1-3/4"	50lbs.	.47	.283	.188
514-10351	10351	A	Black	11	0.177	0.50	1/16"-3"	50lbs.	.61	.377	.251
514-10035	10035	A	Natural	14.5	0.25	0.075	3/16"-3.5"	120lbs.	1.38	.83	.55
514-08441	08441	A	Black	14.5	0.25	0.075	3/16"-3.5"	120lbs.	1.45	.871	.577
514-20085	20085	A	Natural	7.5	0.18	0.05	1/16"-1-3/4"	50lbs.	1.15	.693	.462

HOLE TIES

Hole Ties are an easy way to secure wire, hose, or tubing bundles. Fir Tree Ties are designed with either punched or headed holes of any shape and are ideal for securing bundles in a fixed position on a specific surface. Push Mount Arrow Head Ties require significantly less extraction force than Fir Tree Ties.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Avery Dennison Part No.	Fig.	Color	Dimensions: in.			Bundle Dia min-max.	Min Loop Tensile Strength	Price Each		
				Length	Width	Thickness			1	100	1000
Fir Tree											
514-20049	20049	B	Black	7.5	0.25	0.053	1/16"-1-3/4"	50lbs.	1.54	.924	.619
Arrow Head Push Mount											
514-20060	20060	C	Black	7.5	0.18	0.053	1/16"-5/8"	50lbs.	3.08	1.84	1.23

STUD TIES

A fool-proof bundling tie that really holds tight. Ideal for bundling wires, hoses, and tubing and for attaching the bundle to the bolt, Weld Stud Ties are designed to fit all over threaded bolts that protrude from a surface. They take very little force to insert and much greater force to remove.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Avery Dennison Part No.	Fig.	Color	Dimensions: in.			Bundle Dia min-max.	Min Loop Tensile Strength	Price Each		
				Length	Width	Thickness			1	100	1000
Weld Stud											
514-20014	20014	D	Brown	7.5	0.25	0.053	1/4"-1-3/4"	50lbs.	3.08	1.84	1.23
514-20015	20015	D	Natural	7.5	0.25	0.053	1/16"-1-3/4"	50lbs.	1.08	.651	.43
514-20046	20046	D	Natural	7.5	0.25	0.053	1/16"-1-3/4"	50lbs.	1.08	.651	.43
Mount											
514-20062	20062	E	Natural	7.5	0.175	0.047	1/16"-1-3/4"	50lbs.	1.08	.651	.43

SPECIALTY TIES

Avery Dennison offers many innovative products including: Super Bar-Lok, Ladder Tie, Secure-a-Seal, all of which take advantage of Avery Dennison's highly advanced stretching technology. Using this technology, they continue to produce strong, flexible, light-weight and economical products.


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Avery Dennison Part No.	Fig.	Color	Dimensions: in.			Bundle Dia min-max.	Min Loop Tensile Strength	Price Each		
				Length	Width	Thickness			1	100	1000
Flip-Clip Fasteners											
514-08316	08316	F	--	1.18	0.75	--	1/2"	--	.16	.105	.073
Stopper Ties											
514-20097	20097	G	Gray	5.5	0.12	0.05	17mm	40lbs.	.25	.147	.094
514-20086	20086	G	Brown	8	0.25	0.05	7/8"-1-3/4"	50lbs.	3.08	1.84	1.23
Releasable											
514-10361	10361	H	Natural	7.5	0.177	0.05	1/16"-1-3/4"	50lbs.	.61	.37	.25
514-10362	10362	H	Black	7.5	0.177	0.05	1/16"-1-3/4"	50lbs.	.67	.40	.27
514-10367	10367	H	Natural	11	0.177	0.05	1/16"-3"	50lbs.	.74	.451	.304
514-10368	10368	H	Black	11	0.177	0.05	1/16"-3"	50lbs.	.81	.493	.325
Double Headed											
514-10424	10424	I	Natural	7.5	0.177	0.055	1/16"-1-3/4"	50lbs.	.42	.252	.168
514-10425	10425	I	Black	7.5	0.177	0.055	1/16"-1-3/4"	50lbs.	.46	.273	.189
514-10430	10430	I	Natural	11	0.177	0.055	1/16"-3"	50lbs.	.46	.283	.188
514-10431	10431	I	Black	11	0.177	0.055	1/16"-3"	50lbs.	.51	.304	.199
Convoluting Tubing Tie											
514-20093	20093	J	Black	7.5	0.25	0.04	1/16"-1-3/4"	50lbs.	1.54	.924	.619
Double Strap											
514-20040	20040	K	Black	6	0.13	0.048	1/4"-1-5/8"	20lbs.	1.08	.651	.43
Super Bar-Lok®											
514-10001	10001	L	Natural	7.5	0.195	0.038	1/16"-1-3/4"	50 lbs.	.35	.21	.147
514-10003	10003	L	Black	7.5	0.195	0.038	1/16"-1-3/4"	50 lbs.	.35	.22	.147
Inline Arrow											
514-20087	20087	M	Black	7.5	0.25	0.05	1/4"-1-3/4"	50 lbs.	1.54	.924	.619

CONNECTOR CABLE TIES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Avery Dennison Part No.	Fig.	Description	Price Each		
				1	100	1000
514-20101	20101	--	Amp/Tyco Connector Cable Tie	1.54	.924	.619
514-20111	20111	--	FCI Apex Connector Cable Tie	1.93	1.15	.777
514-20113	20113	--	Delphi GT Connector Cable Tie	1.84	1.10	.74

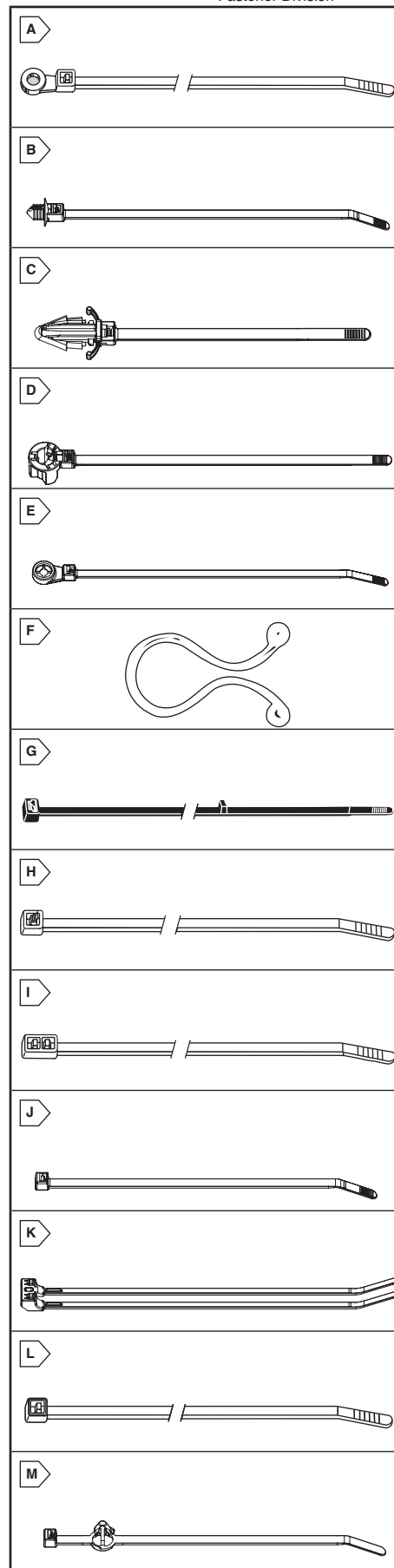

Avery Dennison Wire & Cable Mgmt.

