

EAGLE PLASTIC DEVICES Nylon Cable Ties & Installation Tool



STANDARD TIES



- Color: Natural
- * Material: Type 6/6 Nylon

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each			
					1	100	1000	10000
Miniature Range								
* 561-N3502	17	2.95	.71	.094	.08	.06	.05	.03
481-0102	18	4.0	.98	.098	.07	.05	.04	.03
* 561-N3506	17	6.5	1.73	.098	.10	.08	.06	.04
* 561-N3508	17	7.9	2.16	.098	.12	.09	.06	.04
Intermediate Range								
481-0108	40	6.0	1.50	.146	.14	.07	.06	.05
* 561-N3512	40	7.9	2.16	.126	.13	.10	.08	.06
* 561-N3514	40	11.5	3.35	.142	.16	.13	.09	.08
Standard Range								
* 561-N3522	50	6.3	1.65	.189	.09	.06	.05	.04
* 561-N3515	50	7.48	2.05	.189	.10	.08	.06	.05
* 481-0115	50	8.0	2.17	.181	.12	.079	.066	.053
* 561-N3524	50	9.84	2.91	.189	.10	.08	.07	.06
Light Heavy Range								
* 561-N3540	120	5.9	1.54	.299	.20	.15	.13	.11
* 561-N3542	120	7.9	2.16	.299	.18	.14	.13	.108
* 561-N3544	120	11.02	3.07	.299	.25	.20	.18	.15

STANDARD WEATHER RESISTANT TIES



- UV Resistant
- Color: Black
- * Material: Type 6/6 Nylon

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each			
					1	100	1000	10000
Miniature Range								
* 561-N3503	17	2.95	.71	.094	.10	.08	.07	.05
481-0102UV	18	4.0	.98	.098	.11	.072	.048	.024
* 561-N3507	17	6.5	1.73	.098	.11	.09	.07	.06
* 561-N3509	17	7.9	2.16	.098	.11	.08	.064	.055
Intermediate Range								
481-0108UV	40	6.0	1.5	.146	.10	.08	.06	.04
* 561-N3513	40	7.9	2.16	.126	.12	.10	.08	.06
* 561-N3516	40	11.5	3.35	.142	.16	.14	.11	.08
Standard Range								
* 561-N3523	50	6.3	1.65	.189	.21	.16	.14	.12
* 561-N3534	50	7.48	2.05	.189	.21	.16	.14	.12
481-0115UV	50	8.0	2.17	.181	.21	.14	.115	.10
* 561-N3537	50	9.84	2.91	.189	.23	.18	.15	.13
Light Heavy Range								
* 561-N3541	120	5.9	1.54	.299	.32	.26	.236	.197
* 561-N3543	120	7.9	2.16	.299	.20	.16	.149	.124
* 561-N3545	120	11.02	3.07	.299	.36	.29	.25	.21

SCREWMOUNT TIES

 


- Color: Natural
- Screw Mount: .00.181"

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each			
					1	100	1000	10000
Intermediate Range								
481-0200	40	6.7	1.57	.146	.15	.101	.091	.083

IDENTIFICATION TIES



- Material: Type 6/6 Nylon

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Price Each			
					1	100	1000	10000
Miniature Range								
481-0500	18	4.1	.98	.098	.14	.11	.10	.09
481-0501	18	4.4	.98	.098	.14	.11	.10	.09

RELEASABLE TIES




- Color: Natural

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Price Each				
				1	100	1000	10000	
Standard Release								
481-0300	26	4.9	1.18	.35	.18	.13	.12	
481-0302	50	7.8	1.97	.26	.22	.18	.15	
481-0303	50	11.7	3.15	.55	.382	.276	.23	

LABEL BEADED TIES

Nylon beaded tie with integral label area for writing. Permanent ink pens, felt tip pens, pressure-sensitive adhesive labels, or even Post-it® notes can be used on the polished label area.

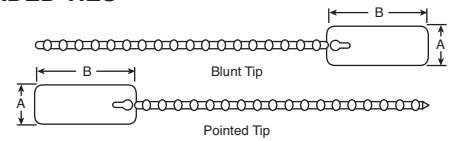

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Description	Dimensions (in.)		Price Each		
		A-Width	B-Length	1	100	1000
Standard Release						
561-0400N	4" Blunt Tip	0.50	1.31	.57	.38	.29
561-0600N	6" Blunt Tip	0.50	1.31	.61	.40	.31
561-0400P	4" Pointed Tip	0.50	1.31	.60	.40	.31
561-0600P	6" Pointed Tip	0.50	1.31	.61	.40	.31

BEADED TIES




- Color: Natural
- Material: Type 6/6 Nylon

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Price Each			
				1	100	1000	10000
561-N3525	30	4 1/4	1.00	.08	.06	.05	.04
561-N3530	30	6	1.25	.09	.073	.062	.052
561-N3535	30	8	2.00	.12	.09	.08	.07
561-N35100	30	10	2.25	.15	.11	.09	.08

 
AC CORD TIES



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Color	Price Each			
					1	100	1000	10000
481-0600	18	6.2	1.77	Natural	.14	.115	.099	.055
481-0601	18	6.2	1.77	Black	.17	.139	.119	.067

NYLON WIRE & CABLE TIE MOUNTS

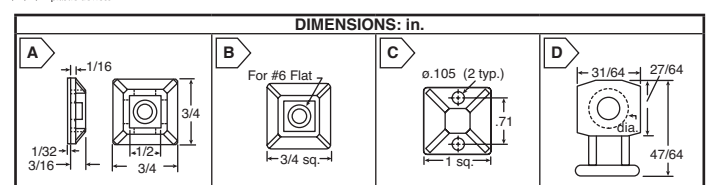

Cradle Mounts

Used in applications where low profile is necessary. Each mount offers a four way entry and is secured with either a screw or adhesive backing. Note: the adhesive mounts have an acrylic foam backing and should be used on a smooth, clean, dry surface.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Mfr. Part No.	Fig.	Description	Price Each			
				1	100	500	1000
561-N3588		A	3/4" Cradle Mount (adhesive)	.21	.17	.15	.09
561-N3608		B	3/4" Cradle Mount (screw)	.38	.304	.251	.188
561-N3590		C	1" Cradle Mount (adhesive)	.34	.24	.18	.15
561-N3590B		C	1" Cradle Mount (adhesive) black	.34	.24	.19	.16

Screw Tabs

Designed for use where space is limited. Tabs are fastened with a screw to provide a low profile assembly.


561-N3595	D	#8 Screw Tab	.14	.11	.074	.064
-----------	---	--------------	-----	-----	------	------

CABLE TIE GUN

Standard adjustable metal tensioning tool for cable tie widths from .087 inch to .189 inch.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Price Each	
	1	5
561-N3000	73.32	68.18

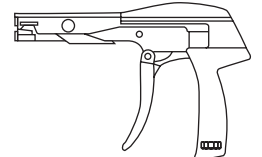

CABLE TIE KITS

- 105 cable ties per kit
- 7 different ties in each
- 15 pieces of each size
- Resealable storage bag

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Mfr. Part No.	Size Range (in.)	Price Each
370-CT-2		6-8	12.95

