

# PANDUIT Wire Identification Products

 


## PAN-CODE™ WIRE MARKER CARDS

All markers are mounted on a flexible release coated plastic for easy marker removal.

- Marker in a variety of legends allows "kitting" for project builds
- 1-1/2" long for wire O.D. up to 3/8"
- One card for each number
- Vinyl cloth
- Temperature: -50°F to +170°F, indoor
- Color- Black/White

644-PCM-1-33 Shown



RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Mounting Method	Dimensions W x L (in.)	Price Each			
			1	25	100	500
644-PCM-0	0	36	2.07	1.57	1.42	1.24
644-PCM-1	1	36	2.94	2.22	2.01	1.78
644-PCM-2	2	36	2.94	2.22	2.01	1.78
644-PCM-3	3	36	2.94	2.22	2.01	1.78
644-PCM-5	5	36	2.64	2.49	2.32	2.20
644-PCM-6	6	36	2.94	2.22	2.01	1.78
644-PCM-7	7	36	2.71	2.17	1.95	1.78
644-PCM-8	8	36	2.94	2.22	2.01	1.78
644-PCM-9	9	36	2.94	2.22	2.01	1.78
644-PCM-1-33	1 thru 33	33	2.97	2.24	2.03	1.79
644-PCM-34-66	34 thru 663	33	3.11	2.35	2.13	1.87
644-PCMCP-1-25	1 thru 25	36	55.23	49.74	43.96	40.48



## PAN-CODE™ WIRE MARKER BOOKS

- Material: GMMI Vinyl cloth
- 1-3/8" long for wire O.D. up to 3/8"
- Each marker is preformed to form half markers for wire O.D. up to 3/16"
- 22 x .25 long terminal block marker is provided for each full length marker
- 10 pages per book
- Legend: Black
- Background: White



644-PCMB-2 Shown



RoHS Compliant

For quantities greater than listed, call for quote.


MOUSER STOCK NO.	Legend	Markers Per Card	Price Each			
			1	10	50	100
644-PCMB-1	0 thru 9	45	24.99	23.11	19.89	18.27
644-PCMB-2	A-Z, 0-15, +, -, /	10	24.99	23.25	19.89	18.27
644-PCMB-3	1 thru 45	10	24.99	23.25	19.89	18.27
644-PCMB-5	A,B,C	150	25.49	23.72	20.28	18.63
644-PCMB-8	1 thru 15 16 thru 90 A-Z, +, -, /, 0	6 4 2	24.04	22.35	19.13	17.57



## TAPE WIRE MARKERS

NEMA Colors Consist of: Black, LT. Blue, Brown, Gray, LT. Green, Orange, Purple, Red, White, Yellow

- Flexible polyester marker tape conforms tightly to wires/cables
- Dispenser allows marker tape to be cut to the exact length required for marking any size wire/cable
- Durable plastic dispenser can be attached to tool belt for industrial use

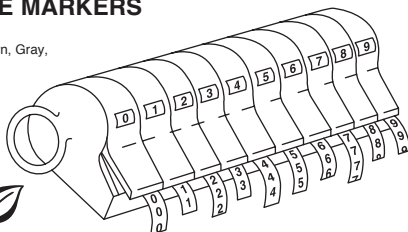

### Dispenser and Tape

- Material: GMMI polyester

RoHS Compliant

MOUSER STOCK NO.	Panduit Part No.	Description	Price Each		
			1	10	25
644-PMD	PMD	Empty Dispenser	19.23	17.27	15.57
644-PMD-NEMA	PMD-NEMA	One roll of each color filled in dispenser	51.60	46.55	41.73

## 8 ft. Length Refill Tape

Used with PMD Dispenser (644-PMD)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Panduit Part No.	Legend	Price Each		
			1	25	100
644-PMDR-0	PMDR-0	0	3.23	2.94	2.61
644-PMDR-1	PMDR-1	1	3.36	3.04	2.70
644-PMDR-2	PMDR-2	2	2.96	2.67	2.39
644-PMDR-3	PMDR-3	3	2.66	2.40	2.14
644-PMDR-4	PMDR-4	4	3.06	2.78	2.47
644-PMDR-5	PMDR-5	5	3.23	2.94	2.61
644-PMDR-6	PMDR-6	6	3.37	3.05	2.71
644-PMDR-7	PMDR-7	7	3.06	2.78	2.47
644-PMDR-8	PMDR-8	8	3.23	2.94	2.61
644-PMDR-9	PMDR-9	9	3.23	2.94	2.61
644-PMDR-0-9	PMDR-0-9	0-9	34.00	30.76	27.52
644-PMDR-BL	PMDR-BL	Blue	3.23	2.94	2.61
644-PMDR-GRN	PMDR-GRN	Green	3.23	2.94	2.61
644-PMDR-RED	PMDR-RED	Red	3.23	2.94	2.61
644-PMDR-YEL	PMDR-YEL	Yellow	3.23	2.94	2.61
644-PMDR-NEMA	PMDR-NEMA	One of ea. Color	34.86	31.44	28.20




## DISPENSER KIT AND TAPE

- White, write on, vinyl label
- Self-laminating labels are provided in handy dispenser which protects markers when not in use
- Clear Section of marker overlaminates and protects write-on legend
- Quick, easy to use for smaller installations and maintenance



RoHS Compliant

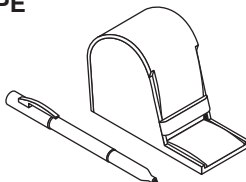

MOUSER STOCK NO.	Panduit Part No.	Description W x L (in.)	Price Each		
			1	10	25
<b>Dispenser, PFX-0 Pen, Tape</b>					
644-S100X125VARY	S100X125VARY	1.0" X 1.25" 200/Roll	37.41	33.69	29.94
644-S100X225VARY	S100X225VARY	1.0" X 2.25" 100/Roll	43.45	39.08	34.71
<b>Self-Laminating Blank Tape Refill</b>					
644-S100X125VAFY	S100X125VAFY	1.0" X 1.25" 200/Roll	24.98	23.48	22.06
644-S100X225VAFY	S100X225VAFY	1.0" X 2.25" 100/Roll	24.98	23.48	22.06



## PANTHER™ LS8E HAND-HELD THERMAL TRANSFER PRINTER

- Cut-to-length functionality eliminates label waste and label trimming labor
- Partial cut feature available to provide tear-apart strips of labels
- Label cassette contains integrated memory device for automatic formatting recall of last legend used and number of labels remaining in cassette
- Fast loading label cassette includes both label material and ribbon to make changing labels easy
- Prints self-laminating labels, heat shrink tubing, die-cut component labels and continuous tape
- Large graphic display with backlight for improved visibility
- USB interface for importing data, system upgrades and printing from a wireless laptop or desktop computer



RoHS Compliant



MOUSER STOCK NO.	Panduit Part No.	Description	Price Each
644-LS8E	LS8E	Includes LS8E printer, 1 cassette of S100X150VAC self-laminating labels, 6 AA alkaline batteries & quick reference card.	339.14
644-LS8E-KIT	LS8E-KIT	Includes above, plus rigid carrying case, USB cable, PC interface software, wrist strap, protective impact bumper	430.00



## LABEL PRODUCTS FOR LS8E HAND-HELD THERMAL TRANSFER PRINTER

### Heat Shrink Labels

- Polyolefin
- Continuous roll
- White

MOUSER STOCK NO.	Panduit Part No.	Size: (in.) W x L	Diameter	AWG	Price Each
644-H000X025F1C	H000X025F1C	.25" x 8'	1/8"	22-16	42.74
644-T100X0044F1C	H000X044F1C	.44" x 6'	1/4"	16-10	41.05

### Black On White Tape Labels

- Vinyl

MOUSER STOCK NO.	Panduit Part No.	Size: (in.) W x L	Labels Per Cassette	Price Each
644-T050X000VPC-BK	T050X000VPC-BK	.50" x 25'	Continuous roll	41.92
644-T100X000VPC-BK	T100X000VPC-BK	1.00" x 25'	Continuous roll	44.69

### Self-Laminating Wire Marker

- White
- Vinyl

MOUSER STOCK NO.	Panduit Part No.	Size: (in.) W x L	Labels Per Cassette	Price Each
644-S050X150VAC	S050X150VAC	.50" x 1.50"	200	28.99
644-S100X125VAC	S100X125VAC	1.00" x 1.25"	225	48.45
644-S100X150VAC	S100X150VAC	1.00" x 1.50"	200	44.46

### Non-Laminated Wire Marker

- Perforated Vinyl cloth for 12-10 AWG wires

MOUSER STOCK NO.	Panduit Part No.	Size: (in.) W x L	Labels Per Cassette	Price Each
644-N100X125CBC	N100X125CBC	1.00" x 1.25"	75	22.55